



Featured Fan: Sonnet 70", Pages 106, 107



Sonnet 52"

Espresso Sonnet with 52" Light Oak Blades and Integrated LED Light Kit | Model . . . **SON52ESP**
 Blade . . . **BSON52-LOK**
 Light . . . **Integrated**

Stripped free of decorative embellishments and extraneous detail, the Sonnet beautifully expresses the art of the ceiling fan at its most basic and elemental. The sleek Chrome or Espresso housings accommodate three extraordinary blades and LED lighting.

FEATURES

- Energy Saving, 2nd Generation, 6 Speed Reversible DC Motor
- 6" Downrod (Included)
- Limited Lifetime Warranty
- Blades Sold Separately
- Integrated Light Kit (14W LED - 3000K)
- Optional Blank Light Lens Cover (Included)
- IDC Remote and Wall Controls (Included)


LED Specs:

- 3000K Color Temp
- 1,300 lm
- 14 Watts
- CRI: 83.7
- LED Module is Guaranteed for 3 Years

SPECS

- Blade Sweep Option. 52"
- Number of Blades 3
- Blade Pitch Variable
- Motor Size (MM) 165 x 25
- AMPS (HI Speed) <1
- Shipping Wt. (lbs.) 9.5
- CU. FT. in Carton 1.2
- Airflow* (Cubic Feet Per Minute) 6,769
- Watts (HI Speed) 34
- Airflow Efficiency* (CFM Per Watt) 175.5

CEILING DROP DIMENSIONS

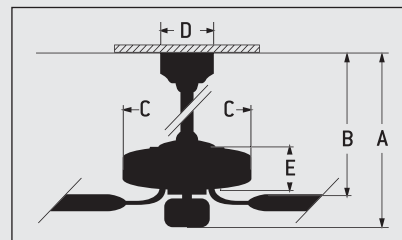

- A: 6" DR - 16.76"
- B: 6" DR - 13.5"
- C: 6.32"
- D: 5.12"
- E: 9.75"
- DR = Downrod

*Compare: 49" to 60" ceiling fans have airflow efficiencies ranging from approximately 51 to 176 cubic feet per minute per watt at high speed.



Saves Energy

A



B



A Chrome Sonnet with 52" Clear Acrylic Blades and Integrated LED Light Kit

Model**SON52CH**
Blade**BSON52-CA**
Light**Integrated**

B Chrome Sonnet with 52" Walnut Blades and Optional Blank Light Lens Cover

Model**SON52CH**
Blade**BSON52-WAL**
Light**Not Shown**

AVAILABLE FINISHES

- CH** Chrome
- ESP** Espresso

BLADE OPTIONS

Model Specific:
BSON52-(Finish) CA (Clear Acrylic), LOK (Light Oak), WAL (Walnut)

LIGHT KIT OPTIONS

Integrated Light Kit (14W LED-3000K) (Dimmable)
Optional Blank Light Lens Cover (Included)

FAN CONTROL OPTIONS



Scan to view video on DC remote control operation

DC Remote and Wall Controls (Included)





Sonnet 60"

Chrome Sonnet with 60" Clear Acrylic
Blades and Integrated LED Light Kit

Model **SON52CH**
Blade **BSON60-CA**
Light **Integrated**

Stripped free of decorative embellishments and extraneous detail, the Sonnet beautifully expresses the art of the ceiling fan at its most basic and elemental. The sleek Chrome or Espresso housings accommodate three extraordinary blades and LED lighting.

FEATURES

- Energy Saving, 2nd Generation, 6 Speed Reversible DC Motor
- 6" Downrod (Included)
- Limited Lifetime Warranty
- Blades Sold Separately
- Integrated Light Kit (14W LED - 3000K)
Optional Blank Light Lens Cover (Included)
- IDC Remote and Wall Controls (Included)


LED Specs:

- 3000K Color Temp
- 1,300 lm
- 14 Watts
- CRI: 83.7
- LED Module is Guaranteed for 3 Years

SPECS

- Blade Sweep Option. 60"
- Number of Blades 3
- Blade Pitch Variable
- Motor Size (MM) 165 x 25
- AMPS (HI Speed) <1
- Shipping Wt. (lbs.) 9.5
- CU. FT. in Carton 1.2
- Airflow*
(Cubic Feet Per Minute) 6,769
- Watts (HI Speed) 34
- Airflow Efficiency*
(CFM Per Watt) 175.5

CEILING DROP DIMENSIONS

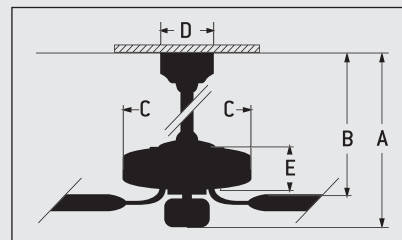

- A: 6" DR - 16.76"
- B: 6" DR - 13.5"
- C: 6.32"
- D: 5.12"
- E: 9.75"
- DR = Downrod

*Compare: 49" to 60" ceiling fans have airflow efficiencies ranging from approximately 51 to 176 cubic feet per minute per watt at high speed.



Saves Energy

A



B



A Espresso Sonnet with 60" Walnut Blades and Integrated LED Light Kit

Model . . . **SON52ESP**
 Blade . . . **BSON60-WAL**
 Light . . . **Integrated**

B Chrome Sonnet with 60" Walnut Blades and Integrated LED Light Kit

Model . . . **SON52CH**
 Blade . . . **BSON60-WAL**
 Light . . . **Integrated**

AVAILABLE FINISHES

- CH** Chrome
- ESP** Espresso

BLADE OPTIONS

Model Specific:
BSON60-(Finish) CA (Clear Acrylic), LOK (Light Oak), WAL (Walnut)

LIGHT KIT OPTIONS

Integrated Light Kit (14W LED-3000K) (Dimmable)
Optional Blank Light Lens Cover (Included)

FAN CONTROL OPTIONS



Scan to view video on DC remote control operation

DC Remote and Wall Controls (Included)





Sonnet 70"

Chrome Sonnet with 70" Light Oak
Blades and Integrated LED Light Kit | Model . . . **SON52CH**
Blade . . . **BSON70-LOK**
Light . . . **Integrated**

Stripped free of decorative embellishments and extraneous detail, the Sonnet beautifully expresses the art of the ceiling fan at its most basic and elemental. The sleek Chrome or Espresso housings accommodate three extraordinary blades and LED lighting.

FEATURES

- Energy Saving, 2nd Generation, 6 Speed Reversible DC Motor
- 6" Downrod (Included)
- Limited Lifetime Warranty
- Blades Sold Separately
- Integrated Light Kit (14W LED - 3000K)
- Optional Blank Light Lens Cover (Included)
- IDC Remote and Wall Controls (Included)


LED Specs:

3000K Color Temp
1,300 lm
14 Watts
CRI: 83.7
LED Module is Guaranteed for 3 Years

SPECS

- Blade Sweep Option. 70"
- Number of Blades 3
- Blade Pitch Variable
- Motor Size (MM) 165 x 25
- AMPS (HI Speed) <1
- Shipping Wt. (lbs.) 9.5
- CU. FT. in Carton 1.2
- Airflow*
(Cubic Feet Per Minute) 6,769
- Watts (HI Speed) 34
- Airflow Efficiency*
(CFM Per Watt) 175.5

CEILING DROP DIMENSIONS

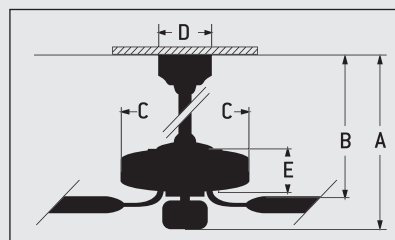

A: 6" DR - 16.76" B: 6" DR - 13.5"
C: 6.32" D: 5.12"
E: 9.75" DR = Downrod

*Compare: 49" to 60" ceiling fans have airflow efficiencies ranging from approximately 51 to 176 cubic feet per minute per watt at high speed.



A



A Espresso Sonnet with 70" Walnut
Blades and Integrated LED Light Kit

Model**SON52ESP**
Blade**BSON70-WAL**
Light**Integrated**

AVAILABLE FINISHES

- CH** Chrome
- ESP** Espresso

BLADE OPTIONS

Model Specific:
BSON70-(Finish) LOK (Light Oak), WAL (Walnut))

LIGHT KIT OPTIONS

Integrated Light Kit (14W LED-3000K) (Dimmable)
Optional Blank Light Lens Cover (Included)

FAN CONTROL OPTIONS



Scan to view video on
DC remote control
operation

DC Remote and Wall Controls (Included)

