



General Construction Finishes

For color photos of finishes see
inside front cover.


STANDARD SHAPE

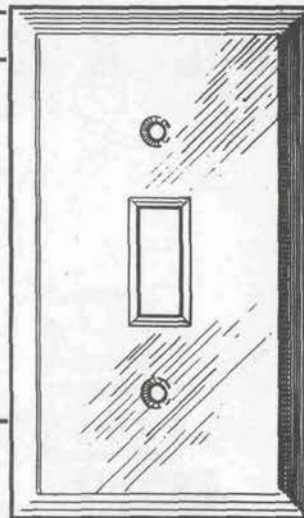

 See page A84 for ordering
Custom Plates not found in
this listing.

	CHROME PLATED	WHITE SEMI- GLOSS	STAIN- LESS TYPE 302 (.035") Spec. Grade Satin Finish (302SS)	STAIN- LESS TYPE 430 (.030") Satin Finish (SS)	BROWN WRINKLE	IVORY WRINKLE
 1 Toggle Switch (1T)	Polished Steel (CA) 83071	Painted Steel (WA) 86071	83071	86071	93071	97071
 2 Toggle Switches (2T)	83072	86072	93072	97072	98072	99072
 3 Toggle Switches (3T)	83073	86073	93073	97073	98073	99073
 4 Toggle Switches (4T)	83074	86074	93074	97074	98074	99074
 5 Toggle Switches (5T)	83075	86075	93075	97075	98075	99075
 6 Toggle Switches (6T)	83076	86076	93076	97076	98076	99076
 7 Toggle Switches (7T)	83077	86077	93077	97077	98077	99077
 8 Toggle Switches (8T)	83078	86078	93078	97078	98078	99078
 9 Toggle Switches (9T)	83079	86079	93079	97079	98079	99079
 10 Toggle Switches (10T)	83080	86080	93080	97080	98080	99080
 1 Duplex Receptacle (10DR)	83101	86101	93101	97101	98101	99101
 2 Duplex Receptacles (20DR)	83102	86102	93102	97102	98102	99102

Material Specifications

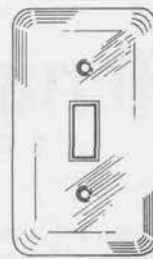

S = Standard Shape

P = Princess Shape



Listed 883C unless marked with asterisk(*).
Meets Federal Specification WP455A. All
plates supplied with matching screws.

Steel

(Preplated to Underwriters
Laboratories, Inc. specifications)

	Finish	Shape	Thickness	U.S. Bureau Standards Symbols	Finish Designator	Cat. Page #
Almond (ALM)	Smooth, Semi-Gloss	S	.030	—	44000	A14-20
Aluminum Paint (CDA)	Semi-Gloss	S	.030	—	88000	A21-27
Black Paint (BL)	Matte	S	.030	—	87000	A21-27
Brass Paint (BA)	Matte	S	.030	—	81000	A14-20
Brass Paint (BA-PRL)	Matte	P	.030	—	71000	A48-53
Brown Paint (BK)	Smooth, Semi-Gloss	S	.030	—	82000	A14-20
Brown Paint (DB)	Hard Baked, Wrinkle	S	.030	—	98000	A7-13
Brown Paint (DB-PRL)	Hard Baked, Wrinkle	P	.030	—	78000	A48-53
Chrome Plate (CA)	Mirror Polish	S	.030	—	83000	A7-13
Chrome Plate (CA-PRL)	Mirror Polish	P	.030	—	73000	A48-53
Gray	Smooth, Semi-Gloss	S	.030	—	58000	A21-27
Ivory (IA)	Smooth, Semi-Gloss	S	.030	—	84000	A14-20
Ivory (IA-PRL)	Smooth, Semi-Gloss	P	.030	—	74000	A48-53
Ivory (DI)	Hard Baked, Wrinkle	S	.030	—	99000	A7-13
Ivory (DI-PRL)	Hard Baked, Wrinkle	P	.030	—	79000	A48-53
Red (RA)	Smooth, Semi-Gloss	S	.030	—	51000	A21-27
White (WA)	Smooth, Semi-Gloss	S	.030	—	86000	A7-13
White (WA-PRL)	Smooth, Semi-Gloss	P	.030	—	76000	A48-53
White (DW)	Hard Baked, Wrinkle	S	.030	—	85000	A14-20
White (DW-PRL)	Hard Baked, Wrinkle	P	.030	—	75000	A48-53
Zinc Coat (AUNF)	Smooth, Dull	S	.030	—	89000	A21-27
Zinc Coat (AUNF-PRL)	Smooth, Dull	P	.030	—	80000	A42-47

Material Specifications

Stainless Steel			Finish	Shape	Thickness	U.S. Bureau Standards Symbols	Finish Designator	Cat. Page #
	Type 302 Spec. Grade (18% chrome-8% nickel) Non-Magnetic and Corrosion Resistant For hospitals, schools and other public institutions.	(302SS)	#4 Fine Satin	S	.035	US #32D	93000	A7-13
		(302SS-PRL)	#4 Fine Satin	P	.035	US #32D	53000	A42-47
		(302-6SS)	#4 Fine Satin	S	.060	US #32D	70000	A28-34
		(302SP)	Mirror Polish	S	.035	US #32	68000	A28-34
		Type 430 (SS)		#4 Fine Satin	S	.030	US #32	97000
	Type 430 (SS-PRL)		#4 Fine Satin	P	.030	US #32D	57000	A42-47


Aluminum	Clear Anodized (5AA)	Matte, Smooth	S	.050	US #28	95000	A28-34
	Clear Anodized (5AA-PRL)	Matte, Smooth	P	.050	US #28	55000	A42-47
	Bright Satin (SAL)	Satin	S	.040	—	62000	A28-34

Brass & Bronze Lacquered to prevent oxidation	Statuary Bronze Dark (4DBR)	Antiqued, Relieved	S	.040	US #20	69000	A35-41
	Bank Bronze Medium (4ABR)	Antiqued, Relieved	S	.040	US #10B	65000	A35-41
	Satin Brass (4BB)	Satin #4 Polish	S	.040	US #4	94000	A28-34
	Satin Brass (4BB-PRL)	Satin #4 Polish	P	.040	US#4	54000	A42-47
	Satin Brass (6BB)	Satin #4 Polish	S	.060	US #4	96000	A28-34
	Satin Bronze (4SBR)	Satin #4 Polish	S	.040	US #10	66000	A35-41
	Satin Bronze (4SBR-PRL)	Satin #4 Polish	P	.040	US #10	56000	A42-47
	Polished Brass (4PB)	Mirror Finish	S	.040	US #3	64000	A28-34


Lexan® Thermoplastic	Brown	91000	A54-57
	Gray	77000G	A54-57
	Ivory	92000	A54-57
	Red	77000R	A54-57
	White	90000	A54-57

WALL PLATE COLOR GUIDE

STANDARD SHAPE

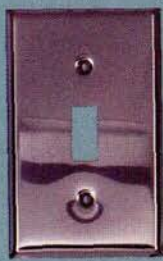


A

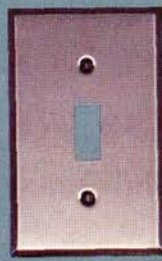

B



C

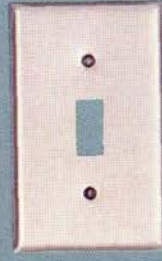

D



E




F




G




H

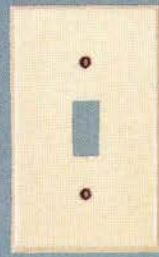

I

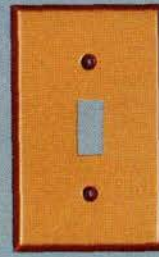


J

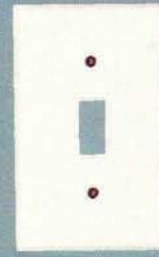

K




L

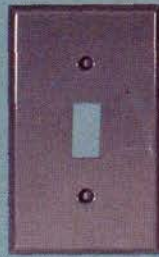

M



N

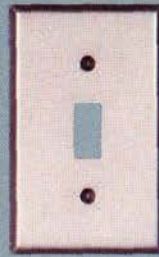

O



P



Q



R



S



T



U

- A. Polished Chrome (83000)
- B. Stainless Steel (97000, 93000, 70000)
- C. Polished Stainless (68000)
- D. Clear Anodized Aluminum (95000)
- E. Satin Aluminum (62000)
- F. Ivory Wrinkle (99000)

- G. Brown Wrinkle (98000)
- H. White Wrinkle (85000)
- I. Ivory Semi-Gloss (84000)
- J. Sprayed Brass Matte (81000)
- K. White Semi-Gloss (86000)
- L. Brown Semi-Gloss (82000)
- M. Gray Semi-Gloss (58000)

- N. Red Semi-Gloss (51000)
- O. Aluminum Painted Steel/Cadilite (88000)
- P. Black Matte (87000)
- Q. Satin Brass (94000, 96000)
- R. Bank Bronze (65000)
- S. Satin Bronze (66000)
- T. Statuary Bronze (69000)
- U. Polished Brass (64000)