



Energy Saver Decoratives

SBC-EL/A G25 9W 4/1


Philips Energy Saver Decorative CFLs provide energy savings and reduce operating costs without sacrificing quality of light compared to incandescent equivalents.

Product data

General Information	
Cap-Base	E26 [Single Contact Medium Screw]
Bulb Shape	EL/A G25 T3
Switching Cycle	5000X
Light Technical	
Color Code	827 [CCT of 2700K]
Luminous Flux (Rated) (Nom)	500 lm
Color Designation	Warm White (WW)
Lumen Maintenance 2000 h (Nom)	80 %
Lumen Maintenance 5000 h (Nom)	70 %
Chromaticity Coordinate X (Nom)	463
Chromaticity Coordinate Y (Nom)	420
Correlated Color Temperature (Nom)	2700 K
Luminous Efficacy (rated) (Nom)	56 lm/W
Color Rendering Index (Min)	80
Color Rendering Index (Nom)	80
Operating and Electrical	
Input Frequency	50 or 60 Hz
Power (Rated) (Nom)	9 W

Lamp Current (Nom)	120 mA
Wattage Equivalent	40 W
Warm Up Time To 60% Light (Max)	180 s
Power Factor (Nom)	0.55
Voltage (Nom)	110-127 V
Controls and Dimming	
Dimmable	No
Approval and Application	
Energy Efficiency Label (EEL)	A
Mercury (Hg) Content (Max)	2 mg
Product Data	
Order product name	SBC-EL/A G25 9W 4/1
EAN/UPC - Product	046677455323
Order code	455329
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	4
Material Nr. (12NC)	929689983610
Net Weight (Piece)	0.092 kg

Dimensional drawing

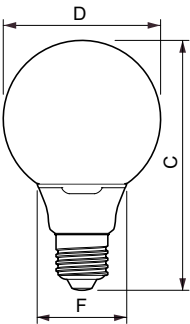

Amb GL G25 9W/827 E26 110-127V

Product	C	F
SBC-EL/A G25 9W 4/1	112 mm	65.4 mm

