

# Communication Products CX Series Style Line®

Communication Outlets and  
Duplex Jack Outlet

**Step 1: Determine voice/data requirements and select corresponding outlet configuration in the color desired (voice/data devices not included, order separately).**

	Two jack openings (duplex jack outlet)	One jack opening	One jack and one 1/2" dia. opening	One jack and one twinaxial opening	One Thinwire Ethernet opening	One 25 pin (RS232) subminiature D opening	One jack and one IBM Connector opening	One 3/4" dia opening (for bushing)	Blank
<b>Color</b>	<b>Catalog Numbers</b>								
Black	DJOBK	-	CX1412BK	CX243BK	-	-	-	CX17BK	2100BK
Brown	-	-	CX1412	CX243	-	-	-	-	2100
Gray	DJOGY	CX14GY	-	-	-	CX1RGY	CX245GY	CX17GY	2100GY
Ivory	DJOI	CX14I	-	-	-	CX1RI	CX245I	-	2100I
Office White	DJOOW	CX14OW	-	-	CX1EOW	-	CX245OW	CX17OW	2100OW
White	DJOW	CX14WA	-	CX243WA	-	-	CX245WA	CX17WA	2100WA

## UL/CSA Characteristics

UL Listed – File #E129878

CSA Certified, File #LR80837


**Step 2: Choose required jack(s) and/or data connector(s). If jacks are used, match colors accordingly (voice/data devices for use in above communication outlets).**

Color	Category 5 8 Position (T568B, AT&T wired)	Category 5 8 Position (T568A, ISDN wired)	Category 3 8 Position (T568B, AT&T wired)	Category 3 8 Position (T568A, ISDN wired)
Black	TS8A5BK	TS8I5BK	TS8A3BK	TS8I3BK
Gray	TS8A5GY	TS8I5GY	TS8A3GY	TS8I3GY
Ivory	TS8A5I	TS8I5I	TS8A3I	TS8I3I
Office White	TS8A5OW	TS8I5OW	TS8A3OW	TS8I3OW
White	TS8A5W	TS8I5W	TS8A3W	TS8I3W
Black (keyed)	TS8AK5BK	-	-	-

Duplex Jack Outlets



Dimensional Data

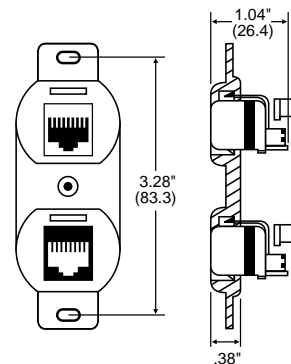

Note: Each jack opening is .58" x .76" (14.7 x 19.3).