


VICTOR "SNAP ON" STEEL CLAMPS

FOR HEAVY WALL CONDUIT (RIGID)

CONDUIT SIZE (RIGID)	VICTOR PART NUMBER	PRICE LIST PAGE	MOUNTING HOLE SIZE	MATERIAL THICKNESS	MATERIAL WIDTH	PIECES PER BOX	PIECES PER CARTON	LBS PER CARTON
----------------------------	--------------------------	-----------------------	--------------------------	-----------------------	-------------------	----------------------	-------------------------	----------------------

STANDARD SERIES

1/8	10010-S	1	9/32	.062	9/16	100	1000	15
1/4	10011-S	1	9/32	.062	9/16	100	1000	19
3/8	10012-S	1	9/32	.062	5/8	100	1000	25
1/2	10013-S	1	9/32	.062	5/8	100	1000	30
3/4	10014-S	1	9/32	.062	3/4	100	500	22
1	10015-S	1	9/32	.093	3/4	50	500	41
1 1/4	10016-S	1	9/32	.093	3/4	50	250	25

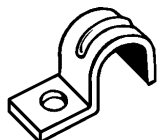

HEAVY SERIES

3/8	10712-S	2	9/32	.093	3/4	100	1000	43
1/2	10713-S	2	9/32	.093	3/4	100	500	24
3/4	10714-S	2	9/32	.093	3/4	100	500	31
1	10715-S	2	13/32	.125	1	50	250	31
1 1/4	10716-S	2	13/32	.125	1	25	125	21
1 1/2	10717-S	2	13/32	.125	1	25	125	23
2	10718-S	2	21/32	.125	1 1/2	-	50	18

EXTRA HEAVY SERIES

1/2	17113-S	4	11/32	.125	1	50	500	46
3/4	17114-S	4	11/32	.125	1	50	250	29
1	17115-S	4	13/32	.188	1	-	100	20
1 1/4	17116-S	4	13/32	.188	1	-	50	14
1 1/2	17117-S	4	13/32	.250	1	-	50	20
2	17118-S	4	21/32	.250	1 1/2	-	25	19
2 1/2	17119-S	4	21/32	.250	1 1/2	-	25	25
3	17120-S	4	21/32	.250	1 1/2	-	25	30
3 1/2	17121-S	4	21/32	.250	1 1/2	-	20	25
4	17122-S	4	21/32	.250	1 1/2	-	20	28
5	17124-S	4	21/32	.375	1 1/2	-	10	24
6	17125-S	4	21/32	.375	1 1/2	-	5	15



SMALL HOLE CLAMPS

1/8	19110-S	4	7/32	.062	9/16	100	1000	15
1/4	19111-S	4	7/32	.062	9/16	100	1000	19
3/8	19112-S	4	7/32	.062	5/8	100	1000	25
1/2	19113-S	4	7/32	.062	5/8	100	1000	30
3/4	19114-S	4	7/32	.062	3/4	100	500	22
2	19118-S	4	13/32	.125	1 1/2	-	50	17



SLOTTED HOLE CLAMPS

3/8	18712-S	4	9/32 X 1/2	.093	3/4	100	1000	47
1/2	18713-S	4	9/32 X 1/2	.093	3/4	100	500	27
3/4	18714-S	4	9/32 X 1/2	.093	3/4	100	500	33
1	18715-S	4	9/32 X 1/2	.125	1	50	250	37





BLANK CLAMPS - STANDARD SERIES (TAIL LENGTH 1 1/8")

1/2	15013-S	4	NONE	.062	3/4	100	500	21
3/4	15014-S	4	NONE	.062	3/4	100	500	24

BLANK CLAMPS - HEAVY SERIES (TAIL LENGTH 1 1/8")

1/2	15713-S	4	NONE	.093	3/4	100	500	33
3/4	15714-S	4	NONE	.093	3/4	100	500	37

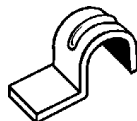

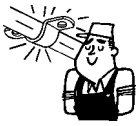


VICTOR "SNAP ON" STEEL CLAMPS

FOR THIN WALL CONDUIT (E.M.T.)

CONDUIT SIZE (E.M.T.)	VICTOR PART NUMBER	PRICE LIST PAGE	MOUNTING HOLE SIZE	MATERIAL THICKNESS	MATERIAL WIDTH	PIECES PER BOX	PIECES PER CARTON	LBS PER CARTON
-----------------------	--------------------	-----------------	--------------------	--------------------	----------------	----------------	-------------------	----------------

STANDARD SERIES

1/2	10043-S	1	9/32	.062	5/8	100	1000	24
3/4	10044-S	1	9/32	.062	5/8	100	1000	31
1	10045-S	1	9/32	.062	3/4	100	500	22
1 1/4	10046-S	1	9/32	.093	3/4	50	250	23

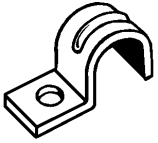

HEAVY SERIES

1/2	10743-S	2	9/32	.093	3/4	100	1000	43
3/4	10744-S	2	9/32	.093	3/4	100	500	28
1	10745-S	2	9/32	.093	3/4	50	500	36
1 1/4	10746-S	2	13/32	.125	1	25	125	20
1 1/2	10747-S	2	13/32	.125	1	25	125	22
2	10748-S	2	21/32	.125	1 1/2	-	50	17

EXTRA HEAVY SERIES

1 1/4	17146-S	4	13/32	.188	1	-	50	13
1 1/2	17147-S	4	13/32	.250	1	-	50	18
2	17148-S	4	21/32	.250	1 1/2	-	25	17
2 1/2	17119-S	4	21/32	.250	1 1/2	-	25	25
3	17120-S	4	21/32	.250	1 1/2	-	25	30
3 1/2	17121-S	4	21/32	.250	1 1/2	-	20	25
4	17122-S	4	21/32	.250	1 1/2	-	20	28



SMALL HOLE CLAMPS

1/2	19143-S	4	7/32	.062	5/8	100	1000	25
3/4	19144-S	4	7/32	.062	5/8	100	1000	31
1	19145-S	4	7/32	.062	3/4	100	500	22
2	19148-S	4	13/32	.125	1 1/2	-	50	17




SLOTTED HOLE CLAMPS

1/2	18743-S	4	9/32X1/2	.093	3/4	100	1000	37
3/4	18744-S	4	9/32X1/2	.093	3/4	100	500	30
1	18745-S	4	9/32X1/2	.093	3/4	50	500	38



BLANK CLAMPS - STANDARD SERIES (TAIL LENGTH 1 1/8")

1/2	15043-S	4	NONE	.062	3/4	100	1000	37
3/4	15044-S	4	NONE	.062	3/4	100	500	23

 

BLANK CLAMPS - HEAVY SERIES (TAIL LENGTH 1 1/8")

1/2	15743-S	4	NONE	.093	3/4	100	500	31
3/4	15744-S	4	NONE	.093	3/4	100	500	35



VICTOR "SNAP ON" STEEL CLAMPS

FOR "BX" CABLE

"BX" CABLE	VICTOR PART NUMBER	PRICE LIST PAGE	MOUNTING HOLE SIZE	MATERIAL THICKNESS	MATERIAL WIDTH	PIECES PER BOX	PIECES PER CARTON	LBS PER CARTON
14-3 TO 12-3	11105-S	2	9/32	.062	9/16	100	1000	17
& 3/8 FLEX	19105-S	4	7/32	.062	9/16	100	1000	18
12-4 TO 10-4 & 3/8 SHELL GROUND	11106-S	2	9/32	.062	5/8	100	1000	20



BX cable outer diameters may vary by manufacturer and material.

VICTOR STEEL CLAMPS

FOR TUBING AND CABLE

TUBING DIA. (O.D.)	VICTOR PART NUMBER	PRICE LIST PAGE	MOUNTING HOLE SIZE	MATERIAL THICKNESS	MATERIAL WIDTH	PIECES PER BOX	PIECES PER CARTON	LBS PER CARTON
-----------------------	--------------------------	-----------------------	--------------------------	-----------------------	-------------------	----------------------	-------------------------	----------------------

STANDARD SERIES


3/32	10543-S	1	5/32	.032	3/8	100	1000	3
1/8	10545-S	1	5/32	.032	3/8	100	1000	3
5/32	10547-S	1	5/32	.032	3/8	100	1000	3
3/16	10550-S	1	5/32	.032	3/8	100	1000	4
1/4	10551-S	1	5/32	.032	3/8	100	1000	4
5/16	10552-S	1	5/32	.032	3/8	100	1000	5
3/8	10553-S	1	5/32	.032	3/8	100	1000	5
3/32	10563-S	1	13/64	.032	3/8	100	1000	3
1/8	10565-S	1	13/64	.032	3/8	100	1000	3
5/32	10567-S	1	13/64	.032	3/8	100	1000	3
3/16	10570-S	1	13/64	.032	3/8	100	1000	4
1/4	10571-S	1	13/64	.032	3/8	100	1000	4
5/16	10572-S	1	13/64	.032	3/8	100	1000	5
3/8	10573-S	1	13/64	.032	3/8	100	1000	5



HEAVY SERIES

1/8	10585-S	1	13/64	.062	3/8	100	1000	6
5/32	10587-S	1	13/64	.062	3/8	100	1000	6
3/16	10590-S	1	13/64	.062	3/8	100	1000	7
1/4	10591-S	1	13/64	.062	3/8	100	1000	7
5/16	10592-S	1	13/64	.062	3/8	100	1000	8
3/8	10593-S	1	13/64	.062	3/8	100	1000	8
1/4	11101-S	2	7/32	.062	1/2	100	1000	10
5/16	11102-S	2	7/32	.062	1/2	100	1000	12
3/8	11103-S	2	7/32	.062	1/2	100	1000	12

HEAVY SERIES - "V" SHAPE

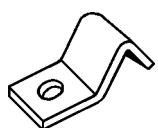

1/8-3/16	11100-S	2	7/32	.062	1/2	100	1000	8
1/8-3/16	11150-S	2	9/32	.062	5/8	100	1000	10
5/16-7/16	10802-S	2	7/32	.062	1/2	100	1000	11
7/16-1/2	19104-S	4	7/32	.062	5/8	100	1000	18
7/16-1/2	10804-S	2	9/32	.062	5/8	100	1000	18

EXTRA HEAVY SERIES



1/4	11151-S	2	9/32	.062	5/8	100	1000	13
5/16	11152-S	2	9/32	.062	5/8	100	1000	15
3/8	11153-S	2	9/32	.062	5/8	100	1000	17
7/16	11104-S	2	9/32	.062	5/8	100	1000	16
1/2	11105-S	2	9/32	.062	9/16	100	1000	17
9/16	11106-S	2	9/32	.062	5/8	100	1000	20
5/8	11108-S	2	9/32	.062	5/8	100	1000	24
11/16	11110-S	2	9/32	.062	5/8	100	1000	25
3/4	11112-S	2	9/32	.062	5/8	100	1000	28
13/16	11115-S	2	9/32	.062	5/8	100	1000	30
7/8	11120-S	2	9/32	.062	5/8	100	1000	31
15/16	11122-S	2	9/32	.062	5/8	100	1000	33
1	11125-S	2	9/32	.062	5/8	100	1000	36
1 1/4	11130-S	2	9/32	.062	5/8	100	500	20



VICTOR STEEL CLAMPS

FOR SERVICE ENTRANCE CABLE

CABLE SIZE & DESCRIPTION	VICTOR PART NUMBER	PRICE LIST PAGE	A	B	D	T	W	PIECES PER BOX	PIECES PER CARTON	LBS PER CARTON
--------------------------------	--------------------------	-----------------------	---	---	---	---	---	----------------------	-------------------------	----------------------

STANDARD SERIES

8-3 & 8-AWG-3C	10076-S	1	11/16	3/8	9/32	.062	5/8	100	1000	21
6-3	10082-S	1	23/32	1/2	9/32	.062	5/8	100	1000	23
6-2 & 8-1										
4-3	10084-S	1	7/8	17/32	9/32	.062	5/8	100	1000	25
2-3	10085-S	1	31/32	17/32	9/32	.062	5/8	100	1000	28
2-2 & 4-1										
2-3	10086-S	1	1	5/8	9/32	.062	5/8	100	1000	32
8-3 & 8-AWG-3C	19176-S	4	11/16	3/8	7/32	.062	5/8	100	1000	21
6-3	19182-S	4	23/32	1/2	7/32	.062	5/8	100	1000	22
6-2 & 8-1										
4-3	19184-S	4	7/8	17/32	7/32	.062	5/8	100	1000	25
2-3	19186-S	4	1	5/8	7/32	.062	5/8	100	1000	32

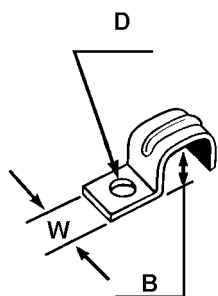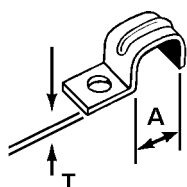


HEAVY SERIES

8-3 & 8-AWG-3C	10776-S	2	11/16	3/8	9/32	.093	3/4	100	1000	41
6-3	10782-S	2	23/32	1/2	9/32	.093	3/4	100	1000	47
6-2 & 8-1										
4-3	10784-S	2	7/8	17/32	9/32	.093	3/4	100	1000	49
2-3	10785-S	2	31/32	17/32	9/32	.093	3/4	100	500	25
2-2 & 4-1										
2-3	10786-S	2	1	5/8	9/32	.093	3/4	100	500	28
2-3(OLD)	10790-S	2	1 1/16	5/8	9/32	.093	3/4	100	500	30
1-3	10793-S	2	1 3/16	5/8	9/32	.093	3/4	100	500	30
2/0-3	10795-S	2	1 9/32	21/32	9/32	.093	3/4	100	500	31
2/0-2 & 1-1										
2/0-3	10796-S	2	1 7/16	3/4	9/32	.120	1	50	250	31
4/0-2 & 2/0-1	10797-S	2	1 15/32	7/8	9/32	.120	1	50	250	34
4/0-3	10798-S	2	1 11/16	15/16	9/32	.120	1	50	250	36
4/0-3	10799-S	2	1 3/4	1 1/16	9/32	.120	1	50	250	38

LIGHT WEIGHT FOR ROMEX CABLE

12-2, 14-2	10090-S	1	19/32	11/32	13/64	.032	1/2	100	1000	10
------------	---------	---	-------	-------	-------	------	-----	-----	------	----

 


Sample clamps are available to determine best fit.

VICTOR STEEL CLAMPS

FOR UF CABLE "ROMEX" AND "P.V.C."


CABLE SIZE & DESCRIPTION	VICTOR PART NUMBER	PRICE LIST PAGE	MOUNTING HOLE SIZE	MATERIAL THICKNESS	MATERIAL WIDTH	PIECES PER BOX	PIECES PER CARTON	LBS PER CARTON
--------------------------	--------------------	-----------------	--------------------	--------------------	----------------	----------------	-------------------	----------------

UF CABLE

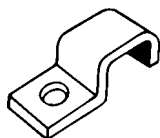

10-2	15323-S	4	7/32	.062	1/2	100	1000	10
10-3,10-3 WITH GROUND 600V	19103-S	4	7/32	.062	1/2	100	1000	10
12-2,14-2,16-3 S.P.T. CORD	10072-S	1	7/32	.062	1/2	100	1000	10
12-3	19178-S	4	7/32	.062	5/8	100	1000	17


P.V.C. AND ROMEX CABLE

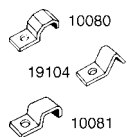

12-2, 14-2	10080-S	1	7/32	.062	9/16	100	1000	14
12-2, 14-2	10081-S	1	7/32	.062	9/16	100	1000	18
12-3, 14-3	19104-S	4	7/32	.062	5/8	100	1000	18

VICTOR STEEL GANG CLAMPS

MADE OF .062 X 1/2 STEEL WITH 7/32 MOUNTING HOLE

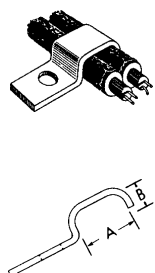

VICTOR PART NUMBER	NUMBER OF LINES	PRICE LIST PAGE	"A" DIM.	"B" DIM.	PIECES PER BOX	PIECES PER CARTON	LBS PER CARTON
15321-S	2	4	5/32	1/8	100	1000	8
15322-S	3	4	5/16	1/8	100	1000	9
15323-S	4	4	15/32	1/8	100	1000	10
15324-S	5	4	5/8	1/8	100	1000	11
15325-S	6	4	25/32	1/8	100	1000	11
15326-S	7	4	15/16	1/8	100	1000	12
15327-S	8	4	1-3/32	1/8	100	1000	15
15328-S	9	4	1-1/4	1/8	100	1000	14
19102-S	2	4	1/2	7/32	100	1000	12
19103-S	3	4	3/4	7/32	100	1000	10

VICTOR STEEL DUPLEX CLAMPS

FOR UF CABLE "ROMEX" AND "P.V.C."


TUBE DIAMETER (O.D.)	VICTOR PART NUMBER	PRICE LIST PAGE	MOUNTING HOLE SIZE	MATERIAL THICKNESS	MATERIAL WIDTH	PIECES PER BOX	PIECES PER CARTON	LBS PER CARTON
----------------------	--------------------	-----------------	--------------------	--------------------	----------------	----------------	-------------------	----------------

STANDARD SERIES

3/16	10690-S	2	5/32	.032	3/8	100	1000	5
1/4	10691-S	2	5/32	.032	3/8	100	1000	6
5/16	10692-S	2	5/32	.032	3/8	100	1000	7
3/8	10693-S	2	5/32	.032	3/8	100	1000	9

HEAVY SERIES

1/4	12701-S	3	7/32	.062	1/2	100	1000	16
5/16	12702-S	3	7/32	.062	1/2	100	1000	18
3/8	12703-S	3	7/32	.062	1/2	100	1000	21
1/2	12705-S	3	9/32	.062	5/8	100	1000	32
5/8	12708-S	3	9/32	.062	5/8	100	500	17
3/4	12712-S	3	9/32	.062	5/8	100	500	19
7/16	13104-S	3	9/32	.062	5/8	100	1000	24
9/16	13106-S	3	9/32	.062	5/8	100	500	13
11/16	13110-S	3	9/32	.062	5/8	100	500	19
13/16	13115-S	3	9/32	.062	5/8	100	500	24
1/2 E.M.T.	12743-S	3	9/32	.062	5/8	100	500	22

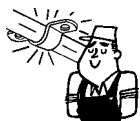

VICTOR 200 SERIES


FOR THIN WALL CONDUIT (E.M.T.)

CONDUIT SIZE (E.M.T.)	VICTOR PART NUMBER	PRICE LIST PAGE	MOUNTING HOLE SIZE	MATERIAL THICKNESS	MATERIAL WIDTH	PIECES PER BOX	PIECES PER CARTON	LBS PER CARTON
-----------------------	--------------------	-----------------	--------------------	--------------------	----------------	----------------	-------------------	----------------

STANDARD SERIES

1/2	20043-S	N/A	9/32	.042	9/16	100	1000	14
3/4	20044-S	N/A	9/32	.042	19/32	100	1000	19
1	20045-S	N/A	9/32	.048	3/4	100	500	17
1/2	20043-SB*	N/A	9/32	.042	9/16	-	1000	14
3/4	20044-SB*	N/A	9/32	.042	19/32	-	1000	19

* BULK PACKED

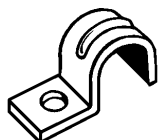


VICTOR STEEL SAFETY CLAMPS

FOR CABLE OR TUBING

TUBING DIA. (O.D.)	VICTOR PART NUMBER	PRICE LIST PAGE	MOUNTING HOLE SIZE	MATERIAL THICKNESS	MATERIAL WIDTH	PIECES PER BOX	PIECES PER CARTON	LBS PER CARTON
-----------------------	--------------------	-----------------	--------------------	--------------------	----------------	----------------	-------------------	----------------

STANDARD SERIES

1/4	16101-S	4	9/32	.032	5/8	100	1000	15
5/16	16102-S	4	9/32	.032	5/8	100	1000	16
3/8	16103-S	4	9/32	.032	5/8	100	1000	17
1/2	16105-S	4	9/32	.032	5/8	100	1000	21
5/8	16108-S	4	9/32	.032	3/4	100	500	14
3/4	16112-S	4	9/32	.032	3/4	100	500	16

 

HEAVY SERIES

1/4	17101-S	4	9/32	.062	5/8	100	1000	22
5/16	17102-S	4	9/32	.062	5/8	100	1000	26
3/8	17103-S	4	9/32	.062	5/8	100	1000	28
1/2	17105-S	4	9/32	.062	5/8	100	1000	33
5/8	17108-S	4	9/32	.062	3/4	100	500	23
3/4	17112-S	4	9/32	.062	3/4	100	500	26

VICTOR "SNAP ON" ALUMINUM CLAMPS

FOR HEAVY WALL CONDUIT (RIGID)

CONDUIT SIZE (RIGID)	VICTOR PART NUMBER	PRICE LIST PAGE	MOUNTING HOLE SIZE	MATERIAL THICKNESS	MATERIAL WIDTH	PIECES PER BOX	PIECES PER CARTON	LBS PER CARTON
----------------------	--------------------	-----------------	--------------------	--------------------	----------------	----------------	-------------------	----------------

STANDARD SERIES

1/2	14413-A	3	9/32	.062	5/8	100	1000	10
3/4	14414-A	3	9/32	.062	3/4	100	500	8
1	14415-A	3	9/32	.093	3/4	50	500	14
1 1/4	14416-A	3	9/32	.093	3/4	50	250	9



HEAVY SERIES

1/2	14713-A	4	9/32	.093	3/4	100	500	11
3/4	14714-A	4	9/32	.093	3/4	100	500	13
1	14715-A	4	13/32	.125	1	50	250	15
1 1/4	14716-A	4	13/32	.125	1	25	125	10
1 1/2	14717-A	4	13/32	.125	1	25	125	11
2	14718-A	4	13/32	.125	1 1/2	-	50	8



VICTOR "SNAP ON" ALUMINUM CLAMPS

FOR THIN WALL CONDUIT (E.M.T.)

CONDUIT SIZE (E.M.T.)	VICTOR PART NUMBER	PRICE LIST PAGE	MOUNTING HOLE SIZE	MATERIAL THICKNESS	MATERIAL WIDTH	PIECES PER BOX	PIECES PER CARTON	LBS PER CARTON
-----------------------	--------------------	-----------------	--------------------	--------------------	----------------	----------------	-------------------	----------------

STANDARD SERIES

1/2	14443-A	4	9/32	.062	5/8	100	1000	8
3/4	14444-A	4	9/32	.062	5/8	100	1000	12
1	14445-A	4	9/32	.062	3/4	100	500	8



HEAVY SERIES

1/2	14743-A	4	9/32	.093	3/4	100	1000	15
3/4	14744-A	4	9/32	.093	3/4	100	500	10
1	14745-A	4	9/32	.093	3/4	50	500	12

VICTOR COPPER PLATED CLAMPS

FOR COPPER TUBING

TUBING DIA. (O.D.)	VICTOR PART NUMBER	PRICE LIST PAGE	MOUNTING HOLE SIZE	MATERIAL THICKNESS	MATERIAL WIDTH	PIECES PER BOX	PIECES PER CARTON	LBS PER CARTON
-----------------------	--------------------	-----------------	--------------------	--------------------	----------------	----------------	-------------------	----------------


SLOTTED HOLE CLAMPS

1/8	15095-SL	4	7/32 X 1/2	.062	5/8	100	1000	12
3/16	15100-SL	4	7/32 X 1/2	.062	5/8	100	1000	13
1/4	15101-SL	4	7/32 X 1/2	.062	5/8	100	1000	16
5/16	15102-SL	4	7/32 X 1/2	.062	5/8	100	1000	18
3/8	15103-SL	4	7/32 X 1/2	.062	5/8	100	1000	20
1/2	15105-SL	4	7/32 X 1/2	.062	5/8	100	1000	22
3/4	15107-SL	4	7/32 X 1/2	.062	5/8	100	1000	29



SLOTTED HOLE DUPLEX CLAMPS

3/16	15700-SL	4	7/32 X 1/2	.062	5/8	100	1000	25
1/4	15701-SL	4	7/32 X 1/2	.062	5/8	100	1000	29
5/16	15702-SL	4	7/32 X 1/2	.062	5/8	100	1000	35
3/8	15703-SL	4	7/32 X 1/2	.062	5/8	100	1000	39
1/2	15705-SL	4	7/32 X 1/2	.062	5/8	100	500	23

 

VICTOR BRASS CLAMPS

FOR CABLE OR TUBING

TUBING DIA. (O.D.)	VICTOR PART NUMBER	PRICE LIST PAGE	MOUNTING HOLE SIZE	MATERIAL THICKNESS	MATERIAL WIDTH	PIECES PER BOX	PIECES PER CARTON	LBS PER CARTON
-----------------------	--------------------	-----------------	--------------------	--------------------	----------------	----------------	-------------------	----------------

STANDARD SERIES

1/8-3/16	17200-B	4	7/32	.062	1/2	100	1000	9
1/4	17201-B	4	7/32	.062	1/2	100	1000	10
5/16	17202-B	4	7/32	.062	1/2	100	1000	12
3/8	17203-B	4	7/32	.062	1/2	100	1000	15
7/16	17204-B	4	7/32	.062	1/2	100	1000	17
1/2	17205-B	4	7/32	.062	1/2	100	1000	20
9/16	17206-B	4	7/32	.062	1/2	100	1000	21
5/8	17208-B	4	7/32	.062	1/2	100	1000	22

WIDE SERIES

1/4	14151-B	3	9/32	.062	5/8	100	1000	12
5/16	14152-B	3	9/32	.062	5/8	100	1000	15
3/8	14153-B	3	9/32	.062	5/8	100	1000	17
7/16	14154-B	3	9/32	.062	5/8	100	1000	19
1/2	14155-B	3	9/32	.062	5/8	100	1000	22
9/16	14156-B	3	9/32	.062	5/8	100	1000	23
5/8	14158-B	3	9/32	.062	5/8	100	1000	26
11/16	14160-B	3	9/32	.062	5/8	100	1000	27
3/4	14162-B	3	9/32	.062	5/8	100	1000	30



MIDGET SERIES

1/8	11575-B	2	13/64	.032	3/8	100	1000	3
3/16	11580-B	2	13/64	.032	3/8	100	1000	3
1/4	11581-B	2	13/64	.032	3/8	100	1000	4
5/16	11582-B	2	13/64	.032	3/8	100	1000	4
3/8	11583-B	2	13/64	.032	3/8	100	1000	5



VICTOR PAD TYPE STEEL CLAMPS

(FITS STANDARD 3/8 HIGH X 3/4 DIA WELDING PADS*)



CABLE DIAMETER	VICTOR PART NUMBER	PRICE LIST PAGE	MOUNTING HOLE SIZE	MATERIAL THICKNESS	MATERIAL WIDTH	PIECES PER BOX	PIECES PER CARTON	LBS PER CARTON
1/4	10101-S	1	9/32	.062	5/8	100	1000	13
5/16	10102-S	1	9/32	.062	5/8	100	1000	13
3/8	10103-S	1	9/32	.062	5/8	100	1000	15
7/16	10104-S	1	9/32	.062	5/8	100	1000	16
1/2	10105-S	1	9/32	.062	5/8	100	1000	16
9/16	10106-S	1	9/32	.062	5/8	100	1000	17
5/8	10108-S	1	9/32	.062	5/8	100	1000	18
11/16	10110-S	1	9/32	.062	5/8	100	1000	20
3/4	10112-S	1	9/32	.062	5/8	100	1000	22
13/16	10115-S	1	9/32	.062	5/8	100	1000	23
7/8	10120-S	1	9/32	.062	5/8	100	1000	25
15/16	10122-S	1	9/32	.062	5/8	100	1000	26
1	10125-S	1	9/32	.062	5/8	100	1000	28

*PADS ARE NOT INCLUDED