

# Zinc Cable Connectors

## For Armored Cable and Flexible Metallic Conduit

### Application:

Used with a locknut to terminate steel or aluminum flexible metal conduit and armored cable to enclosure.

### Features:

- Assembled with die cast locknut and tri-combo screws

### Standard Materials:

Zinc Die Cast



UL Listed:

E155411


CSA File No. LR57925



## Squeeze Type



Type C27Z

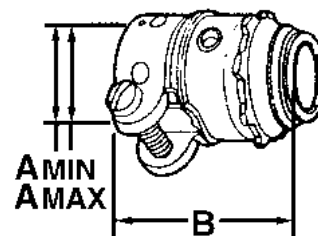


CATALOG NUMBER	TRADE SIZE	DIM. A MIN.	DIM. A MAX	DIM. B	UNIT PACK	STANDARD PACK	WEIGHT (LBS.) PER 100	NAED MFG #78-5994 UPC/DCI #
C47Z	3/8"	0.530	0.620	0.982	50	500	7	24708
C27Z	1/2"	0.850	0.914	1.470	25	250	10	32708
C28Z	3/4"	1.100	1.135	1.580	25	250	13	32808
C29Z	1"	1.255	1.375	1.750	10	100	20	32908
C30Z	1-1/4"	1.550	1.610	1.910	10	100	29	33008
C31Z	1-1/2"	1.810	1.895	2.090	5	50	39	33108
C32Z	2"	2.260	2.485	2.340	10	40	46	33208

## Squeeze Type – Insulated Throat



Type C27ZT

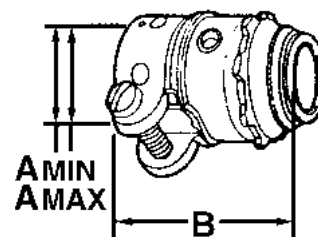

CATALOG NUMBER	TRADE SIZE	DIM. A MIN.	DIM. A MAX	DIM. B	UNIT PACK	STANDARD PACK	WEIGHT (LBS.) PER 100	NAED MFG #78-5994 UPC/DCI #
C47ZT	3/8"	0.530	0.620	0.982	50	500	7	32646
C27ZT	1/2"	0.850	0.914	1.470	25	250	10	32757
C28ZT	3/4"	1.100	1.135	1.580	25	250	13	32867
C29ZT	1"	1.255	1.375	1.750	10	100	20	32967
C30ZT	1-1/4"	1.550	1.610	1.910	10	100	29	33067
C31ZT	1-1/2"	1.810	1.895	2.090	5	50	39	33167
C32ZT	2"	2.260	2.485	2.340	10	40	46	33267