




Table of Contents



Nylon Wallplates



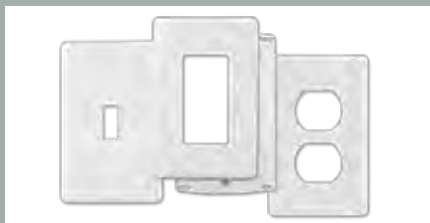Snap-On Wallplates



While-In-Use Weatherproof Covers



Product	Page
Features and Benefits	N-2
Snap-On Wallplates	N-4
Toggle Switch Wallplates	N-6
Duplex and Single Receptacle Wallplates	N-7
Single Receptacle Wallplates	N-8
Blank Wallplates	N-9
347 Volt Wallplates	N-10
Decorator Wallplates	N-11
Combination Wallplates, 2-Gang	N-12
Combination Wallplates, 3-Gang	N-14
Combination Wallplates, 4- and 5-Gang	N-15
Telephone and Coaxial Outlet Plates	N-16
Jumbo, Metal Wallplates	N-17
Pre-Marked "EMERGENCY" and Barrel Key Switch Wallplates	N-18
Pre-Marked "ISOLATED GROUND" or "COMPUTER ONLY" Wallplates	N-19

Product	Page
Security Wallplates	N-20
Accessories and Selection Charts	N-21
Weatherproof Plates for Receptacles	N-22
Weatherproof Plates for Receptacles and Switches	N-23
Weatherproof Covers for Flanged Devices	N-24
Weatherproof Switch Plates, Covers and Locking Covers	N-25
Heavy Duty Weatherproof Covers	N-26
Weatherproof Covers	N-27
Metallic EXTRA DUTY® While-In-Use Covers	N-28
Non-Metallic While-In-Use Covers	N-29
Screws and Accessories	N-30
Wallplate Dimensions	N-31
Custom Metal Wallplates	N-32
Configuration Chart	N-33



Features and Benefits

Nylon Wallplates

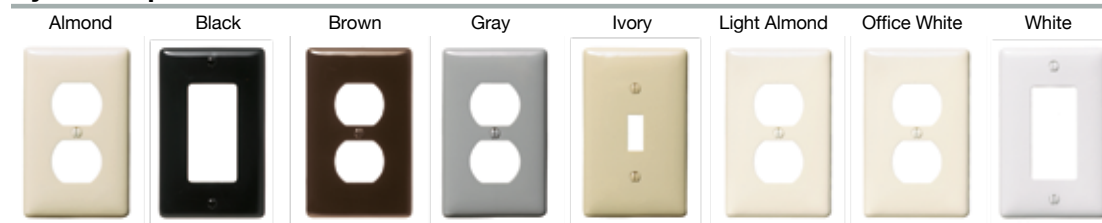
Our line of nylon wallplates features larger standard sized wallplates to provide extra coverage to hide rough box opening, improved aesthetics, greater strength, impact resistance, along with excellent cleanability in all different types of environments.

- Standard size is 1/8 inch larger to give you extra coverage to hide rough box openings. Also available in mid-size and pre-marked.
- Curved corners for improved aesthetics, for use in any application.
- Reinforcement ribs for extra strength.
- Captive screw feature holds mounting screw in place for quick and easy installation.
- High-impact, self-extinguishing nylon material, which is virtually unbreakable.
- Smooth, easy to clean finish is highly resistant to solvents and cleaning solutions, providing long life in the harshest environments.



Hubbell's standard sized wallplates are 1/8 inch larger to provide you that extra coverage to hide rough box openings. The depth is 1/4 inch so that it will comfortably fit over the device even on imperfect installations or on retrofit work.


Nylon Wallplates



Nylon Pre-Marked Wallplates



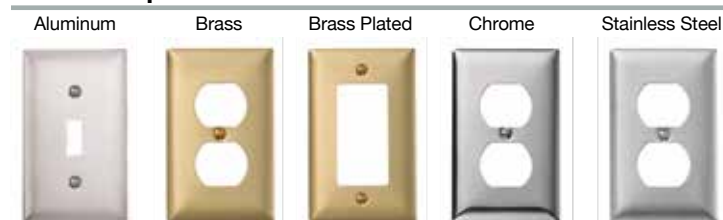Metal Wallplates



Pre-Marked





Features and Benefits

Stainless Steel Wallplates

Provide solutions for a variety of industrial and commercial applications.

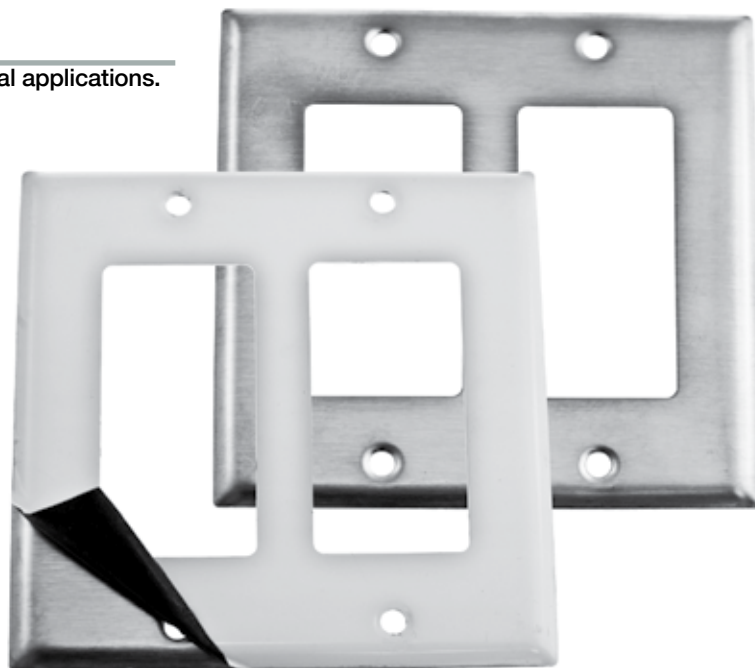
- Environments subjected to heavy abuse.
- The 302/304 type stainless steel wallplates are ideal for highly corrosive environments such as food processing, hospitals, static free requirements and more.
Non-magnetic: 18.0% Chromium
8.0% Nickel
- Standard commercial use.
- The 430 type stainless steel wallplates are aesthetically identical to the 302/304 type stainless steel wallplates and are best suited for environments where corrosion resistance is less critical.
Magnetic: 17.0% Chromium
Less than 0.5% Nickel

Smooth Solid Brass

- Provides a plush appearance with the durability of metal.
- Finish is lacquer coated to inhibit oxidation.

Anodized Aluminum

- Non-magnetic and corrosion resistance for a wide range of applications.
- Finish is lacquer coated to inhibit oxidation.



Protective plastic film helps to prevent scratches and damage.

Extra-Duty Metallic While-in-Use Covers

These covers are designed for use whenever protection is required while an outlet is in use. Covers meet or exceed the extra-duty rating per UL 514D, and are NEMA 3R rated.

- Die-cast aluminum construction
- Powder coated “chip resistant” paint corrosion protection
- Unique plug management provision for securing device and cord



2014 National Electrical Code (NEC®) Requirement

406.9 Receptacles in Damp or Wet Locations.

406.9 Receptacles in Damp or Wet Locations.

(B) Wet Locations.

(1) 15 and 20 Ampere Receptacles in a Wet Location. 15 and 20 ampere, 125 and 250 volt receptacles installed in a wet location shall have an enclosure that is weatherproof whether or not the attachment plug cap is inserted. An outlet box hood installed for this purpose shall be listed, and shall be identified as “extra-duty.” All 15 and 20 ampere, 125 and 250 volt nonlocking-type receptacles shall be listed weather-resistant type.

Exception: 15 and 20 ampere, 125 through 250 volt receptacles installed in a wet location and subject to routine high-pressure spray washing shall be permitted to have an enclosure that is weatherproof when the attachment plug is removed.

(2) Other Receptacles. All other receptacles installed in a wet location shall comply with (B)(2)(a) or (B)(2)(b).

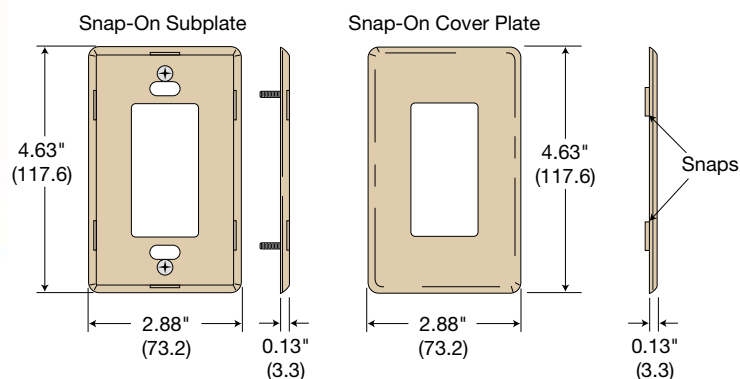
(a) A receptacle installed in a wet location, where the product intended to be plugged into it is not attended while in use, shall have an enclosure that is weatherproof with the attachment plug cap inserted or removed.

(b) A receptacle installed in a wet location where the product intended to be plugged into it will be attended while in use (e.g., portable tools) shall have an enclosure that is weatherproof when the attachment plug is removed.



More Style In a Snap

- Snap-on wallplates offer a clean, elegant look
- Installs in seconds
- Cover snaps into place
- Meets UL and CSA standards




Snap-On Wallplates

Description		Color	Decorator Catalog Number	Toggle Catalog Number
1-Gang, 1-Decorator	1-Gang, 1-Toggle	Ivory Light Almond White	RCW1I RCW1LA RCW1W	RFW1I - RFW1W
				
2-Gang, 2-Decorator	2-Gang, 2-Toggle	Ivory Light Almond White	RCW2I RCW2LA RCW2W	RFW2I - RFW2W
				
3-Gang, 3-Decorator	3-Gang, 3-Toggle	Ivory Light Almond White	RCW3I RCW3LA RCW3W	RFW3I - RFW3W
				
4-Gang, 4-Decorator		Ivory Light Almond White	RCW4I RCW4LA RCW4W	- - -
				
5-Gang, 5-Decorator		Ivory Light Almond White	RCW5I RCW5LA RCW5W	- - -
				
6-Gang, 6-Decorator		Ivory Light Almond White	RCW6I RCW6LA RCW6W	- - -
				

Dimensions in Inches (mm)

New and Improved Snap

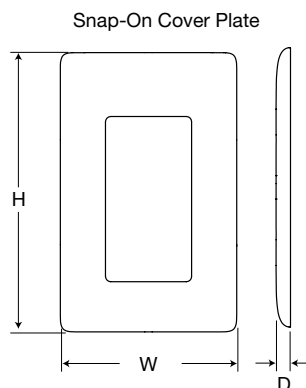- Clean, elegant look
- No visible screws
- Snap-on cover plate completely covers sub-plate eliminating dirt build-up around the edges
- Snap-on cover plate hides any paint or scratches on sub-plate caused during installation
- Appearance is consistent with other Hubbell wallplates
- Meets UL and CSA standards



Gang	Height (H)	Width (W)	Depth (D)
1	4.75" (120.6)	3.00" (76.2)	.25" (6.2)
2	4.75" (120.6)	4.81" (122.2)	.25" (6.2)
3	4.75" (120.6)	6.62" (168.2)	.25" (6.2)
4	4.75" (120.6)	8.44" (214.3)	.25" (6.2)

Snap-On Wallplates

Description		Color	Decorator Catalog Number	Toggle Catalog Number
1-Gang, 1-Decorator	1-Gang, 1-Toggle	Ivory Light Almond White	NPS26I NPS26LA NPS26W	NPS1I NPS1LA NPS1W
2-Gang, 2-Decorator	2-Gang, 2-Toggle	Ivory Light Almond White	NPS262I NPS262LA NPS262W	NPS2I NPS2LA NPS2W
3-Gang, 3-Decorator	3-Gang, 3-Toggle	Ivory Light Almond White	NPS263I NPS263LA NPS263W	NPS3I NPS3LA NPS3W
4-Gang, 4-Decorator		Ivory Light Almond White	NPS264I NPS264LA NPS264W	- - -
1-Gang, 1-Duplex		Ivory Light Almond White	NPS8I NPS8LA NPS8W	- - -

Dimensions in Inches (mm)



Toggle Switch Wallplates

Description	Color	Nylon Standard	Nylon Mid-Size	Nylon Jumbo	Material	Metal Catalog Number
 1-Gang, 1-Toggle	Almond	NP1AL	NPJ1AL	-	Aluminum	SA1
	Black	NP1BK	NPJ1BK	-	Brass	SB1
	Brown	NP1	NPJ1	-	Brass Plated	SBP1
	Gray	NP1GY	NPJ1GY	-	Chrome	SCH1
	Ivory	NP1I	NPJ1I	NPJJ1I	S/S 302/304	SS1
	Light Almond	NP1LA	NPJ1LA	NPJJ1LA	S/S 430	SS1L
	Office White	NP1OW	NPJ1OW	-	Steel, Almond	SP1AL*
	Red	NP1R	NPJ1R	-	Steel, Gray	SP1G*
	White	NP1W	NPJ1W	NPJJ1W		
 2-Gang, 2-Toggle	Almond	NP2AL	NPJ2AL	-	Aluminum	SA2
	Black	NP2BK	NPJ2BK	-	Brass	SB2
	Brown	NP2	NPJ2	-	Brass Plated	SBP2
	Gray	NP2GY	NPJ2GY	-	Chrome	SCH2
	Ivory	NP2I	NPJ2I	NPJJ2I	S/S 302/304	SS2
	Light Almond	NP2LA	NPJ2LA	NPJJ2LA	S/S 430	SS2L
	Office White	NP2OW	NPJ2OW	-	Steel, Almond	SP2AL*
	Red	NP2R	NPJ2R	-	Steel, Gray	SP2G*
	White	NP2W	NPJ2W	NPJJ2W		
 3-Gang, 3-Toggle	Almond	NP3AL	NPJ3AL	-	Aluminum	①
	Black	NP3BK	NPJ3BK	-	Brass	SB3
	Brown	NP3	NPJ3	-	Brass Plated	SBP3
	Gray	NP3GY	NPJ3GY	-	Chrome	SCH3
	Ivory	NP3I	NPJ3I	-	S/S 302/304	SS3
	Light Almond	NP3LA	NPJ3LA	-	S/S 430	SS3L
	Office White	NP3OW	NPJ3OW	-	Steel, Almond	SP3AL*
	Red	-	NPJ3R	-		
	White	NP3W	NPJ3W	-		
 4-Gang, 4-Toggle	Black	NP4BK	NPJ4BK	-	Aluminum	①
	Brown	NP4	NPJ4	-	Brass	SB4
	Gray	NP4GY	NPJ4GY	-	Brass Plated	SBP4
	Ivory	NP4I	NPJ4I	-	Chrome	①
	Light Almond	NP4LA	NPJ4LA	-	S/S 302/304	SS4
	Office White	NP4OW	NPJ4OW	-	S/S 430	SS4L
	White	NP4W	NPJ4W	-	Steel, Almond	SP4AL*
 5-Gang, 5-Toggle	Black	NP5BK	-	-	Aluminum	①
	Brown	NP5	-	-	Brass	SB5
	Gray	NP5GY	-	-	Brass Plated	①
	Ivory	NP5I	-	-	Chrome	①
	Light Almond	NP5LA	-	-	S/S 302/304	SS5
	White	NP5W	-	-	S/S 430	-
 6-Gang, 6-Toggle	Brown	NP6	-	-	Aluminum	①
	Gray	NP6GY	-	-	Brass	SB6
	Ivory	NP6I	-	-	Brass Plated	①
	Light Almond	NP6LA	-	-	Chrome	①
	White	NP6W	-	-	S/S 302/304	SS6
					S/S 430	-
 7-Gang, 7-Toggle	Almond	-	-	-	Aluminum	①
	Brown	-	-	-	Brass	①
	Gray	-	-	-	Brass Plated	①
	Ivory	-	-	-	Chrome	①
	White	-	-	-	S/S 302/304	SS607
					S/S 430	-
 8-Gang, 8-Toggle	Almond	-	-	-	Aluminum	①
	Brown	-	-	-	Brass	①
	Gray	-	-	-	Brass Plated	①
	Ivory	-	-	-	Chrome	①
	White	-	-	-	S/S 302/304	SS608
					S/S 430	-
 2-Gang, 1-Toggle	Almond	-	-	-	Aluminum	-
	Brown	-	-	-	Brass	-
	Gray	-	-	-	Brass Plated	-
	Ivory	-	-	-	Chrome	-
	White	-	-	-	S/S 302/304	SS740
					S/S 430	-

Note: All standard and mid-size nylon wallplates feature pre-inserted captive screws for faster assembly, up to 6-gang.

① Available as a custom wallplate, see pages N-32 to N-36. Consult custom wallplates section for additional openings and combinations.

*Powder coat paint finish.

Dimensions in Inches (mm)

Duplex Receptacle Wallplates

Description	Color	Nylon Standard	Nylon Mid-Size	Nylon Jumbo	Material	Metal Catalog Number
 1-Gang, 1-Duplex	Almond	NP8AL	NPJ8AL	—	Aluminum	SA8
	Black	NP8BK	NPJ8BK	—	Brass	SB8
	Blue	—	NPJ8BL	—	Brass Plated	SBP8
	Brown	NP8	NPJ8	—	Chrome	SCH8
	Gray	NP8GY	NPJ8GY	—	S/S 302/304	SS8
	Ivory	NP8I	NPJ8I	NPJJ8I	S/S 430	SS8L
	Light Almond	NP8LA	NPJ8LA	NPJJ8LA	Steel, Almond	SP8AL*
	Office White	NP8OW	NPJ8OW	—	Steel, Gray	SP8G*
	Orange	NP8OR	—	—		
	Red	NP8R	NPJ8R	—		
	White	NP8W	NPJ8W	NPJJ8W		
 2-Gang, 2-Duplex	Black	NP82BK	NPJ82BK	—	Aluminum	SA82
	Brown	NP82	NPJ82	—	Brass	SB82
	Gray	NP82GY	NPJ82GY	—	Brass Plated	SBP82
	Ivory	NP82I	NPJ82I	—	Chrome	SCH82
	Light Almond	NP82LA	NPJ82LA	—	S/S 302/304	SS82
	Office White	NP82OW	NPJ82OW	—	S/S 430	SS82L
	Orange	NP82OR	—	—	Steel, Almond	SP82AL*
	Red	NP82R	NPJ82R	—	Steel, Gray	SP82G*
	White	NP82W	NPJ82W	—		
 3-Gang, 3-Duplex	Brown	NP83	—	—	Aluminum	①
	Ivory	NP83I	—	—	Brass	①
	White	NP83W	—	—	Brass Plated	①
					Chrome	①
					S/S 302/304	SS83
 4-Gang, 4-Duplex	Brown	NP84	—	—	Aluminum	①
	Ivory	NP84I	—	—	Brass	①
	White	NP84W	—	—	Brass Plated	①
					Chrome	①
					S/S 302/304	SS84
 2-Gang, 1-Duplex	—	—	—	—	Aluminum	①
	—	—	—	—	Brass	①
	—	—	—	—	Brass Plated	①
	—	—	—	—	Chrome	①
	—	—	—	—	S/S 302/304	SS748

Single 15/20A Straight Blade or 15A Twist-Lock® Receptacle Wallplates

Description	Color	Nylon Standard	Nylon Mid-Size	Nylon Jumbo	Material	Metal Catalog Number
 1-Gang, 1-Single 1.40 in. (35.6) Dia. Hole	Black	NP7BK	NPJ7BK	—	Aluminum	SA7
	Brown	NP7	NPJ7	—	Brass	SB7
	Gray	NP7GY	NPJ7GY	—	Brass Plated	SBP7
	Ivory	NP7I	NPJ7I	—	Chrome	SCH7
	Light Almond	NP7LA	NPJ7LA	—	S/S 302/304	SS7
	Office White	NP7OW	NPJ7OW	—	S/S 430	SS7L
	Red	NP7R	NPJ7R	—	Steel, Almond	SP7AL*
	White	NP7W	NPJ7W	—	Steel, Gray	SP7G*
 2-Gang, 1-Single 1.40 in. (35.6) Dia. Hole	—	—	—	—	Aluminum	—
	—	—	—	—	Brass	—
	—	—	—	—	Brass Plated	—
	—	—	—	—	Chrome	—
	—	—	—	—	S/S 302/304	SS747
	—	—	—	—	S/S 430	—
 2-Gang, 2-Single 1.40 in. (35.6) Dia. Hole	—	—	—	—	Aluminum	①
	—	—	—	—	Brass	①
	—	—	—	—	Brass Plated	①
	—	—	—	—	Chrome	①
	—	—	—	—	S/S 302/304	SS72
	—	—	—	—	S/S 430	—

Note: All standard and mid-size nylon wallplates feature pre-inserted captive screws for faster assembly, up to 6-gang.

①Available as a custom wallplate, see pages N-32 to N-36. Consult custom wallplates section for additional openings and combinations.

*Powder coat paint finish.

Dimensions in Inches (mm)



Single 20/30A Twist-Lock® Receptacle Wallplates

Description	Color	Nylon Standard	Nylon Mid-Size	Material	Metal Catalog Number
	1-Gang, 1-Single 1.60 in. (40.6) Dia. Hole	Black Brown Gray Ivory Office White Red White	— — — — — — —	Aluminum Brass Brass Plated Chrome S/S 302/304 S/S 430	SA720 SB720 ① ① SS720 —
	1-Gang, 1-Single 1.74 in. (44.2) Dia. Hole	— — — — —	— — — — —	Aluminum Brass Brass Plated Chrome S/S 302/304	— — — — SS725
	2-Gang, 1-Single 1.60 in. (40.6) Dia. Hole	— — — —	— — — —	Aluminum Brass Brass Plated Chrome S/S 302/304	— — — — SS749
	3-Gang, 2-Single 1.60 in. (40.6) Dia. Hole	— — — — —	— — — — —	Aluminum Brass Brass Plated Chrome S/S 302/304	① ① ① ① SS320
	3-Gang, 2-Single 1.74 in. (44.2) Dia. Hole	— — — — —	— — — — —	Aluminum Brass Brass Plated Chrome S/S 302/304	— — — — SS330

Single Receptacle Wallplates

Description		Color	Nylon Standard	Nylon Mid-Size	Material	Metal Catalog Number
	1-Gang, 1-Single 1.97 in. (50.0) Dia. Hole	—	—	—	Aluminum	—
		—	—	—	Brass	—
		—	—	—	Chrome	—
		—	—	—	S/S 302/304	SS737
		—	—	—	S/S 430	—
	1-Gang, 1-Single 2.16 in. (54.9) Dia. Hole	Black	NP724BK	NPJ724BK	Aluminum	SA723
		Brown	NP724	NPJ724	Brass	①
		Gray	NP724GY	NPJ724GY	Brass Plated	①
		Ivory	NP724I	NPJ724I	Chrome	SCH723
		White	NP724W	NPJ724W	S/S 302/304	SS723
				S/S 430	SS723L	
	2-Gang, 1-Single 2.16 in. (54.9) Dia. Hole	—	—	—	Aluminum	—
		—	—	—	Brass	—
		—	—	—	Chrome	SCH702
		—	—	—	S/S 302/304	SS702
		—	—	—	S/S 430	—
	2-Gang, 1-Single 2.16 in. (54.9) Dia. Hole	Black	NP703BK	NPJ703BK	Aluminum	—
		Brown	NP703	NPJ703	Brass	—
		Gray	NP703GY	NPJ703GY	Brass Plated	—
		Ivory	NP703I	NPJ703I	Chrome	—
		White	NP703W	NPJ703W	S/S 302/304	SS703
				S/S 430	SS703L	
	2-Gang, 1-Single 2.48 in. (63.0) Dia. Hole	—	—	—	Aluminum	—
		—	—	—	Brass	—
		—	—	—	Chrome	—
		—	—	—	S/S 302/304	SS701
		—	—	—	S/S 430	—
	2-Gang, 1-Single 2.66 in. (67.6) Dia. Hole	—	—	—	Aluminum	—
		—	—	—	Brass	—
		—	—	—	Chrome	—
		—	—	—	S/S 302/304	SS716
		—	—	—	S/S 430	—

Note: All standard and mid-size nylon wallplates feature pre-inserted captive screws for faster assembly, up to 6-gang.

① Available as a custom wallplate, see pages N-32 to N-36. Consult custom wallplates section for additional openings and combinations.

Dimensions in Inches (mm)

Wallplates and Covers



Blank Wallplates, Box Mount and Strap Mount

Description	Color	Nylon Standard	Nylon Mid-Size	Nylon Jumbo	Material	Metal Catalog Number
	Almond	NP13AL	NPJ13AL	-	Aluminum	SA13A
	Black	NP13BK	NPJ13BK	-	Brass	SB13
	Brown	NP13	NPJ13	-	Brass Plated	SBP13
	Gray	NP13GY	NPJ13GY	-	Chrome	SCH13
	Ivory	NP13I	NPJ13I	NPJJ13I	S/S 302/304	SS13
	Light Almond	NP13LA	NPJ13LA	NPJJ13LA	S/S 430	SS13L
	Office White	NP13OW	NPJ13OW	-	Steel, Almond	SP14BAL*
	White	NP13W	NPJ13W	NPJJ13W	Steel, Gray	SP14BG*
	Almond	NP23AL	NPJ23AL	-	Aluminum	SA23
	Black	NP23BK	-	-	Brass	SB23
	Brown	NP23	NPJ23	-	Brass Plated	①
	Gray	NP23GY	-	-	Chrome	SCH23
	Ivory	NP23I	NPJ23I	-	S/S 302/304	SS23
	Light Almond	NP23LA	NPJ23LA	-	S/S 430	SS23L
	White	NP23W	NPJ23W	-	Steel, Almond	SP24BAL*
					Steel, Gray	SP24BG*
	Brown	NP33	-	-	Aluminum	①
	Ivory	NP33I	-	-	Brass	①
	White	NP33W	-	-	Brass Plated	①
					Chrome	①
	Brown	NP43	-	-	S/S 302/304	SS33
	Ivory	NP43I	-	-	S/S 430	-
	White	NP43W	-	-	Steel, Almond	SP34BAL*
	Black	NP14BK	-	-	Aluminum	①
	Brown	NP14	-	-	Brass	SB14
	Gray	NP14GY	-	-	Brass Plated	①
	Ivory	NP14I	-	-	Chrome	①
	Office White	NP14OW	-	-	S/S 302/304	SS14
	Red	NP14R	-	-	S/S 430	SS14L
	White	NP14W	-	-	Steel, Almond	SP14AL*
					Steel, Gray	SP14G*
	Black	NP24BK	-	-	Aluminum	①
	Brown	NP24	-	-	Brass	①
	Gray	NP24GY	-	-	Brass Plated	①
	Ivory	NP24I	-	-	Chrome	①
	Office White	NP24OW	-	-	S/S 302/304	SS24
	Red	NP24R	-	-	S/S 430	SS24L
	White	NP24W	-	-	Steel, Almond	SP24AL*
					Steel, Gray	SP24G*
	Brown	NP34	-	-	Aluminum	①
	Ivory	NP34I	-	-	Brass	①
	White	NP34W	-	-	Brass Plated	①
					Chrome	①
	Brown	NP44	-	-	S/S 302/304	SS34
	Ivory	NP44I	-	-	S/S 430	-
	White	NP44W	-	-	Steel, Almond	SP34AL*

Note: All standard and mid-size nylon wallplates feature pre-inserted captive screws for faster assembly, up to 6-gang.

①Available as a custom wallplate, see pages N-32 to N-36. Consult custom wallplates section for additional openings and combinations.

*Powder coat paint finish.


Dimensions in Inches (mm)



347 Volt Toggle Wallplates with 2.25" (57.2) Spacing Between Gangs, Stamped "347V"

Description	Color	Nylon Catalog Number	Material	Metal Catalog Number
1-Gang, 1-Toggle 2.25 in. (57.2) Spacing 	-	-	Aluminum	-
	-	-	Brass	-
	-	-	Brass Plated	-
	-	-	Chrome	-
	-	-	S/S 302/304	SS1C
	-	-	S/S 430	-
2-Gang, 2-Toggle 2.25 in. (57.2) Spacing 	-	-	Aluminum	-
	-	-	Brass	-
	-	-	Brass Plated	-
	-	-	Chrome	-
	-	-	S/S 302/304	SS2C
	-	-	S/S 430	-
3-Gang, 3-Toggle 2.25 in. (57.2) Spacing 	-	-	Aluminum	-
	-	-	Brass	-
	-	-	Brass Plated	-
	-	-	Chrome	-
	-	-	S/S 302/304	SS3C
	-	-	S/S 430	-
4-Gang, 4-Toggle 2.25 in. (57.2) Spacing 	-	-	Aluminum	-
	-	-	Brass	-
	-	-	Brass Plated	-
	-	-	Chrome	-
	-	-	S/S 302/304	SS4C
	-	-	S/S 430	-
5-Gang, 5-Toggle 2.25 in. (57.2) Spacing 	-	-	Aluminum	-
	-	-	Brass	-
	-	-	Brass Plated	-
	-	-	Chrome	-
	-	-	S/S 302/304	SS5C
	-	-	S/S 430	-
6-Gang, 6-Toggle 2.25 in. (57.2) Spacing 	-	-	Aluminum	-
	-	-	Brass	-
	-	-	Brass Plated	-
	-	-	Chrome	-
	-	-	S/S 302/304	SS6C
	-	-	S/S 430	-

 347 Volt Decorator Wallplates

Description	Color	Nylon Catalog Number	Material	Metal Catalog Number
1-Gang, 1-Decorator 	Black	HPS1347BK	Aluminum	-
	Gray	HPS1347GY	Brass	-
	Ivory	HPS1347I	Brass Plated	-
	White	HPS1347W	Chrome	-
			S/S 302/304	-
			S/S 430	-
2-Gang, 2-Decorator 	Black	HPS2347BK	Aluminum	-
	Gray	HPS2347GY	Brass	-
	Ivory	HPS2347I	Brass Plated	-
	White	HPS2347W	Chrome	-
			S/S 302/304	-
			S/S 430	-
3-Gang, 3-Decorator 	Ivory	HPS3347I	Aluminum	-
	White	HPS3347W	Brass	-
			Brass Plated	-
			Chrome	-
			S/S 302/304	-
			S/S 430	-

Note: All standard and mid-size nylon wallplates feature pre-inserted captive screws for faster assembly, up to 6-gang.

Dimensions in Inches (mm)

GFCI, Surge Receptacles and Style Line® Device Wallplates

Description	Color	Nylon Standard	Nylon Mid-Size	Nylon Jumbo	Material	Metal Catalog Number
1-Gang, 1-Decorator 	Almond	NP26AL	NPJ26AL	-	Aluminum	①
	Black	NP26BK	NPJ26BK	-	Brass	SB26
	Blue	-	NPJ26BL	-	Brass Plated	SBP26
	Brown	NP26	NPJ26	-	Chrome	SCH26
	Gray	NP26GY	NPJ26GY	-	S/S 302/304	SS26
	Ivory	NP26I	NPJ26I	NPJJ26I	S/S 430	SS26L
	Light Almond	NP26LA	NPJ26LA	NPJJ26LA	Steel, Almond	PHPS1AL*
	Office White	NP26OW	NPJ26OW	-	Steel, Gray	PHPS1G*
	Red	NP26R	NPJ26R	-		
	White	NP26W	NPJ26W	NPJJ26W		
2-Gang, 2-Decorator 	Almond	NP262AL	NPJ262AL	-	Aluminum	①
	Black	NP262BK	NPJ262BK	-	Brass	SB262
	Brown	NP262	NPJ262	-	Brass Plated	SBP262
	Gray	NP262GY	NPJ262GY	-	Chrome	SCH262
	Ivory	NP262I	NPJ262I	-	S/S 302/304	SS262
	Light Almond	NP262LA	NPJ262LA	-	S/S 430	SS262L
	Office White	NP262OW	NPJ262OW	-	Steel, Almond	PHPS2AL*
	Red	NP262R	NPJ262R	-	Steel, Gray	PHPS2G*
	White	NP262W	NPJ262W	-		
3-Gang, 3-Decorator 	Almond	NP263AL	NPJ263AL	-	Aluminum	①
	Black	NP263BK	NPJ263BK	-	Brass	①
	Brown	NP263	NPJ263	-	Brass Plated	SBP263
	Gray	NP263GY	NPJ263GY	-	Chrome	①
	Ivory	NP263I	NPJ263I	-	S/S 302/304	SS263
	Light Almond	NP263LA	NPJ263LA	-	S/S 430	-
	Office White	NP263OW	NPJ263OW	-	Steel, Almond	PHPS3AL*
	Red	NP263R	NPJ263R	-		
	White	NP263W	NPJ263W	-		
4-Gang, 4-Decorator 	Almond	NP264AL	NPJ264AL	-	Aluminum	①
	Black	NP264BK	NPJ264BK	-	Brass	①
	Brown	NP264	NPJ264	-	Brass Plated	①
	Gray	NP264GY	NPJ264GY	-	Chrome	①
	Ivory	NP264I	NPJ264I	-	S/S 302/304	SS264
	Light Almond	NP264LA	NPJ264LA	-	S/S 430	-
	Office White	NP264OW	NPJ264OW	-	Steel, Almond	PHPS4AL*
	White	NP264W	NPJ264W	-		
5-Gang, 5-Decorator 	Black	NP265BK	-	-	Aluminum	①
	Brown	NP265	-	-	Brass	①
	Gray	NP265GY	-	-	Brass Plated	①
	Ivory	NP265I	-	-	Chrome	①
	Light Almond	NP265LA	-	-	S/S 302/304	SS265
	White	NP265W	-	-	S/S 430	-
6-Gang, 6-Decorator 	Black	NP266BK	-	-	Aluminum	①
	Brown	NP266	-	-	Brass	①
	Gray	NP266GY	-	-	Brass Plated	①
	Ivory	NP266I	-	-	Chrome	①
	Light Almond	NP266LA	-	-	S/S 302/304	SS266
	White	NP266W	-	-	S/S 430	-
					Steel, Almond	PHPS6AL*

Note: All standard and mid-size nylon wallplates feature pre-inserted captive screws for faster assembly, up to 6-gang.

① Available as a custom wallplate, see pages N-32 to N-36. Consult custom wallplates section for additional openings and combinations.

*Powder coat paint finish.

Dimensions in Inches (mm)



Combination Wallplates, 2-Gang

Description	Color	Nylon Standard	Nylon Mid-Size	Material	Metal Catalog Number
2-Gang, 1-Toggle, 1-Duplex 	Almond Black Brown Gray Ivory Light Almond Office White Red White	NP18AL NP18BK NP18 NP18GY NP18I NP18LA NP18OW NP18R NP18W	NPJ18AL NPJ18BK NPJ18 NPJ18GY NPJ18I NPJ18LA NPJ18OW NPJ18R NPJ18W	Aluminum Brass Brass Plated Chrome S/S 302/304 S/S 430 Steel, Almond Steel, Gray	① ① SBP18 SCH18 SS18 SS18L SP18AL* SP18G*
2-Gang, 1-Duplex, 1-Decorator 	Almond Black Brown Gray Ivory Light Almond Office White White	NP826AL NP826BK NP826 NP826GY NP826I NP826LA NP826OW NP826W	NPJ826AL NPJ826BK NPJ826 NPJ826GY NPJ826I NPJ826LA - NPJ826W	Aluminum Brass Brass Plated Chrome S/S 302/304 S/S 430	① SB826 ① ① SS826 -
2-Gang, 1-Toggle, 1-Decorator 	Almond Black Brown Gray Ivory Light Almond White	NP126AL NP126BK NP126 NP126GY NP126I NP126LA NP126W	NPJ126AL NPJ126BK NPJ126 NPJ126GY NPJ126I NPJ126LA NPJ126W	Aluminum Brass Brass Plated Chrome S/S 302/304 S/S 430 Steel, Almond Steel, Gray	① SB126 SBP126 ① SS126 SS126L PJS126AL* PJS126G*
2-Gang, 1-Duplex, 1-Telephone .406 in. (10.3) Hole Strap Mount 	Black Brown Gray Ivory White	NP128BK NP128 NP128GY NP128I NP128W	- - - - -	Aluminum Brass Brass Plated Chrome S/S 302/304 S/S 430	- - - - - -
2-Gang, 1-Toggle, 1-Telephone .406 in. (10.3) Hole Strap Mount 	Black Brown Gray Ivory Office White White	NP112BK NP112 NP112GY NP112I NP112OW NP112W	- - - - - -	Aluminum Brass Brass Plated Chrome S/S 302/304 S/S 430	- - - - - -
2-Gang, 1-Decorator, 1-Telephone .406 in. (10.3) Hole Strap Mount 	Black Brown Gray Ivory White	NP1226BK NP1226 NP1226GY NP1226I NP1226W	- - - - -	Aluminum Brass Brass Plated Chrome S/S 302/304 S/S 430	- - - - - -
2-Gang, 1-Single Receptacle 1.40 in. (35.6) Hole, 1-Duplex 	Almond Brown Gray Ivory White	NP78AL NP78 NP78GY NP78I NP78W	- - - - -	Aluminum Brass Brass Plated Chrome S/S 302/304 S/S 430	① ① ① ① SS78 -
2-Gang, 1-Single Recept. 1.60 in. (40.6) Hole, 1-Duplex 	Almond Brown Ivory White	- - - -	- - - -	Aluminum Brass Brass Plated Chrome S/S 302/304 S/S 430	① ① ① ① SS8720 -

Note: All standard and mid-size nylon wallplates feature pre-inserted captive screws for faster assembly, up to 6-gang.

① Available as a custom wallplate, see pages N-32 to N-36. Consult custom wallplates section for additional openings and combinations.

*Powder coat paint finish.

Dimensions in Inches (mm)

Combination Wallplates, 2-Gang

Description	Color	Nylon Standard	Nylon Mid-Size	Material	Metal Catalog Number
2-Gang, 1-Toggle, 1-Single Receptacle 1.40 in. (35.6) Hole 	Black Brown Gray Ivory White	NP17BK NP17 NP17GY NP17I NP17W	— — — — —	Aluminum Brass Brass Plated Chrome S/S 302/304 S/S 430	① ① ① ① SS17 —
2-Gang, 1-Toggle, 1-Blank, Box Mount 	Black Brown Gray Ivory Light Almond White	NP113BK NP113 NP113GY NP113I NP113LA NP113W	— NPJ113 — NPJ113I — —	Aluminum Brass Brass Plated Chrome S/S 302/304 S/S 430	① ① ① ① SS113 —
2-Gang, 1-Toggle, 1-Blank, Strap Mount 	Black Brown Gray Ivory Light Almond White	— — — — — —	— — — — — —	Aluminum Brass Brass Plated Chrome S/S 302/304 S/S 430	① ① ① ① SS114 —
2-Gang, 1-Blank, 1-Duplex, Box Mount 	Black Brown Gray Ivory Light Almond White	NP138BK NP138 NP138GY NP138I NP138LA NP138W	— NPJ138 — NPJ138I — NPJ138W	Aluminum Brass Brass Plated Chrome S/S 302/304 S/S 430	① ① ① ① SS138 —
2-Gang, 1-Blank, 1-Duplex, Strap Mount 	Black Brown Gray Ivory Light Almond White	— — — — — —	— — — — — —	Aluminum Brass Brass Plated Chrome S/S 302/304 S/S 430	① ① ① ① SS148 —
2-Gang, 1-Blank, 1-Decorator, Box Mount 	Black Brown Gray Ivory Light Almond White	NP1326BK NP1326 NP1326GY NP1326I NP1326LA NP1326W	NPJ1326BK NPJ1326 NPJ1326GY NPJ1326I NPJ1326LA NPJ1326W	Aluminum Brass Brass Plated Chrome S/S 302/304 S/S 430	① ① ① ① SS1426* —
2-Gang, 1-Telephone, .406 in. (10.3) Hole, 1-Blank, Strap Mount 	Black Brown Gray Ivory White	NP1214BK NP1214 NP1214GY NP1214I NP1214W	— — — — —	Aluminum Brass Brass Plated Chrome S/S 302/304 S/S 430	— — — — — —
2-Gang, 1-Single Receptacle 1.40 in. (35.6) Hole 1-Blank, Strap Mount 	Black Brown Gray Ivory White	NP147BK NP147 NP147GY NP147I NP147W	— — — — —	Aluminum Brass Brass Plated Chrome S/S 302/304 S/S 430	① ① ① ① ① —

Note: All standard and mid-size nylon wallplates feature pre-inserted captive screws for faster assembly, up to 6-gang.

①Available as a custom wallplate, see pages N-32 to N-36. Consult custom wallplates section for additional openings and combinations.

*Strap Mount.

Dimensions in Inches (mm)



Combination Wallplates, 3-Gang

Description	Color	Nylon Standard	Nylon Mid-Size	Material	Metal Catalog Number
3-Gang, 2-Toggle, 1-Duplex 	Brown Gray Ivory Light Almond White	NP28 NP28GY NP28I NP28LA NP28W	NPJ28 — NPJ28I NPJ28LA NPJ28W	Aluminum Brass Brass Plated Chrome S/S 302/304 S/S 430 Steel, Almond Steel, Gray	① ① SBP28 ① SS28 — SP28AL* SP28G*
3-Gang, 1-Toggle, 2-Duplex 	Black Brown Gray Ivory White	NP182BK NP182 NP182GY NP182I NP182W	— — — — —	Aluminum Brass Brass Plated Chrome S/S 302/304 S/S 430	① ① ① ① SS182 —
3-Gang, 2-Toggle, 1-Decorator 	Black Brown Gray Ivory Light Almond White	NP226BK NP226 NP226GY NP226I NP226LA NP226W	NPJ226BK NPJ226 NPJ226GY NPJ226I NPJ226LA NPJ226W	Aluminum Brass Brass Plated Chrome S/S 302/304 S/S 430 Steel, Gray	① ① ① ① SS226 — PJS226G*
3-Gang, 1-Toggle, 2-Decorator 	Black Brown Gray Ivory Light Almond White	NP1262BK NP1262 NP1262GY NP1262I NP1262LA NP1262W	— — — — — —	Aluminum Brass Brass Plated Chrome S/S 302/304 S/S 430	① ① ① ① ① —
3-Gang, 2-Duplex, 1-Blank 	Black Brown Gray Ivory Light Almond White	— — — — — —	— — — — — —	Aluminum Brass Brass Plated Chrome S/S 302/304 S/S 430	① ① ① ① SS211 —
3-Gang, 1-Duplex, 1-Blank, 1-Duplex 	Black Brown Gray Ivory Light Almond White	— — — — — —	— — — — — —	Aluminum Brass Brass Plated Chrome S/S 302/304 S/S 430	① ① ① ① SS8147 —
3-Gang, 2-Toggle, 1-Blank 	Black Brown Gray Ivory Light Almond White	— — — — — —	— — — — — —	Aluminum Brass Brass Plated Chrome S/S 302/304 S/S 430	① ① ① ① SS213 —

Note: All standard and mid-size nylon wallplates feature pre-inserted captive screws for faster assembly, up to 6-gang.

①Available as a custom wallplate, see pages N-32 to N-36. Consult custom wallplates section for additional openings and combinations.

*Powder coat paint finish.

Dimensions in Inches (mm)

Combination Plates, 4- and 5-Gang

Description	Color	Nylon Standard	Nylon Mid-Size	Material	Metal Catalog Number
4-Gang, 3-Toggle, 1-Duplex 	Brown	NP38	—	Aluminum	①
	Ivory	NP38I	—	Brass	①
	Light Almond	NP38LA	—	Brass Plated	①
	White	NP38W	—	Chrome	①
				S/S 302/304	SS38
				S/S 430	—
4-Gang, 3-Toggle, 1-Decorator 	Black	NP326BK	—	Aluminum	①
	Brown	NP326	—	Brass	①
	Gray	NP326GY	—	Brass Plated	①
	Ivory	NP326I	—	Chrome	①
	Light Almond	NP326LA	—	S/S 302/304	SS326
	White	NP326W	—	S/S 430	—
4-Gang, 2-Toggle, 2-Decorator 	Black	NP2262BK	—	Aluminum	①
	Brown	NP2262	—	Brass	①
	Gray	NP2262GY	—	Brass Plated	①
	Ivory	NP2262I	—	Chrome	①
	Light Almond	NP2262LA	—	S/S 302/304	①
	White	NP2262W	—	S/S 430	—
5-Gang, 4-Toggle, 1-Duplex 	Brown	NP48	—	Aluminum	①
	Ivory	NP48I	—	Brass	①
	White	NP48W	—	Brass Plated	①
				Chrome	①
				S/S 302/304	①
				S/S 430	—

Note: All standard and mid-size nylon wallplates feature pre-inserted captive screws for faster assembly, up to 6-gang.

① Available as a custom wallplate, see pages N-32 to N-36. Consult custom wallplates section for additional openings and combinations.

Dimensions in Inches (mm)



Telephone and Coaxial Outlet Plates

Description	Color	Nylon Standard	Nylon Mid-Size	Material	Metal Catalog Number
 1-Gang, 1-Tel Nylon .406 in. (10.3) Hole, Metal .640 in. (16.3) Hole, Box Mount	Almond	NP11AL	NPJ11AL	Aluminum	①
	Black	NP11BK	—	Brass	①
	Brown	NP11	NPJ11	Brass Plated	①
	Gray	NP11GY	—	Chrome	①
	Ivory	NP11I	NPJ11I	S/S 302/304	SS11*
	Light Almond	NP11LA	NPJ11LA	S/S 430	SS11L*
	Red	NP11R	—		
	White	NP11W	NPJ11W		
 1-Gang, 1-Tel Nylon .406 in. (10.3) Hole, Metal .640 in. (16.3) Hole, Strap Mount	Almond	NP12AL	—	Aluminum	①
	Black	NP12BK	—	Brass	SB12*
	Brown	NP12	—	Brass Plated	SBP12*
	Gray	NP12GY	—	Chrome	SCH12*
	Ivory	NP12I	—	S/S 302/304	SS12*
	White	NP12W	—	S/S 430	SS12L*
 1-Gang, 1-Tel .625 in. (15.9) Hole, Box Mount	Almond	NP737AL	—	Aluminum	—
	Brown	NP737	—	Brass	—
	Ivory	NP737I	—	Brass Plated	—
	White	NP737W	—	Chrome	—
				S/S 302/304	—
				S/S 430	—
 1-Gang, 1-Tel .625 in. (15.9) Hole, Strap Mount	Brown	NP730	—	Aluminum	—
	Ivory	NP730I	—	Brass	—
	White	NP730W	—	Brass Plated	—
				Chrome	—
				S/S 302/304	—
				S/S 430	—
 1-Gang, 1-Tel .380 in. (9.7) Hole, Box Mount or Strap Mount	Almond	—	—	Aluminum	①
	Brown	—	—	Brass	①
	Ivory	—	—	Brass Plated	①
	White	—	—	Chrome	①
				S/S 302/304	SS739
				S/S 302/304, Strap Mount	SS738
				S/S 430	—
 2-Gang, 2-Tel Nylon .406 in. (10.3) Hole, Metal .640 in. (16.3) Hole, Box Mount	Black	NP21BK	—	Aluminum	①
	Brown	NP21	—	Brass	①
	Gray	NP21GY	—	Brass Plated	①
	Ivory	NP21I	—	Chrome	①
	White	NP21W	—	S/S 302/304, Strap Mount	SS22*
				S/S 430	—
 2-Gang, 1-Tel .640 in. (16.3) Hole, Box Mount	Almond	—	—	Aluminum	—
	Brown	—	—	Brass	—
	Ivory	—	—	Brass Plated	—
	White	—	—	Chrome	—
				S/S 302/304	SS741*
				S/S 430	—

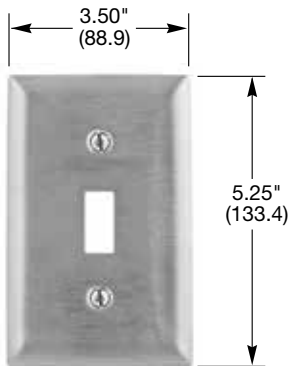
Note: All standard and mid-size nylon wallplates feature pre-inserted captive screws for faster assembly, up to 6-gang.

① Available as a custom wallplate, see pages N-32 to N-36. Consult custom wallplates section for additional openings and combinations.

* .50" (12.7) I.D. nylon bushing provided.

Dimensions in Inches (mm)

Jumbo, Smooth, Stainless Steel Type 302/304 Wallplates

Configuration	Catalog Number	Configuration	Catalog Number
1-Gang, 1-Toggle 	SSJ1	1-Gang, 1-Single Receptacle for 2.09–2.13 in. (53.1–54.1) Dia. Face 	SSJ723
2-Gang, 2-Toggle 	SSJ2	1-Gang, 1-Blank, Box Mount 	SSJ13
1-Gang, 1-Duplex 	SSJ8	1-Gang, 1-Telephone Opening, .640 in. (16.3) Box Mount 	SSJ11*
2-Gang, 2-Duplex 	SSJ82	2-Gang, 1-Toggle, 1-Duplex 	SSJ18
1-Gang, 1-Decorator 	SSJ26	2-Gang, 1-Toggle, 1-Decorator 	SSJ126
2-Gang, 2-Decorator 	SSJ262	 3.50" (88.9) 5.25" (133.4)	
1-Gang, 1-Single Receptacle for 1.36–1.39 in. (34.5–35.3) Dia. Face 	SSJ7		

Note: *.50 in. (12.7) I.D. nylon bushing provided.
Specifications are subject to change without notice.

Jumbo Wallplate

Oversize dimensions (see page N-31 for more details).

1-Gang, 5.25 in. x 3.50 in. (133.4 x 88.9).

2-Gang, 5.25 in. x 5.31 in. (133.4 x 134.9).

Dimensions in Inches (mm)



Pre-Marked "EMERGENCY" Wallplates

Description	Color	Nylon Standard	Nylon Mid-Size	Material	Metal Catalog Number
1-Gang, 1-Duplex, paint filled white lettering 	Red	—	NPJ8RMEV	Aluminum Brass Brass Plated Chrome S/S 302/304 S/S 430	— — — — SS8MEV —
1-Gang, 1-Toggle, paint filled white lettering 	Red	—	NPJ1RME	Aluminum Brass Brass Plated Chrome S/S 302/304 S/S 430	— — — — SS1ME —
2-Gang, 2 Duplex, paint filled red lettering 	—	—	—	Aluminum Brass Brass Plated Chrome S/S 302/304 S/S 430	— — — — SS82MEV —

Note: See page N-31 for mid-size plate dimensions.
All lettering .25 in. (6.3) high.



Stainless Steel Barrel Key Switch Wallplates

Description	1-Gang, with on/off markings	1-Gang, with position markings	2-Gang, with on/off markings	2-Gang, with position markings
Stainless steel, 302/304, smooth.	SS12RKL	SS12RKLM	SS22RKL	SS22RKLM
				

Note: See page D-6 for barrel key switch selection.

Single Count Screws and Accessories

Description	Catalog Number
Stainless steel screw, standard slot, .38 in. (9.7) long.	HBL7341SS
Security spanner head screws, 6-32 thread, 100 count.	HBL7342RKL
Screwdriver with spanner head security bit.	HBL7372RKL



HBL7342RKL



HBL7372RKL

Dimensions in Inches (mm)

Pre-Marked "ISOLATED GROUND" Wallplates

Description	Color	Nylon Standard	Nylon No Marking	Material	Metal Catalog Number
1-Gang, 1-Duplex, paint filled black 	Orange	NP80IG	NP80R	Aluminum Brass Brass Plated Chrome S/S 302/304 S/S 430	- - - - - -
1-Gang, 1-Decorator, paint filled black 	Orange	NP260IG	-	Aluminum Brass Brass Plated Chrome S/S 302/304 S/S 430	- - - - - -
1-Gang, 1-Single Receptacle 1.40 in. (35.6) Hole for 1.36–1.39 in. (34.5–35.3) Dia. face, paint filled black 	Orange	NP70IG	-	Aluminum Brass Brass Plated Chrome S/S 302/304 S/S 430	- - - - - -
1-Gang, 1-Single Receptacle 1.60 in. (40.6) Hole for 20 and 30A Twist-Lock® with 1.55–1.58 in. (39.4–40.1) Dia. face, paint filled black 	Orange	NP7200IG	-	Aluminum Brass Brass Plated Chrome S/S 302/304 S/S 430	- - - - - -

Pre-Marked "COMPUTER ONLY" Wallplates

Description	Color	Nylon Standard	Nylon Mid-Size	Material	Metal Catalog Number
1-Gang, 1-Duplex, paint filled black 	Orange Ivory	- -	NPJ8CO NPJ8C	Aluminum Brass Brass Plated Chrome S/S 302/304 S/S 430	- - - - - -
2-Gang, 2-Duplex, paint filled black 	Orange	-	NPJ82CO	Aluminum Brass Brass Plated Chrome S/S 302/304 S/S 430	- - - - - -
1-Gang, 1-Decorator, paint filled black 	Blue Ivory	- -	NPJ26CBL NPJ26C	Aluminum Brass Brass Plated Chrome S/S 302/304 S/S 430	- - - - - -

Louver Plate, 1-Gang, Box Mount

Description	Color	Nylon Standard	Nylon Mid-Size	Material	Metal Catalog Number
1-Gang, Vertical Mounted Louver 	- - - - -	- - - - -	- - - - -	Aluminum Brass Brass Plated Chrome S/S 302/304 S/S 430	① SB771 SBP771 ① SS771 -

Note: *See page N-31 for mid-size plate dimensions.

① Available as a custom wallplate, see pages N-32 to N-36. Consult custom wallplates section for additional openings and combinations.

Dimensions in Inches (mm)



SWP1



SWP8

1-Gang Security Wallplates, White

Description	Catalog Number
1-Toggle switch	SWP1
1-Duplex receptacle	SWP8
1-GFCI/Style Line® opening	SWP26
1-Telephone or TV opening .640 in. (16.3)	SWP12
1-Blank	SWP13



SWP82



SWP18

2-Gang Security Wallplates, White

Description	Catalog Number
2-Toggle switches	SWP2
2-Duplex receptacles	SWP82
1-Toggle switch, 1-Duplex receptacle	SWP18
2-GFCI/Style Line® openings	SWP262
1-Toggle switch, 1-GFCI/Style Line® opening	SWP126
1-Duplex receptacle, 1-Telephone or TV	SWP812
1-Duplex receptacle, 1-Blank	SWP813
2-Blank	SWP23




SWP28

3-Gang Security Wallplates, White

Description	Catalog Number
2-Toggle switches, 1-Duplex receptacle	SWP28

Dimensions Inches (mm)

	A	B	C	D	E	F	G	H
1-Gang	3.77" (95.8)	5.52" (140.2)	.55" (14.0)	3.37" (85.6)	5.13" (130.3)	1.00" (25.4)	4.63" (117.6)	2.88" (73.2)
2-Gang	5.52" (140.2)	5.52" (140.2)	.55" (14.0)	5.13" (130.3)	5.13" (130.3)	1.00" (25.4)	4.63" (117.6)	4.63" (117.6)
3-Gang	7.39" (187.71)	5.52" (140.21)	.55" (14.0)	7.00" (177.8)	5.13" (130.3)	1.00" (25.4)	4.63" (117.6)	6.50" (165.1)

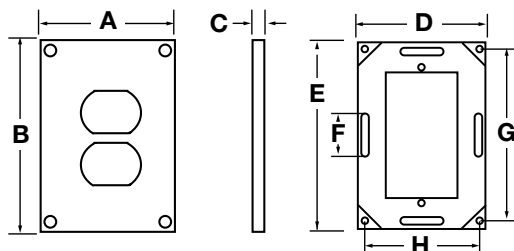

Specifications

Tamper resistant wallplate 1-gang duplex receptacle shall be of the following construction:

Cover plate: One piece #14 cold rolled zinc plated steel. Plate shall have a five stage baked white polyester powder enamel finish.
Gloss: 85%; reflectance: 93%; hardness minimum: 2H and pass 600 hour salt spray test.

Back plate: #10 cold rolled galvanized steel. Plate assembly shall use four (4) #8-32 X 1/2 inch stainless steel T-15 TORX® head screws with center pin reject. Plate must be UL listed to UL 514D and comply with the NEC®.

TORX® is a registered trademark of Textron Inc.

NEC® is a registered trademark of the The National Electrical Code.

Dimensions in Inches (mm)

Brass Locking Cover Plate

Description	Catalog Number
Locking cover plate for single 15 and 20A straight blade receptacles and 15A Twist-Lock® receptacles. Straight cylinder type lock. All cylinder locks keyed alike.	HBL96067



HBL96067
Shown with receptacle
(sold separately)



HBL6187
Shown with receptacle
and back box
(sold separately)

Weather Shield Plate

Description	Catalog Number
20° angle plate for duplex receptacles.	HBL6187

Catalog Number of Receptacles in Groups A through E below

Group A		Group B			Group C	Group D		Group E
Boss diameter 1.36" to 1.39" (34.5 to 35.3)		Boss diameter 1.55" to 1.58" (39.4 to 40.1)			Boss diameter 1.68" to 1.72" (42.7 to 43.7)	Boss diameter 2.09" to 2.13" (53.1 to 54.1)		Boss diameter 2.28" to 2.44" (57.9 to 62.0)
HBL23000HG	HBL5661	HBL23CM10	HBL2530	HBL2770	HBL45105	HBL7962	HBL7301A	
HBL23030	HBL6810	HBL2310	HBL26CM10	HBL2810	HBL45205	HBL9350	HBL8330A	
HBL4560	HBL7210B	HBL2320	HBL2610	HBL2820	HBL45305	HBL9308	HBL8350A	
HBL4710	HBL7250	HBL2330	HBL2620	HBL2830	HBL45905	HBL9315	HBL8430A	
HBL4760	HBL7310B	HBL2340	HBL2630	HBL3330		HBL9330	HBL8450A	
HBL5251	HBL7310BG	HBL2410	HBL2640	HBL3330G		HBL9360•	HBL8460A	
HBL52CM61	HBL7535	HBL2420	HBL2650	HBL3430		HBL9365•	HBL9430A	
HBL5261	HBL7582	HBL2430	HBL2710	HBL3430G		HBL9367•	HBL9450A	
HBL53CM61	HBL8210	HBL2440	HBL2720	HBL3520			HBL9460A	
HBL5361	HBL8310	HBL2450	HBL2730	HBL7410B				
HBL5461	HBL8410	HBL2460	HBL2740	HBL7410BG				
HBL5552B	HBL8420	HBL2510	HBL2750					
		HBL2520	HBL2760					

Note: •50A 2P 3W.

Wallplates for Single Receptacles

Description	Group A		Group B		Group C		Group D		Group E
	Boss diameter 1.36" to 1.39" (34.5 to 35.3)		Boss diameter 1.55" to 1.58" (39.4 to 40.1)		Boss diameter 1.68" to 1.72" (42.7 to 43.7)		Boss diameter 2.09" to 2.13" (53.1 to 54.1)		Boss diameter 2.28" to 2.44" (57.9 to 62.0)
	1-Gang	2-Gang	1-Gang	2-Gang	1-Gang	2-Gang	1-Gang	2-Gang	2-Gang
Smooth nylon, brown.	NP7*	–	NP720*	–	–	–	NP724*	NP703*	–
Cast aluminum.	HBL7320	–	HBL7320	–	HBL3394	–	HBL9419	–	–
Stainless steel, 302/304, smooth.	SS7**	SS72	SS720	–	SS725	–	SS723	SS703	SS701

Note: See pages N-7 and N-8 for complete plate descriptions.

*Catalog number indicated is Brown, add with the following to designate color: "AL" (Almond), "BK" (Black), "GY" (Gray), "I" (Ivory), and "W" (white).

**Catalog number indicated is Stainless Steel, replace "SS" with the following prefix to designate material: "SA" for Anodized Aluminum, "SB" for Solid Brass.

Weatherproof Lift Covers for WDL "Closed" and WDL "Open", Wet Locations, 1-Gang

Description	Group A	Group B	Group C	Group D		
	Boss diameter 1.36" to 1.39" (34.5 to 35.3)	Boss diameter 1.55" to 1.58" (39.4 to 40.1)	Boss diameter 1.68" to 1.72" (42.7 to 43.7)	Boss diameter 2.09" to 2.13" (53.1 to 54.1)	50A Twist-Lock® Receptacles	30A 4W Hubbell® Receptacles
Thermoplastic, with cover "open", gray.	HBL7423WO	HBL7425WOA	HBL7424WO	–	HBL7774WO▲	–
Thermoplastic, with cover "open", yellow.	HBL74CM23WO	HBL74CM25WOA	HBL74CM24WO	–	HBL77CM74WO▲	–
Cast aluminum, with cover "closed".	HBL7420	HBL7420	HBL3393	HBL9420 HBL9425•	HBL7770	HBL20405† HBL20446†

Note: •50A 2P 3W.

▲The "CS" versions of 50A Twist-Lock® receptacles will only fit these thermoplastic plates.

†HBL20446 plate painted red for use with HBL20443 only. HBL20405 plate is for use with HBL20403 only. See page B-62 for devices.



HBL7777A

For Receptacles with Face Diameters of 2.28–2.44 in. (57.9–62.0)

Description	Catalog Number
Thermoplastic, 2-gang, wet and damp locations with cover “closed”, gray.	HBL7777A[▲]
Thermoplastic, 2-gang, wet and damp locations with cover “closed”, yellow.	HBL77CM77A[▲]
Thermoplastic, 2-gang, wet and damp locations with cover “closed”, gray.	HBL7777[▽]



HBL9420

For Receptacles with Face Diameters of 2.09–2.13 in. (53.1–54.1)

Description	Catalog Number
Cast aluminum, wet locations only when cover “closed” and damp locations.	HBL9420
Cast aluminum, no lift cover. NOT weatherproof.	HBL9419

For 50A Twist-Lock[®] Single Receptacles

Description	Catalog Number
Thermoplastic, wet and damp locations with cover “open”, gray.	HBL7774WO[*]
Thermoplastic, wet and damp locations with cover “open”, yellow.	HBL77CM74WO[*]
Cast aluminum, wet locations only when cover “closed” and damp locations.	HBL7770
Galvanized Steel, fits 4" square or 2-gang box.	HBL50SC^{**}
Stainless steel, single gang, wallplate. NOT weatherproof.	SS750[▲]



HBL7774WO

For 30A, 4 Wire Hubbellock[®] Receptacles

Description	Catalog Number
Thermoplastic, wet and damp locations with cover “open”, gray.	HBL7428WOG[*]
Thermoplastic, wet and damp locations with cover “open”, yellow.	HBL7428WOY[*]
Thermoplastic, wet and damp locations with cover “open”, red.	HBL7428WOR[*]
Cast aluminum, wet locations only when cover “closed” and damp locations, lift cover plate.	HBL20405
Cast aluminum, wet locations only when cover “closed” and damp locations, red finish.	HBL20446
Cast aluminum, no lift cover. NOT weatherproof.	HBL20406

Note: [▲]Will fit FS/FD boxes having plate mounting holes on 3.25 in. x 3.75 in. (82.6 x 95.3) centers.

[▽]Will only fit old style porcelain face devices.

^{*}The “CS” versions of 50A Twist-Lock[®] will only fit these plates.

^{**}IP20 Suitability.



HBL7770

Weatherproof Covers for Single Receptacles for Use on FS/FD Boxes

Note: All weatherproof plates are UL Listed for WET LOCATIONS WITH COVER CLOSED, for intermittent use in wet locations or use in damp locations. Those with suffix “WO” are listed for WET LOCATIONS with cover open in continuous use. All plates are gasketed and self-closing.

Accessories

Description	Catalog Number
Sub-plate for mounting and weatherproofing flanged devices with mounting centers of 1.76", 1.94" or 2.13" such as HBL7556, HBL4716, etc. when used with a HBL7420 or HBL7425WOA type weatherproof plate.	7452[•]
Adapter plate for mounting HBL7423WO, HBL7424WO, HBL7425WOA or HBL7420 plates to standard boxes.	HBL7349[•]

Note: [•]Not UL Listed.





HBL20405



HBL7349

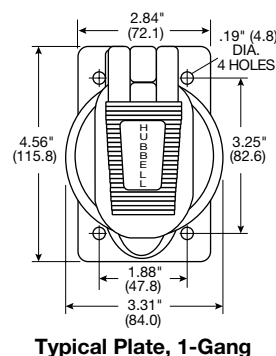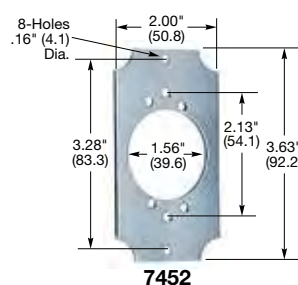Dimensions in Inches (mm)



IP44 SUITABILITY

For Receptacles with Face Diameters of 1.36–1.39 in. (34.5–35.3)

Description	Catalog Number
Thermoplastic, wet and damp locations with cover “open”, gray.	HBL7423WO
Thermoplastic, wet and damp locations with cover “open”, yellow.	HBL74CM23WO
Cast aluminum, wet location only when cover “closed” and damp locations.	HBL7420
Cast aluminum, no lift cover, NOT weatherproof.	HBL7320*



HBL7423WO

For Switches and Receptacles with Face Diameters of 1.55–1.58 in. (39.4–40.1)

Description	Catalog Number
Thermoplastic, wet and damp locations with cover “open”, gray.	HBL7425WOA
Thermoplastic, wet and damp locations with cover “open”, yellow.	HBL74CM25WOA
Thermoplastic, wet and damp locations with cover “open”, white.	HBL74CM25WOAW
Cast aluminum, wet and damp locations with cover “closed.”	HBL7420*
Cast aluminum, no lift cover, NOT weatherproof.	HBL7320*
Thermoplastic, wet and damp locations with cover “open”, gray.	HBL7428WOG**
Thermoplastic, wet and damp locations with cover “open”, yellow.	HBL7428WOY**
Thermoplastic, wet and damp locations with cover “open”, red.	HBL7428WOR**



HBL7425WOA

For Receptacles with Face Diameters of 1.68–1.72 in. (42.7–43.7)

Description	Catalog Number
Thermoplastic, wet and damp locations with cover “open”, gray.	HBL7424WO
Thermoplastic, wet and damp locations with cover “open”, yellow.	HBL74CM24WO
Cast aluminum, wet location only when cover “closed” and damp locations.	HBL3393
Cast aluminum, no lift cover, NOT weatherproof.	HBL3394*



HBL7420

Note: *Cast aluminum lift cover with fibershield for standard toggle and PresSwitch® Switches.

**Features two #6-32 threaded inserts to back mount device to cover.

▲IP20 SUITABILITY.

All weatherproof lift cover plates on this page are UL Listed as “WDL Closed” for use in wet locations with cover closed and in damp locations.

Weatherproof Covers for Single Receptacles on FS/FD Boxes

Note: All weatherproof plates are UL Listed for WET LOCATIONS WITH COVER CLOSED for intermittent use in wet locations or use in damp locations. Those with suffix “WO” are listed for WET LOCATIONS with cover open in continuous use. All plates are gasketed and self-closing.




HBL7320

2011 National Electrical Code (NEC®)

406.9 Receptacles in Damp or Wet Locations.

(A) Damp Locations. A receptacle installed outdoors in a location protected from the weather or in other damp locations shall have an enclosure for the receptacle that is weatherproof when the receptacle is covered (attachment plug cap not inserted and receptacle covers closed). An installation suitable for wet locations shall also be considered suitable for damp locations. A receptacle shall be considered to be in a location protected from the weather where located under roofed open porches, canopies, marquees, and the like, and will not be subjected to a beating rain or water runoff. All 15 and 20A, 125 and 250V nonlocking receptacles shall be listed weather-resistant type. FPN: The types of receptacles covered by this requirement are identified as 5-15, 5-20, 6-15 and 6-20 in ANSI/NEMA WD 6-2002, National Electrical Manufacturers Association Standard for Dimensions of Attachment Plugs and Receptacles.

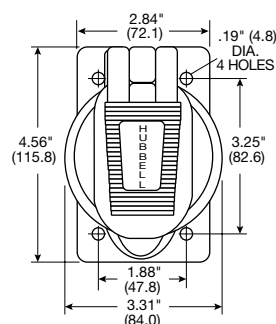(B) Wet Locations. 15 and 20A, 125 and 250V receptacles installed in a wet location shall have an enclosure that is weatherproof whether or not the attachment plug cap is inserted. For other one or two family dwellings, an outlet box hood installed for this purpose shall be listed, and where installed on an enclosure supported from grade as described in 314.23(B) or as described in 314.23(F) shall be identified as “extra-duty”. All 15 and 20A, 125 and 250V nonlocking type receptacles shall be listed weather resistant type.



Typical Plate, 1-Gang



HBL7424WO



HBL3393

Dimensions in Inches (mm)



IP44
SUITABILITY

Weatherproof Thermoplastic Cover For Flanged Inlets and Flanged Receptacles

Description	Catalog Number
For use with 15 and 20A, 2 pole, 2 wire and 2 pole, 3 wire Insulgrip® flanged inlets and flanged receptacles below.	WP1

Straight Blade, 2 pole, 3 wire Flanged Inlets

Flanged Receptacles

	HBL5278C HBL5378C HBL5478C HBL5678C		HBL5279C HBL5379C HBL5479C HBL5679C
---	--	--	--

Twist-Lock®, 2 pole, 2 wire and 2 pole, 3 wire Flanged Inlets

Flanged Receptacles

	HBL8815C HBL7524C HBL4716C HBL4586C HBL4786C		HBL8809C HBL7526C HBL4715C HBL4585C HBL4785C
---	--	--	--



Weatherproof Thermoplastic Cover For Flanged Inlets and Flanged Receptacles

Description	Catalog Number
For 20 and 30A, 3, 4, and 5 wire Insulgrip flanged inlets and flanged receptacles below.	WP2

Twist-Lock®, 2 pole, 3 wire; 3 pole, 4 wire; 4 pole, 4 wire; 4 pole, 5 wire Flanged Inlets

	HBL2315 HBL2325 HBL2335 HBL2345 HBL2355 HBL2415 HBL2425 HBL2435	HBL2445 HBL2455 HBL2465 HBL2515 HBL2525 HBL2535 HBL2615 HBL2625	HBL2635 HBL2645 HBL2655 HBL2715 HBL2725 HBL2735 HBL2745 HBL2755	HBL2765 HBL2775 HBL2815 HBL2825 HBL2835 HBL3325C HBL3334C HBL7408C
---	--	--	--	---

Flanged Receptacles

	HBL2316 HBL2326 HBL2336 HBL2346 HBL2356 HBL2416 HBL2426 HBL2436	HBL2446 HBL2456 HBL2466 HBL2516 HBL2526 HBL2536 HBL2616 HBL2626	HBL2636 HBL2646 HBL2656 HBL2716 HBL2726 HBL2736 HBL2746 HBL2756	HBL2766 HBL2776 HBL2816 HBL2826 HBL2836 HBL3326C HBL3335C HBL7409C
---	--	--	--	---



WP1



WP2

Weatherproof Thermoplastic Cover For Flanged Inlets 50 Amp CS Series

Description	Catalog Number
For 50A, 2 pole, 3 wire and 3 pole, 4 wire flanged inlets below.	HBL7780

Twist-Lock®, 2 pole, 3 wire; 3 pole, 4 wire Flanged Inlets

	CS6377 CS8275 CS8475	CS6375 CS8375 CS8175	HBL3777 HBL3775 HBL7958
---	----------------------------	----------------------------	-------------------------------



HBL7780



IP44
SUITABILITY

Weatherproof Plates

Description	Catalog Number
Clear bubble plate, silicone rubber for use with all general purpose AC toggle and PresSwitch® Switches. Fits both FS/FD and standard boxes.	HBL1795



HBL1795

Weatherproof Plates

Description	Catalog Number
Gray neoprene PresSwitch® Plate. Fits FS/FD and standard boxes.	HBL1750*
Same as above except yellow.	HBL17CM50*



HBL1750

Note: *Not UL Listed.

Weatherproof Plates

Description	Catalog Number
Gray neoprene PresSwitch® Plate with 125V red pilot light. Fits only FS/FD boxes.	HBL1785*
Same as above except yellow.	HBL17CM85*



HBL1785

Note: *Not UL Listed.

Weatherproof Covers

Description	Catalog Number
Cast aluminum lift cover plate with fiber shield. For standard toggle and PresSwitch® Switches. Fits only FS/FD boxes.	HBL7420



HBL7420

Brass Locking Covers Attachment for Switches

Description	Catalog Number
Straight keying (all locks alike) appropriate for most applications. Straight cylinder type lock, each HBL96061 ordered operates on the same key—all locks are keyed alike.	HBL96061*
Same as above except in dull chrome finish to match stainless steel plates.	HBL96061DCH*
Straight keying (individual). Straight cylinder type lock, each HBL96062 ordered operates on a different key. All locks are keyed differently and individually. This type cannot be master keyed.	HBL96062*

Note: *Not UL Listed.



HBL96061
shown with wallplate and
switch (sold separately)

Locking Device

Description	Catalog Number
Locking device for weatherproof covers.	HBLWLC



HBLWLC


HBL5221

Duplex Covers For Vertical Mounting

Description	Dimensions	Catalog Number
	Height x Width x Depth	
Thermoplastic, gray, for FS/FD box mounting.	4.56" x 2.89" x 1.08" (115.8 x 73.4 x 27.4)	HBL5221
Thermoplastic, yellow, for FS/FD box mounting.	4.56" x 2.89" x 1.08" (115.8 x 73.4 x 27.4)	HBL52CM21
Thermoplastic, white, for FS/FD box mounting.	4.56" x 2.89" x 1.08" (115.8 x 73.4 x 27.4)	HBL52CM21W
Thermoplastic, gray, for device mounting.	4.56" x 2.89" x 1.08" (115.8 x 73.4 x 27.4)	HBL5222
Thermoplastic, yellow, for device mounting.	4.56" x 2.89" x 1.08" (115.8 x 73.4 x 27.4)	HBL52CM22
Die cast aluminum, gray, commercial grade, vertical position, device mount.	4.56" x 2.81" x 0.75" (115.8 x 71.4 x 19.1)	WP8V


WP8V

Duplex Covers For Horizontal Mounting

Description	Dimensions	Catalog Number
	Height x Width x Depth	
Cast aluminum, for device mounting.	2.88" x 4.56" x 0.79" (73.2 x 115.8 x 20.1)	HBL5205WO
Cast aluminum, for FS/FD box mounting.	2.88" x 4.56" x 0.79" (73.2 x 115.8 x 20.1)	HBL5206WO
Die cast aluminum, gray, commercial grade, horizontal position, device mount.	2.90" x 4.60" x 0.75" (73.7 x 116.8 x 19.1)	WP8H


HBL5206WO

WP8H

GFCI, Surge and Style Line® Covers

Description	Dimensions	Catalog Number
	Height x Width x Depth	
Die cast aluminum, gray, commercial grade, vertical position, device mount.	4.56" x 2.81" x 0.75" (115.8 x 71.4 x 19.1)	WP26V
Die cast aluminum, gray, commercial grade, horizontal position, device mount.	2.30" x 4.75" x 0.73" (58.4 x 120.7 x 18.5)	WP26H


WP26V

WP26H

Toggle Cover

Description	Dimensions	Catalog Number
	Height x Width x Depth	
Thermoplastic, gray, for FS/FD box mounting.	4.56" x 2.89" x 1.08" (115.8 x 73.4 x 27.4)	HBL5201

Note: All weatherproof plates are UL Listed for WET LOCATIONS WITH COVER CLOSED, for intermittent use in wet locations or use in damp locations. Those with Suffix "WO" are listed for WET LOCATIONS with cover open in continuous use. All plates are gasketed and self-closing.

1-Gang Weatherproof Covers for Vertical Mounting

Description	Dimensions	
	Height x Width x Depth	Catalog Number
Zinc die cast, gray, duplex cover for box mounting.	4.58" x 2.82" x 0.57" (116.3 x 71.6 x 14.5)	RW51470
Zinc die cast, gray, 1.40 in. (35.6) cover for single receptacle or toggle switch for device mounting.	4.56" x 2.81" x 0.88" (115.8 x 71.4 x 22.4)	RW51550*
Zinc die cast, gray, GFCI, Surge and Style Line® cover for device mounting.	4.58" x 2.81" x 0.57" (116.3 x 71.4 x 14.5)	RW51040



1-Gang Weatherproof Covers for Horizontal Mounting

Description	Dimensions	
	Height x Width x Depth	Catalog Number
Zinc die cast, gray, duplex cover for device mounting.	2.82" x 4.57" x 0.79" (71.6 x 116.1 x 20.1)	RW51810
Zinc die cast, gray, 1.40 in. (35.6) cover for single receptacle or toggle switch for device mounting.	2.81" x 4.56" x 0.99" (71.4 x 115.8 x 25.1)	RW51520*
Zinc die cast, gray, GFCI, Surge and Style Line® cover for device mounting.	2.82" x 4.56" x 0.52" (71.6 x 115.8 x 13.2)	RW51020



2-Gang Weatherproof Covers for Vertical Mounting

Description	Dimensions	
	Height x Width x Depth	Catalog Number
Zinc die cast, gray, duplex cover for device mounting.	4.54" x 4.54" x 0.75" (115.3 x 115.3 x 19.1)	RW51320
Zinc die cast, gray, one duplex/one GFCI, Surge and Style Line® cover for box mounting.	4.54" x 4.54" x 0.77" (115.3 x 115.3 x 19.6)	RW51330
Zinc die cast, gray, 1.40 in. (35.6) cover for single receptacle or toggle switch for device mounting.	4.54" x 4.54" x 0.77" (115.3 x 115.3 x 19.6)	RW51380
Zinc die cast, gray, two GFCI, Surge and Style Line® cover for box mounting.	4.54" x 4.56" x 0.73" (115.3 x 115.8 x 18.5)	RW51450



Note: All weatherproof plates are UL Listed for WET LOCATIONS WITH COVER CLOSED, for intermittent use in wet locations or use in damp locations. All plates are gasketed and self-closing.
*cULus Listed.

Dimensions in Inches (mm)



Features and Benefits

Weatherproof Metallic While-In-Use Covers

The NEMA 3R Rated EXTRA DUTY® Metallic and Non-metallic While-in-Use Covers offer weather protection for outlets when they are in use.

- Patented keyhole mounting system allows installation in under a minute
- Pre-configured for GFCI with patented technology for alternate devices
- Lockable tab for OSHA compliance
- Sealed-in-place gasket
- Premium powder coat
- External cord retention chamber
- Each box contains three or six plates to make a variety of configurations (8 or 55)




Metallic EXTRA DUTY® While-In-Use Covers

Description	Dimensions Height x Width x Depth	Catalog Number
Heavy duty die-cast aluminum 1-Gang box with gray lid for vertical mounting offers superior commercial quality 8-in-1 configurations	6.12" X 3.37" X 3.5" (155.4 X 85.6 X 89.0)	WP26E
Heavy duty die-cast metal 1-gang box with gray lid for horizontal mounting; 8-in-1 configurations	4.37" X 5.12" X 3.5" 111.0 X 130.0 X 89.0	WP26EH
Heavy duty die-cast metal 2-gang box with gray lid for vertical mounting; 55-in-1 configurations	6.12" X 5.12" X 3.5" (155.4 X 130.0 X 89.0)	WP262E


1.8
Product Variations

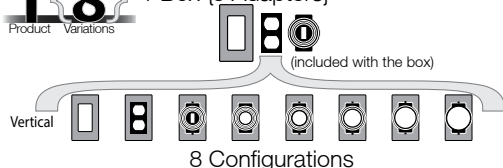1 Box {3 Adapters}




1.8
Product Variations

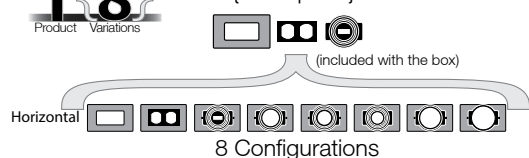1 Box {3 Adapters}




1.55
Product Variations

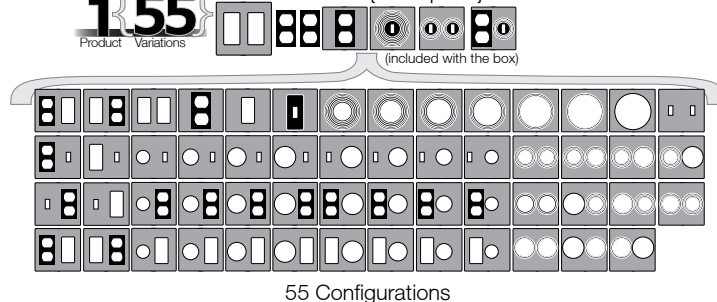1 Box {6 Adapters}



Metallic Cover Dimensions - inches (mm)

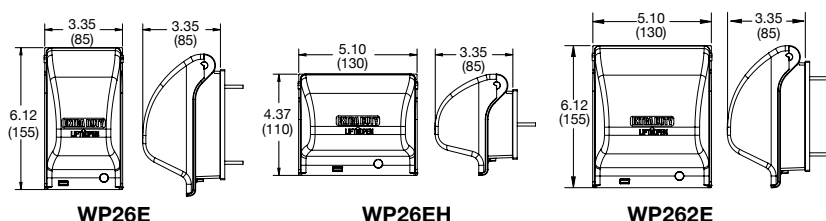

Dimensions in Inches (mm)

Features and Benefits

Weatherproof Non-Metallic While-In-Use Covers

The NEMA 3R Rated EXTRA DUTY® Metallic and Non-metallic While-in-Use Covers offer weather protection for outlets when they are in use.

- Patented keyhole mounting system allows installation in under a minute
- Pre-configured for GFCI with patented technology for alternate devices
- Lockable tab for OSHA compliance
- Sealed-in-place gasket
- High-impact polycarbonate construction provides maximum durability
- Each box contains three or six plates to make a variety of configurations (16 or 55)



Non-Metallic While-In-Use Covers

Description		Dimensions Height x Width x Depth	Standard	EXTRA DUTY®
Standard 1-gang box with clear tinted cover, for horizontal or vertical mounting; 16-in-1 configurations	1.16 Product Variations	5.90" X 4.18" X 2.75" (149.8 X 106.1 X 69.9)	RW57300	RW58300
Extra deep 1-gang box with clear tinted cover, for horizontal or vertical mounting; 16-in-1 configurations	1.16 Product Variations	5.92" X 4.20" X 4.75" (150.4 X 106.7 X 120.7)	RW57350	RW58350
Standard 2-gang box, clear tinted cover, for horizontal or vertical mounting; 55-in-1 configurations	1.55 Product Variations	5.54" X 5.43" X 2.75" (140.7 X 138.0 X 69.9)	RW57750	RW58750



RW57300



RW58300



RW57350





RW58350




RW57750



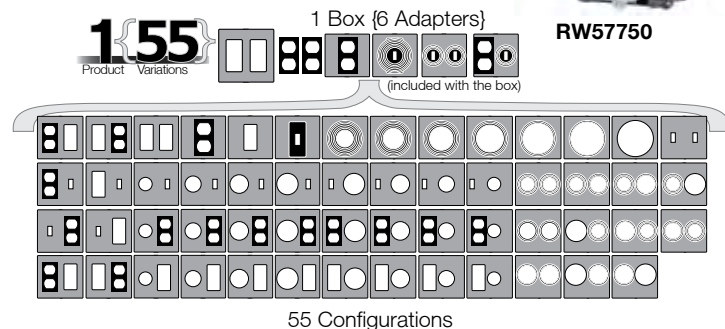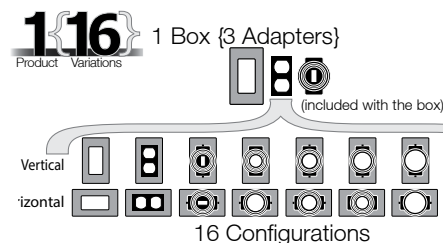RW58750



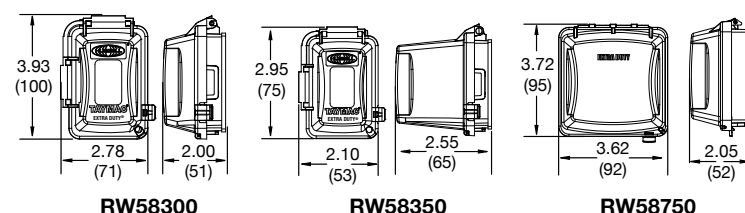Non-Metallic Cover Dimensions - inches (mm)



Dimensions in Inches (mm)



RA38IPK100



RA12IPK100



RA58SSPK100



RA88IPK100

Screws, 6-32 Thread, 100 Count

Description	Color/Material	Catalog Number
Decorator Wallplate Screws, Oval Head Milled Slot, ¾ in. Long – 6-32 Thread, 100 per Box (Order 1 to receive a box of 100)	Almond	RA38ALPK100
	Black	RA38BKPK100
	Brown	RA38PK100
	Gray	RA38GYPK100
	Ivory	RA38IPK100
	Light Almond	RA38LAPK100
	White	RA38WPK100
	Stainless Steel	RA38SSPK100
Standard Wallplate Screws, Oval Head Milled Slot, ½ in. Long – 6-32 Thread, 100 per Box (Order 1 to receive a box of 100)	Almond	RA12ALPK100
	Black	RA12BKPK100
	Brown	RA12PK100
	Gray	RA12GYPK100
	Ivory	RA12IPK100
	Light Almond	RA12LAPK100
	White	RA12WPK100
	Stainless Steel	RA12SSPK100
Standard Wallplate Screws, Oval Head Milled Slot, ¾ in. Long – 6-32 Thread, 100 per Box (Order 1 to receive a box of 100)	Ivory	-
	White	-
	Stainless Steel	RA58SSPK100
Standard Wallplate Screws, Oval Head Milled Slot, 1.0 in. Long – 6-32 Thread, 100 per Box (Order 1 to receive a box of 100)	Ivory	RA88IPK100
	White	RA88WPK100
	Stainless Steel	RA88SSPK100



RA756I



RA40



NS620I



NS621I



HBL7341


Single Count Screws and Accessories

Description	Color	Catalog Number
Blank adapter, to fill a toggle opening.	Brown	RA756
	Ivory	RA756I
	White	RA756W
Blank adapter, to fill a decorator opening.	Ivory	NS620I
	Light Almond	NS620LA
	White	NS620W
Blank adapter, .406" (10.30) dia. hole, to fill a decorator opening.	Ivory	NS621I
	Light Almond	NS621LA
	White	NS621W
Mounting strap, with screws.	Steel	RA40
Brass plated screw, standard slot, .38 in. (9.7) long.	Brass	HBL7341


Dimensions in Inches (mm)



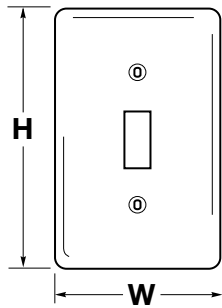
Product Dimensions



Standard Nylon			Mid-Size Nylon		Jumbo-Size Nylon	
Size	Height	Width	Height	Width	Height	Width
1-Gang	4.63" (117.6)	2.88" (73.2)	4.88" (124.0)	3.13" (79.5)	5.25" (133.4)	3.50" (88.9)
2-Gang	4.63" (117.6)	4.69" (119.1)	4.88" (124.0)	4.94" (125.4)	5.25" (133.4)	5.31" (134.9)
3-Gang	4.63" (117.6)	6.50" (165.1)	4.88" (124.0)	6.75" (171.5)		
4-Gang	4.63" (117.6)	8.31" (211.1)	4.88" (124.0)	8.56" (217.4)		
5-Gang	4.63" (117.6)	10.12" (256.1)				
6-Gang	4.63" (117.6)	11.93" (303.0)				

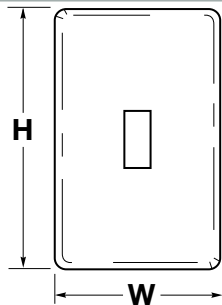

Snap-On Nylon (RCW Series)			Snap-On Nylon (NPS Series)		
Size	Height	Width	Height	Width	Depth
1-Gang	4.68" (118.9)	2.94" (74.7)	4.75" (120.6)	3.00" (76.2)	.25" (6.2)
2-Gang	4.68" (118.9)	4.75" (120.7)	4.75" (120.6)	4.81" (122.2)	.25" (6.2)
3-Gang	4.68" (118.9)	6.56" (166.6)	4.75" (120.6)	6.62" (168.2)	.25" (6.2)
4-Gang	4.68" (118.9)	8.37" (212.6)	4.75" (120.6)	8.44" (214.3)	.25" (6.2)
5-Gang	4.68" (118.9)	10.18" (258.6)			
6-Gang	4.68" (118.9)	11.99" (304.5)			

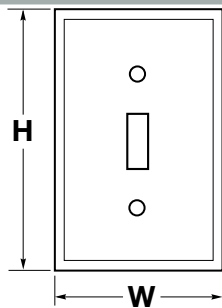


Standard Metal			Painted Metal		Jumbo Metal	
Size	Height	Width	Height	Width	Height	Width
1-Gang	4.50" (114.3)	2.87" (72.9)	4.50" (114.3)	2.75" (69.8)	5.25" (133.4)	3.50" (88.9)
2-Gang	4.50" (114.3)	4.60" (116.8)	4.50" (114.3)	4.56" (115.8)	5.25" (133.4)	5.31" (134.9)
3-Gang	4.50" (114.3)	6.41" (162.8)	4.50" (114.3)	6.38" (162.1)		
4-Gang	4.50" (114.3)	8.22" (208.8)	4.50" (114.3)	8.18" (207.8)		
5-Gang	4.50" (114.3)	10.03" (254.8)	4.50" (114.3)	10.00" (254.0)		
6-Gang	4.50" (114.3)	11.81" (300.0)	4.50" (114.3)	11.81" (300.0)		
7-Gang	4.50" (114.3)	13.68" (347.5)				
8-Gang	4.50" (114.3)	15.44" (392.1)				

Wallplate Openings and Mounting Dimensions

#6-32 Oval Head Screws Typical

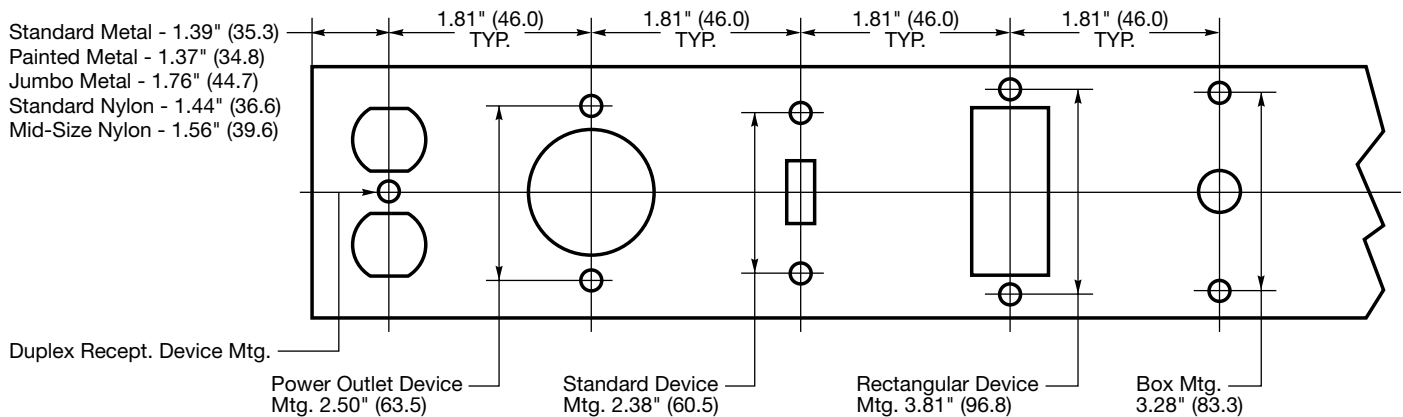Standard Metal - 1.39" (35.3)
 Painted Metal - 1.37" (34.8)
 Jumbo Metal - 1.76" (44.7)
 Standard Nylon - 1.44" (36.6)
 Mid-Size Nylon - 1.56" (39.6)



Note: Specifications are subject to change without notice.

Dimensions in Inches (mm)



Custom Metal Wallplates

How To Select A Custom Metal Wallplate

Step 1:

Determine wallplate material and enter in box marked "Catalog Number"

Smooth Metal Material	Code
Anodized Aluminum	AL
Brass plated steel	BP
Solid brass	BR
Chrome plated steel	CH
Stainless steel 302/304	SS

Determine number of gangs required and enter in box marked "Catalog Number" next to material.

Number of Gangs	Code
1-gang	1
2-gang	2
3-gang	3
4-gang	4
5-gang	5
6-gang	6
7-gang	7
8-gang	8

Enter Catalog Number

♦ **WC*** **SS** **4**

Step 2:

Enter quantity.

Step 3:

Select the custom metal wallplate configuration.


Refer to the custom wallplate configuration chart to select a configuration for each gang in the wallplate. Each configuration has a specific 3-digit code located in the right hand side of the chart on pages N-33 to N-36. Enter this 3-digit configuration code in the corresponding box on the order form grid to match the position required on the finished custom wallplate.

Item No.	Catalog Number	Quantity	Code	Position 1	Position 2	Position 3	Position 4
1	WCSS4		H*	001	149	008	026
2							

Note: *WC and H are preprinted on the distributor order form.

























♦ Number to use for pricing.

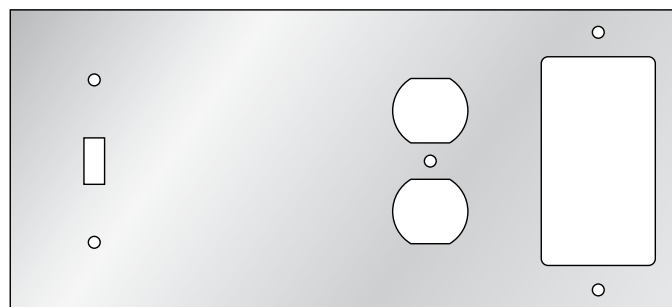The 3-digit numbers listed at the upper right of the Sample Order Form (001, 149, etc.) represent the custom metal wallplate selected on the right. See Configuration Chart and Hubbell Configuration Selector Guide on pages N-33 to N-36 for additional configuration choices.





Configuration Chart

                        	001 Switch.		079 Barrel Key Switch with hash marks.		456 .375" (9.5) Dia. Round Box Mounted.
	007 Single Receptacle. 1.40" ID (35.6) Hole.		080 Barrel Key Switch with On/Off and hash marks.		458 .500" (12.7) Dia. Round Box Mounted.
	008 Duplex Receptacle.		091 Single Receptacle. 1.60" ID (40.5) Hole.		411 .635" (16.1) Dia. Round Box Mounted.
	011 1-gang .635" ID (16.1) Hole Box Mounted with .50" ID (12.7) Nylon Bushing.		098 Single Receptacle. 2.16" ID (54.7) Hole.		435 9-Pin Vertical Box Mounted.
	012 1-gang .635" ID (16.1) Hole Strap Mtd. incl. Strap with .50" ID (12.7) Nylon Bushing.		135 Vertical Mounted Louver.		438 15-Pin Vertical Box Mounted.
	013 Blank Box Mounted.		149 Totally Blank (no mounting holes).		295 25-Pin Vertical Box Mounted.
	014 Blank Strap Mounted incl. Strap.	Coax/Twinax and Modular Jack Openings			314 IBM® Type Opening Box Mounted.
	026 Rectangular Opening.		422 .51" (12.8) Dia. "D" Box Mounted.		415 IBM® Type Opening with One .586" x .762" (14.9 x 19.3).
	055 1-gang .375" ID (9.5) Hole Strap Mounted incl. Strap.		425 .51" (12.8) Dia. "D" Box Mounted.	Voice/Data Opening	
	056 1-gang .375" ID (9.5) Hole Box Mounted.		428 .58" (14.7) Dia. "D" Box Mounted.		470 .542" x .750" (13.8 x 19.0) Vertical Box Mounted.
	057 1-gang .50" ID (12.7) Hole Strap Mounted incl. Strap.		430 .76" (19.2) Dia. "D" Box Mounted.		473 .586" x .762" (14.9 x 19.4) Vertical Box Mounted.
	058 1-gang .50" ID (12.7) Hole Box Mounted.		431 .73" (18.6) Flat Dia. "D" Box Mounted.		476 .586" x .815" (14.9 x 20.7) Vertical Box Mounted.
	078 Barrel Key Switch.		423 .51" (12.8) Dia. "D" Box Mounted.		477 .586" x .815" (14.9 x 20.7) Vertical Box Mounted.
			426 .51" (12.8) "D" Box Mounted.		480 .575" x .783" (14.6 x 19.9) Vertical Box Mounted.
			429 .47" (12) Flat Dia. "D" Box Mounted.		
			431 .73" (18.6) Flat Dia. "D" Box Mounted.		

Note: For detailed dimensions of the above configurations, see pages N-34 to N-36. Available in smooth metal, standard size only up to and including 8-gang type.

IBM® is a registered trademark of International Business Machines Corporation.



Configuration Chart (Continued)

	Configuration 001 Toggle Switch Plate.		Configuration 026 GFI/Rectangular Opening.
	Configuration 007 Single 15 or 20A Straight Blade Receptacle. 15A Twist-Lock® Receptacle.		Configuration 055 Single .375" (9.5) Telephone (Strap Mount).
	Configuration 008 Duplex Receptacle.		Configuration 056 Single .375" (9.5) Telephone (Box Mount).
	Configuration 011 Single .635" (16.1) Telephone (Box Mount).		Configuration 057 Single .50" (12.7) Telephone (Strap Mount).
	Configuration 012 Single .635" (16.1) Telephone (Strap Mount).		Configuration 058 Single .50" (12.7) Telephone (Box Mount).
	Configuration 013 Blank Plate (Box Mount).		Configuration 078 Barrel Key Switch.
	Configuration 014 Blank Plate (Strap Mount).		Configuration 079 Barrel Key Switch with hash marks.

Note: Specifications are subject to change without notice.



Configuration Chart (Continued)

	Configuration 080 Barrel Key Switch with On/Off and hash marks.		Configuration 411 Dual .635" (16.1) Holes (Box Mount).
	Configuration 091 Single 20 or 30A Twist-Lock® Receptacle.		Configuration 415 IBM® Type and Modular Jack (Box Mount).
	Configuration 098 Single Receptacle, 30 or 50A Straight Blade, 3 Wire Power Outlet.		Configuration 422 Single .505" (12.8) D-Hole (Box Mount).
	Configuration 135 Louvered Plate (Strap Mount).		Configuration 423 Dual .505" (12.8) D-Holes (Box Mount).
	Configuration 149 Totally Blank Plate.		Configuration 425 Single .505" (12.8) D-Hole (Box Mount).
	Configuration 295 RS232 Port Single 25-Pin (Box Mount).		Configuration 426 Dual .505" (12.8) D-Holes (Box Mount).
	Configuration 314 IBM® Type (Box Mount).		Configuration 428 Single .580" (14.7) D-Hole (Box Mount).

Note: Specifications are subject to change without notice.

IBM® is a registered trademark of International Business Machines Corporation.



Configuration Chart (Continued)

	Configuration 429 Dual .580" (14.7) D-Holes (Box Mount).
	Configuration 430 Single .755" (19.2) D-Hole (Box Mount).
	Configuration 431 Dual .755" (19.2) D-Holes (Box Mount).
	Configuration 435 Single 9-Pin RS232 (Box Mount).
	Configuration 438 Single 15-Pin RS232 (Box Mount).
	Configuration 456 Dual .375" (9.5) Round (Box Mount).
	Configuration 458 Dual .50" (12.7) Round (Box Mount).
	Configuration 470 Single Modular Jack (Box Mount).

	Configuration 471 Dual Modular Jack (Box Mount).
	Configuration 473 Single Modular Jack (Box Mount).
	Configuration 474 Dual Modular Jack (Box Mount).
	Configuration 476 Dual Modular Jack (Box Mount).
	Configuration 477 Dual Modular Jack (Box Mount).
	Configuration 479 Single Modular Jack (Box Mount).
	Configuration 480 Dual Modular Jack (Box Mount).

Note: Specifications are subject to change without notice.