

# TASKWORK DIRECT WIRE – 12V XENON

*TaskWork Direct Wire 12V Xenon offers you a simple installation solution for illuminating a task area or adding ambient lighting.*



**10584 BZ**  
30" Fixture shown in Bronze

## Select Appropriate Light Fixture Size & Finish

- 10579 BZ, SS, WH** 7"
- 7" L x 5" W x 1" H
  - 1 light
  - 12V, 18 Watt Xenon bulb included

- 10580 BZ, SS, WH** 12-1/4"
- 12-1/4" L x 5" W x 1" H
  - 2 light
  - 12V, 18 Watt Xenon bulbs included

- 10581 BZ, SS, WH** 21-1/2"
- 21-1/2" L x 5" W x 1" H
  - 3 light
  - 12V, 18 Watt Xenon bulbs included

 
- 10584 BZ, SS, WH** 30"
- 30" L x 5" W x 1" H
  - 4 light
  - 12V, 18 Watt Xenon bulbs included

- 10595 BZ, SS, WH** 40"
- 40" L x 5" W x 1" H
  - 5 light
  - 12V, 18 Watt Xenon bulbs included

## Replacement Bulb

- 10574 CLR**
- 12V, 18 Watt Xenon, clear

## Accessories



- 10588 SI** - Duplex BX cable connector



- 10589 SI** - Connector for NM & BX cable

## AVAILABLE FINISHES


Bronze (BRZ), Brushed Stainless Steel (SS) and White (WH)



**BZ** Bronze




**SS** Brushed  
Stainless Steel

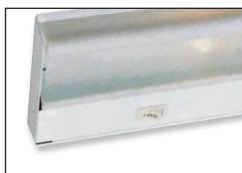

**WH** White

## BACK MOUNT DESIGN

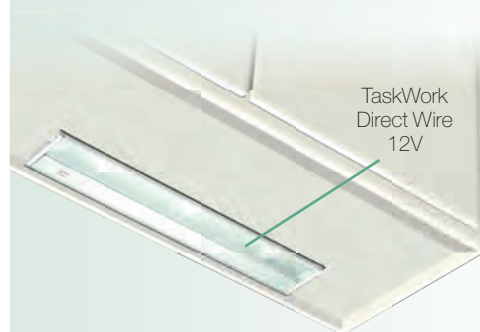


## FEATURES

- Low 1" profile x 5" wide
- Fastener-free hinge assembly
- Keyhole mounting
- NM & BX single cable connector included
- High/Low/On-Off switch

## PERFORMANCE DATA (10580)

|                            |             |
|----------------------------|-------------|
| Lumens/Watt                | 6.1         |
| Light Output FC            |             |
| A – Counter Front          | 14.1        |
| B – Counter Middle         | 31.2        |
| C – Counter Back           | 47.3        |
| D – Counter Wall           | 17.8        |
| CRI<br>(color rendering)   | min 100     |
| CCT<br>(color temperature) | 2700K       |
| Light Source Life          | 10,000 hrs. |

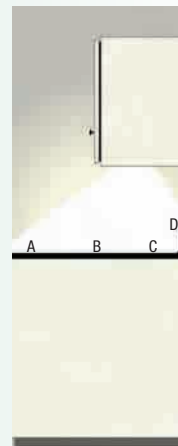

# TASKWORK DIRECT WIRE – 120V XENON

*TaskWork Direct Wire 120V Xenon design features large wiring compartments and multiple 1/2" trade-size knockouts for fast and easy installation.*



**12013 BZ**  
22" Fixture shown in Bronze

## Select Appropriate Light Fixture Size & Finish

### 12011 BZ, SI, WH

7"

- 7" L x 5" W x 1-1/4" H
- 1 light
- 120V, 20 Watt Xenon bulb included

### 12012 BZ, SI, WH

12"

- 12" L x 5" W x 1-1/4" H
- 2 light
- 120V, 20 Watt Xenon bulbs included

### 12013 BZ, SI, WH

21"

- 21" L x 5" W x 1-1/4" H
- 3 light
- 120V, 20 Watt Xenon bulbs included

### 12014 BZ, SI, WH

30"

 
- 30" L x 5" W x 1-1/4" H
- 4 light
- 120V, 20 Watt Xenon bulbs included

## Replacement Bulb

### 12090 CLR

- 120V, 20 Watt Xenon, clear

## Accessories




**10588 SI** - Duplex BX cable connector



**10589 SI** - Connector for NM & BX cable

## BACK MOUNT DESIGN

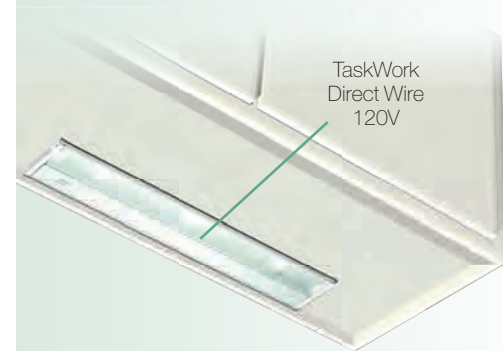


## FEATURES

- 1-1/4" profile x 5" wide
- 120V, 20 Watt Xenon bulb(s)
- High/Low/On-Off switch
- cUL Listed


## PERFORMANCE DATA (12012)

|                         |            |
|-------------------------|------------|
| Lumens/Watt             | 5          |
| Light Output FC         |            |
| A – Counter Front       | 8.6        |
| B – Counter Middle      | 21.1       |
| C – Counter Back        | 38.2       |
| D – Counter Wall        | 13.2       |
| CRI (color rendering)   | min 100    |
| CCT (color temperature) | 2620K      |
| Light Source Life       | 2,500 hrs. |

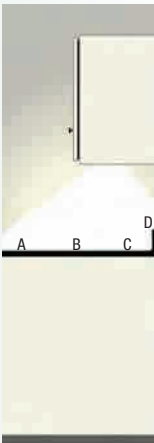


## AVAILABLE FINISHES

Bronze (BRZ), Silver (SI) and White (WH)

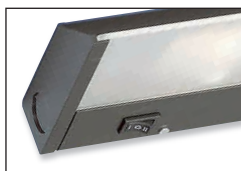

**BZ** Bronze

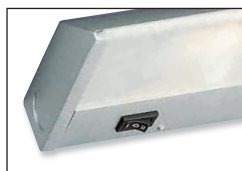

**SI** Silver



**WH** White