

HBB ELECTRIC HYDRONIC BASEBOARD HEATERS



APPLICATIONS

The HBB Series Heaters are ideal whether for new home construction, remodeling or room additions. All it takes is simple mounting and the electrical hookup. No basement boiler. No duct work, chimney, pump or plumbing. Just clean, quiet, comfortable heat, when and where it's needed.

FEATURES

A sheathed electric heating element is totally immersed in a heat-transfer liquid and sealed in a heater-length copper tube. The large diameter reservoir maximizes the volume of heat storage fluid to prolong the thermal constant of the entire heater. All available heat is delivered into the room with strong convection flow. Gentle heat keeps radiating even after the thermostat turns off because of the hydronic elements retention qualities.

GO-ANYWHERE DESIGN. The entire unit mounts flush to any wall and flat on any floor — wood, carpet or tile. The trim, three-inch thick functional design and low operating temperatures allow carpeting to be installed up to and around the baseboard. Efficient air flow is achieved even if the unit is mounted above the floor.

QUALITY INSIDE AND OUT. Heavy-duty welded steel louvered grilles discourage insertion of foreign objects and direct heat outward into the room. Designer-style junction boxes are made of high-strength Lexan® to resist scratches and wear marks. Corrosion resistant aluminum fins are pressure-fitted to copper tubing to assure rapid heat transfer and air flow. Built-in cut-off automatically shuts down the heater should any overheating occur.



NAVAJO WHITE FINISH



CATALOG NUMBER	UPC 6-85360	VOLTS	WATTS	AMPS	LGTH.	SHIP WT. (LBS.)
HBB500	03577 2	120	500	4.2	28 inches	10
HBB508	03580 2	208	500	2.4		
HBB504	03578 9	240/208	500/375	2.1/1.8	34 inches	12
HBB750	03581 9	120	750	6.3		
HBB758	03584 0	208	750	3.6		
HBB754	03582 6	240/208	750/563	3.1/2.7		
HBB1000	03562 8	120	1000	8.3	46 inches	15
HBB1008	03565 9	208	1000	4.8		
HBB1004	03563 5	240/208	1000/750	4.2/3.6	58 inches	19
HBB1250	03566 6	120	1250	10.4		
HBB1258	03569 7	208	1250	6	70 inches	22
HBB1254	03567 3	240/208	1250/938	5.2/4.5		
HBB1500	03570 3	120	1500	12.5	94 inches	30
HBB1508	03573 4	208	1500	7.2		
HBB1504	03571 0	240/208	1500/1125	6.3/5.8		
HBB2008	03576 5	208	2000	9.6		
HBB2004	03574 1	240/208	2000/1500	8.3/7.2		

ACCESSORIES & CONTROLS (OPTIONAL)

CATALOG NUMBER	UPC 6-85360	DESCRIPTION	SHIP WT. (LBS.)
HBBT1	03557 4	25 amp @ 120-277 VAC Single Pole Thermostat Snap Action Type. Field Installed in Junction Box.	1
HBBT2	03559 8	25 amp @ 120-277 VAC Double Pole Thermostat Snap Action Type. Field Installed in Junction Box.	1
HBBT1TP	03558 1	Same as Model HBBT1 except Tamper resistant.	1
HBBT2TP	03560 4	Same as Model HBBT2 except Tamper resistant.	1
*HBBAC	03538 3	Air Conditioner Outlet Section, 20 amps @ 208/240 VAC.	2
HBBDR	03542 0	Duplex Receptacle Section, 15 amps @ 120 VAC.	2
HBBSDR120	14797 0	2 Pole Disconnect switch /120v receptacle	3
HBBWS	03561 1	8" Blank Wiring Section	1
HBBLVR0	03547 5	Low Voltage Relay Control Section, 25 amps @ 120 VAC.	3
*HBBLVR8	03550 5	Low Voltage Relay Control Section, 25 amps @ 208 VAC.	3
HBBLVR4	03548 2	Low Voltage Relay Control Section, 25 amps @ 240 VAC.	3
HBBDCS2	03539 0	2 Pole Disconnect Switch Section.	2
*CBDBS2	01453 1	2' Blank Section.	6
*CBDBS3	01454 8	3' Blank Section	8
*CBDBS4	01455 5	4' Blank Section.	11
*CBDBS5	01456 2	5' Blank Section.	14
*CBDBS6	01457 9	6' Blank Section.	16
*CBDBS8	01458 6	8' Blank Section.	22
*CBDCIC	01460 9	Inside Corner.	1
*CBDCOC	01461 6	Outside Corner	1

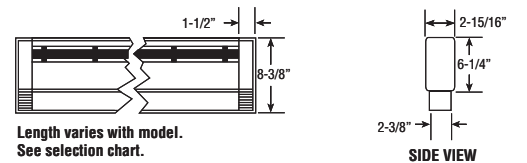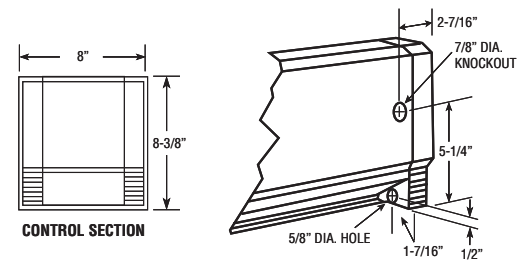

** HBBAC - HBBDR - HBBLVR - HBBWS accessories add 8" to baseboard length