
 
 







# Wall Plates Toggle Switch Openings

Standard Size Plastic & Metal

 Description	Color	Nylon	Thermoset	Metal	
		TradeMaster® Plates	Smooth	Material	Smooth
<b>Toggle Switch Openings</b>					
<b>One Gang</b> 	Ivory White Brown Gray Black Red Light Almond	TP1-I TP1-W TP1 TP1-GRY TP1-BK TP1-RED TP1-LA	SP1-I SP1-W SP1 SP1-GRY  SP1-LA	Aluminum Brass Polished Brass 430S/S 302S/S Brushed Bronze Chrome	SA1 SB1 SB1-PB SL1 SS1 SB1-BZ SB1-CH
<b>Two Gang</b> 	Ivory White Brown Gray Black Red Light Almond	TP2-I TP2-W TP2 TP2-GRY TP2-BK TP2-RED TP2-LA	SP2-I SP2-W SP2 SP2-GRY  SP2-LA	Aluminum Brass Polished Brass 430S/S 302S/S Brushed Bronze Chrome	SA2 SB2 SB2-PB SL2 SS2 SB2-BZ SB2-CH
<b>Three Gang</b> 	Ivory White Brown Gray Black Red Light Almond	TP3-I TP3-W TP3 TP3-GRY TP3-BK TP3-RED TP3-LA	SP3-I SP3-W SP3 SP3-GRY  SP3-LA	Aluminum Brass Polished Brass 430S/S 302S/S Brushed Bronze Chrome	SA3 SB3 SB3-PB SL3 SS3 SB3-BZ SB3-CH
<b>Four Gang</b> 	Ivory White Brown Gray Black Red Light Almond	TP4-I TP4-W TP4 TP4-GRY TP4-BK TP4-RED TP4-LA	SP4-I SP4-W SP4 SP4-GRY  SP4-LA	Aluminum Brass Polished Brass 430S/S 302S/S	SA4 SB4 SB4-PB SL4 SS4
<b>Five Gang</b> 	Ivory White Brown Gray Black Light Almond	TP5-I TP5-W TP5 TP5-GRY TP5-BK TP5-LA	SP5-I SP5-W SP5 SP5-GRY  SP5-LA	Brass Polished Brass  302S/S	SB5 SB5-PB  SS5
<b>Six Gang</b> 	Ivory White Brown Gray Black Light Almond	TP6-I TP6-W TP6 TP6-GRY TP6-BK TP6-LA	SP6-I SP6-W  SP6-GRY  SP6-LA	Polished Brass  302S/S	SB6-PB  SS6
<b>Seven Gang</b> 				302S/S 302S/S Painted Ivory 302S/S Painted White	SS601 SS601-I SS601-W
<b>Eight Gang</b> 				302S/S 302S/S Painted Ivory 302S/S Painted White	SS602 SS602-I SS602-W

# Wall Plates Specifications



Thermoset SP Series



Nylon TP Series



Screwless Polycarbonate SW Series

### Application

Pass & Seymour/Legrand's broad line of Standard Size Plastic and Metal Wall Plates features the most complete range of types, sizes, colors, and finishes available. Choose from more than 1,900 standard plates in non-combustible thermoset plastic material, self-extinguishing nylon material, screwless polycarbonate material, or attractively finished metal, for residential, commercial, institutional, and industrial applications. All plastic wall plates color match to Pass & Seymour/Legrand devices.

### Thermoset Plastic Wall Plates Features

- Molded of non-combustible mar-proof material.
- Available in "SP" series in Standard, Junior-Jumbo, and Jumbo sizes.
- Seven standard colors available – Ivory, White, Brown, Gray, Black, Red, and Light Almond.
- Individually wrapped with color-matching screws.
- Resistant to discoloration, grease, oil, solvent and moisture.
- Nominal thickness, .070"

### TradeMaster® Thermoplastic Wall Plates Features

- Molded of rugged, practically indestructible self-extinguishing nylon. ("TP" series only.)
- Available in "TP" series, extra 3/16" width and height than Standard size plates; and "TPJ" series, extra 3/16" width and height than Junior-Jumbo size plates.
- Available in Ivory, White, Brown, Gray, Black, Blue, Orange, Red, and Light Almond.
- Preferred for hospital, industrial, institutional, and other high-abuse applications.
- Nominal thickness, .070"

### Screwless Polycarbonate Wall Plates Features

- Molded of .065" thick polycarbonate with matte finish.
- Subplate made of .042" zinc-plated steel.
- Available in "SW" series, extra 1/8" width and height than Standard size plates.
- Available in Ivory, White, Gray, Black, and Light Almond.
- Oversized opening to accommodate all NEMA 26 decorator-style openings.

### Metal Wall Plates Features

- Constructed of corrosion-resistant stainless steel, brass, aluminum, chrome, brushed bronze or galvanized steel.
- Standard, Jumbo, and Tandem size plates available, as well as special Panel size plates up to 5-gangs high and 10-gangs wide.
- Packaged in protective film, with finish-matching screws.
- Variety of special plated finishes. Paintable to match plastic plates.
- Can be silk-screened or engraved, and custom punched with over 300 opening styles.

### Materials

- Type 302 Stainless Steel, non-magnetic, .032" nominal thickness, brushed finish. This alloy contains 18% chromium and 8% nickel for superior resistance to corrosion. Recommended for use in food processing plants, dairies, chemical plants, and other industrial, institutional, and commercial applications where corrosive atmospheres exist.
- Type 430 Stainless Steel, magnetic, .032" nominal thickness, brushed finish. Less corrosion-resistant than Type 302, but ideal for general service in high abuse applications in industrial plants, commercial, and institutional buildings.
- Chrome, Brushed and Polished Brass, .040" thick. 70% copper, 30% zinc alloy gives warm, appealing finish to modern decor as well as retrofit applications. Lacquered to prevent corrosion.
- Aluminum, .040" thick. Lustrous satin finish. Lacquered to prevent corrosion.
- Galvanized Steel. Used only for Handy Box Plates.
- Brushed Bronze, .040" thick. 90% copper, 10% zinc. Lacquered to prevent corrosion.



302 Stainless Steel



Polished Brass



Brushed Brass




Aluminum

# Wall Plates Specifications

Pass & Seymour




Standard Size Wall Plates					
<ul style="list-style-type: none"> <li>Standard size wall plates for all applications.</li> <li>Best fit for surface mount boxes.</li> </ul>			<ul style="list-style-type: none"> <li>Available in plastic and metal only.</li> </ul>		
Dimensions					
1 gang	2.75" x 4.5"	4 gang	8.125" x 4.5"	7 gang	13.62" x 4.5"
2 gang	4.56" x 4.5"	5 gang	10" x 4.5"	8 gang	15.44" x 4.5"
3 gang	6.375" x 4.5"	6 gang	11.812" x 4.5"		

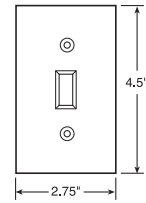


STANDARD

TradeMaster® Wall Plates					
<ul style="list-style-type: none"> <li>Extra 3/16" width and height than Standard size wall plates.</li> <li>Provide better sheet rock coverage with standard size appearance.</li> <li>Available in unbreakable nylon 6 construction only.</li> <li>Screws pre-installed in the duplex, toggle, and decorator single gang plates.</li> </ul>					
Dimensions					
1 gang	2.9375" x 4.6875"	3 gang	6.563" x 4.6875"	5 gang	10.188" x 4.6875"
2 gang	4.75" x 4.6875"	4 gang	8.375" x 4.6875"	6 gang	12" x 4.6875"

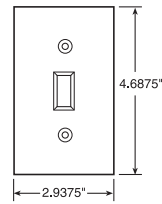


TRADEMASTER STANDARD

Screwless Polycarbonate Wall Plates					
<ul style="list-style-type: none"> <li>Extra 1/8" width and height than Standard size wall plates.</li> <li>Provide better sheet rock coverage with standard size appearance.</li> <li>Molded of .065" thick polycarbonate.</li> <li>Subplate made of .042" zinc-plated steel.</li> <li>Oversized opening to accommodate all NEMA 26 decorator-style openings.</li> </ul>					
Wall Plate Dimensions					
1 gang	3.10" x 4.87"	3 gang	6.724" x 4.87"	5 gang	10.348" x 4.87"
2 gang	4.912" x 4.87"	4 gang	8.536" x 4.87"	6 gang	12.16" x 4.87"
Subplate Dimensions					
1 gang	2.85" x 4.62"	3 gang	6.474" x 4.62"	5 gang	10.098" x 4.62"
2 gang	4.662" x 4.62"	4 gang	8.286" x 4.62"	6 gang	11.910" x 4.62"

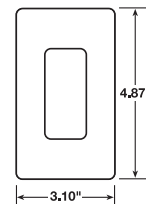


SCREWLESS

Junior-Jumbo Wall Plates					
<ul style="list-style-type: none"> <li>Extra 3/8" width and height than Standard size wall plates.</li> <li>Additional coverage for sheet rock gaps.</li> </ul>			<ul style="list-style-type: none"> <li>Available in plastic and metal only.</li> </ul>		
Dimensions					
1 gang	3.125" x 4.87"	3 gang	6.75" x 4.87"		
2 gang	4.93" x 4.87"	4 gang	8.56" x 4.87"		

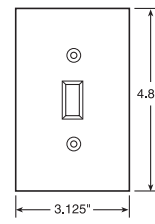


JUNIOR-JUMBO

TradeMaster Jumbo Wall Plates					
<ul style="list-style-type: none"> <li>Extra 3/16" width and height than Junior-Jumbo size wall plates.</li> <li>Provide additional coverage for sheet rock gaps, matching the appearance of the TradeMaster Plates.</li> <li>Available in unbreakable nylon 6 construction only.</li> <li>Screws pre-installed in the duplex, toggle, and decorator single gang plates.</li> </ul>					
Dimensions					
1 gang	3.3125" x 5.0625"	3 gang	6.9375" x 5.0625"		
2 gang	5.125" x 5.0625"	4 gang	8.75" x 5.0625"		

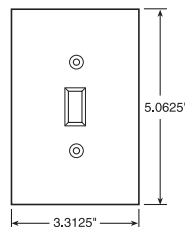

TRADEMASTER JUMBO

Jumbo Wall Plates					
<ul style="list-style-type: none"> <li>Extra 3/4" width and height than Standard size wall plates.</li> <li>Largest size wall plates to cover larger wall damage.</li> </ul>			<ul style="list-style-type: none"> <li>Available in plastic and metal only.</li> </ul>		
Dimensions					
1 gang	3.5" x 5.25"	3 gang	7.12" x 5.25"		
2 gang	5.31" x 5.25"	4 gang	8.93" x 5.25"		

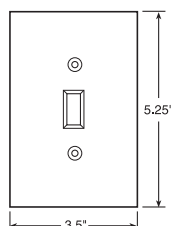

JUMBO