


PERIMALITER® WALLPACK PGM3 GLASS SERIES	Cat.#		 HUBBELL Outdoor Lighting
	Job	Type	
			Approvals

APPLICATIONS


- Perimeter lighting for safety and security. High performance with wide lateral spread

SPECIFICATIONS

- Cast aluminum door frame with prismatic glass refractor. Door seals to housing gasket with twin Hubbell Gard® captive fasteners
- Die cast aluminum housing allows firm mounting over recessed junction boxes or on flat surfaces for 1/2" surface conduit. Casting dissipates ballast heat for long life. Top hub supplied for field installation of button photo control, ordered separately
- Specular aluminum reflector with kicker panels drive maximum lamp lumens to the refractor prisms. Vertical socket position with these optics provide six to one spacing to mounting height ratio for maximum spacing or better uniformity, greater lumens and lamp life
- PGM features 100-250W pulse start metal halide. Many listings include lamp for contractor convenience; see standard selections below
- Dark bronze 800 Series powder paint finish standard on frame and housing. For optional finishes, black, gray, white and platinum consult factory

LISTINGS

- Listed to UL1598 for use in wet locations

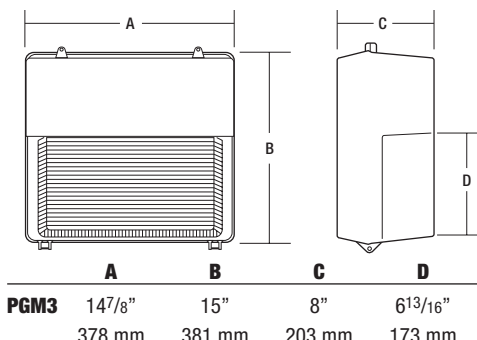

ORDERING INFORMATION

ORDERING EXAMPLE: PGM3-150P-18-BZ

Catalog Number	Wattage	Lamp Type	Voltage	Ballast	Lamp Included/Base	Weight lbs. (kg)
Pulse Start Metal Halide						
PGM3-100P-18-BZ-L	100	PSMH	Quad Tap	HX-HPF	Yes/Med.	25 (11.3)
PGM3-150P-18-BZ	150	PSMH	Quad Tap	HX-HPF	No/Med.	25 (11.3)
PGM3-150P-18-BZ-L	150	PSMH	Quad Tap	HX-HPF	Yes/Med.	25 (11.3)
PGM3-250P-18-BZ	250	PSMH	Quad Tap	CWA-HPF	No/Mog.	27 (12.2)
PGM3-250P-18-BZ-L	250	PSMH	Quad Tap	CWA-HPF	Yes/Mog.	27 (12.2)
Less Ballast						
PGM3-LB	250Max	None	None	None	No/Mog.	15 (6.8)

- Notes:
- L - Indicates lamp included with the fixture
 - Above units (-18) are Quad Tap (120,208,240,277V) 480V available on 150/250w units, change 8 to 5
 - For TriTap Canadian ballast (120,277,347V) change 8 to 6
 - BZ - Dark Bronze finish is standard; For alternate finish - consult factory for price adder and availability
 - BL - Black, GR - Gray, WH - White, PS - Platinum
 - 50HZ ballast is available - consult factory

ORDERING INFORMATION

ACCESSORIES - Order Separately

Catalog Number	Description
PBT-1	Photocontrol, button type, 120V
PBT-234	Photocontrol, button type, 208, 240, 277V
PG-PS ¹	Polycarbonate shield for refractor
PG-WG ¹	Wire guard for refractor
PVL3V	Full cut-off visor, formed aluminum, bronze finish

¹ Guard and shield can be used on the same fixture

REPLACEMENT PARTS

Catalog Number	Description
80033990104	Aluminum/glass front, bronze (glass conversion)



HUBBELL
Outdoor Lighting

Hubbell Outdoor Lighting • 701 Millennium Boulevard • Greenville, SC 29607 • Phone: 864-678-1000

Due to our continued efforts to improve our products, product specifications are subject to change without notice.

© 2016 HUBBELL OUTDOOR LIGHTING, All Rights Reserved • For more information visit our website: www.hubbelloutdoor.com • Printed in USA

PGM-SPEC 1/17