

Application


- Octagon boxes are used in the installation of ceiling or wall lighting fixtures

Product Features


- Combination screw heads provide for faster installation
- RACO® offers a variety of labor saving mounting brackets that allow for easy positioning of box along studs or joists
- See Box Selection section in the front of this catalog for complete description of bracket types and features

Compliance


- UL – File E195978

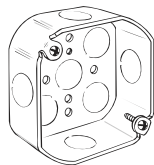


125, 8125

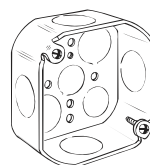


126

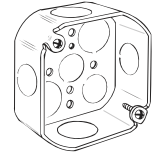

127, 8127

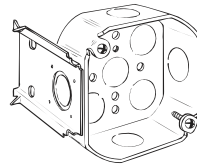

158

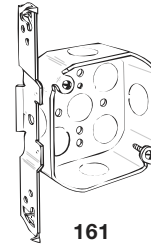


161

ORDERING INFORMATION - DIMENSIONS

4" OCTAGON BOX – 1-1/2" DEEP – DRAWN WITH CONDUIT KO'S – 15.5 CUBIC INCHES							
CATALOG NUMBER	DESCRIPTION BRACKET & SETBACK	KNOCKOUTS		STD. PKG.	UPC BAR CODE	MAX. RECOMMENDED SUPPORT LOADS	
		SIDES	BOTTOM			CEILING FAN (DYNAMIC) LBS.	FIXTURE (STATIC) LBS.
		COND.	COND.				
125	—	4-1/2"	5-1/2"	50	—	No	50
8125	—	4-1/2"	5-1/2"	50		No	50
126	—	4-3/4"	3-1/2" 2-3/4"	50	—	No	50
127	—	2-1/2" 2-3/4"	3-1/2" 2-3/4"	50	—	No	50
8127	—	2-1/2" 2-3/4"	3-1/2" 2-3/4"	50		No	50
158	J brkt., 3/8" or 1/2"	4 –1/2"	5-1/2"	50		No	50
161	TS brkt., 1/2"	3-1/2"	5-1/2"	50		No	50

4" OCTAGON

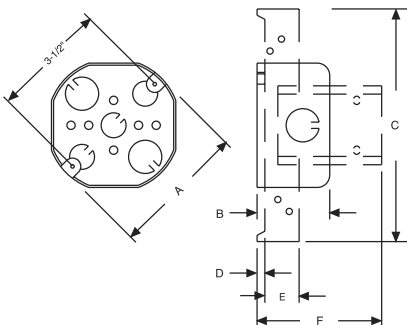

DIMENSIONS						
CATALOG NUMBER	A	B	C	D	E	F
125, 8125	4"	1-9/16"	—	—	—	—
126	4"	1-9/16"	—	—	—	—
127, 8127	4"	1-9/16"	—	—	—	—
158	4"	1-9/16"	—	1/2"	—	3-1/8"
161	4"	1-9/16"	7-5/32"	1/2"	1-1/4"	—

**RACO®**