



SPECIFICATIONS AND FEATURES
<ul style="list-style-type: none"> <li>• IP 54 Suitability Rating</li> <li>• Glass-filled thermoplastic cover and plate for outstanding impact resistance and durability</li> <li>• Dual gaskets, one under plate and one under lid, for weather-resistant fit</li> <li>• UL Listed and CSA certified for wet locations with cover closed</li> </ul>

ENVIRONMENTAL	
FLAMMABILITY	OPERATING TEMP.
Rated V-2 per UL 94	-40°C to 60°C

STANDARDS & CERTIFICATIONS		
CSA Certified	UL Listed	NOM
#LR-16347	#E13397	#057



FD BOX — See Section D

7420-CR



WP1

WP2



7788-CR




7770


## Industrial Weather-Resistant Covers

DESCRIPTION	COLOR	CAT. NO.
For use with 15-amp locking, 15-amp and 20-amp straight-blade flanged inlets and outlets	GRAY	WP1
For use with 20-amp and 30-amp 3-, 4-, and 5-wire locking flanged inlets and outlets; 30-amp and 50-amp 3-wire power receptacles	GRAY	WP2
For use with 20-amp and 30-amp single locking receptacles and FS/FD boxes	YELLOW	7420-CR
For use with 50-amp single locking receptacles and FS/FD boxes	GRAY	7770
For use with 50-amp single locking receptacles and FS/FD boxes	YELLOW	7788-CR



III. 1 - WP1 Weather-Resistant Cover Installation

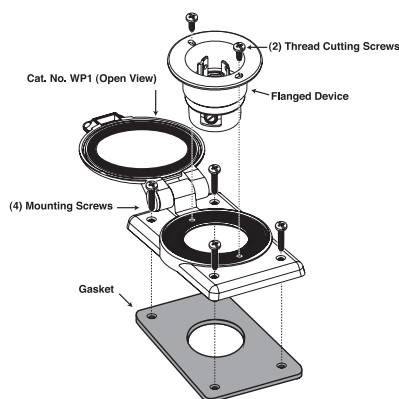


III. 3 - WP2 Weather-Resistant Cover Installation

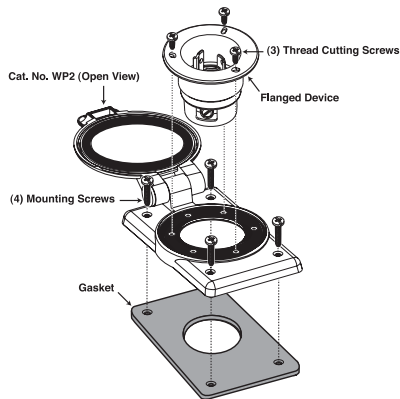

III. 5 - 7420-CR Weather-Resistant Cover Installation

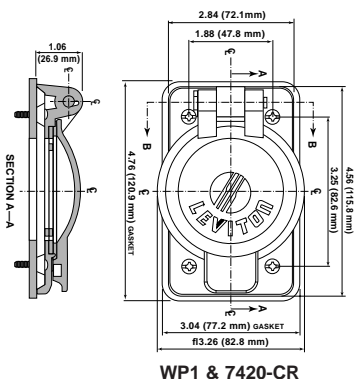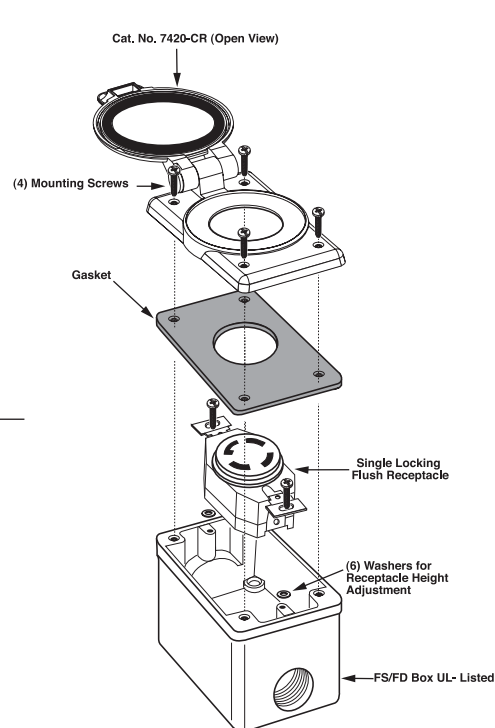

WP1 & 7420-CR

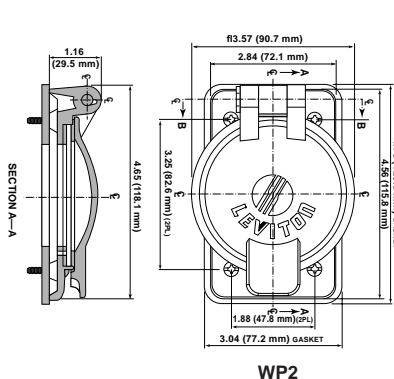

WP2

All wallplates are UL Listed and CSA Certified.