




 



 

 
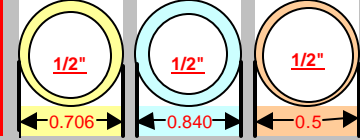


NOMINAL TRADE SIZE																	
	EMT 1 HOLE CLAMP	EMT 2 HOLE STRAP	RIGID 1 HOLE CLAMP	RIGID 2 HOLE STRAP	1 HOLE CABLE & TUBE	2 HOLE CABLE & TUBE	BRASS 1 HOLE CLAMP for Cable & Tube	SAFETY CLAMP	DUPLEX for "UF", "PVC" & "ROMEX"	SERVICE ENTRANCE CABLE	1 HOLE CLAMP	SERVICE ENTRANCE CABLE	2 HOLE STRAP	FITS UF CABLE "ROMEX" & "P.V.C."	1 HOLE CLAMP		
3/32"					10543-S									"UF" CABLE			
1/8"			10010-S	10020-S	10585-S		17200-B			1 - 3	10793-S	6 - 3 "UF"	10074-S	10 - 2	15323-S		
5/32"					10587-S					4 - 3	(19184-S)	8 - 3	10678-S	12 - 3	19178-S		
3/16"					10590-S		17200-B		10690-S	8-3 & 8-AWG-3C	10076-S	8-3 & 8-AWG-3C	10078-S	12-2,14-2,16-3 S.P.T. CORD	10072-S		
1/4"			10011-S	10021-S	11101-S 11151-S	12101-S	17201-B 14151-B	16101-S 17101-S	10691-S 12701-S	6 - 3	10082-S	6 - 3	10052-S				
5/16"					11102-S 11152-S	12201-S	17202-B 14152-B	16102-S 17102-S	10692-S 12702-S	6 - 2 & 8 - 1	10782-S	6 - 2 & 8 - 1	10752-S				
3/8"			10012-S 10712-S	10022-S	11103-S 11153-S	12301-S	17203-B 14153-B	16103-S 17103-S	10693-S 12703-S	4 - 3	10084-S 10784-S	4 - 3	10054-S 10754-S	1 HOLE CLAMP			
7/16"					11104-S	11204-S	17204-B 14154-B		13104-S	2 - 3	10085-S	2 - 3	10055-S	P.V.C. & ROMEX CABLE			
1/2"	10043-S* 10743-S	10063-S* 10763-S	10013-S* 10713-S*	10023-S* 10723-S	11105-S	11205-S	17205-B 14155-B	16105-S 17105-S	12705-S / "EMT"	2 - 3	10086-S 10786-S	2 - 3	10056-S 10756-S	12 - 3, 14 - 3	19104-S		
9/16"					11106-S	11206-S	17206-B 14156-B		13106-S	2 - 3 (OLD)	10790-S	2 - 3 (OLD)	10058-S 10758-S	10 - 3, 10 - 3 with ground conv	19103-S		
5/8"					11108-S	11208-S	17208-B 14158-B	16108-S 17108-S	12708-S	2/0 - 3	10796-S	4/0 - 2	10061-S	12 - 2, 14 - 2	10081-S		
11/16"					11110-S	11210-S	14160-B		13110-S	4/0 - 2 & 2/0 - 1	10797-S	4/0 - 2 & 2/0 - 1	10062-S	12 - 2, 14 - 2	10080-S		
3/4"	10044-S* 10744-S*	10064-S* 10764-S	10014-S* 10714-S*	10024-S* 10724-S	11112-S	11212-S	14162-B	16112-S 17112-S	12712-S	4/0 - 3	10798-S	4/0 - 3	10761-S				
13/16"					11115-S	11215-S			13115-S	2/0 - 3	10795-S	2/0 - 3	10060-S	"STAND OFF" FOR			
7/8"					11120-S	11220-S				2/0 - 2 & 1 - 1	10795-S	2/0 - 2 & 1 - 1	10060-S	1/2" - 9/16" TUBE			
15/16"					11122-S	11222-S				4/0 - 3	10799-S	4/0 - 3	10762-S	1" HIGH	10296-S		
1"	10045-S* 10745-S*	10065-S* 10765-S	10015-S* 10715-S*	10025-S* 10725-S	11125-S	11225-S				SERVICE ENTRANCE CABLE	SMALL HOLE CLAMP	SERVICE ENTRANCE CABLE	SMALL HOLE STRAP	1-1/2" HIGH	10298-S		
1-1/4"	10046-S 10746-S 17146-S	10066-S 10766-S	10016-S* 10716-S*	10026-S* 10726-S	11130-S	11230-S				2 - 3	(19186-S)	2 - 3	(10656-S) (19256-S)*	2 HOLE "SER"	100 AMP 222-4	10623-S 10023-S 10723-S	
1-1/2"	10747-S 17147-S	10067-S 10767-S	10717-S* 17117-S	10027-S* 10727-S	1 HOLE V		"BX" & "MC"			4 - 3	(19184-S)	4 - 3	(10654-S) (19254-S)*	150 AMP 2/0 2/0-1	10065-S 10765-S		
2"	10748-S 17148-S	10068-S 10768-S	10718-S* 17118-S	10028-S* 10728-S	1/8"-3/16"	11100-S with (7/32" hole)		1 HOLE CLAMP	2 HOLE STRAP	8-3 & 8-AWG-3C	(19176-S)	8-3 & 8-AWG-3C	(10678-S) (19278-S)	200 AMP 4/0 4/0-2/0	10025-S 10725-S		
2-1/2"		10029-S* 10729-S	17119-S	10029-S* 10729-S	1/8"-3/16"	11150-S with (9/32" hole)	14-3 - 12-3 & 3/8" FLEX	11105-S with (9/32" hole)	10605-S with (3/16" hole)	6 - 3	(19182-S)	6 - 2 & 8 - 1	(10658-S) (19258-S)	Underlined Parts #			
3"		10030-S* 10730-S	17120-S	10030-S* 10730-S	5/16"-7/16"	10802-S with (7/32" hole)		(19105-S) w (7/32" hole)	(19205-S) w (7/32" hole)	Part # 's Starting with (19__-S) have 7/32" hole		2 - 3 (OLD)	(10652-S) (19252-S)*	Available with a Slotted Hole			
3-1/2"		10031-S* 10731-S	17121-S	10031-S* 10731-S	7/16"-1/2"	19104-S with (7/32" hole)	12-4 - 10-4 & 3/8" SHELL GROUND	11106-S w (9/32" hole)	11206-S w (9/32" hole)	6 - 3		6 - 3	(10652-S) (19252-S)*				
4"		10032-S* 10732-S	17122-S	10032-S* 10732-S	7/16"-1/2"	10804-S with (9/32" hole)				12 - 2 / 14 - 2		12 - 2 / 14 - 2	10051-S + (19251-S)+	(+) Takes ROMEX Cable			
5"			17124-S	10033-S 10733-S	(*) ALUMINUM: AVAILABLE BY CHANGING THE FIRST 3 # TO 144 or 147 & (S) TO (A										12 - 3 / 14 - 3	10806-S^ (19206-S)^	Round Takes Cable 3/8" to
												12 - 2 / 14 - 2	10100-S # 10050-S #	(#) Takes P. V. C. Cable			

NOMINAL TRADE SIZE														
	EMT 1 HOLE CLAMP	EMT 2 HOLE STRAP	RIGID 1 HOLE CLAMP	RIGID 2 HOLE STRAP	1 HOLE CABLE & TUBE	2 HOLE CABLE & TUBE	BRASS 1 HOLE CLAMP for Cable & Tube	SAFETY CLAMP	DUPLEX for "UF", "PVC" & "ROMEX"	SERVICE ENTRANCE CABLE	1 HOLE CLAMP	SERVICE ENTRANCE CABLE	2 HOLE STRAP	FITS UF CABLE "ROMEX" & "P.V.C."
6"			17125-S	10034-S 10734-S	PARTS ENDING IN (S) ARE C.R.S., ZINC PLATED AFTER MFG.						12-2714- 212-214- 2	(19250-S)# (19251-S)+	Design By Von Bergen	2/1/2005

NOMINAL TRADE SIZE OF PIPE	HANGERS WITH NUTS & BOLTS			HANGERS WITHOUT NUTS & BOLTS			HANGERS WITH NUTS & CARRIAGE BOLTS			NOMINAL TRADE SIZE	EMT THIN WALL "OD"	RIGID HEAVY WALL "OD"	TUBE & CABLE "OD"
	(EMT) THIN WALL CONDUIT	(RIGID) HEAVY WALL CONDUIT	CABLE OR TUBE "OD" DIAMETER	(EMT) THIN WALL CONDUIT	(RIGID) HEAVY WALL CONDUIT	CABLE OR TUBE DIAMETER	(EMT) THIN WALL CONDUIT	(RIGID) HEAVY WALL CONDUIT	CABLE OR TUBE DIAMETER				
3/8"		18400-S*			14200-S*			18400-CB*		1/8"		0.405"	0.125"
7/16"										1/4"		0.54"	0.25"
1/2"	18400-S*	18401-S*		14200-S*	14201-S*		18400-CB*	18401-CB*		3/8"		0.675"	0.375"
9/16"										1/2"	0.706"	0.84"	0.5"
5/8"			18400-S*			14200-S*			18400-CB*	3/4"	0.922"	1.05"	0.75"
11/16"										1"	1.163"	1.315"	1"
3/4"	18401-S*	18401-S*	18400-S*	14201-S*	14201-S*	14200-S*	18401-CB*	18401-CB*	18400-CB*	1-1/4"	1.503"	1.66"	1.25"
13/16"										1-1/2"	1.738"	1.9"	1.5"
7/8"										2"	2.195"	2.375"	2"
15/16"										2-1/2"	2.875"	2.875"	2.5"
1"	18402-S*	18402-S*	18401-S*	14202-S*	14202-S*	14201-S*	18402-CB*	18402-CB*	18401-CB*	3"	3.5"	3.5"	3"
1-1/4"	18403-S	18404-S	18402-S*	14203-S	14204-S	14202-S*	18403-CB	18404-CB	18402-CB*	3-1/2"	4"	4"	3.5"
1-1/2"	18404-S	18405-S	18403-S	14204-S	14205-S	14203-S	18404-CB	18405-CB	18403-CB	4"	4.5"	4.5"	4"
1-3/4"			18404-S			14204-S			18404-CB	4-1/2"		5"	4.5"
2"	18406-S#	18406-S#	18405-S	14206-S#	14206-S#	14205-S	18406-CB#	18406-CB#	18405-CB	5"		5.563"	5"
2-1/2"	18407-S#	18407-S#	18406-S#	14207-S#	14207-S#	14206-S#	18407-CB#	18407-CB#	18406-CB#	6"		6.625"	6"
3"	18408-S#	18408-S#	18407-S#	14208-S#	14208-S#	14207-S#	18408-CB#	18408-CB#	18407-CB#				
3-1/2"	18409-S<	18409-S<	18408-S#	14209-S<	14209-S<	14208-S#	18409-CB<	18409-CB<	18408-CB#				
4"	18410-S<	18410-S<	18409-S<	14210-S<	14210-S<	14209-S<	18409-CB<	18410-CB<	18409-CB<				
4-1/2"			18410-S<			14210-S<			18410-CB<				



HANGERS MADE FROM .062 WITH 9/32" MOUNTING HOLE

* HANGERS MADE OF .048 STEEL

25/64" DIAMETER MOUNTING HOLE

< 33/64" DIAMETER MOUNTING HOLE

NUTS & BOLTS ARE 1 / 4" - 20 THD

HOW TO DETERMINE THE THICKNESS OF A PART

PART # STARTING WITH (100) RANGE FROM .062 TO .93 THICK

PART # STARTING WITH (107) RANGE FROM .93 TO .125 THICK

PART # STARTING WITH (17_) RANGE FROM .125 TO .375 THICK

SLOTTED HOLES ARE AVAILABLE:

BY REPLACING THE FIRST 2 #'S WITH " 18 " ; WHICH ARE UNDER-LINED ON THE OPPOSITE SIDE OF THIS CHART

FOR MORE DETAIL INFORMATION ON PARTS FOUND ON THIS VICTOR CHART; REFER TO THE "PINK PRICE SHEET" FOR THE CORRECT PAGE NUMBER IN THE VICTOR CATALOG

# OF DEVICES	1-5/8" DEEP & 2-1/2" DEEP GANG BOX			1-5/8" DEEP & 2-1/2" DEEP COLLARS			GANG BOX LINE		
	12" & 3/4" KO	1/2" & 3/4" KO	3/4" & 1" KO	12" & 3/4" KO	1/2" & 3/4" KO	3/4" & 1" KO			
2 GANG	VGB158-2	VGB212-2	VGB212-2-341	VCOLL158-2	VCOLL212-2	VCOLL212-2-341			
3 GANG	VGB158-3	VGB212-3	VGB212-3-341	VCOLL158-3	VCOLL212-3	VCOLL212-3-341			
4 GANG	VGB158-4	VGB212-4	VGB212-4-341	VCOLL158-4	VCOLL212-4	VCOLL212-4-341			
5 GANG	VGB158-5	VGB212-5	VGB212-5-341	VCOLL158-5	VCOLL212-5	VCOLL212-5-341			
6 GANG	VGB158-6	VGB212-6	VGB212-6-341	VCOLL158-6	VCOLL212-6	VCOLL212-6-341			
7 GANG	VGB158-7	VGB212-7	VGB212-7-341	VCOLL158-7	VCOLL212-7	VCOLL212-7-341			
8 GANG	VGB158-8	VGB212-8	VGB212-8-341	VCOLL158-8	VCOLL212-8	VCOLL212-8-341			
9 GANG	VGB158-9	VGB212-9	VGB212-9-341	VCOLL158-9	VCOLL212-9	VCOLL212-9-341			
	DEVICE COVERS			BOX COVERS					
# OF DEVICES	NO RISE	1/2" RISE	3/4" RISE	FLAT	TOGGLE	DUPLEX	NO RISE	1/2 RISE	3/4" RISE
2 GANG	VCOVFD-2	VCOV12-2	VCOV34-2	VCOVFL-2	VCOVTS-2	VCOVDR-2	VPTAB158-SQ	VPTAB158-12	VPTAB158-34
3 GANG	VCOVFD-3	VCOV12-3	VCOV34-3	VCOVFL-3	VCOVTS-3	VCOVDR-3	VPTAB212-SQ	VPTAB212-12	VPTAB212-34
4 GANG	VCOVFD-4	VCOV12-4	VCOV34-4	VCOVFL-4	VCOVTS-4	VCOVDR-4	<u>1" RISE</u>	VPTAB158-1	VPTAB212-1
5 GANG	VCOVFD-5	VCOV12-5	VCOV34-5	VCOVFL-5	VCOVTS-5	VCOVDR-5	SPECIAL PARTS		
6 GANG	VCOVFD-6	VCOV12-6	VCOV34-6	VCOVFL-6	VCOVTS-6	VCOVDR-6	C.B.S BAR - CEILING BOX SUPPORT		
7 GANG	VCOVFD-7	VCOV12-7	VCOV34-7	VCOVFL-7	VCOVTS-7	VCOVDR-7	VAC-1 - GANG BOX ADAPTOR COVER		
8 GANG	VCOVFD-8	VCOV12-8	VCOV34-8	VCOVFL-8	VCOVTS-8	VCOVDR-8	VCOV14-3 - 1/4" RISE 3 GANG DEVICE COVER		
9 GANG	VCOVFD-9	VCOV12-9	VCOV34-9	VCOVFL-9	VCOVTS-9	VCOVDR-9	VCOV13 - 1" RISE 3 GANG DEVICE COVER		

Victor Specialties
 1350 Garrison Ave., Bronx NY 10474
 Ph: (718) 893-2763 Fax: (800) 221-3932
 Web Site www.victorspecialties.com

Form CS-102- Rev. 2A 4/17/2006 Made in America