


3310 Series Fan Forced Wall Heater - Without Summer Fan Switch

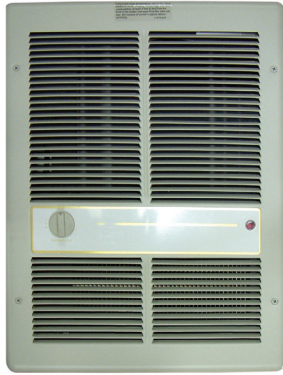

Features

- Powder coated 18 Gauge steel front.
- Automatic reset thermal limit.
- Steel block fin element.
- Weight 22 lbs.
- Vane axial fan blade: 600 RPM / 175 CFM.
- Rough in dimensions: 14-3/16" Wide x 19-15/16" High x 4" Deep.
- Grill dimensions: 15-3/8" Wide x 20-9/64" High.
- Units with dual wattage, factory wired to highest wattage.
- Wattage selectable at time of installation on some models.



Manufactured in U.S.A.

Standard Models

MODELS WITH IN-BUILT DOUBLE POLE THERMOSTAT (50° - 90° F TEMPERATURE RANGE)								
IVORY		WHITE		WATTS	MAX BTU's	VOLTS	AMPS	LIST
UPC 686334	IVORY MODEL	UPC 686334	WHITE MODEL					
326346	E3312T2RP	326483	E3312T2RPW	1000	3413	120	8.3	488
326353	E3313T2RP	326490	E3313T2RPW	1500	5120		12.5	
				750	2560		6.25	
326360	F3316T2RP	326506	F3316T2RPW	4000	13648	208	19.2	496
326377	F3317T2RP	326513	F3317T2RPW	4800	16380		23	509
326407	HF3315T2RP	326544	HF3315T2RPW	3000 / 2250	10240	240 / 208	12.5 / 10.8	495
				1500 / 1125	5120		6.2 / 5.4	
326414	HF3316T2RP	326551	HF3316T2RPW	4000 / 3000	13648		16.8 / 14.4	
				2000 / 1500	6826	8.3 / 7.2		
326421	H3317T2RP	326568	H3317T2RPW	4800	16380	240	20.0	520
326438	G3314T2RP	326575	G3314T2RPW	2000	6826	277	7.2	495
326445	G3315T2RP	326582	G3315T2RPW	3000	10240		10.8	
326452	G3316T2RP	326599	G3316T2RPW	4000	13648		14.4	
326469	G3317T2RP	326605	G3317T2RPW	4800	16380		17.3	

MODELS WITH IN-BUILT SINGLE POLE THERMOSTAT (50° - 90° F TEMPERATURE RANGE)								
382526	E3312TRP	382618	E3312TRPW	1000	3413	120	8.3	455
380652	E3313TRP	384162	E3313TRPW	1500	5120		12.5	
				750	2560		6.25	
379946	F3316TRP	384186	F3316TRPW	4000	13648	208	19.2	463
380300	F3317TRP	384193	F3317TRPW	4800	16380		23	476
380560	HF3315TRP	382229	HF3315TRPW	3000 / 2250	10240	240 / 208	12.5 / 10.8	476
				1500 / 1125	5120		6.2 / 5.4	
379984	HF3316TRP	382236	HF3316TRPW	4000 / 3000	13648		16.8 / 14.4	
				2000 / 1500	6826	8.3 / 7.2		
380317	H3317TRP	382243	H3317TRPW	4800	16380	240	20.0	486
329873	G3314TRP	384261	G3314TRPW	2000	6826	277	7.2	462
328494	G3315TRP	328517	G3315TRPW	3000	10240		10.8	
328500	G3316TRP	328524	G3316TRPW	4000	13648		14.4	
379179	G3317TRP	384292	G3317TRPW	4800	16380		17.3	

MODELS WITHOUT AN IN-BUILT THERMOSTAT								
326629	E3312RP	326766	E3312RPW	1000	3413	120	8.3	432
326636	E3313RP	326773	E3313RPW	1500	5120		12.5	
				750	2560		6.25	
328531	F3316RP	326780	F3316RPW	4000	13648	208	19.2	442
326650	F3317RP	326797	F3317RPW	4800	16380		23	455
326681	HF3315RP	326827	HF3315RPW	3000 / 2250	10240	240 / 208	12.5 / 10.8	442
				1500 / 1125	5120		6.2 / 5.4	
326698	HF3316RP	326834	HF3316RPW	4000 / 3000	13648		16.8 / 14.4	
				2000 / 1500	6826	8.3 / 7.2		
326704	H3317RP	326841	H3317RPW	4800	16380	240	20.0	465
326711	G3314RP	326858	G3314RPW	2000	6826	277	7.2	441
326728	G3315RP	326865	G3315RPW	3000	10240		10.8	
326735	G3316RP	326872	G3316RPW	4000	13648		14.4	
326742	G3317RP	326889	G3317RPW	4800	16380		17.3	