


# HR-3LED-T318

3.5" Tesla™ LED 0°-30° Adjustable Trim

# WAC LIGHTING

Responsible Lighting®

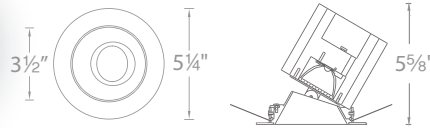

Fixture Type:

Catalog Number:

Project:

Location:

## PRODUCT DESCRIPTION

Minimum profile, round 0° to 30° adjustable trim with interior open reflector.

## FEATURES

- 3.5" aperture
- Damp location listed
- 30° visual cutoff angle for glare control
- Adjustable fixtures are ideal for sloped ceiling applications
- 50,000 hour rated life
- 5 year WAC Lighting product warranty

## SPECIFICATIONS

**Construction:** Durable die-cast aluminum construction with borosilicate glass lens. Extruded aluminum heat sink.

**Power Consumption:** 21.5W

**Dimming:** 0-10V Dimming: 100%-10%  
ELV Dimming: 100%-15% (120V only)

**Mounting:** Two heavy gauge retention clips hold trim firmly to housing.

**Finish:** Powder coated white  
Electroplated brushed nickel and copper bronze

**Standards:** ETL & cETL Listed.

## TRIMS

Model#	Beam	Color Temp	CRI	Lumens	CBCP	Finish
HR-3LED-T318 0° to 30° Adjustable	S 15°	27 2700K	85	775	3883	<b>HBN</b> Haze/Brushed Nickel <b>HCB</b> Haze/Copper Bronze <b>HWT</b> Haze/White <b>BBN</b> Specular Black/Brushed Nickel <b>BCB</b> Specular Black/Copper Bronze <b>BWT</b> Specular Black/White <b>BN</b> Brushed Nickel <b>CB</b> Copper Bronze <b>WT</b> White
		W 3000K	85	830	4393	
		9W 3000K	90	764	2667	
		35 3500K	85	845	4176	
		C 4000K	85	775	4130	
	N 28°	27 2700K	85	815	2016	
		W 3000K	85	855	2114	
		9W 3000K	90	787	1831	
		35 3500K	85	875	2188	
		C 4000K	85	840	2227	
	F 50°	27 2700K	85	785	1105	
		W 3000K	85	865	1196	
		9W 3000K	90	796	1045	
		35 3500K	85	860	1203	
		C 4000K	85	800	1169	

**HR-3LED-T318**  -  -

Example: HR-3LED-T318F-C-SB/BN

**COMPATIBLE HOUSINGS** See individual housing spec sheets for complete information.

### New Construction

<b>HR-3LED-H18D1-ICA</b> Narrow, IC-Rated, Airtight 120V-277V	<b>HR-3LED-H18D1-ICAC</b> Narrow, IC-Rated, Airtight Chicago Plenum 120V-277V
<b>HR-3LED-H18D-ICA</b> IC-Rated, Airtight 120V-277V	<b>HR-3LED-H18D-ICAC</b> IC-Rated, Airtight Chicago Plenum 120V-277V
<b>HR-3LED-H18D-EMICA</b> IC-Rated, Airtight Emergency Backup Battery 120V	<b>HR3LED-H18D-EMICAF</b> IC-Rated, Airtight Emergency Backup Battery 277V

### Remodel

<b>HR-3LED-R22D</b> Non-IC 120V-277V
--

## REPLACEMENT MODULES

### Reflectors

Spot	<b>SL-REF-LUX10-S</b>
Narrow Flood	<b>SL-REF-LUX10-N</b>
Flood	<b>SL-REF-LUX10-F</b>

### LED

2700K	85 CRI	<b>LXS8-PW27</b>
3000K	85 CRI	<b>LXS8-PW30</b>
3000K	90 CRI	<b>LXS9-PW30</b>
3500K	85 CRI	<b>LXS8-PW35</b>
4000K	85 CRI	<b>LXS8-PW40</b>

waclighting.com

Phone (800) 526.2588

Fax (800) 526.2585

Headquarters/Eastern Distribution Center

44 Harbor Park Drive

Port Washington, NY 11050

Central Distribution Center

1600 Distribution Ct

Lithia Springs, GA 30122

Western Distribution Center

1750 Archibald Avenue

Ontario, CA 91760