




Compact Fluorescent Lamp Program

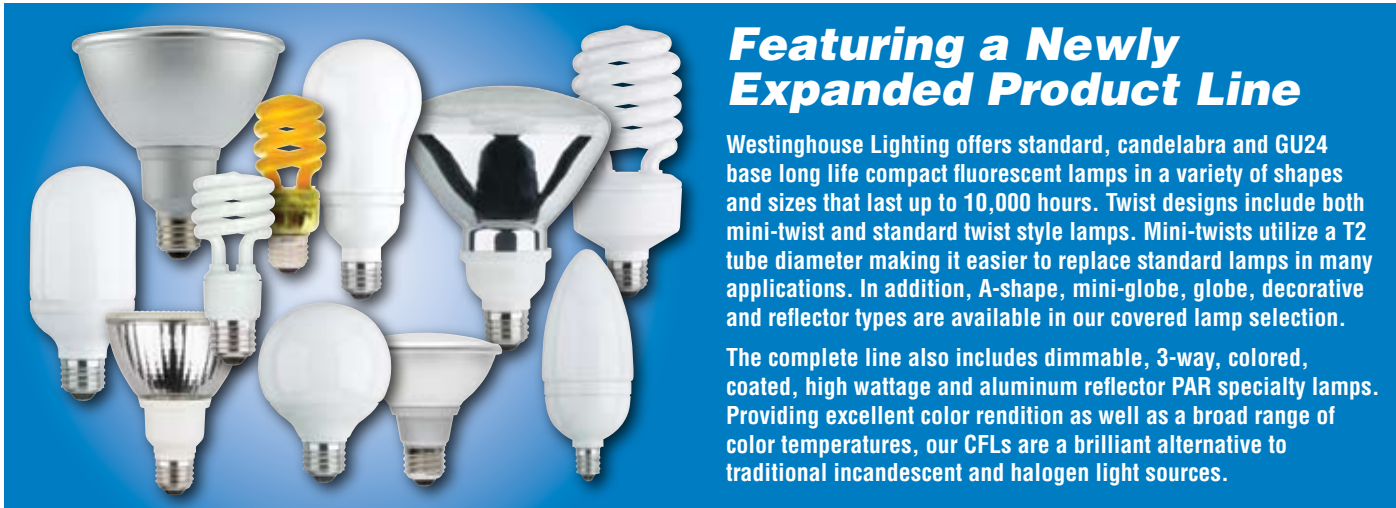

Featuring a Newly Expanded Product Line

Westinghouse Lighting offers standard, candelabra and GU24 base long life compact fluorescent lamps in a variety of shapes and sizes that last up to 10,000 hours. Twist designs include both mini-twist and standard twist style lamps. Mini-twists utilize a T2 tube diameter making it easier to replace standard lamps in many applications. In addition, A-shape, mini-globe, globe, decorative and reflector types are available in our covered lamp selection.

The complete line also includes dimmable, 3-way, colored, coated, high wattage and aluminum reflector PAR specialty lamps. Providing excellent color rendition as well as a broad range of color temperatures, our CFLs are a brilliant alternative to traditional incandescent and halogen light sources.

Key Features and Benefits

Energy-saving alternatives to incandescent lamps save up to 75% energy compared to similar lumen output incandescent lamps.

- **NEW!** T2 smaller size mini-twists are available in wattages ranging from 9 to 23.
- Long Life – 8,000 to 10,000 hours average rated life
- Variety of shapes and wattages to satisfy most applications
- Flicker-free instant start
- Dimmable twist, reflector and decorative lamps dim to 20% of their light output.
- High wattage replacement twist lamps up to 105 watt
- Durable Toughshell™ rubber-coated mini-twists can be used in a variety of applications.
- Variety of color temperatures: 2700K, 3000K, 3500K, 4100K, 5000K, 6500K
- Colored twists available in red, yellow (bug light), green, blue and blacklight (ideal for holiday decorations and festive celebrations).
- Colored PARs available in red, green, blue and yellow (bug light).

Application Information

For use in the following:

Chandeliers	Recessed Down Lights	Sconces
Vanity Bars	Ceiling Fixtures	Ceiling Fans
Table Lamps	Decorative Fixtures	Security Lighting
Difficult-to-Service Areas		


- CFL lamps can be installed on dimming circuits **only** if the lamp is labelled as "Dimmable".
- Outdoor Application – use indoor/outdoor rated lamps in enclosed fixtures only to avoid exposure to weather.
- Do not use in emergency exit fixtures or lights.
- Do not use on electronic timers, photocells or lighted switches.
- Meets CSA, FCC and UL requirements.
- Use only 120V AC, 60Hz circuit.
- Install and remove lamp from fixture by handling plastic base, not lamp glass.

Product Offering

Lamp Type	Watt
NEW! T2 Mini-Twist	4W, 9W, 13W, 14W, 18W, 20W, 23W
High Wattage Twist	27W, 32W, 42W, 65W, 68W, 85W, 105W
Twist GU24 Base	13W, 23W, 27W
3-Way Twist	12/19/28W
A-Shape	9W (Fan), 14W, 20W
Mini-Globe	9W
Globe	9W, 15W
Lantern	14W
Decorative	4W, 7W
Reflector	9W, 15W, 23W
Dimmable	5W/B10, 11W/R20, 15W/R30, 20W/R40
Colored Mini-Twist/PAR38	13W, 23W
Toughshell™ Mini-Twist	14W, 23W


You can be sure...if it's Westinghouse



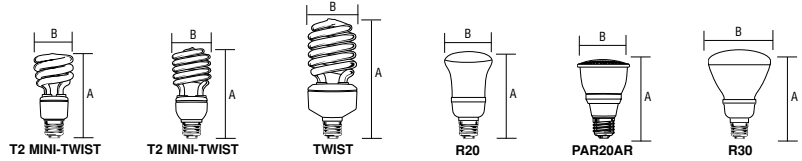

NEW!

Master Carton/													(A) (B)	
Watts	Base	WLC#	Code Abbreviation	Inner Pack	Incand. Equiv.	Lamp	Finish	Kelvin	CRI	Lumens	Average Rated Hours	MOL	MOD	
T2 Smaller Size Mini-Twist Lamps														
4	Std.	36670	4MINITWIST/27	96/24	25	Mini-Twist	Soft White	2700	82	250	8000	3 ³ / ₁₆ "	1 ⁵ / ₈ "	
9	Std.	37934	9MINITWIST/27	24/8	40	Mini-Twist	Soft White	2700	80	500	10000	4"	1 ⁵ / ₈ "	
	Std.	37937	9MINITWIST/27/4	6	40	Mini-Twist	Soft White	2700	80	500	10000	4"	1 ⁵ / ₈ "	
	Std.	37935	9MINITWIST/35	24/8	40	Mini-Twist	Bright White	3500	80	500	10000	4"	1 ⁵ / ₈ "	
	Std.	37938	9MINITWIST/35/4	6	40	Mini-Twist	Bright White	3500	80	500	10000	4"	1 ⁵ / ₈ "	
	Std.	37936	9MINITWIST/65	24/8	40	Mini-Twist	Daylight	6500	80	500	10000	4"	1 ⁵ / ₈ "	
	Std.	37939	9MINITWIST/65/4	6	40	Mini-Twist	Daylight	6500	80	500	10000	4"	1 ⁵ / ₈ "	
13	GU24	37990	13MINITWIST/GU24/27	24/8	60	Mini-Twist	Soft White	2700	82	800	10000	3 ⁵ / ₈ "	1 ¹³ / ₁₆ "	
	Cand.	37948	13MINITWIST/CB/27/2	12/6	60	Mini-Twist	Soft White	2700	80	800	10000	4 ¹ / ₈ "	1 ¹³ / ₁₆ "	
	Std.	37945	13MINITWIST/27	24/8	60	Mini-Twist	Soft White	2700	80	800	10000	4 ¹ / ₈ "	1 ¹³ / ₁₆ "	
	Std.	37946	13MINITWIST/27/4	6	60	Mini-Twist	Soft White	2700	80	800	10000	4 ¹ / ₈ "	1 ¹³ / ₁₆ "	
	Std.	37947	13MINITWIST/27/6	4	60	Mini-Twist	Soft White	2700	80	800	10000	4 ¹ / ₈ "	1 ¹³ / ₁₆ "	
	Std.	37940	13MINITWIST/27/12	4	60	Mini-Twist	Soft White	2700	80	800	10000	4 ¹ / ₈ "	1 ¹³ / ₁₆ "	
	Std.	37941	13MINITWIST/35	24/8	60	Mini-Twist	Bright White	3500	80	800	10000	4 ¹ / ₈ "	1 ¹³ / ₁₆ "	
	Std.	37942	13MINITWIST/35/4	6	60	Mini-Twist	Bright White	3500	80	800	10000	4 ¹ / ₈ "	1 ¹³ / ₁₆ "	
	Std.	37714	13MINITWIST/50	24/8	60	Mini-Twist	850	5000	82	880	10000	4 ¹ / ₈ "	1 ¹³ / ₁₆ "	
	Std.	37943	13MINITWIST/65	24/8	60	Mini-Twist	Daylight	6500	80	800	10000	4 ¹ / ₈ "	1 ¹³ / ₁₆ "	
	Std.	37944	13MINITWIST/65/4	6	60	Mini-Twist	Daylight	6500	80	800	10000	4 ¹ / ₈ "	1 ¹³ / ₁₆ "	
14	Std.	36660	14MINITWIST/41	48/4	60	Mini-Twist	Cool White	4100	82	800	10000	4 ⁵ / ₈ "	1 ¹³ / ₁₆ "	
18	GU24	36308	18MINITWIST/GU24/27	48/12	75	Mini-Twist	Soft White	2700	82	1200	10000	3 ¹³ / ₁₆ "	2 ⁵ / ₁₆ "	
	Std.	37950	18MINITWIST/27	24/8	75	Mini-Twist	Soft White	2700	80	1100	10000	4 ¹ / ₂ "	2 ¹ / ₈ "	
	Std.	37949	18MINITWIST/27/4	6	75	Mini-Twist	Soft White	2700	80	1100	10000	4 ¹ / ₂ "	2 ¹ / ₈ "	
	Std.	37951	18MINITWIST/35	24/8	75	Mini-Twist	Bright White	3500	80	1100	10000	4 ¹ / ₂ "	2 ¹ / ₈ "	
	Std.	37952	18MINITWIST/35/4	6	75	Mini-Twist	Bright White	3500	80	1100	10000	4 ¹ / ₂ "	2 ¹ / ₈ "	
	Std.	37715	18MINITWIST/50	24/8	75	Mini-Twist	850	5000	82	1200	10000	4 ¹ / ₂ "	2 ¹ / ₈ "	
	Std.	37953	18MINITWIST/65	24/8	75	Mini-Twist	Daylight	6500	80	1100	10000	4 ¹ / ₂ "	2 ¹ / ₈ "	
	Std.	37954	18MINITWIST/65/4	6	75	Mini-Twist	Daylight	6500	80	1100	10000	4 ¹ / ₂ "	2 ¹ / ₈ "	
20	Std.	36613	20MINITWIST/41	48/4	75	Mini-Twist	Cool White	4100	82	1100	10000	4 ¹³ / ₁₆ "	2 ³ / ₈ "	
23	GU24	37994	23MINITWIST/GU24/27	24/8	100	Mini-Twist	Soft White	2700	82	1600	10000	4 ¹ / ₄ "	2 ¹ / ₈ "	
	Std.	37955	23MINITWIST/27	24/8	100	Mini-Twist	Soft White	2700	80	1600	10000	4 ⁷ / ₈ "	2 ¹ / ₈ "	
	Std.	37956	23MINITWIST/27/4	6	100	Mini-Twist	Soft White	2700	80	1600	10000	4 ⁷ / ₈ "	2 ¹ / ₈ "	
	Std.	37957	23MINITWIST/27/6	4	100	Mini-Twist	Soft White	2700	80	1600	10000	4 ⁷ / ₈ "	2 ¹ / ₈ "	
	Std.	37958	23MINITWIST/35	24/8	100	Mini-Twist	Bright White	3500	80	1600	10000	4 ⁷ / ₈ "	2 ¹ / ₈ "	
	Std.	37959	23MINITWIST/35/4	6	100	Mini-Twist	Bright White	3500	80	1600	10000	4 ⁷ / ₈ "	2 ¹ / ₈ "	
	Std.	36611	23MINITWIST/41	48/4	100	Mini-Twist	Cool White	4100	82	1500	10000	5 ¹ / ₈ "	2 ³ / ₈ "	
	Std.	37716	23MINITWIST/50	24/8	100	Mini-Twist	850	5000	82	1600	10000	4 ⁷ / ₈ "	2 ¹ / ₈ "	
	Std.	37960	23MINITWIST/65	24/8	100	Mini-Twist	Daylight	6500	80	1600	10000	4 ⁷ / ₈ "	2 ¹ / ₈ "	
	Std.	37961	23MINITWIST/65/4	6	100	Mini-Twist	Daylight	6500	80	1600	10000	4 ⁷ / ₈ "	2 ¹ / ₈ "	
High Wattage Twist Lamps														
27	GU24	36310	27MINITWIST/GU24/27	48/12	100	Twist	Soft White	2700	82	1850	10000	4 ¹³ / ₁₆ "	2 ³ / ₈ "	
	Std.	36609	27MINITWIST/27	48/4	100	Twist	Soft White	2700	82	1750	10000	5 ¹ / ₁₆ "	2 ³ / ₈ "	
	Std.	36608	27MINITWIST/35	48/4	100	Twist	Bright White	3500	82	1750	10000	5 ¹ / ₁₆ "	2 ³ / ₈ "	
	Std.	36607	27MINITWIST/41	48/4	100	Twist	Cool White	4100	82	1750	10000	5 ¹ / ₁₆ "	2 ³ / ₈ "	
	Std.	36662	27MINITWIST/FS/55	48/4	100	Twist	Full Spectrum	5500	90	1750	10000	5 ¹ / ₁₆ "	2 ³ / ₈ "	
32	Std.	37917	32TWIST/27	4	125	Twist	Soft White	2700	82	2100	10000	6"	2 ¹³ / ₁₆ "	
	Std.	37717	32TWIST/50	4	125	Twist	850	5000	80	1920	8000	5 ¹³ / ₁₆ "	2 ¹³ / ₁₆ "	
42	Std.	37918	42TWIST/27	4	150	Twist	Soft White	2700	82	2800	10000	7"	2 ¹³ / ₁₆ "	
	Std.	37720	42TWIST/50	4	150	Twist	850	5000	80	2800	8000	7"	2 ¹³ / ₁₆ "	
	Std.	37919	42TWIST/65	4	150	Twist	Daylight	6500	82	2800	10000	7"	2 ¹³ / ₁₆ "	
65	Std.	37721	65TWIST/50	6	200	Twist	850	5000	82	3800	8000	11"	3 ⁷ / ₈ "	
68	Std.	37921	68TWIST/27	4	300	Twist	Soft White	2700	82	4200	8000	9 ⁵ / ₈ "	3 ⁷ / ₈ "	
	Mogul	37920	68TWIST/E39/65	4	300	Twist	Daylight	6500	82	4200	8000	9 ¹ / ₂ "	3 ⁷ / ₈ "	
85	Std.	37722	85TWIST/50	6	340	Twist	850	5000	82	4800	8000	11 ³ / ₄ "	3 ¹⁵ / ₁₆ "	
	Std.	37072	85TWIST/65	6	340	Twist	Daylight	6500	82	5200	8000	11 ³ / ₄ "	3 ¹⁵ / ₁₆ "	
105	Std.	37723	105TWIST/50	6	420	Twist	850	5000	82	5800	8000	12 ¹ / ₂ "	3 ¹⁵ / ₁₆ "	
	Std.	37073	105TWIST/65	6	420	Twist	Daylight	6500	82	6250	8000	12 ¹ / ₂ "	3 ¹⁵ / ₁₆ "	
Reflector Lamps														
R20														
9	Std.	37966	9CFLR20/F/27	12	40	R20	Soft White	2700	82	300	8000	4 ⁵ / ₁₆ "	2 ¹ / ₂ "	
	Std.	37968	9CFLR20/F/27/2	4	40	R20	Soft White	2700	82	300	8000	4 ⁵ / ₁₆ "	2 ¹ / ₂ "	
	Std.	37967	9CFLR20/F/35	4	40	R20	Bright White	3500	82	300	8000	4 ⁵ / ₁₆ "	2 ¹ / ₂ "	
	Std.	37969	9CFLR20/F/65	4	40	R20	Daylight	6500	82	300	8000	4 ⁵ / ₁₆ "	2 ¹ / ₂ "	
PAR20														
9	Std.	37987	9CFLPAR20/30/AR	6	35	PAR20	Bright White	3000	82	320	8000	3 ¹⁵ / ₁₆ "	2 ⁵ / ₈ "	
	Std.	36692	9CFLPAR20/50/AR	50	35	PAR20	850	5000	82	350	8000	3 ¹⁵ / ₁₆ "	2 ⁵ / ₈ "	
R30														
15	Std.	37970	15CFLR30/F/27	4	60	R30	Soft White	2700	82	650	8000	5 ³ / ₈ "	3 ¹¹ / ₁₆ "	
	Std.	37971	15CFLR30/F/27/2	4	60	R30	Soft White	2700	82	650	8000	5 ³ / ₈ "	3 ¹¹ / ₁₆ "	
	Std.	37972	15CFLR30/F/27/6	6	60	R30	Soft White	2700	82	650	8000	5 ³ / ₈ "	3 ¹¹ / ₁₆ "	
	Std.	37973	15CFLR30/F/35	4	60	R30	Bright White	3500	82	650	8000	5 ³ / ₈ "	3 ¹¹ / ₁₆ "	
	Std.	37974	15CFLR30/F/65	4	60	R30	Daylight	6500	82	650	8000	5 ³ / ₈ "	3 ¹¹ / ₁₆ "	

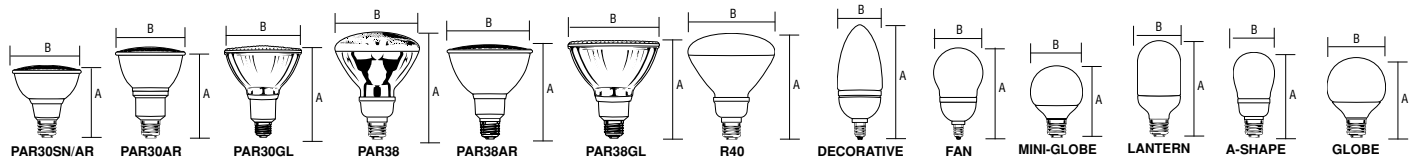

Master Carton/ Code Abbreviation												Average Rated Hours		(A) MOL	(B) MOD
Watts	Base	WLC#	Inner Pack	Incand. Equiv.	Lamp	Finish	Kelvin	CRI	Lumens	Hours	Hours				
PAR30															
11	Std.	36714 †	11CFLPAR30/SN/30/AR	24	45	PAR30	830	3000	80	500	8000	3 3/4"	3 13/16"		
	Std.	36715 †	11CFLPAR30/SN/41/AR	24	45	PAR30	841	4100	80	500	8000	3 3/4"	3 13/16"		
	Std.	36716 †	11CFLPAR30/SN/50/AR	24	45	PAR30	850	5000	80	500	8000	3 3/4"	3 13/16"		
15	Std.	37982 †	15CFLPAR30LN/27/GL	6	50	PAR30	Soft White	2700	82	750	8000	5 1/8"	3 13/16"		
	Std.	37985 †	15CFLPAR30LN/30/AR	6	50	PAR30	Bright White	3000	82	700	8000	4 11/16"	3 13/16"		
	Std.	36694 †	15CFLPAR30LN/41/AR	50	50	PAR30	841	4100	82	670	8000	4 5/8"	3 13/16"		
	Std.	36695 †	15CFLPAR30LN/50/AR	50	50	PAR30	850	5000	82	670	8000	4 5/8"	3 13/16"		
	Std.	37724 †	15CFLPAR30LN/50/GL	6	50	PAR30	850	5000	82	690	8000	5 1/8"	3 13/16"		
PAR38															
23	Std.	37975 •	23PAR38/27	8	75	PAR38	Soft White	2700	82	1200	8000	6 5/16"	4 13/16"		
	Std.	37976 •	23PAR38/27/2	4	75	PAR38	Soft White	2700	82	1200	8000	6 5/16"	4 11/16"		
	Std.	37984 †	23CFLPAR38/27/GL	4	90	PAR38	Soft White	2700	82	1370	8000	5 1/2"	4 7/8"		
	Std.	37986 †	23CFLPAR38/30/AR	4	90	PAR38	Bright White	3000	82	1200	8000	5 5/16"	4 7/8"		
	Std.	36697 †	23CFLPAR38/41/AR	20	90	PAR38	841	4100	82	1200	8000	5 3/8"	4 13/16"		
	Std.	36698 †	23CFLPAR38/50/AR	20	90	PAR38	850	5000	82	1200	8000	5 3/8"	4 13/16"		
	Std.	37725 †	23CFLPAR38/50/GL	4	90	PAR38	850	5000	82	1150	8000	5 1/2"	4 13/16"		
	Std.	37983 †	23CFLPAR38/65/GL	4	90	PAR38	Daylight	6500	82	1150	8000	5 1/2"	4 13/16"		
R40															
23	Std.	37979	23CFLR40/F/27	4	75	R40	Soft White	2700	82	1200	8000	6 3/16"	4 13/16"		
	Std.	37978	23CFLR40/F/35	4	75	R40	Bright White	3500	82	1250	8000	6 3/16"	4 13/16"		
	Std.	37977	23CFLR40/F/65	4	75	R40	Daylight	6500	82	1250	8000	6 3/16"	4 13/16"		

† Approved for Damp Location • Approved for Wet Location

Covered Lamps

4	Std.	37995	4/DEC/27	8	25	Dec	Soft White	2700	82	195	8000	4 3/16"	1 5/8"
7	Cand.*	37997	7DEC/CB/ADP/27/2	4	40	Dec	Soft White	2700	82	280	8000	4 13/16"	1 11/16"
9	Cand.*	37905	9FAN/CB/ADP/27/2	4	40	A Shape	Soft White	2700	82	450	8000	4 3/8"	2 1/8"
	Cand.*	37906	9FAN/CB/ADP/35/2	4	40	A Shape	Bright White	3500	82	450	8000	4 3/8"	2 1/8"
	Cand.*	37907	9FAN/CB/ADP/65/2	4	40	A Shape	Daylight	6500	82	450	8000	4 3/8"	2 1/8"
	Std.	38005	9MINIGLOBE/27/2	4	40	Globe	Soft White	2700	82	380	8000	5 5/16"	2 1/8"
	Std.	38007	9GLOBE/27	8	40	Globe	Soft White	2700	82	495	8000	4 3/8"	3 1/8"
	Std.	38008	9GLOBE/27/2	4	40	Globe	Soft White	2700	82	495	8000	4 3/8"	3 1/8"
14	Std.	37993	14LANTERN/27	4	60	Capsule	Soft White	2700	82	800	8000	5 3/8"	2 3/8"
	Std.	37900	14ASHAPE/27	8	60	A Shape	Soft White	2700	82	800	8000	5 1/8"	2 3/8"
	Std.	37901	14ASHAPE/27/2	4	60	A Shape	Soft White	2700	82	800	8000	5 1/8"	2 3/8"
	Std.	37902	14ASHAPE/35/2	4	60	A Shape	Bright White	3500	82	800	8000	5 1/8"	2 3/8"
	Std.	37903	14ASHAPE/65/2	4	60	A Shape	Daylight	6500	82	800	8000	5 1/8"	2 3/8"
15	Std.	38001	15GLOBE/27	8	60	Globe	Soft White	2700	82	800	8000	4 3/8"	3 1/8"
	Std.	38002	15GLOBE/27/2	4	60	Globe	Soft White	2700	82	800	8000	4 3/8"	3 1/8"
	Std.	38003	15GLOBE/35/2	4	60	Globe	Bright White	3500	82	800	8000	4 3/8"	3 1/8"
	Std.	38004	15GLOBE/65/2	4	60	Globe	Daylight	6500	82	800	8000	4 3/8"	3 1/8"
20	Std.	37904	20ASHAPE/27	4	75	A Shape	Soft White	2700	82	1100	8000	5 7/8"	2 11/16"

* Std. Base Adapter(s) Included

Specialty Lamps

Decorative and Twist Lamps (Dimmable, 3-Way, Colored and Toughshell™)													
5	Cand.*	37916	5DEC/CB/ADP/DIM/27	8	25	Dec	Soft White	2700	82	200	25000	4 3/8"	1 3/8"
12/19/28	Std.	37962	12/19/28MINITWIST/3WAY/27	6	30/70/100	Mini-Twist	Soft White	2700	82	600/1200/1800	10000	5 5/8"	2 3/8"
	Std.	37963	12/19/28MINITWIST/3WAY/65	6	30/70/100	Mini-Twist	Daylight	6500	82	500/1100/1700	10000	5 5/8"	2 3/8"
13	Std.	37924	13MINITWIST/BL	4	60	Specialty Twist	Black Light	-	82	-	8000	4 5/8"	1 13/16"
	Std.	37925	13MINITWIST/BUG	4	60	Specialty Twist	Yellow	-	82	-	8000	4 5/8"	1 13/16"
	Std.	37926	13MINITWIST/B	4	60	Specialty Twist	Blue	-	82	-	8000	4 5/8"	1 13/16"
	Std.	37927	13MINITWIST/G	4	60	Specialty Twist	Green	-	82	-	8000	4 5/8"	1 13/16"
	Std.	37928	13MINITWIST/O	4	60	Specialty Twist	Orange	-	82	-	8000	4 5/8"	1 13/16"
	Std.	37929	13MINITWIST/R	4	60	Specialty Twist	Red	-	82	-	8000	4 5/8"	1 13/16"
14	Std.	37988	14MINITWIST/TS/27	24/6	60	Mini-Twist	Soft White	2700	81	730	10000	4 5/16"	1 13/16"
15	Std.	37909	15MINITWIST/DIM/27	6	60	Mini-Twist	Soft White	2700	82	900	10000	5 3/8"	2 5/16"
	Std.	37910	15MINITWIST/DIM/27/3	4	60	Mini-Twist	Soft White	2700	82	900	10000	5 3/8"	2 5/16"
23	Std.	37989	23MINITWIST/TS/27	24/6	60	Mini-Twist	Soft White	2700	81	1350	10000	4 7/8"	2 1/8"
25	Std.	37913	25MINITWIST/DIM/27	6	100	Mini-Twist	Soft White	2700	82	1600	10000	5 13/16"	2 5/8"

Reflectors (Dimmable and Colored)

11	Std.	37908	11CFLR20/DIM/27	6	40	R20	Soft White	2700	82	400	6000	5 1/8"	2 3/8"
15	Std.	37911	15CFLR30/DIM/27	6	50	R30	Soft White	2700	82	600	8000	5 1/2"	4 5/8"
20	Std.	37914	20CFLR40/DIM/27	6	65	R40	Soft White	2700	82	900	6000	6 5/16"	4 5/8"
23	Std.	37931	23CFLPAR38/GL/BUG	4	90	PAR38	Yellow	-	80	-	8000	5 1/2"	4 13/16"
	Std.	37930	23CFLPAR38/GL/B	4	90	PAR38	Blue	-	80	-	8000	5 1/2"	4 13/16"
	Std.	37932	23CFLPAR38/GL/G	4	90	PAR38	Green	-	80	-	8000	5 1/2"	4 13/16"
	Std.	37933	23CFLPAR38/GL/R	4	90	PAR38	Red	-	80	-	8000	5 1/2"	4 13/16"

* Std. Base Adapter(s) Included



Westinghouse

Technical Information


TYPICAL FLUORESCENT LAMP MORTALITY




LUMEN MAINTENANCE CURVE




2700K

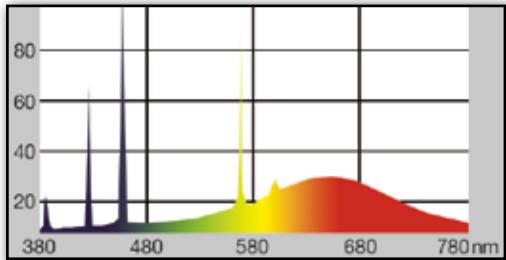


3000K

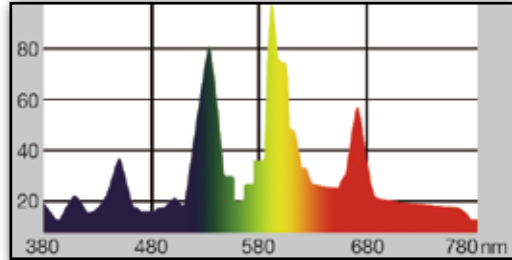


3500K

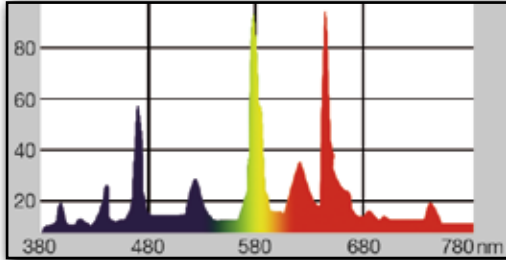


4100K

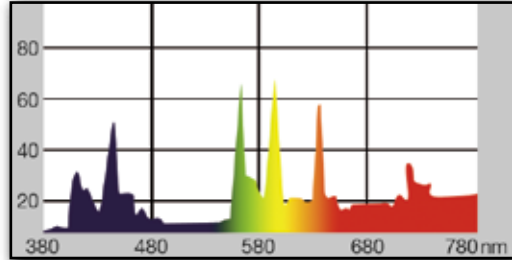

5100K

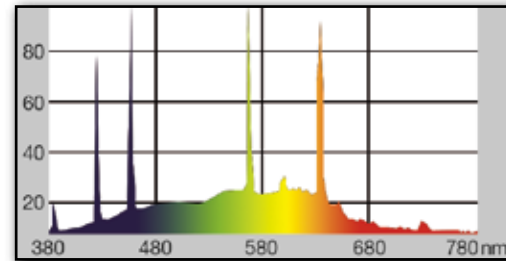

6500K

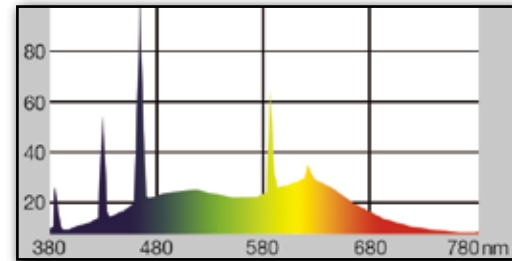

 Contains mercury. Dispose of according to local, state or federal laws.
 For more information, go to www.lamprecycle.org or call 1-888-417-6222.

Call 1-800-999-2226 EST/CST, 1-800-421-3433 PST/MST, or log on at www.westinghouselightbulbs.com
 Westinghouse Lighting Corporation, Philadelphia, PA 19154-1029, U.S.A. Westinghouse Lighting Corporation, a Westinghouse Electric Corporation licensee
 © "Westinghouse" and "You can be sure...if it's Westinghouse" are all registered trademarks of Westinghouse Electric Corporation



You can be sure...if it's Westinghouse 