


**1081/1004IC/N**  
*Lyte<sup>ning</sup>*  
Convertible IC/Non-IC

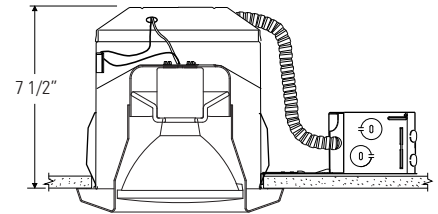

**1081 /1004ICR**  
*Lyte<sup>ning</sup>* Remodeler  
Convertible IC/Non-IC

Complete Fixture consists of Reflector Trim & Frame-In Kit. Select each separately.

Reflector Trim	Frame-In Kit - See Individual Frame-In Kit Specification Sheets			
	Frame-In Kit	Installation Type	Lamping	Height
<b>1081WH</b> Gloss White	<b>Incandescent</b>			
<b>1081CD</b> Clear Diffuse	1004IC/N	5" IC	75W PAR30 outdoor rated*	7 1/2"
	1004ICR	5" IC Remodeler	75W PAR30 outdoor rated*	7 1/2"
	1004IC/N	5" Non-IC	75W PAR30 outdoor rated*	7 1/2"
	1004ICR	5" Non-IC Remodeler	75W PAR30 outdoor rated*	7 1/2"

\* For safe operation, you must use Sylvania outdoor rated lamp.

### Features

- Reflector:** Formed aluminum, 0.040" thick (18 ga.);Gloss White and Clear Diffuse finish.
- Frame-In Kit:** Use only with Frame-In Kits shown above. See Frame-In Kit specification sheets for more details.
- Gasket:** Flexible, high temperature silicone gasket ensure sealing of electrical components.

### Accessories

LFG 356 - Replacement Gasket

### Labels

U.L. (Suitable for Wet Locations - Covered Ceiling Only), I.B.E.W.

NEC® is a registered trademark of the National Fire Protection Association.

Job Information	Type:
<b>Job Name:</b>	
<b>Cat. No.:</b>	
<b>Lamp(s):</b>	
<b>Notes:</b>	

Lightolier a Genlyte company www.lightolier.com  
 631 Airport Road, Fall River, MA 02720 • (508) 679-8131 • Fax (508) 674-4710  
 We reserve the right to change details of design, materials and finish.  
 © 2011 Genlyte Group LLC • E0711

**LIGHTOLIER®**