


## Carlton® Cement

(MSDS sheets available at [www.carlon.com](http://www.carlon.com))

### Standard Grade Clear Solvent Cement with dauber

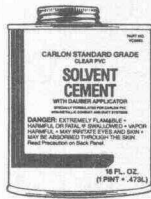

Part No.	Size	Std. Ctn. Qty.	Broken Ctn. Price per Hu.	Full Ctn. Price per Hu.
VC9964	1/2 Pint	10	\$505.89	\$439.90
VC9963	Pint	24	\$697.21	\$606.27
VC9962	Quart	12	\$1167.07	\$1014.84
VC9961P	Gallon	6	\$5040.57	\$4383.10

### Recommended pipe application and sizes

Recommended for all grades and types of Carlton PVC conduit, duct, wireway and fittings, except Flex-Plus® Blue™ ENT (Electrical Nonmetallic Tubing.)  
Up through 6" diameter.

### Set-up time (Evaporation Rate)

10°-30°F Not recommended  
30°-50°F 5-6 minutes  
50°-70°F 3-4 minutes  
70°-90°F 1-2 minutes

### Recommended installation temperature

40° to 100°F


### Lap Shear @ 73°F

2 hrs. 350 psi  
16 hrs. 800 psi  
72 hrs. 1,500 psi

### Viscosity at 75° as manufactured

500-900 cps

### Regular Grade Grey Solvent Cement with dauber\*

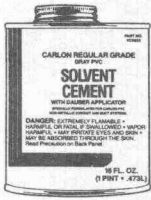

Part No.	Size	Std. Ctn. Qty.	Broken Ctn. Price per Hu.	Full Ctn. Price per Hu.
VC9924	1/2 Pint	10	\$511.98	\$445.20
VC9923	Pint	24	\$729.04	\$633.95
VC9922	Quart	12	\$1217.09	\$1058.34
VC9941P	Gallon	6	\$5046.66	\$4388.40

Recommended for all grades and types of Carlton PVC conduit, duct, wireway and fittings, except Flex-Plus® Blue™ ENT (Electrical Nonmetallic Tubing.)  
Up through 6" diameter.

10°-30°F Not recommended  
30°-50°F 5-6 minutes  
50°-70°F 3-4 minutes  
70°-90°F 1-2 minutes

40° to 100°F

2 hrs. 350 psi  
16 hrs. 800 psi  
72 hrs. 1,500 psi

500-900 cps

### All-Weather "Quick-Set" Clear Solvent Cement with dauber\*



Part No.	Size	Std. Ctn. Qty.	Broken Ctn. Price per Hu.	Full Ctn. Price per Hu.
VC9984	1/2 Pint	10	\$518.36	\$450.75
VC9983	Pint	24	\$865.46	\$752.57
VC9982	Quart	12	\$1385.34	\$1204.64
VC9981P	Gallon	6	\$5881.68	\$5114.50

Recommended for all grades and types of Carlton PVC conduit, duct, wireway and fittings, except Flex-Plus® Blue™ ENT (Electrical Nonmetallic Tubing.)  
Up through 6" diameter.

10°-30°F 4-5 minutes  
30°-50°F 3-4 minutes  
50°-70°F 1-2 minutes  
70°-90°F 1/2-1 1/2 minutes

5° to 100°F

2 hrs. 350 psi  
16 hrs. 800 psi  
72 hrs. 1,500 psi

400-700 cps

### All-Weather ENT Blue "Quick-Set" Solvent Cement with brush\*



Part No.	Size	Std. Ctn. Qty.	Broken Ctn. Price per Hu.	Full Ctn. Price per Hu.
VC9992	Quart	12	\$1424.75	\$1238.91
VC9993	Pint	24	\$873.03	\$759.19

Recommended for use with Flex-Plus® Blue™ ENT (Electrical Nonmetallic Tubing), Riser-Gard® & PVC Optic-Gard®, P&C Flex®, and Carlton PVC fittings.  
Up through 4" diameter.

10°-30°F 4-5 minutes  
30°-50°F 3-4 minutes  
50°-70°F 1-2 minutes  
70°-90°F 1/2-1 1/2 minutes

4° to 100°F

2 hrs. 350 psi  
16 hrs. 800 psi  
72 hrs. 1,500 psi

400-700 cps

### Low VOC Solvent Cement with dauber\*



Part No.	Size	Std. Ctn. Qty.	Broken Ctn. Price per Hu.	Full Ctn. Price per Hu.
VC9LV4	1/2 Pint	10	\$578.99	\$503.47
VC9LV3	Pint	24	\$932.14	\$810.56
VC9LV2	Quart	12	\$1624.80	\$1412.87

Recommended for all grades and types of Carlton PVC conduit, duct, wireway and fittings, except Flex-Plus® Blue™ ENT (Electrical Nonmetallic Tubing.)  
Up through 6" diameter.

VOC emission of 490 grams/liter per the Bay and South Coast test method.

10°-30°F Not recommended  
30°-50°F 5-6 minutes  
50°-70°F 3-4 minutes  
70°-90°F 1-2 minutes

40° to 100°F

2 hrs. 350 psi  
16 hrs. 800 psi  
72 hrs. 1,500 psi

500-900 cps

### Primer with dauber



Part No.	Size	Std. Ctn. Qty.	Broken Ctn. Price per Hu.	Full Ctn. Price per Hu.
VC9903	Pint	24	\$776.03	\$674.81
VC9902	Quart	12	\$1271.66	\$1105.79
<b>Purple:</b>				
VC9932	Quart	12	\$1233.78	\$1072.85

Recommended for use with Carlton cement and all types and sizes of Carlton WireSafe™ wireway.

N/A

5° to 100°F

N/A

N/A

Vendor/UPC Number	Part Number	Description	List Price	Broken Carton Price	UOM	Std. Carton Qty.	Std. Carton Wt. (lbs.)	Price Sch. Code	Price Guide Page
034481229278	UB9HNB	4" SCH 80 90 X 48" ELBOW-BELLED	\$220.86	\$253.99	1 EA	1	21.4	13	151
034481192251	UB9HP	5" SCH 80 90° X 48" ELBOW	\$170.45	\$196.02	1 EA	1	27.0	13	151
034481229315	UB9HR	6" SCH 80 90° X 48" ELBOW	\$175.43	\$201.74	1 EA	1	37.6	13	151
034481341888	UC5CKB	21/2 UTIL40 221/2X18R SWP	\$28.41	\$32.67	1 EA	1	1.5	Q	168
034481229483	UC5FKB	2-1/2" SCH 40 22-1/2" X 36" ELBOW-BELLED	\$35.33	\$40.63	1 EA	1	2.5	Q	168
034481229490	UC5FNB	4 UTIL40 221/2X36 TC6 BE	\$53.27	\$61.26	1 EA	1	5.3	Q	168
034481229506	UC5FRB	6 UTIL40 221/2X36 TC6 BE	\$129.82	\$149.29	1 EA	1	11.8	Q	168
034481342038	UC7CKB	21/2 UTIL 40 45DX18R BELL	\$26.34	\$30.29	1 EA	1	2.3	Q	168
034481229544	UC7FHB	11/2 UTIL 40 45D 36R BELL	\$36.69	\$42.19	1 EA	1	1.7	Q	168
034481342113	UC7FJB	2" SCH 40 45° X 36" ELBOW-BELLED	\$18.10	\$20.82	1 EA	1	2.1	17	168
034481342120	UC7FJCP	2 UTIL 40 45D X 36R TC6	\$994.70	\$1,143.91	100 EA	1	2.2	Q	
034481229568	UC7FKB	2-1/2" SCH 40 45° X 36" ELBOW-BELLED	\$35.88	\$41.26	1 EA	1	4.1	Q	168
034481342137	UC7FLB	3" SCH 40 45° X 36" ELBOW-BELLED	\$33.12	\$38.09	1 EA	1	5.0	Q	168
034481342144	UC7FLCP	3 UTIL 40 45D X 36R TC6	\$1,740.73	\$2,001.84	100 EA	1	5.3	Q	
034481229599	UC7FNB	4" SCH 40 45° X 36" ELBOW-BELLED	\$54.28	\$62.42	1 EA	1	8.1	Q	168
034481342151	UC7FNCP	4 UTIL 40 45D X 36R TC6	\$2,486.76	\$2,859.77	100 EA	1	8.1	Q	
034481229612	UC7HRB	6 UTIL40 45DX48R TC6 BE	\$141.68	\$162.93	1 EA	1	17.2	Q	168
034481342168	UC7HRCP	6 UTIL 40 45DX48R TC 6	\$6,216.90	\$7,149.44	100 EA	1	17.2	Q	
034481342267	UC9HNB	1-1/2" SCH 40 90° X 12" ELBOW-BELLED	\$26.13	\$30.05	1 EA	20	25.0	Q	168
034481342274	UC9BJB	2" SCH 40 90° X 12" ELBOW-BELLED	\$20.75	\$23.86	1 EA	1	1.4	Q	168
034481229643	UC9DHB	1-1/2" SCH 40 90° X 24" ELBOW-BELLED	\$15.31	\$17.61	1 EA	1	2.1	Q	168
034481342328	UC9DJB	2" SCH 40 90° X 24" ELBOW-BELLED	\$21.86	\$25.14	1 EA	1	2.8	Q	168
034481342335	UC9DKB	2-1/2" SCH 40 90° X 24" ELBOW-BELLED	\$19.27	\$22.16	1 EA	1	5.0	Q	168
034481342342	UC9DLB	3" SCH 40 90° X 24" ELBOW-BELLED	\$36.33	\$41.78	1 EA	1	6.6	Q	168
034481229650	UC9DNB	4" SCH 40 90° X 24" ELBOW-BELLED	\$61.19	\$70.37	1 EA	1	10.6	Q	168
034481229667	UC9FHB	1-1/2" SCH 40 90° X 36" ELBOW-BELLED	\$15.55	\$17.88	1 EA	1	3.0	Q	168
034481229674	UC9FJB	2" SCH 40 90° X 36" ELBOW-BELLED	\$31.09	\$35.75	1 EA	1	4.1	Q	168
034481342427	UC9FJCP	2 UTIL 40 90D X 36R TC6	\$1,492.06	\$1,715.87	100 EA	1	4.1	Q	
034481229681	UC9FKB	2-1/2" SCH 40 90° X 36" ELBOW-BELLED	\$26.11	\$30.03	1 EA	1	7.2	Q	168
034481229698	UC9FLB	3" SCH 40 90° X 36" ELBOW-BELLED	\$51.68	\$59.43	1 EA	1	9.2	Q	168
034481342489	UC9FLCP	3 UTIL 40 90D X 36R TC6	\$1,989.41	\$2,287.82	100 EA	1	9.2	Q	
034481229711	UC9FNB	4" SCH 40 90° X 36" ELBOW-BELLED	\$36.06	\$41.47	1 EA	1	13.6	Q	168
034481342519	UC9FNCP	4 UTIL 40 90D X 36R TC2	\$2,797.61	\$3,217.25	100 EA	1	12.9	Q	
034481229728	UC9FRB	6" SCH 40 90° X 36" ELBOW-BELLED	\$163.80	\$188.37	1 EA	1	25.8	Q	168
034481342540	UC9HJB	2" SCH 40 90° X 48" ELBOW-BELLED	\$48.06	\$55.27	1 EA	1	5.1	Q	168
034481229735	UC9HNB	4" SCH 40 90 X 48" ELBOW-BELLED	\$101.06	\$116.22	1 EA	1	17.7	Q	168
034481229759	UC9HRB	6" SCH 40 90° X 48" ELBOW-BELLED	\$203.51	\$234.04	1 EA	1	32.2	Q	168
034481342557	UC9HRCP	6 UTIL 40 90D X 48R TC6	\$69.63	\$80.07	1 EA	1	32.2	Q	
034481229827	VC9902	QUART CLEAR PRIMER W/DAUBER	\$1,105.79	\$1,271.66	100 EA	12	24.7	16	188
034481229834	VC9903	PINT CLEAR PRIMER W/DAUBER	\$674.81	\$776.03	100 EA	24	25.4	16	188
034481069713	VC9922	QUART REGULAR GREY CEMENT	\$1,058.34	\$1,217.09	100 EA	12	27.3	16	188
034481069706	VC9923	PINT REGULAR GREY CEMENT	\$633.95	\$729.04	100 EA	24	27.8	16	188
034481069690	VC9924	1/2 PINT REGULAR GREY CEMENT	\$445.20	\$511.98	100 EA	10	6.4	16	188
034481040477	VC9932	QUART PURPLE PRIMER W/DAUBER	\$1,072.85	\$1,233.78	100 EA	12	28.2	16	188
034481069737	VC9941P	GALLON REGULAR GREY CEMENT	\$4,388.40	\$5,046.66	100 EA	6	49.8	16	188
034481050049	VC9961P	GALLON STANDARD CLEAR CEMENT	\$4,383.10	\$5,040.57	100 EA	6	53.8	16	188
034481050018	VC9962	QUART STANDARD CLEAR CEMENT	\$1,014.84	\$1,167.07	100 EA	12	28.2	16	188
034481050001	VC9963	PINT STANDARD CLEAR CEMENT	\$606.27	\$697.21	100 EA	24	28.6	16	188
034481050117	VC9964	1/2 PINT STANDARD CLEAR CEMENT	\$439.90	\$505.89	100 EA	10	6.1	16	188