



1084/1002P1
Standard Incandescent

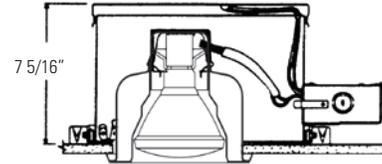

1084/1000 IC Series
Incandescent Insulated Ceiling

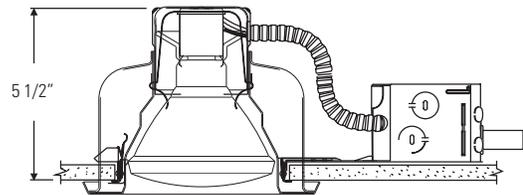

1084/1003R
Lytefiring™ Non-IC
Remodeler

Complete Fixture consists of Frame-In Kit & Reflector Trim. Select each separately.

Reflector Trim	Frame-In Kit - See Individual Frame-In Kit Specification Sheets			
	Frame-In Kit	Ceiling Type	Lamping	Height
1084WH Gloss White 1084CD Clear Diffuse	Incandescent			
	1002P1	Non IC	75W PAR30L Outdoor Rated* †	5 1/2"
	1003R	Non IC Remodeler	75W PAR30L Outdoor Rated* †	5 1/2"
	1000IC	IC	60W PAR30 Outdoor Rated*	7 5/16"
	1000AICM	AirSeal® IC	60W PAR30 Outdoor Rated*	7 5/16"
	1004ICX	AirSeal® IC	60W PAR30 Outdoor Rated*	7 1/4"

* For safe operation, you must use Sylvania outdoor rated lamp.
 † (Use Socket Extender Accessory with Short Neck)

Features

- 1. Reflectors:** Formed aluminum, .040 minimum thickness; gloss white and clear diffuse finish.
- 2. Frame-In Kit:** (1002P1 standard frame shown). Other frames listed above and shown on the right. See Frame-In Kit specification sheets for more details.
- 3. Gasket:** Flexible, high temperature silicone gasket ensure sealing of electrical components.

Accessories

- LFG 356 - Replacement Gasket
- Medium Base Par 30 Socket Extender
- 1968-For use with Short Neck PAR30 Lamps

Labels

U.L. (Suitable for Wet Locations - Covered Ceiling Only)

NEC® is a registered trademark of the National Fire Protection Association.

Job Information	Type:
Job Name:	
Cat. No.:	
Lamp(s):	
Notes:	