



1184/1102P1
Standard Incandescent

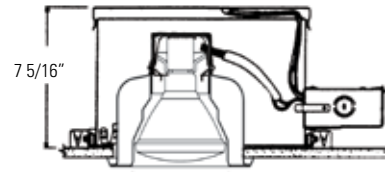

1184/1100 IC Series
Incandescent Insulated Ceiling

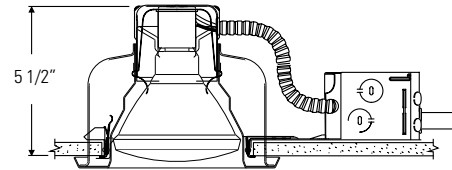

1184/1103R
LyteFining™ Non-IC
Remodeler Ring

Complete Fixture consists of Frame-In Kit & Reflector Trim. Select each separately.

Reflector Trim		Frame-In Kit — See Individual Frame-In Kit Specification Sheets			
		LED			
		Frame-In Kit	Installation Type	Lamping	Height
1184WH 1184CD	Gloss White Clear Diffuse	1101LED	Non-IC	LED	5 1/2"
		1100LEDREM	Non-IC Remodeler	LED	5 1/2"
		L56LED	Non-IC Retrofit	LED	5 1/2"
		Incandescent			
		Frame-In Kit	Installation Type	Lamping	Height
		1102P1	Non-IC	75W PAR38 Outdoor Rated*	5 1/2"
		1103R	Non-IC Remodeler	75W PAR38 Outdoor Rated*	5 1/2"
		1100IC	IC	75W PAR38 Outdoor Rated*	7 5/16"
		1100AICM	AirSeal® IC	75W PAR38 Outdoor Rated*	7 5/16"
		1104ICX	AirSeal® IC	75W PAR38 Outdoor Rated*	7 1/4"

* For safe operation, you must use Sylvania or GE outdoor rated lamp.

Features

- Reflectors:** Formed aluminum, .040 minimum thickness; gloss white and clear diffuse finish.
- Frame-In Kit:** (1102P1 standard frame shown). Other frames listed above and shown on the right. See Frame-In Kit specification sheets for more details.
- Gasket:** Flexible, high temperature silicone gasket ensure sealing of electrical components.

Accessories

LFG 356 - Replacement Gasket

Labels

U.L. (Suitable for Wet Locations - Covered Ceiling Only), I.B.E.W.

Job Information	Type:
Job Name:	
Cat. No.:	
Lamp(s):	
Notes:	