

 
 





Elbows, Sweeps and Accessories

Schedule 80 Elbows

Standard Radius

ITEM	PLAIN END CAT. NO.	BELLED END CAT. NO.	SIZE (IN.)	PLAIN END STD. CTN.	BELLED END STD. CTN.
90° ELBOW					
	UB9AD	—	½	50	—
	UB9AE	—	¾	25	—
	UB9AF	—	1	25	—
	UB9AG	—	1¼	20	—
	UB9AH	—	1½	25	—
	UB9AJ	—	2	20	—
	UB9AK	—	2½	10	—
	UB9AL	—	3	5	—
	UB9AN	—	4	1	—
	UB9AP	UB9APB	5	1	1
	UB9AR	—	6	1	—
45° ELBOW					
	UB7AD	—	½	50	—
	UB7AE-UPC	—	¾	25	—
	UB7AF-UPC	—	1	20	—
	UB7AG	—	1¼	20	—
	UB7AH	—	1½	20	—
	UB7AH-CAR	—	1½	5	—
	UB7AJ-UPC	—	2	20	—
	UB7AK	—	2½	20	—
	UB7AL	—	3	1	—
	UB7AN	—	4	1	—
	UB7AP	UB7APB	5	1	1
	UB7AR	—	6	1	—
30° ELBOW					
	UB6AD	—	½	50	—
	UB6AE	—	¾	25	—
	UB6AF	—	1	25	—
	UB6AG	—	1¼	5	—
	UB6AH	—	1½	25	—
	UB6AJ	—	2	20	—
	UB6AK	—	2½	1	—
	UB6AL	—	3	1	—
	UB6AN	—	4	1	—
	UB6AP	—	5	1	—
	UB6AR	—	6	1	—
22½° ELBOW					
	UB5AL	—	3	5	—
	UB5AN	—	4	1	—
	UB5AP	UB5APB	5	1	1
11¼° ELBOW					
	UB3AL	—	3	1	—
	UB3AR	—	6	1	—

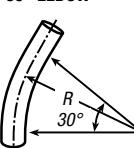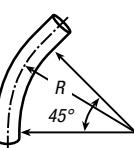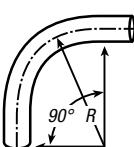

For use with non-metallic solvent weld fittings.

Special Radius

SEGMENT	PLAIN END CAT. NO.	BELLED END CAT. NO.	NOM. DIAM. (IN.)	RADIUS (IN.)	PLAIN END STD. CTN.	BELLED END STD. CTN.
90° ELBOW						
	UB9CF	—	1	18	1	—
	UB9DF	—	1	24	1	—
	UB9FF	—	1	36	1	—
	UB9HF	—	1	48	1	—
	UB9CG	—	1¼	18	1	—
	UB9DG	—	1¼	24	1	—
	UB9FG	—	1¼	36	1	—
	UB9HG	—	1¼	48	1	—
	UB9CH	—	1½	18	1	—
	UB9DH-UPC	UB9DHB	1½	24	1	1
	UB9FH	—	1½	36	1	—
	UB9HH	—	1½	48	1	—
	UB9CJ	—	2	18	1	—
	UB9DJ-UPC	UB9DJB	2	24	1	1
	UB9FJ	UB9FJB	2	36	1	1
	UB9HJ	—	2	48	1	—
	UB9CK	—	2½	18	1	—
	UB9DK-UPC	UB9DKB	2½	24	1	1
	UB9FK	UB9FKB	2½	36	1	1
	UB9HK	—	2½	48	1	—
	UB9CL	—	3	18	1	—
	UB9DL	UB9DLB	3	24	1	1
	UB9FL	UB9FLB	3	36	1	1
	UB9HL	—	3	48	1	—
	UB9DN	UB9DNB	4	24	1	1
	UB9FN	UB9FNB	4	36	1	1
	UB9HN	UB9HNB	4	48	1	1
	UB9NN	—	4	120	1	—
	UB9FP	—	5	36	1	—
	UB9HP	—	5	48	1	—
	UB9IP	—	5	60	1	—
	UB9FR	—	6	36	1	—
	UB9HR	—	6	48	1	—
	UB9IR	—	6	60	1	—

Note: Elbows 72" and larger may be shipped in segments. Consult factory for specifics.

Elbows, Sweeps and Accessories

Schedule 80 Elbows — Special Radius (*continued*)

SEGMENT	PLAIN END CAT. NO.	BELLED END CAT. NO.	NOM. DIAM. (IN.)	RADIUS (IN.)	PLAIN END STD. CTN.	BELLED END STD. CTN.
45° ELBOW						
	UB7CF	—	1	18	1	—
	UB7DF	—	1	24	1	—
	UB7FF	—	1	36	1	—
	UB7HF	—	1	48	1	—
	UB7DG	—	1 1/4	24	1	—
	UB7FG	—	1 1/4	36	1	—
	UB7HG	—	1 1/4	48	1	—
	UB7CH	—	1 1/2	18	1	—
	UB7DH	UB7DHB	1 1/2	24	1	1
	UB7FH	—	1 1/2	36	1	—
	UB7HH	—	1 1/2	48	1	—
	UB7CJ	—	2	18	1	—
	UB7DJ	UB7DJB	2	24	1	1
	UB7FJ	UB7FJB	2	36	1	1
	UB7HJ	—	2	48	1	—
	UB7DK	UB7DKB	2 1/2	24	1	1
	UB7FK	—	2 1/2	36	1	—
	UB7HK	—	2 1/2	48	1	—
	UB7CL	—	3	18	1	—
	UB7DL	UB7DLB	3	24	1	1
	UB7FL	UB7FLB	3	36	1	1
	UB7HL	—	3	48	1	—
	UB7DN	UB7DNB	4	24	1	1
	UB7FN	UB7FNB	4	36	1	1
	UB7HN	—	4	48	1	—
	UB7FP	—	5	36	1	—
	UB7HP	—	5	48	1	—
	UB7FR	—	6	36	1	—
	UB7HR	—	6	48	1	—
	UB7IR	—	6	60	1	—
30° ELBOW						
	UB6FN	—	4	36	1	—
	UB6FR	—	6	36	1	—
22 1/2° ELBOW	—	UB5DHB	1 1/2	24	—	20
	—	UB5DJB	2	24	—	20
	—	UB5FJB	2	36	—	25
	—	UB5DKB	2 1/2	24	—	15
	UB5DL	UB5DLB	3	24	1	10
	—	UB5FLB	3	36	—	1
	UB5DN	UB5DNB	4	24	1	5
	—	UB5FNB	4	36	—	1
	UB5FP	—	5	36	1	—
11 1/4° ELBOW	UB3FP	—	5	36	1	—

Note: Elbows 72" and larger may be shipped in segments. Consult factory for specifics.

Flexible PVC Elbows



- UL Listed for exposed and direct-burial applications in accordance with Article 356 of the NEC®
- 0°–90° bending and offset applications
- O-ring seal for moisture-tight connections
- Maintains round shape throughout bend
- Sunlight resistant
- Non-corrosive — all PVC and Neoprene material
- Fully assembled and ready to use

CAT. NO.	SIZE (IN.)	STD. CTN.	STD. WT. (LBS.)	LENGTH FULLY ASSEMBLED (IN.)
UAFAD	1/2	8	1.6	8.5
UAFAE	3/4	6	1.9	9.6
UAFAF	1	6	2.4	11.9

NEC and National Electrical Code are registered trademarks of the National Fire Protection Association, Inc.