

VICTOR STEEL CLAMPS

FOR TUBING AND CABLE

TUBING DIA. (O.D.)	VICTOR PART NUMBER	PRICE LIST PAGE	MOUNTING HOLE SIZE	MATERIAL THICKNESS	MATERIAL WIDTH	PIECES PER BOX	PIECES PER CARTON	LBS PER CARTON
--------------------	--------------------	-----------------	--------------------	--------------------	----------------	----------------	-------------------	----------------

STANDARD SERIES


3/32	10543-S	1	5/32	.032	3/8	100	1000	3
1/8	10545-S	1	5/32	.032	3/8	100	1000	3
5/32	10547-S	1	5/32	.032	3/8	100	1000	3
3/16	10550-S	1	5/32	.032	3/8	100	1000	4
1/4	10551-S	1	5/32	.032	3/8	100	1000	4
5/16	10552-S	1	5/32	.032	3/8	100	1000	5
3/8	10553-S	1	5/32	.032	3/8	100	1000	5
3/32	10563-S	1	13/64	.032	3/8	100	1000	3
1/8	10565-S	1	13/64	.032	3/8	100	1000	3
5/32	10567-S	1	13/64	.032	3/8	100	1000	3
3/16	10570-S	1	13/64	.032	3/8	100	1000	4
1/4	10571-S	1	13/64	.032	3/8	100	1000	4
5/16	10572-S	1	13/64	.032	3/8	100	1000	5
3/8	10573-S	1	13/64	.032	3/8	100	1000	5



HEAVY SERIES

1/8	10585-S	1	13/64	.062	3/8	100	1000	6
5/32	10587-S	1	13/64	.062	3/8	100	1000	6
3/16	10590-S	1	13/64	.062	3/8	100	1000	7
1/4	10591-S	1	13/64	.062	3/8	100	1000	7
5/16	10592-S	1	13/64	.062	3/8	100	1000	8
3/8	10593-S	1	13/64	.062	3/8	100	1000	8
1/4	11101-S	2	7/32	.062	1/2	100	1000	10
5/16	11102-S	2	7/32	.062	1/2	100	1000	12
3/8	11103-S	2	7/32	.062	1/2	100	1000	12

HEAVY SERIES - "V" SHAPE

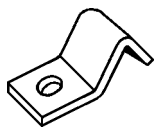

1/8-3/16	11100-S	2	7/32	.062	1/2	100	1000	8
1/8-3/16	11150-S	2	9/32	.062	5/8	100	1000	10
5/16-7/16	10802-S	2	7/32	.062	1/2	100	1000	11
7/16-1/2	19104-S	4	7/32	.062	5/8	100	1000	18
7/16-1/2	10804-S	2	9/32	.062	5/8	100	1000	18

EXTRA HEAVY SERIES



1/4	11151-S	2	9/32	.062	5/8	100	1000	13
5/16	11152-S	2	9/32	.062	5/8	100	1000	15
3/8	11153-S	2	9/32	.062	5/8	100	1000	17
7/16	11104-S	2	9/32	.062	5/8	100	1000	16
1/2	11105-S	2	9/32	.062	9/16	100	1000	17
9/16	11106-S	2	9/32	.062	5/8	100	1000	20
5/8	11108-S	2	9/32	.062	5/8	100	1000	24
11/16	11110-S	2	9/32	.062	5/8	100	1000	25
3/4	11112-S	2	9/32	.062	5/8	100	1000	28
13/16	11115-S	2	9/32	.062	5/8	100	1000	30
7/8	11120-S	2	9/32	.062	5/8	100	1000	31
15/16	11122-S	2	9/32	.062	5/8	100	1000	33
1	11125-S	2	9/32	.062	5/8	100	1000	36
1 1/4	11130-S	2	9/32	.062	5/8	100	500	20


VICTOR STEEL CLAMPS

FOR SERVICE ENTRANCE CABLE

CABLE SIZE & DESCRIPTION	VICTOR PART NUMBER	PRICE LIST PAGE	A	B	D	T	W	PIECES PER BOX	PIECES PER CARTON	LBS PER CARTON
--------------------------	--------------------	-----------------	---	---	---	---	---	----------------	-------------------	----------------


STANDARD SERIES

8-3 & 8-AWG-3C	10076-S	1	11/16	3/8	9/32	.062	5/8	100	1000	21
6-3	10082-S	1	23/32	1/2	9/32	.062	5/8	100	1000	23
6-2 & 8-1										
4-3	10084-S	1	7/8	17/32	9/32	.062	5/8	100	1000	25
2-3	10085-S	1	31/32	17/32	9/32	.062	5/8	100	1000	28
2-2 & 4-1										
2-3	10086-S	1	1	5/8	9/32	.062	5/8	100	1000	32
8-3 & 8-AWG-3C	19176-S	4	11/16	3/8	7/32	.062	5/8	100	1000	21
6-3	19182-S	4	23/32	1/2	7/32	.062	5/8	100	1000	22
6-2 & 8-1										
4-3	19184-S	4	7/8	17/32	7/32	.062	5/8	100	1000	25
2-3	19186-S	4	1	5/8	7/32	.062	5/8	100	1000	32

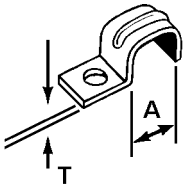


HEAVY SERIES

8-3 & 8-AWG-3C	10776-S	2	11/16	3/8	9/32	.093	3/4	100	1000	41
6-3	10782-S	2	23/32	1/2	9/32	.093	3/4	100	1000	47
6-2 & 8-1										
4-3	10784-S	2	7/8	17/32	9/32	.093	3/4	100	1000	49
2-3	10785-S	2	31/32	17/32	9/32	.093	3/4	100	500	25
2-2 & 4-1										
2-3	10786-S	2	1	5/8	9/32	.093	3/4	100	500	28
2-3(OLD)	10790-S	2	1 1/16	5/8	9/32	.093	3/4	100	500	30
1-3	10793-S	2	1 3/16	5/8	9/32	.093	3/4	100	500	30
2/0-3	10795-S	2	1 9/32	21/32	9/32	.093	3/4	100	500	31
2/0-2 & 1-1										
2/0-3	10796-S	2	1 7/16	3/4	9/32	.120	1	50	250	31
4/0-2 & 2/0-1	10797-S	2	1 15/32	7/8	9/32	.120	1	50	250	34
4/0-3	10798-S	2	1 11/16	15/16	9/32	.120	1	50	250	36
4/0-3	10799-S	2	1 3/4	1 1/16	9/32	.120	1	50	250	38

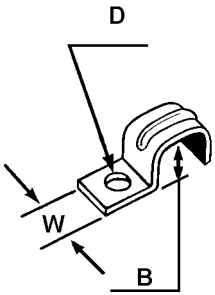

LIGHT WEIGHT FOR ROMEX CABLE

12-2, 14-2	10090-S	1	19/32	11/32	13/64	.032	1/2	100	1000	10
------------	---------	---	-------	-------	-------	------	-----	-----	------	----

 


Sample clamps are available to determine best fit.

VICTOR STEEL CLAMPS

FOR UF CABLE "ROMEX" AND "P.V.C."


CABLE SIZE & DESCRIPTION	VICTOR PART NUMBER	PRICE LIST PAGE	MOUNTING HOLE SIZE	MATERIAL THICKNESS	MATERIAL WIDTH	PIECES PER BOX	PIECES PER CARTON	LBS PER CARTON
--------------------------	--------------------	-----------------	--------------------	--------------------	----------------	----------------	-------------------	----------------

UF CABLE

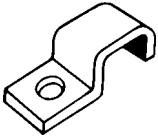

10-2	15323-S	4	7/32	.062	1/2	100	1000	10
10-3, 10-3 WITH GROUND 600V	19103-S	4	7/32	.062	1/2	100	1000	10
12-2, 14-2, 16-3 S.P.T. CORD	10072-S	1	7/32	.062	1/2	100	1000	10
12-3	19178-S	4	7/32	.062	5/8	100	1000	17


P.V.C. AND ROMEX CABLE

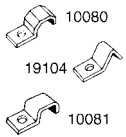

12-2, 14-2	10080-S	1	7/32	.062	9/16	100	1000	14
12-2, 14-2	10081-S	1	7/32	.062	9/16	100	1000	18
12-3, 14-3	19104-S	4	7/32	.062	5/8	100	1000	18

VICTOR STEEL GANG CLAMPS

MADE OF .062 X 1/2 STEEL WITH 7/32 MOUNTING HOLE

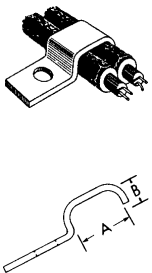

VICTOR PART NUMBER	NUMBER OF LINES	PRICE LIST PAGE	"A" DIM.	"B" DIM.	PIECES PER BOX	PIECES PER CARTON	LBS PER CARTON
15321-S	2	4	5/32	1/8	100	1000	8
15322-S	3	4	5/16	1/8	100	1000	9
15323-S	4	4	15/32	1/8	100	1000	10
15324-S	5	4	5/8	1/8	100	1000	11
15325-S	6	4	25/32	1/8	100	1000	11
15326-S	7	4	15/16	1/8	100	1000	12
15327-S	8	4	1-3/32	1/8	100	1000	15
15328-S	9	4	1-1/4	1/8	100	1000	14
19102-S	2	4	1/2	7/32	100	1000	12
19103-S	3	4	3/4	7/32	100	1000	10