




VICTOR "SNAP ON" STEEL CLAMPS

FOR THIN WALL CONDUIT (E.M.T.)

CONDUIT SIZE (E.M.T.)	VICTOR PART NUMBER	PRICE LIST PAGE	MOUNTING HOLE SIZE	MATERIAL THICKNESS	MATERIAL WIDTH	PIECES PER BOX	PIECES PER CARTON	LBS PER CARTON
-----------------------	--------------------	-----------------	--------------------	--------------------	----------------	----------------	-------------------	----------------

STANDARD SERIES

1/2	10043-S	1	9/32	.062	5/8	100	1000	24
3/4	10044-S	1	9/32	.062	5/8	100	1000	31
1	10045-S	1	9/32	.062	3/4	100	500	22
1 1/4	10046-S	1	9/32	.093	3/4	50	250	23

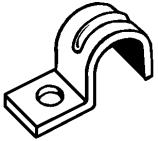

HEAVY SERIES

1/2	10743-S	2	9/32	.093	3/4	100	1000	43
3/4	10744-S	2	9/32	.093	3/4	100	500	28
1	10745-S	2	9/32	.093	3/4	50	500	36
1 1/4	10746-S	2	13/32	.125	1	25	125	20
1 1/2	10747-S	2	13/32	.125	1	25	125	22
2	10748-S	2	21/32	.125	1 1/2	-	50	17

EXTRA HEAVY SERIES

1 1/4	17146-S	4	13/32	.188	1	-	50	13
1 1/2	17147-S	4	13/32	.250	1	-	50	18
2	17148-S	4	21/32	.250	1 1/2	-	25	17
2 1/2	17119-S	4	21/32	.250	1 1/2	-	25	25
3	17120-S	4	21/32	.250	1 1/2	-	25	30
3 1/2	17121-S	4	21/32	.250	1 1/2	-	20	25
4	17122-S	4	21/32	.250	1 1/2	-	20	28



SMALL HOLE CLAMPS

1/2	19143-S	4	7/32	.062	5/8	100	1000	25
3/4	19144-S	4	7/32	.062	5/8	100	1000	31
1	19145-S	4	7/32	.062	3/4	100	500	22
2	19148-S	4	13/32	.125	1 1/2	-	50	17




SLOTTED HOLE CLAMPS

1/2	18743-S	4	9/32X1/2	.093	3/4	100	1000	37
3/4	18744-S	4	9/32X1/2	.093	3/4	100	500	30
1	18745-S	4	9/32X1/2	.093	3/4	50	500	38



BLANK CLAMPS - STANDARD SERIES (TAIL LENGTH 1 1/8")

1/2	15043-S	4	NONE	.062	3/4	100	1000	37
3/4	15044-S	4	NONE	.062	3/4	100	500	23

 

BLANK CLAMPS - HEAVY SERIES (TAIL LENGTH 1 1/8")

1/2	15743-S	4	NONE	.093	3/4	100	500	31
3/4	15744-S	4	NONE	.093	3/4	100	500	35



VICTOR "SNAP ON" STEEL CLAMPS

FOR "BX" CABLE

"BX" CABLE	VICTOR PART NUMBER	PRICE LIST PAGE	MOUNTING HOLE SIZE	MATERIAL THICKNESS	MATERIAL WIDTH	PIECES PER BOX	PIECES PER CARTON	LBS PER CARTON
14-3 TO 12-3	11105-S	2	9/32	.062	9/16	100	1000	17
& 3/8 FLEX	19105-S	4	7/32	.062	9/16	100	1000	18
12-4 TO 10-4 & 3/8 SHELL GROUND	11106-S	2	9/32	.062	5/8	100	1000	20



BX cable outer diameters may vary by manufacturer and material.