









Wall Plates Combination Openings

Standard Size Plastic & Metal

Pass & Seymour



| Description | Color | Nylon | Thermoset | Metal | |
|--|---|--|--|--|---|
| | | TradeMaster® Plates | Smooth | Material | Smooth |
| Toggle Switch & Duplex Receptacle Openings | | | | | |
| Two Gang 1 Toggle, 1 Duplex  | Ivory White Brown Gray Black Red Light Almond | TP18-I TP18-W TP18 TP18-GRY TP18-BK TP18-RED TP18-LA | SP18-I SP18-W SP18 SP18-GRY SP18-LA | Brass Polished Brass 302S/S | SB18 SB18-PB SS18 |
| Three Gang 2 Toggles, 1 Duplex  | Ivory White Brown Gray Black Red Light Almond | TP28-I TP28-W TP28 TP28-GRY TP28-BK TP28-RED TP28-LA | SP28-I SP28-W SP28 SP28-GRY SP28-LA | Brass Polished Brass 302S/S | SB28 SB28-PB SS28 |
| Four Gang 3 Toggles, 1 Duplex  | Ivory White Brown Gray Light Almond | | SP38-I SP38-W SP38 SP38-GRY SP38-LA | Polished Brass 302S/S | SB38-PB SS38 |
| Five Gang 4 Toggles, 1 Duplex  | | | | 302S/S 302S/S Painted Ivory 302S/S Painted White | SS48 SS48-I SS48-W |
| Toggle Switch & Decorator Openings | | | | | |
| Two Gang 1 Toggle, 1 Decorator  | Ivory White Brown Gray Black Light Almond | TP126-I TP126-W TP126 TP126-GRY TP126-BK TP126-LA | SP126-I SP126-W SP126 SP126-GRY SP126-BK SP126-LA | Aluminum Brass Polished Brass 302S/S | SA126 SB126 SB126-PB SS126 |
| Three Gang 2 Toggles, 1 Decorator  | Ivory White Brown Gray Light Almond Black | TP226-I TP226-W TP226 TP226-GRY TP226-LA TP226-BK | SP226-I SP226-W SP226 SP226-GRY SP226-LA | 302S/S | SS226 |
| Three Gang 1 Toggle, 2 Decorator  | Ivory White Brown Gray Black Light Almond | | SP1262-I SP1262-W SP1262 SP1262-GRY SP1262-BK SP1262-LA | 302S/S | SS1262 |
| Four Gang 3 Toggles, 1 Decorator  | Ivory White Brown Gray Light Almond | | SP326-I SP326-W SP326 SP326-GRY SP326-LA | 302S/S | SS326 |

Wall Plates Specifications



Thermoset SP Series



Nylon TP Series



Screwless Polycarbonate SW Series

Application

Pass & Seymour/Legrand's broad line of Standard Size Plastic and Metal Wall Plates features the most complete range of types, sizes, colors, and finishes available. Choose from more than 1,900 standard plates in non-combustible thermoset plastic material, self-extinguishing nylon material, screwless polycarbonate material, or attractively finished metal, for residential, commercial, institutional, and industrial applications. All plastic wall plates color match to Pass & Seymour/Legrand devices.

Thermoset Plastic Wall Plates Features

- Molded of non-combustible mar-proof material.
- Available in "SP" series in Standard, Junior-Jumbo, and Jumbo sizes.
- Seven standard colors available – Ivory, White, Brown, Gray, Black, Red, and Light Almond.
- Individually wrapped with color-matching screws.
- Resistant to discoloration, grease, oil, solvent and moisture.
- Nominal thickness, .070"

TradeMaster® Thermoplastic Wall Plates Features

- Molded of rugged, practically indestructible self-extinguishing nylon. ("TP" series only.)
- Available in "TP" series, extra 3/16" width and height than Standard size plates; and "TPJ" series, extra 3/16" width and height than Junior-Jumbo size plates.
- Available in Ivory, White, Brown, Gray, Black, Blue, Orange, Red, and Light Almond.
- Preferred for hospital, industrial, institutional, and other high-abuse applications.
- Nominal thickness, .070"

Screwless Polycarbonate Wall Plates Features

- Molded of .065" thick polycarbonate with matte finish.
- Subplate made of .042" zinc-plated steel.
- Available in "SW" series, extra 1/8" width and height than Standard size plates.
- Available in Ivory, White, Gray, Black, and Light Almond.
- Oversized opening to accommodate all NEMA 26 decorator-style openings.

Metal Wall Plates Features

- Constructed of corrosion-resistant stainless steel, brass, aluminum, chrome, brushed bronze or galvanized steel.
- Standard, Jumbo, and Tandem size plates available, as well as special Panel size plates up to 5-gangs high and 10-gangs wide.
- Packaged in protective film, with finish-matching screws.
- Variety of special plated finishes. Paintable to match plastic plates.
- Can be silk-screened or engraved, and custom punched with over 300 opening styles.

Materials

- Type 302 Stainless Steel, non-magnetic, .032" nominal thickness, brushed finish. This alloy contains 18% chromium and 8% nickel for superior resistance to corrosion. Recommended for use in food processing plants, dairies, chemical plants, and other industrial, institutional, and commercial applications where corrosive atmospheres exist.
- Type 430 Stainless Steel, magnetic, .032" nominal thickness, brushed finish. Less corrosion-resistant than Type 302, but ideal for general service in high abuse applications in industrial plants, commercial, and institutional buildings.
- Chrome, Brushed and Polished Brass, .040" thick. 70% copper, 30% zinc alloy gives warm, appealing finish to modern decor as well as retrofit applications. Lacquered to prevent corrosion.
- Aluminum, .040" thick. Lustrous satin finish. Lacquered to prevent corrosion.
- Galvanized Steel. Used only for Handy Box Plates.
- Brushed Bronze, .040" thick. 90% copper, 10% zinc. Lacquered to prevent corrosion.



302 Stainless Steel



Polished Brass



Brushed Brass




Aluminum

Wall Plates Specifications

Pass & Seymour




| Standard Size Wall Plates | | | | | |
|--|---------------|---------------|--|---------------|---------------|
| <ul style="list-style-type: none"> Standard size wall plates for all applications. Best fit for surface mount boxes. | | | <ul style="list-style-type: none"> Available in plastic and metal only. | | |
| Dimensions | | | | | |
| 1 gang | 2.75" x 4.5" | 4 gang | 8.125" x 4.5" | 7 gang | 13.62" x 4.5" |
| 2 gang | 4.56" x 4.5" | 5 gang | 10" x 4.5" | 8 gang | 15.44" x 4.5" |
| 3 gang | 6.375" x 4.5" | 6 gang | 11.812" x 4.5" | | |

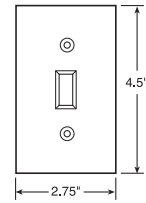


STANDARD

| TradeMaster® Wall Plates | | | | | |
|---|-------------------|---------------|------------------|---------------|-------------------|
| <ul style="list-style-type: none"> Extra 3/16" width and height than Standard size wall plates. Provide better sheet rock coverage with standard size appearance. Available in unbreakable nylon 6 construction only. Screws pre-installed in the duplex, toggle, and decorator single gang plates. | | | | | |
| Dimensions | | | | | |
| 1 gang | 2.9375" x 4.6875" | 3 gang | 6.563" x 4.6875" | 5 gang | 10.188" x 4.6875" |
| 2 gang | 4.75" x 4.6875" | 4 gang | 8.375" x 4.6875" | 6 gang | 12" x 4.6875" |

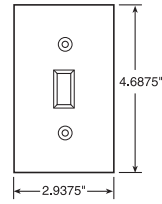


TRADEMASTER STANDARD

| Screwless Polycarbonate Wall Plates | | | | | |
|---|----------------|---------------|----------------|---------------|-----------------|
| <ul style="list-style-type: none"> Extra 1/8" width and height than Standard size wall plates. Provide better sheet rock coverage with standard size appearance. Molded of .065" thick polycarbonate. Subplate made of .042" zinc-plated steel. Oversized opening to accommodate all NEMA 26 decorator-style openings. | | | | | |
| Wall Plate Dimensions | | | | | |
| 1 gang | 3.10" x 4.87" | 3 gang | 6.724" x 4.87" | 5 gang | 10.348" x 4.87" |
| 2 gang | 4.912" x 4.87" | 4 gang | 8.536" x 4.87" | 6 gang | 12.16" x 4.87" |
| Subplate Dimensions | | | | | |
| 1 gang | 2.85" x 4.62" | 3 gang | 6.474" x 4.62" | 5 gang | 10.098" x 4.62" |
| 2 gang | 4.662" x 4.62" | 4 gang | 8.286" x 4.62" | 6 gang | 11.910" x 4.62" |

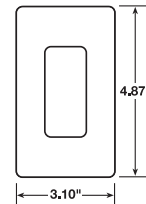


SCREWLESS

| Junior-Jumbo Wall Plates | | | | | |
|---|----------------|---------------|--|--|--|
| <ul style="list-style-type: none"> Extra 3/8" width and height than Standard size wall plates. Additional coverage for sheet rock gaps. | | | <ul style="list-style-type: none"> Available in plastic and metal only. | | |
| Dimensions | | | | | |
| 1 gang | 3.125" x 4.87" | 3 gang | 6.75" x 4.87" | | |
| 2 gang | 4.93" x 4.87" | 4 gang | 8.56" x 4.87" | | |

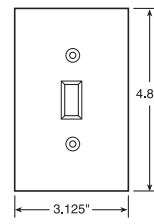


JUNIOR-JUMBO

| TradeMaster Jumbo Wall Plates | | | | | |
|---|-------------------|---------------|-------------------|--|--|
| <ul style="list-style-type: none"> Extra 3/16" width and height than Junior-Jumbo size wall plates. Provide additional coverage for sheet rock gaps, matching the appearance of the TradeMaster Plates. Available in unbreakable nylon 6 construction only. Screws pre-installed in the duplex, toggle, and decorator single gang plates. | | | | | |
| Dimensions | | | | | |
| 1 gang | 3.3125" x 5.0625" | 3 gang | 6.9375" x 5.0625" | | |
| 2 gang | 5.125" x 5.0625" | 4 gang | 8.75" x 5.0625" | | |

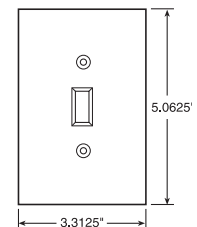

TRADEMASTER JUMBO

| Jumbo Wall Plates | | | | | |
|--|---------------|---------------|--|--|--|
| <ul style="list-style-type: none"> Extra 3/4" width and height than Standard size wall plates. Largest size wall plates to cover larger wall damage. | | | <ul style="list-style-type: none"> Available in plastic and metal only. | | |
| Dimensions | | | | | |
| 1 gang | 3.5" x 5.25" | 3 gang | 7.12" x 5.25" | | |
| 2 gang | 5.31" x 5.25" | 4 gang | 8.93" x 5.25" | | |

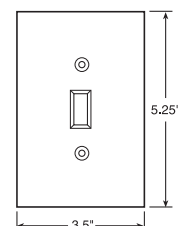

JUMBO