

LBL Curved Basket LED Wraparound



eldoLED



AGGRESSIVELY PRICED

The LBL has closed the price gap between fluorescent and LED, providing dimming as STANDARD at similar price as dimming fluorescent today!!



FAMILIAR LOOK


The LBL provides the look of an existing fluorescent curved basket wrap allowing one for one replacements without disrupting the look of the overall space.



ENERGY SAVINGS

Savings up to 50% over linear fluorescent.

Performance LBL Contractor Select

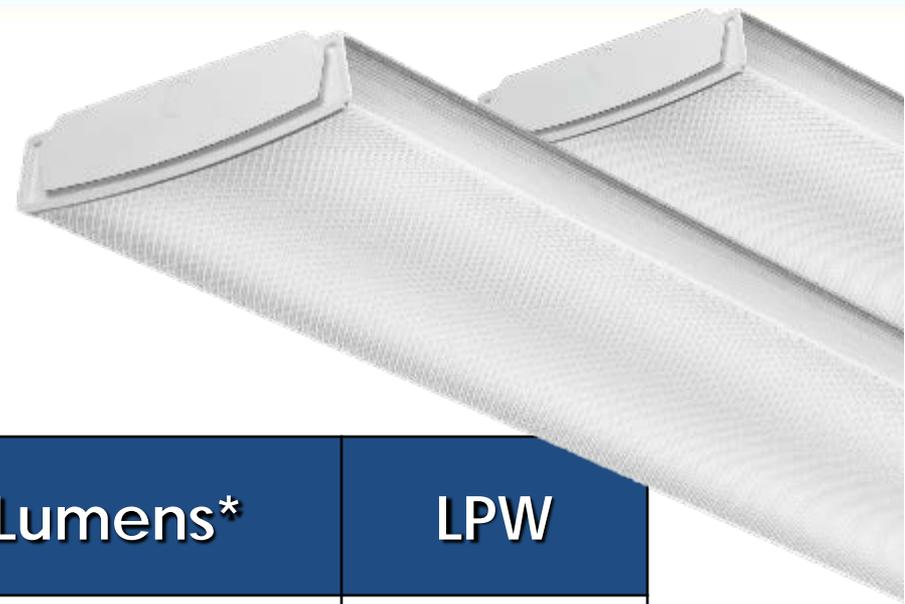

Size	Watts	Lumens*	LPW
LBL2	23W	2248, 2267	98
LBL4	41W	4564, 4600	112

*3500 and 4000K CCT

Suggested Replacements

LBL Contractor Select



Size	System	Lamp Type	Inputs Watts	% Savings with LED
2'	LBL2	LED	23W	-
	2-Lamp T12	F20T12	41.6W*	47%
	2-Lamp T8	F17T8	28W	18%

*Based on a 20W energy savings magnetic ballast.

Suggested Replacements

LBL Contractor Select

Size	System	Lamp Type	Inputs Watts	% Savings with LED
4'	LBL4	LED	41W	-
	2-Lamp T12	F40T12	74.5W*	45%
	2-Lamp T8	F32T8	59W	30%

*Based on a 40W electronic normal power ballast.

Performance LBL Configurable 2'



Lumen Package	Watts	Lumens*	LPW
20L	23W	2203-2295	95-99

*Lumens vary based on CCT chosen.

Performance LBL Configurable 4'



Lumen Package	Watts	Lumens*	LPW
30L	27W	3018-3145	111-116
40L	41W	4471-4659	109-114
48L	48W	5103-5317	106-111
60L	55W	6187-6447	112-117
72L	70W	7223-7527	103-107

*Lumens vary based on CCT chosen.



Lumen Package	Watts	Lumens*	LPW
65L	56W	6523-6797	116-121
80L	71W	8055-8393	113-118

*Lumens vary based on CCT chosen.

CCT	3000K, 3500K, 4000K, 5000K
LED LUMEN MAINTENANCE	L90 / 60,000 hrs
LUMEN PACKAGES	(2') 2000 Lumens; (4') 3000 – 7200 Lumens; (4' Wide Channel) 6500, 8000 Lumens.
WATTAGE RANGE	(2') 23W; (4') 27-71W
DRIVER DIMMING LEVEL	0-10V dimming – Standard eldoLED Dimming 1%
OPTIONAL DRIVER OPTIONS	Step Level Dimming (SLD); eldoLED non-dimming (EOHN)
DIFFUSER TYPE	Prismatic Acrylic Diffuser with light diffusing film
SERVICEABILITY	Replaceable/upgradeable LED Boards and Drivers
VOLTAGES	MVOLT (120-277), 347V
CHANNEL AND END PLATES	Steel Channel and end plates
CONTROL OPTIONS	nLight and Sensor Switch LSXR Occupancy Sensor
WARRANTY	5-Year Limited Warranty

eldoLED



EZ1

eldoLED Dimming 1%



EOHN

eldoLED Non-Dimming



SLD

Step Level Dimming

Options

Battery Pack

The LBL is available with an optional integral emergency battery pack in the 4' version up to 6000 lumens in the LBL and 6500 lumens in the LBLW that is designed to operate for 90 minutes in emergency mode.



EL7L

700 lumen battery pack



EL14L

1400 lumen battery pack

Options Occupancy Sensor



OPTION	LENS	OPERATION	DIM LEVEL	TIME DELAY
LSXR10	10 – Low Mount 360°	On/Off	Off	5M – 5 Minutes
LSXRHL	10 – Low Mount 360°	HL - High/Low Occupancy	3V – Approx. 10% Light Output	5M – 5 Minutes


Example Nomenclature: LBL4 40L EZ1 LP840 LSXRHL

Comparison LBL vs SBL

Category	LBL	SBL
Sizes	(2') – LBL2, (4') – LBL4, (4' Wide Body) – LBL4W	(2') – SBL2, (4') – SBL4
Diffuser	Reduced lamp image through use of light diffusing film. Sonically welded luminous ends.	Prismatic Translucent white diffuser reduces LED pixilation.
Lumens	(2') 2000; (4') 3000, 4000, 4800, 6000, 7200; (4' Wide Housing) – 6500, 8500	(2') 2000; (4') 3000, 4000, 4800, 6000, 7200
CCT	3000K, 3500K, 4000K, 5000K	3000, 3500K, 4000K, 5000K
Controls	nLight; LSXR10 on/off and High/Low Occ sensor	nLight; LSXR10 on/off and High/Low Occ sensor

Surface Mount Solutions

Good

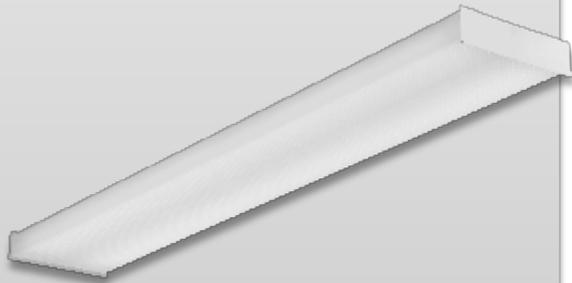

SBL

Better



LBL

Best



STL