

FEATURES & SPECIFICATIONS

INTENDED USE

Designed for low to medium mounting heights. Ideal for applications where dirt, dust, humidity, moisture and cold temperatures are present. **Certain airborne contaminants can diminish integrity of acrylic.** [Click here for Acrylic Environmental Compatibility table for suitable uses.](#)

CONSTRUCTION

Rugged light gray polycarbonate housing with continuous poured gasket for an airtight seal, keeping out moisture, dust and humidity. Cold-rolled steel enclosed wireway included.

Provided with one open hole and knockout at opposite end.

OPTICS

UV stabilized, impact-resistant, polycarbonate lens. Ten (10) snap-fit polycarbonate latches attach the lens to the housing for a tight seal.

ELECTRICAL SYSTEM

Standard electronic ballast (120-277V, 60Hz) ensures no flickering and quiet operation.

Starts instantly down to 0°F (-18°C) with two 32W linear T8 lamps and with two 54W linear T5HO lamps (lamps not included).

INSTALLATION

Two stainless steel mounting brackets included, which allow for flush or chain mounting (chain not included).

LISTINGS

UL listed to US and Canadian safety standards. UL listed for 25°C ambient and wet locations. IP65 rated.

WARRANTY

2-year limited warranty. Complete warranty terms located at www.acuitybrands.com/CustomerResources/Terms_and_conditions.aspx


Actual performance may differ as a result of end-user environment and application.

Note: Specifications subject to change without notice.

Catalog Number
Notes
Type

Contractor Select

Industrial Wet Location

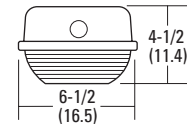

XWL



SPECIFICATIONS			
All dimensions are shown in inches (centimeters) unless otherwise noted.			
Length	Width	Depth	Weight
49-5/8 (126.8)	6-1/2 (16.5)	4-1/2 (11.4)	10.4 lbs. (4.7 kg)

ORDERING INFORMATION

Catalog Number	UPC	Description	# of Lamps	Wattage	Voltage	Lamp Included	Pallet Qty.	Standard Carton Qty.
XWL232 MV	745975639755	Enclosed industrial	2	32	120-277	N	63	1
XWL254 MV	745976008697	Enclosed industrial	2	54	120-277	N	63	1

Accessories: Order as separate catalog number.	
DXWL48	Enclosed industrial replacement lens.
XWL LATCH M10	Enclosed industrial replacement latch.

PHOTOMETRICS

Please see www.lithonia.com.