

Conduit Reducer Bushings

For Threaded Rigid Conduit and IMC

Application:

To reduce the trade size of a tapered entry on a conduit fitting.


Features:

- Threaded for rigid conduit and IMC.
- Made with rolled edge, protects wire insulation.




UL Listed:
E198258

Flush Type

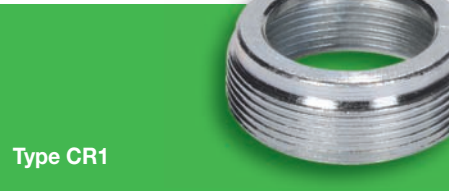

Type CR1

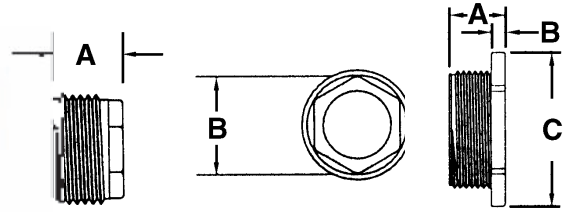

CATALOG NUMBER	TRADE SIZE	DIM A	DIM B	DIM C	UNIT PACK	STANDARD PACK	WEIGHT (LBS.) PER 100 PCS.	NAED MFG #78-5994 UPC/DCI #
CR0	1/2" x 3/8"	0.638	0.908		-	200	3	80007
CR1	3/4" x 1/2"	0.650	0.930		-	200	4	80017
CR2	1" x 1/2"	0.715	1.125		-	100	13	80027
CR3	1" x 3/4"	0.715	1.125		-	100	8	80037
CR4	1-1/4" x 1/2"	0.820	1.470		-	50	29	80047
CR5	1-1/4" x 3/4"	0.820	1.470		-	50	22	80057
CR6	1-1/4" x 1"	0.810	1.470		-	50	14	80067
CR7	1-1/2" x 1/2"	0.850	1.700		-	50	38	80077
CR8	1-1/2" x 3/4"	0.850	1.700		-	50	32	80087
CR9	1-1/2" x 1"	0.850	1.700		-	50	24	80097
CR10	1-1/2" x 1-1/4"	0.850	1.700		-	50	12	80107
CR11	2" x 1/2"	0.970	2.230		-	25	45	80117
CR12	2" x 3/4"	0.970	2.230		-	25	68	80127
CR13	2" x 1"	0.970	2.230		-	25	54	80137
CR14	2" x 1-1/4"	0.970	2.230		-	25	44	80147
CR15	2" x 1-1/2"	0.970	2.230		-	25	31	80157
CR16	2-1/2" x 1/2"	1.070	0.430	1.340	-	10	85	80167
CR17	2-1/2" x 3/4"	1.070	0.500	1.630	-	10	80	80177
CR18	2-1/2" x 1"	1.070	0.580	1.950	-	10	88	80187
CR19	2-1/2" x 1-1/4"	1.070	0.670	2.390	-	10	91	80197
CR20	2-1/2" x 1-1/2"	1.070	0.700	2.680	-	10	80	80207
CR21	2-1/2" x 2"	1.200	0.750	3.485	-	10	50	80217
CR22	3" x 1/2"	1.130	0.430	1.340	-	10	110	80227
CR23	3" x 3/4"	1.130	0.500	1.630	-	10	108	80237
CR24	3" x 1"	1.785	0.500	4.075	-	10	116	80247
CR25	3" x 1-1/4"	2.100	0.410	3.445	-	10	126	80257
CR26	3" x 1-1/2"	2.020	0.440	3.460	-	10	117	80267
CR27	3" x 2"	2.000	0.400	3.380	-	10	121	80277
CR28	3" x 2-1/2"	1.390	0.375	4.395	-	10	100	80287
CR29	3-1/2" x 1/2"	1.180	0.430	1.950	-	5	233	80297
CR30	3-1/2" x 3/4"	1.180	0.500	1.950	-	5	231	80307
CR31	3-1/2" x 1"	1.180	0.580	1.950	-	5	230	80317
CR32	3-1/2" x 1-1/4"	1.180	0.670	2.390	-	5	202	80327
CR33	3-1/2" x 1-1/2"	1.180	0.700	3.280	-	5	200	80337
CR34	3-1/2" x 2"	1.180	0.750	3.280	-	5	233	80347
CR35	3-1/2" x 2-1/2"	1.180	0.920	3.860	-	5	180	80357
CR36	3-1/2" x 3"	1.180	0.980	4.920	-	5	150	80367
CR37	4" x 1/2"	1.220	0.500	1.950	-	5	250	80377
CR38	4" x 3/4"	1.220	0.560	1.950	-	5	240	80387
CR39	4" x 1"	1.220	0.580	1.950	-	5	235	80397
CR40	4" x 1-1/4"	1.220	0.670	2.350	-	5	220	80407
CR41	4" x 1-1/2"	1.220	0.700	2.680	-	5	180	80417
CR42	4" x 2"	1.220	0.750	2.680	-	5	304	80427
CR43	4" x 2-1/2"	1.220	0.920	3.200	-	5	350	80437
CR44	4" x 3"	1.775	0.980	4.625	-	5	238	80447
CR45	4" x 3-1/2"	1.400	1.030	5.200	-	5	138	80457
CR46	5" x 4"	2.130	1.030	5.630	-	5	375	80467
CR47	6" x 5"	2.830	1.030	6.563	-	5	463	80468