

EMT Straps

For EMT Conduit

Application:

Click-on type one-hole straps for E.M.T. Provides support for the conduits, as required by the National Electrical Code.

Standard Materials:

Steel

Standard Finish:

Zinc Plated




UL Listed:
E198338

One-Hole



Type 143S

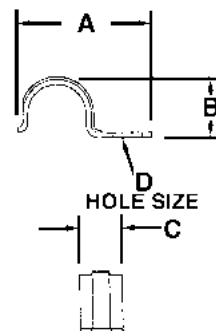


CATALOG NUMBER	TRADE SIZE	DIM A	DIM B	DIM C	DIM D	UNIT PACK	STANDARD PACK	WEIGHT (LBS.) PER 100 PCS.	NAED MFG #78-5994 UPC/DCI #
142S	1/2"	1.720	0.700	0.550	0.312	100	1000	2	81427
143S	3/4"	1.980	0.975	0.630	0.312	100	1000	3	81437
144S	1"	2.210	1.090	0.750	0.312	50	500	4	81447
145S	1-1/4"	2.880	1.540	0.880	0.355	50	500	10	81457
146S	1-1/2"	3.140	1.750	0.990	0.335	-	50	16	81467
147S	2"	3.890	2.150	1.110	0.450	-	50	22	81477
158S	2-1/2"	4.925	2.825	1.245	0.550	-	25	62	81587
159S	3"	5.540	3.430	1.250	0.550	-	25	76	81597
160S	3-1/2"	6.260	3.900	1.250	0.575	-	10	120	81607
161S	4"	6.830	4.390	1.240	0.575	-	10	125	81613

Two-Hole



Type 2143S

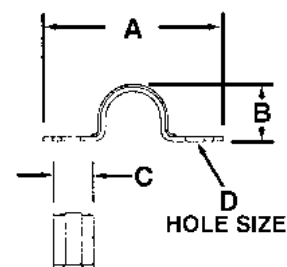

Application:

Snap-on type two-hole straps for E.M.T. are used where higher load bearing supports are desired.

Standard Materials:

Steel

Standard Finish:

Zinc Plated



UL Listed:
E198338

CATALOG NUMBER	TRADE SIZE	DIM A	DIM B	DIM C	DIM D	UNIT PACK	STANDARD PACK	WEIGHT (LBS.) PER 100 PCS.	NAED MFG #78-5994 UPC/DCI #
2142S	1/2"	2.200	0.790	0.560	0.200	-	250	1	21427
2143S	3/4"	2.700	0.980	0.620	0.200	-	200	2	21437
2144S	1"	2.975	1.185	0.690	0.200	-	100	4	21447
2145S	1-1/4"	3.650	1.535	0.750	0.275	-	50	5	21457
2146S	1-1/2"	4.250	1.765	0.870	0.275	-	50	8	21467
2147S	2"	4.730	2.300	0.995	0.325	-	25	13	21477
2158S	2-1/2"	6.025	2.855	0.985	0.345	-	25	20	21533
2159S	3"	6.460	3.425	0.995	0.345	-	20	25	21597
2160S	3-1/2"	7.300	3.925	0.990	0.345	-	10	33	21535
2161S	4"	7.895	4.435	0.995	0.345	-	10	36	21617