


CONDUIT BODIES & RIGID CONDUIT FITTINGS



**MAKE ALL YOUR RIGID &
IMC CONNECTIONS WITH
THE QUALITY, SELECTION
AND EASY-INSTALL LEADER**

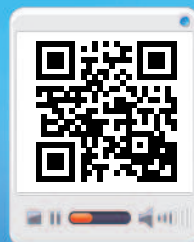

SCAN HERE
TO VISIT OUR
**YOUTUBE
CHANNEL**

BRIDGEPORT'S BETTER BODIES.

How do you get a better body? Bridgeport's high quality production standards make our conduit bodies the better choice for fast, hassle-free installation every time. From the laser-accurate threads on our rigid bodies to the foolproof versatility of our combination LL/LR bodies, Bridgeport conduit bodies are the top performers.

▶ **Threaded bodies for Rigid Conduit and IMC.**

Delivering easy access for inspection, pulling and maintenance. Aluminum units are available with covers and gaskets. Gaskets provide rain-tight protection and are impervious to most liquids and oil. Available mogul bodies and service entrance LBs allow larger access into a raceway for wire pulling. Service entrance LBs mount flush, allowing access to the interior of a conduit system for inspection, pulling and maintenance.

▶ **Set Screw Type conduit bodies for EMT.**

These rugged, copper-free aluminum bodies are available with optional covers and gaskets. Gaskets provide both dust and rain-tight protection and are impervious to most liquids and oil.

▶ **Combination conduit bodies for both Rigid and EMT.** Units have a threaded interior for use with rigid as well as set screws for EMT, reducing your inventory costs. Constructed of rugged, copper-free aluminum.

- Threaded for Rigid Conduit or IMC
- Constructed of Aluminum or Malleable Iron
- Aluminum bodies available with or without covers and gaskets
- UL Listed. File No. E11077
CSA File No. 702847 (Selected Units)

- Set Screw Type
- Optional covers and gaskets
- UL Listed.
File No. E11077

- Combination conduit bodies for use with EMT or Rigid Conduit
- Combination bodies have both:
 - Threaded interior for use with Rigid
 - Set screws for use with EMT
- Preassembled with cover and gasket
- UL Listed.
File No. E11077



CONDUIT BODIES FOR RIGID & IMC CONDUIT

Type C Conduit Bodies

 File No. E11077

 File No. 702847 (C-41CG thru C-46CG)



Catalog Number	Trade Size	Material
C-41	1/2"	Aluminum
C-42	3/4"	Aluminum
C-43	1"	Aluminum
C-44	1 1/4"	Aluminum
C-45	1 1/2"	Aluminum
C-46	2"	Aluminum
C-47	2 1/2"	Aluminum
C-48	3"	Aluminum
C-49	3 1/2"	Aluminum
C-50	4"	Aluminum



C-41CG	1/2"	Aluminum w/ Cover and Gasket
C-42CG	3/4"	Aluminum w/ Cover and Gasket
C-43CG	1"	Aluminum w/ Cover and Gasket
C-44CG	1 1/4"	Aluminum w/ Cover and Gasket
C-45CG	1 1/2"	Aluminum w/ Cover and Gasket
C-46CG	2"	Aluminum w/ Cover and Gasket



C-61	1/2"	Malleable Iron
C-62	3/4"	Malleable Iron
C-63	1"	Malleable Iron
C-64	1 1/4"	Malleable Iron
C-65	1 1/2"	Malleable Iron
C-66	2"	Malleable Iron
C-67	2 1/2"	Malleable Iron
C-68	3"	Malleable Iron

Type LB Conduit Bodies

 File No. E11077

 File No. 702847 (LB-41CG thru LB-50CG)



Catalog Number	Trade Size	Material
LB-41	1/2"	Aluminum
LB-42	3/4"	Aluminum
LB-43	1"	Aluminum
LB-44	1 1/4"	Aluminum
LB-45	1 1/2"	Aluminum
LB-46	2"	Aluminum
LB-47	2 1/2"	Aluminum
LB-48	3"	Aluminum
LB-49	3 1/2"	Aluminum
LB-50	4"	Aluminum

LB-41CG	1/2"	Aluminum w/ Cover and Gasket
LB-42CG	3/4"	Aluminum w/ Cover and Gasket
LB-43CG	1"	Aluminum w/ Cover and Gasket
LB-44CG	1 1/4"	Aluminum w/ Cover and Gasket
LB-45CG	1 1/2"	Aluminum w/ Cover and Gasket

Type LB Conduit Bodies (cont.)



Catalog Number	Trade Size	Material
LB-46CG	2"	Aluminum w/ Cover and Gasket
LB-47CG	2 1/2"	Aluminum w/ Cover and Gasket
LB-48CG	3"	Aluminum w/ Cover and Gasket
LB-49CG	3 1/2"	Aluminum w/ Cover and Gasket
LB-50CG	4"	Aluminum w/ Cover and Gasket



LB-61	1/2"	Malleable Iron
LB-62	3/4"	Malleable Iron
LB-63	1"	Malleable Iron
LB-64	1 1/4"	Malleable Iron
LB-65	1 1/2"	Malleable Iron
LB-66	2"	Malleable Iron
LB-67	2 1/2"	Malleable Iron
LB-68	3"	Malleable Iron
LB-69	3 1/2"	Malleable Iron
LB-70	4"	Malleable Iron



LB-61CG	1/2"	Malleable Iron
LB-62CG	3/4"	Malleable Iron
LB-63CG	1"	Malleable Iron
LB-64CG	1 1/4"	Malleable Iron
LB-65CG	1 1/2"	Malleable Iron
LB-66CG	2"	Malleable Iron
LB-67CG	2 1/2"	Malleable Iron
LB-68CG	3"	Malleable Iron
LB-69CG	3 1/2"	Malleable Iron
LB-70CG	4"	Malleable Iron

Type LL Conduit Bodies

 File No. E11077

 File No. 702847 (LL-41CG thru LL-46CG)



Catalog Number	Trade Size	Material
LL-41	1/2"	Aluminum
LL-42	3/4"	Aluminum
LL-43	1"	Aluminum
LL-44	1 1/4"	Aluminum
LL-45	1 1/2"	Aluminum
LL-46	2"	Aluminum
LL-47	2 1/2"	Aluminum
LL-48	3"	Aluminum
LL-49	3 1/2"	Aluminum
LL-50	4"	Aluminum



LL-41CG	1/2"	Aluminum w/ Cover and Gasket
LL-42CG	3/4"	Aluminum w/ Cover and Gasket
LL-43CG	1"	Aluminum w/ Cover and Gasket
LL-44CG	1 1/4"	Aluminum w/ Cover and Gasket
LL-45CG	1 1/2"	Aluminum w/ Cover and Gasket
LL-46CG	2"	Aluminum w/ Cover and Gasket

CONDUIT BODIES FOR RIGID & IMC CONDUIT (CONT.)

Type LL Conduit Bodies (cont.)



Catalog Number	Trade Size	Material
LL-61	1/2"	Malleable Iron
LL-62	3/4"	Malleable Iron
LL-63	1"	Malleable Iron
LL-64	1 1/4"	Malleable Iron
LL-65	1 1/2"	Malleable Iron
LL-66	2"	Malleable Iron
LL-67	2 1/2"	Malleable Iron
LL-68	3"	Malleable Iron

Type LR Conduit Bodies



File No. E11077



File No. 702847 (LR-41CG thru LR-46CG)



Catalog Number	Trade Size	Material
LR-41	1/2"	Aluminum
LR-42	3/4"	Aluminum
LR-43	1"	Aluminum
LR-44	1 1/4"	Aluminum
LR-45	1 1/2"	Aluminum
LR-46	2"	Aluminum
LR-47	2 1/2"	Aluminum
LR-48	3"	Aluminum
LR-49	3 1/2"	Aluminum
LR-50	4"	Aluminum



LR-41CG	1/2"	Aluminum w/ Cover and Gasket
LR-42CG	3/4"	Aluminum w/ Cover and Gasket
LR-43CG	1"	Aluminum w/ Cover and Gasket
LR-44CG	1 1/4"	Aluminum w/ Cover and Gasket
LR-45CG	1 1/2"	Aluminum w/ Cover and Gasket
LR-46CG	2"	Aluminum w/ Cover and Gasket



LR-61	1/2"	Malleable Iron
LR-62	3/4"	Malleable Iron
LR-63	1"	Malleable Iron
LR-64	1 1/4"	Malleable Iron
LR-65	1 1/2"	Malleable Iron
LR-66	2"	Malleable Iron
LR-67	2 1/2"	Malleable Iron
LR-68	3"	Malleable Iron

Type T Conduit Bodies



File No. E11077



File No. 702847 (T-41CG thru T-46CG)



Catalog Number	Trade Size	Material
T-41	1/2"	Aluminum
T-42	3/4"	Aluminum
T-43	1"	Aluminum
T-44	1 1/4"	Aluminum
T-45	1 1/2"	Aluminum
T-46	2"	Aluminum
T-47	2 1/2"	Aluminum
T-48	3"	Aluminum
T-49	3 1/2"	Aluminum
T-50	4"	Aluminum

Type T Conduit Bodies (cont.)



Catalog Number	Trade Size	Material
T-41CG	1/2"	Aluminum w/ Cover and Gasket
T-42CG	3/4"	Aluminum w/ Cover and Gasket
T-43CG	1"	Aluminum w/ Cover and Gasket
T-44CG	1 1/4"	Aluminum w/ Cover and Gasket
T-45CG	1 1/2"	Aluminum w/ Cover and Gasket
T-46CG	2"	Aluminum w/ Cover and Gasket



T-61	1/2"	Malleable Iron
T-62	3/4"	Malleable Iron
T-63	1"	Malleable Iron
T-64	1 1/4"	Malleable Iron
T-65	1 1/2"	Malleable Iron
T-66	2"	Malleable Iron
T-67	2 1/2"	Malleable Iron
T-68	3"	Malleable Iron

Mogul Conduit Bodies

Allows larger access to the inside of a raceway for wire pulling. Raintight.



File No. E11077



File No. E11077 (MLB-47 thru MLB-50)



Catalog Number	Trade Size	Material	Cu. In. of Volume
MLB-44	1 1/4"	Aluminum	40
MLB-45	1 1/2"	Aluminum	128
MLB-46	2"	Aluminum	128
MLB-47	2 1/2"	Aluminum	437
MLB-48	3"	Aluminum	437
MLB-49	3 1/2"	Aluminum	824
MLB-50	4"	Aluminum	824



Service Entrance LB

Allows access to the interior of a conduit system for inspection, pulling and maintenance. Mounts flush against structure. Raintight.




File No. E11077



Catalog Number	Trade Size	Material
1025	1/2"	Aluminum
1026	3/4"	Aluminum
1027	1"	Aluminum
1028	1 1/4"	Aluminum
1029	1 1/2"	Aluminum
1030	2"	Aluminum
1028-XL	1 1/4"	Aluminum
1030-XL	2"	Aluminum

CONDUIT BODIES FOR EMT CONDUIT

 Type C Set Screw Type




 File No. E11077

Catalog Number	Trade Size	Material
C-31	1/2"	Aluminum
C-32	3/4"	Aluminum
C-33	1"	Aluminum
C-34	1 1/4"	Aluminum
C-35	1 1/2"	Aluminum
C-36	2"	Aluminum
C-37CG*	2 1/2"	Aluminum
C-38CG*	3"	Aluminum
C-39CG*	3 1/2"	Aluminum
C-40CG*	4"	Aluminum

*Provided with cover and neoprene gasket.

 Type LR Set Screw Type



 File No. E11077

Catalog Number	Trade Size	Material
LR-31	1/2"	Aluminum
LR-32	3/4"	Aluminum
LR-33	1"	Aluminum
LR-34	1 1/4"	Aluminum
LR-35	1 1/2"	Aluminum
LR-36	2"	Aluminum

Type T Set Screw Type



 File No. E11077

Catalog Number	Trade Size	Material
T-31	1/2"	Aluminum
T-32	3/4"	Aluminum
T-33	1"	Aluminum
T-34	1 1/4"	Aluminum
T-35	1 1/2"	Aluminum
T-36	2"	Aluminum

Type LB Set Screw Type



 File No. E11077

Catalog Number	Trade Size	Material
LB-31	1/2"	Aluminum
LB-32	3/4"	Aluminum
LB-33	1"	Aluminum
LB-34	1 1/4"	Aluminum
LB-35	1 1/2"	Aluminum
LB-36	2"	Aluminum
LB-37	2 1/2"	Aluminum
LB-38	3"	Aluminum
LB-39	3 1/2"	Aluminum
LB-40	4"	Aluminum

Type LL Set Screw Type



 File No. E11077

Catalog Number	Trade Size	Material
LL-31	1/2"	Aluminum
LL-32	3/4"	Aluminum
LL-33	1"	Aluminum
LL-34	1 1/4"	Aluminum
LL-35	1 1/2"	Aluminum
LL-36	2"	Aluminum

COMBINATION CONDUIT BODIES FOR RIGID, IMC AND EMT CONDUIT

Type C Combination

 File No. E11077

 Listed Raintight when used with rigid conduit.



Catalog Number	Trade Size	Material
C-41CGC	1/2"	Aluminum w/ Cover and Gasket
C-42CGC	3/4"	Aluminum w/ Cover and Gasket
C-43CGC	1"	Aluminum w/ Cover and Gasket
C-44CGC	1 1/4"	Aluminum w/ Cover and Gasket
C-45CGC	1 1/2"	Aluminum w/ Cover and Gasket
C-46CGC	2"	Aluminum w/ Cover and Gasket

Type LL/LR Combination

 File No. E11077

 Listed Raintight when used with rigid conduit.



Catalog Number	Trade Size	Material
LLR-41	1/2"	Aluminum w/ Cover and Gasket
LLR-42	3/4"	Aluminum w/ Cover and Gasket
LLR-43	1"	Aluminum w/ Cover and Gasket
LLR-44	1 1/4"	Aluminum w/ Cover and Gasket
LLR-45	1 1/2"	Aluminum w/ Cover and Gasket
LLR-46	2"	Aluminum w/ Cover and Gasket

Type LB Combination

 File No. E11077

 Listed Raintight when used with rigid conduit.



Catalog Number	Trade Size	Material
LB-41CGC	1/2"	Aluminum w/ Cover and Gasket
LB-42CGC	3/4"	Aluminum w/ Cover and Gasket
LB-43CGC	1"	Aluminum w/ Cover and Gasket
LB-44CGC	1 1/4"	Aluminum w/ Cover and Gasket
LB-45CGC	1 1/2"	Aluminum w/ Cover and Gasket
LB-46CGC	2"	Aluminum w/ Cover and Gasket

Type LR Combination

 File No. E11077

 Listed Raintight when used with rigid conduit.



Catalog Number	Trade Size	Material
LR-41CGC	1/2"	Aluminum w/ Cover and Gasket
LR-42CGC	3/4"	Aluminum w/ Cover and Gasket
LR-43CGC	1"	Aluminum w/ Cover and Gasket
LR-44CGC	1 1/4"	Aluminum w/ Cover and Gasket
LR-45CGC	1 1/2"	Aluminum w/ Cover and Gasket
LR-46CGC	2"	Aluminum w/ Cover and Gasket

Type LL Combination

 File No. E11077

 Listed Raintight when used with rigid conduit.



Catalog Number	Trade Size	Material
LL-41CGC	1/2"	Aluminum w/ Cover and Gasket
LL-42CGC	3/4"	Aluminum w/ Cover and Gasket
LL-43CGC	1"	Aluminum w/ Cover and Gasket
LL-44CGC	1 1/4"	Aluminum w/ Cover and Gasket
LL-45CGC	1 1/2"	Aluminum w/ Cover and Gasket
LL-46CGC	2"	Aluminum w/ Cover and Gasket

Type T Combination

 File No. E11077

 Listed Raintight when used with rigid conduit.



Catalog Number	Trade Size	Material
T-41CGC	1/2"	Aluminum w/ Cover and Gasket
T-42CGC	3/4"	Aluminum w/ Cover and Gasket
T-43CGC	1"	Aluminum w/ Cover and Gasket
T-44CGC	1 1/4"	Aluminum w/ Cover and Gasket
T-45CGC	1 1/2"	Aluminum w/ Cover and Gasket
T-46CGC	2"	Aluminum w/ Cover and Gasket

RIGID, IMC AND EMT ACCESSORIES

Conduit Body Covers

Encloses conduit body; supplied with screws.

 File No. E11077 Aluminum Only
(SC-41 thru SC-49)



Catalog Number	Trade Size	Material
SC-41	1/2"	Aluminum
SC-42	3/4"	Aluminum
SC-43	1"	Aluminum
SC-44	1 1/4" - 1 1/2"	Aluminum
SC-46	2"	Aluminum
SC-47	2 1/2" - 3"	Aluminum
SC-49	3 1/2" - 4"	Aluminum

SC-61	1/2"	Steel
SC-62	3/4"	Steel
SC-63	1"	Steel
SC-64	1 1/4" - 1 1/2"	Steel
SC-66	2"	Steel
SC-67	2 1/2" - 3"	Steel
SC-69	3 1/2" - 4"	Steel

Conduit Body Gaskets

SG series provides dust-tight seal between conduit body and cover.

SGN series provides both dust and rain-tight protection.

SGN gaskets are impervious to most liquids and oil.



Catalog Number	Trade Size	Material
SG-61	1/2"	Cellulose
SG-62	3/4"	Cellulose
SG-63	1"	Cellulose
SG-64	1 1/4" - 1 1/2"	Cellulose
SG-66	2"	Cellulose
SG-67	2 1/2" - 3"	Cellulose
SG-69	3 1/2" - 4"	Cellulose

SGN-61	1/2"	Neoprene
SGN-62	3/4"	Neoprene
SGN-63	1"	Neoprene
SGN-64	1 1/4" - 1 1/2"	Neoprene
SGN-66	2"	Neoprene
SGN-67	2 1/2" - 3"	Neoprene
SGN-69	3 1/2" - 4"	Neoprene

TECHNICAL SPECIFICATIONS

Die Cast Aluminum Conduit Bodies

Trade Size	Maximum Number of Conductors				
	LB	C	LL	LR	T
1/2"	N/A	N/A	N/A	N/A	N/A
3/4"	3 #6 AWG	3 #6 AWG	3 #6 AWG	3 #6 AWG	3 #6 AWG
1"	3 #4 AWG	3 #4 AWG	3 #4 AWG	3 #4 AWG	3 #4 AWG
1 1/4"	3 #2 AWG	3 #2 AWG	3 #2 AWG	3 #2 AWG	3 #2 AWG
1 1/2"	3 #1/0 AWG	3 #1/0 AWG	3 #1/0 AWG	3 #1/0 AWG	3 #2 AWG
2"	3 #4/0 AWG*	3 #2/0 AWG	3 #4/0 AWG	3 #4/0 AWG	3 #1 AWG
2 1/2"	3 #300 MCM	3 #250 MCM	3 #300 MCM*	3 #300 MCM*	3 #250 MCM*
3"	3 #350 MCM*	3 #250 MCM	3 #350 MCM*	3 #350 MCM*	3 #250 MCM*
3 1/2"	3 #400 MCM	3 #300 MCM*	3 #350 MCM*	3 #350 MCM*	3 #250 MCM*
4"	3 #400 MCM	3 #300 MCM*	3 #350 MCM*	3 #350 MCM*	3 #250 MCM*

Trade Size	Volume in Cu. In.				
	LB	C	LL	LR	T
1/2"	4.35	4.35	4.35	4.35	4.35
3/4"	7.3	7.3	7.3	7.3	7.3
1"	12.0	12.2	12.2	12.2	12.2
1 1/4"	32.3	33.5	35.8	35.8	33.1
1 1/2"	33.8	33.5	35.8	35.8	33.1
2"	71.2	69.5	69.7	69.7	67.0
2 1/2"	71.2	69.5	69.7	69.7	67.0
3"	183.5	188.0	186.0	186.0	175.0
3 1/2"	304.9	307.0	306.0	306.0	298.0
4"	308.0	309.0	308.0	308.0	300.0

Malleable Iron Conduit Bodies

Trade Size	Maximum Number of Conductors				
	LB	C	LL	LR	T
1/2"	N/A	N/A	N/A	N/A	N/A
3/4"	3 #6 AWG	3 #6 AWG	3 #6 AWG	3 #6 AWG	3 #6 AWG
1"	3 #4 AWG	3 #4 AWG	3 #4 AWG	3 #4 AWG	3 #4 AWG
1 1/4"	3 #2 AWG	3 #2 AWG	3 #2 AWG	3 #2 AWG	3 #2 AWG
1 1/2"	3 #1/0 AWG	3 #1/0 AWG	3 #1/0 AWG*	3 #1/0 AWG*	3 #1 AWG
2"	3 #4/0 AWG	3 #4/0 AWG*	3 #4/0 AWG	3 #4/0 AWG	3 #2/0 AWG
2 1/2"	3 #300 MCM	3 #300 MCM*	3 #300 MCM	3 #300 MCM	3 #300 MCM*
3"	3 #400 MCM*	3 #300 MCM*	3 #350 MCM	3 #350 MCM	3 #300 MCM*
3 1/2"	3 #500 MCM	3 #350 MCM	3 #350 MCM	3 #350 MCM	3 #350 MCM
4"	3 #500 MCM	3 #350 MCM	3 #350 MCM	3 #350 MCM	3 #350 MCM

Trade Size	Volume in Cu. In.				
	LB	C	LL	LR	T
1/2"	4.5	4.5	4.5	4.5	4.0
3/4"	7.5	7.5	7.5	7.5	7.0
1"	12.5	12.5	12.5	12.5	12.0
1 1/4"	32.3	32.3	32.3	32.3	32.0
1 1/2"	32.3	32.3	32.3	32.3	32.0
2"	73.0	73.0	73.0	73.0	70.0
2 1/2"	138.0	138.0	138.0	138.0	130.0
3"	170.0	170.0	170.0	170.0	168.0
3 1/2"	300.0	300.0	300.0	300.0	290.0
4"	328.0	328.0	328.0	328.0	324.0

* MAX # OF CONDUCTORS MAY VARY. CONSULT FACTORY.

LEGENDARY QUALITY IN RIGID & IMC BORN OF INNOVATION.

In malleable, zinc and steel, Bridgeport Rigid and IMC conduit products are engineered with the quality and innovation that allows contractors to save time and money on every job. Labor-savings, problem solving products are the key elements in Bridgeport's operating philosophy. So you can do more with less.

 Made for performance.

When you need connectors, coupling, locknuts, bushings or straps, you need Bridgeport Rigid and IMC conduit fittings. Features like captive, deep-slot, tri-drive screws, serrated and reversible fully threaded locknuts and smooth and rounded throat openings make Bridgeport products the best choice for unparalleled field performance.



 Manufactured to be better.

We're investing in equipment, improving process automation, further strengthening quality control and developing new products – all in the U.S. And still today, nearly three-quarters of our product volume is manufactured in the U.S. We've got American-made products for projects that require them.

 Size matters.

From massive mogul conduit bodies to the smallest locknut or strap, we stock the trade sizes contractors need to get more jobs done right.



▶ **Quality is in every box we ship.**
Even our boxes are higher-quality, so our products get to market damage-free and ready for installation. Our state-of-the-art inventory and shipping processes help get products where you need them – on time, every time.



RIGID AND IMC CONDUIT FITTINGS

Set Screw Connectors

 File No. E24001*: 236-DC2 thru 239-DC2; 236-DCI2 thru 239-DCI2

 File No. E24001: 3500 thru 3505; 236 thru 239; 236-I thru 239-I



1/2" thru 1"



2 1/2" thru 4"



2 1/2" thru 4"



1/2" thru 1 1/2"



2"



1/2" thru 2"
Malleable



5" & 6"
Malleable

Catalog Number	Trade Size	Material
30-DC2	1/2"	Zinc Die Cast
31-DC2	3/4"	Zinc Die Cast
32-DC2	1"	Zinc Die Cast
236-DC2	2 1/2"	Zinc Die Cast
237-DC2	3"	Zinc Die Cast
238-DC2	3 1/2"	Zinc Die Cast
239-DC2	4"	Zinc Die Cast

236-DCI2	2 1/2"	Zinc Die Cast/ Insulated Throat
237-DCI2	3"	Zinc Die Cast/ Insulated Throat
238-DCI2	3 1/2"	Zinc Die Cast/ Insulated Throat
239-DCI2	4"	Zinc Die Cast/ Insulated Throat

236	2 1/2"	Steel
237	3"	Steel
238	3 1/2"	Steel
239	4"	Steel

236-I	2 1/2"	Steel/Insulated Throat
237-I	3"	Steel/Insulated Throat
238-I	3 1/2"	Steel/Insulated Throat
239-I	4"	Steel/Insulated Throat

3500-US	1/2"	Made in the USA/Steel
3501-US	3/4"	Made in the USA/Steel
3502-US	1"	Made in the USA/Steel
3503-US	1 1/4"	Made in the USA/Steel
3504-US	1 1/2"	Made in the USA/Steel
3505-US	2"	Made in the USA/Steel

3500	1/2"	Malleable Iron
3501	3/4"	Malleable Iron
3502	1"	Malleable Iron
3503	1 1/4"	Malleable Iron
3504	1 1/2"	Malleable Iron
3505	2"	Malleable Iron
3510	5"	Malleable Iron
3511	6"	Malleable Iron

3510-I	5"	Malleable Iron/ Insulated Throat
3511-I	6"	Malleable Iron/ Insulated Throat



Zinc



Steel



Malleable



Zinc 1/2" thru 1"



Zinc 2 1/2" thru 4"



Steel 2 1/2" thru 4"

Compression Connectors

 File No. E9391

Catalog Number	Trade Size	Material
256-DC2	2 1/2"	Zinc Die Cast
257-DC2	3"	Zinc Die Cast
258-DC2	3 1/2"	Zinc Die Cast
259-DC2	4"	Zinc Die Cast

256-DCI2	2 1/2"	Zinc Die Cast/ Insulated Throat
257-DCI2	3"	Zinc Die Cast/ Insulated Throat
258-DCI2	3 1/2"	Zinc Die Cast/ Insulated Throat
259-DCI2	4"	Zinc Die Cast/ Insulated Throat

3000-US	1/2"	Made in the USA/Steel
3001-US	3/4"	Made in the USA/Steel
3002-US	1"	Made in the USA/Steel
3003-US	1 1/4"	Made in the USA/Steel
3004-US	1 1/2"	Made in the USA/Steel
3005-US	2"	Made in the USA/Steel

3000	1/2"	Malleable Iron
3001	3/4"	Malleable Iron
3002	1"	Malleable Iron
3003	1 1/4"	Malleable Iron
3004	1 1/2"	Malleable Iron
3005	2"	Malleable Iron
3006	2 1/2"	Malleable Iron
3007	3"	Malleable Iron
3008	3 1/2"	Malleable Iron
3009	4"	Malleable Iron

Set Screw Couplings

 File No. E24001*: 3600 thru 3605; 246 thru 249; 246-DC thru 249-DC

 File No. E9391: 3600-US thru 3605-US

 File No. LR39354: 246-DC thru 249-DC

Catalog Number	Trade Size	Material
40-DC	1/2"	Zinc Die Cast
41-DC	3/4"	Zinc Die Cast
42-DC	1"	Zinc Die Cast
246-DC	2 1/2"	Zinc Die Cast
247-DC	3"	Zinc Die Cast
248-DC	3 1/2"	Zinc Die Cast
249-DC	4"	Zinc Die Cast

246	2 1/2"	Steel
247	3"	Steel
248	3 1/2"	Steel
249	4"	Steel

RIGID AND IMC CONDUIT FITTINGS (CONT.)

Set Screw Couplings (cont.)



Steel
1/2" thru 1 1/2"



Steel 2"



1/2" thru 2" Malleable



Malleable 5" & 6"

Catalog Number	Trade Size	Material
3600-US	1/2"	Made in the USA/Steel
3601-US	3/4"	Made in the USA/Steel
3602-US	1"	Made in the USA/Steel
3603-US	1 1/4"	Made in the USA/Steel
3604-US	1 1/2"	Made in the USA/Steel
3605-US	2"	Made in the USA/Steel
3600	1/2"	Malleable Iron
3601	3/4"	Malleable Iron
3602	1"	Malleable Iron
3603	1 1/4"	Malleable Iron
3604	1 1/2"	Malleable Iron
3605	2"	Malleable Iron
3610	5"	Malleable Iron
3611	6"	Malleable Iron

Compression Couplings

UL File No. E9391



Zinc



Steel



Malleable

Catalog Number	Trade Size	Material
266-DC	2 1/2"	Zinc Die Cast
267-DC	3"	Zinc Die Cast
268-DC	3 1/2"	Zinc Die Cast
269-DC	4"	Zinc Die Cast
3100-US	1/2"	Made in the USA/Steel
3101-US	3/4"	Made in the USA/Steel
3102-US	1"	Made in the USA/Steel
3103-US	1 1/4"	Made in the USA/Steel
3104-US	1 1/2"	Made in the USA/Steel
3105-US	2"	Made in the USA/Steel
3100	1/2"	Malleable Iron
3101	3/4"	Malleable Iron
3102	1"	Malleable Iron
3103	1 1/4"	Malleable Iron
3104	1 1/2"	Malleable Iron
3105	2"	Malleable Iron
3106	2 1/2"	Malleable Iron
3107	3"	Malleable Iron
3108	3 1/2"	Malleable Iron
3109	4"	Malleable Iron



Zinc



Steel



EMT to Rigid Combination Couplings

UL File No. E9391: 290-S thru 292-S

UL File No. E9391: 292-MS

Catalog Number	Trade Size	Material
290-DC	1/2"	Zinc Die Cast
291-DC	3/4"	Zinc Die Cast
292-DC	1"	Zinc Die Cast
290-S	1/2"	Steel
291-S	3/4"	Steel
292-S	1"	Steel
290-MS	1/2"	Zinc Plated Steel
291-MS	3/4"	Zinc Plated Steel
292-MS	1"	Zinc Plated Steel

Mighty-Merge® EMT to Rigid Raintight Combination Couplings

ETL Listed



NEW

Catalog Number	Trade Size	Material
290-RT	1/2"	Zinc Die Cast
291-RT	3/4"	Zinc Die Cast
292-RT	1"	Zinc Die Cast

Rigid to Liquid Tight Combination Couplings

UL File No. E9391



NEW

Catalog Number	Trade Size	Material
4369-LT	3/8"	Malleable Iron
4370-LT	1/2"	Malleable Iron
4371-LT	3/4"	Malleable Iron
4372-LT	1"	Malleable Iron
4373-LT	1 1/4"	Malleable Iron
4374-LT	1 1/2"	Malleable Iron
4375-LT	2"	Malleable Iron

Three-Piece Couplings

UL File No. E9391: 1121 thru 1130 & 1121-AL thru 1130-AL

SF File No. LR39354: 1121 thru 1132



Catalog Number	Trade Size	Material
1121	1/2"	Malleable Iron
1122	3/4"	Malleable Iron
1123	1"	Malleable Iron
1124	1 1/4"	Malleable Iron
1125	1 1/2"	Malleable Iron
1126	2"	Malleable Iron
1127	2 1/2"	Malleable Iron
1128	3"	Malleable Iron
1129	3 1/2"	Malleable Iron
1130	4"	Malleable Iron
1131	5"	Malleable Iron
1132	6"	Malleable Iron

RIGID AND IMC CONDUIT FITTINGS (CONT.)

Three-Piece Couplings (cont.)

Catalog Number	Trade Size	Material
1121-AL	1/2"	Aluminum
1122-AL	3/4"	Aluminum
1123-AL	1"	Aluminum
1124-AL	1 1/4"	Aluminum
1125-AL	1 1/2"	Aluminum
1126-AL	2"	Aluminum
1127-AL	2 1/2"	Aluminum
1128-AL	3"	Aluminum
1129-AL	3 1/2"	Aluminum
1130-AL	4"	Aluminum

Mighty-Align™ Self-Aligning, Raintight, Three-Piece Couplings

UL File No. E9391

Catalog Number	Trade Size	Material
1121-RT	1/2"	Malleable Iron
1122-RT	3/4"	Malleable Iron
1123-RT	1"	Malleable Iron
1124-RT	1 1/4"	Malleable Iron
1125-RT	1 1/2"	Malleable Iron
1126-RT	2"	Malleable Iron
1127-RT	2 1/2"	Malleable Iron
1128-RT	3"	Malleable Iron
1129-RT	3 1/2"	Malleable Iron
1130-RT	4"	Malleable Iron

Split Rigid Couplings

UL File No. E9391

Catalog Number	Trade Size	Material
SRC-050	1/2"	Zinc Plated Malleable Iron
SRC-075	3/4"	Zinc Plated Malleable Iron
SRC-100	1"	Zinc Plated Malleable Iron
SRC-125	1 1/4"	Zinc Plated Malleable Iron
SRC-150	1 1/2"	Zinc Plated Malleable Iron
SRC-200	2"	Zinc Plated Malleable Iron
SRC-250	2 1/2"	Zinc Plated Malleable Iron
SRC-300	3"	Zinc Plated Malleable Iron
SRC-350	3 1/2"	Zinc Plated Malleable Iron
SRC-400	4"	Zinc Plated Malleable Iron
SRC-500	5"	Zinc Plated Malleable Iron
SRC-600	6"	Zinc Plated Malleable Iron

Threaded Hubs

UL File No. E9391: Type 4 - Water Tight

SP File No. LR39354



Catalog Number	Trade Size	Material
151-DC	1/2"	Zinc Die Cast
152-DC	3/4"	Zinc Die Cast
153-DC	1"	Zinc Die Cast
154-DC	1 1/4"	Zinc Die Cast
155-DC	1 1/2"	Zinc Die Cast
156-DC	2"	Zinc Die Cast
157-DC	2 1/2"	Zinc Die Cast
158-DC	3"	Zinc Die Cast
159-DC	3 1/2"	Zinc Die Cast
160-DC	4"	Zinc Die Cast

3161	5"	Malleable Iron
3162	6"	Malleable Iron

Bushings

UL File No. E9391: 321 thru 332

UL File No. E11259: 321-B thru 330-B

SP File No. LR39354



Catalog Number	Trade Size	Material
321	1/2"	Plastic 105°C
322	3/4"	Plastic 105°C
323	1"	Plastic 105°C
324	1 1/4"	Plastic 105°C
325	1 1/2"	Plastic 105°C
326	2"	Plastic 105°C
327	2 1/2"	Plastic 105°C
328	3"	Plastic 105°C
329	3 1/2"	Plastic 105°C
330	4"	Plastic 105°C
331	5"	Plastic 105°C
332	6"	Plastic 105°C

321-B	1/2"	Plastic 150°C
322-B	3/4"	Plastic 150°C
323-B	1"	Plastic 150°C
324-B	1 1/4"	Plastic 150°C
325-B	1 1/2"	Plastic 150°C
326-B	2"	Plastic 150°C
327-B	2 1/2"	Plastic 150°C
328-B	3"	Plastic 150°C
329-B	3 1/2"	Plastic 150°C
330-B	4"	Plastic 150°C

Insulated Bushings

 File No. E9391: 361 thru 370

 File No. E9391 (361-DC thru 370-DC)


Catalog Number	Trade Size	Material
361	1/2"	Malleable Iron/ Plastic Metaliner
362	3/4"	Malleable Iron/ Plastic Metaliner
363	1"	Malleable Iron/ Plastic Metaliner
364	1 1/4"	Malleable Iron/ Plastic Metaliner
365	1 1/2"	Malleable Iron/ Plastic Metaliner
366	2"	Malleable Iron/ Plastic Metaliner
367	2 1/2"	Malleable Iron/ Plastic Metaliner
368	3"	Malleable Iron/ Plastic Metaliner
369	3 1/2"	Malleable Iron/ Plastic Metaliner
370	4"	Malleable Iron/ Plastic Metaliner
371	5"	Malleable Iron/ Plastic Metaliner
372	6"	Malleable Iron/ Plastic Metaliner

361-DC	1/2"	Zinc Die Cast/ Plastic Metaliner
362-DC	3/4"	Zinc Die Cast/ Plastic Metaliner
363-DC	1"	Zinc Die Cast/ Plastic Metaliner
364-DC	1 1/4"	Zinc Die Cast/ Plastic Metaliner
365-DC	1 1/2"	Zinc Die Cast/ Plastic Metaliner
366-DC	2"	Zinc Die Cast/ Plastic Metaliner
367-DC	2 1/2"	Zinc Die Cast/ Plastic Metaliner
368-DC	3"	Zinc Die Cast/ Plastic Metaliner
369-DC	3 1/2"	Zinc Die Cast/ Plastic Metaliner
370-DC	4"	Zinc Die Cast/ Plastic Metaliner

Insulated Grounding Bushings

 File No. E20412


Catalog Number	Wire Capacity	Trade Size
381-DC*	#14 - #4	1/2"
382-DC*	#14 - #4	3/4"
383-DC*	#14 - #4	1"
384-DC*	#14 - #1/0	1 1/4"
384-DC14*	#14 - #4	1 1/4"
385-DC*	#14 - #1/0	1 1/2"
385-DC14*	#14 - #4	1 1/2"
386-DC*	#14 - #1/0	2"
386-DC14*	#14 - #4	2"
387-DC*	#14 - #1/0	2 1/2"
387-DC40*	#6 - #250 MCM	2 1/2"
388-DC*	#14 - #1/0	3"
388-DC40*	#6 - #250 MCM	3"

Insulated Grounding Bushings (cont.)

Catalog Number	Trade Size	Material
389-DC*	#14 - #1/0	3 1/2"
389-DC40*	#6 - #250 MCM	3 1/2"
390-DC*	#14 - #1/0	4"
390-DC40*	#6 - #250 MCM	4"

*Zinc Die Cast/Plastic Metaliner - 150°C

381*	#14 - #4	1/2"
382*	#14 - #4	3/4"
383*	#14 - #4	1"
384*	#14 - #1/0	1 1/4"
384-14*	#14 - #4	1 1/4"
385*	#14 - #1/0	1 1/2"
385-14*	#14 - #4	1 1/2"
386*	#14 - #1/0	2"
386-14*	#14 - #4	2"
387*	#14 - #1/0	2 1/2"
387-40*	#6 - #250 MCM	2 1/2"
388*	#14 - #1/0	3"
388-40*	#6 - #250 MCM	3"
389*	#14 - #1/0	3 1/2"
389-40*	#6 - #250 MCM	3 1/2"
390*	#14 - #1/0	4"
390-40*	#6 - #250 MCM	4"
391*	#6 - #250 MCM	5"
392*	#6 - #250 MCM	6"

*Malleable Iron/Plastic Metaliner - 150°C

Insulated Grounding Bushings w/Copper Lugs

 File No. E20412


Catalog Number	Wire Capacity	Trade Size
351-DC*	#14 - #6	1/2"
352-DC*	#14 - #6	3/4"
353-DC*	#14 - #6	1"
354-DC*	#14 - #6	1 1/4"
355-DC*	#8 - #2	1 1/2"
356-DC*	#8 - #2	2"
357-DC*	#6 - #1/0	2 1/2"
358-DC*	#6 - #1/0	3"
359-DC*	#6 - #1/0	3 1/2"
360-DC*	#6 - #1/0	4"

*Zinc Die Cast/Plastic Insulator - 150°C

Threadless Malleable Grounding Bushings

 File No. E20412


Catalog Number	Wire Capacity	Trade Size
TL-381	#14-#4	1/2"
TL-382	#14-#4	3/4"
TL-383	#14-#4	1"
TL-38414	#14-#4	1 1/4"
TL-384	#8-#1/0	1 1/4"
TL-38514	#14-#4	1 1/2"
TL-385	#8-#1/0	1 1/2"
TL-38614	#14-#4	2"
TL-386	#8-#1/0	2"
TL-387	#8-#1/0	2 1/2"
TL-38740	#6-#250MCM	2 1/2"
TL-388	#8-#1/0	3"
TL-38840	#6-#250MCM	3"
TL-389	#6-#3/0	3 1/2"
TL-38940	#6-#250MCM	3 1/2"
TL-390	#6-#3/0	4"
TL-39040	#6-#250MCM	4"

RIGID AND IMC CONDUIT FITTINGS (CONT.)

Mighty-Rite® Split Grounding Bushings



UL File No. E20412

Catalog Number	Grounding Lug Wire Capacity		Trade Size
	Min.	Max.	
SGB-382CL*	#14 to #4		3/4"
SGB-383CL*	#14 to #4		1"
SGB-38414*	#14 to #4		1 1/4"
SGB-384CL*	#14 to #1/0		1 1/4"
SGB-38514*	#14 to #4		1 1/2"
SGB-385CL*	#14 to #1/0		1 1/2"
SGB-38614*	#14 to #4		2"
SGB-386CL*	#14 to #1/0		2"
SGB-38740*	#6 to 250 MCM		2 1/2"
SGB-387CL*	#14 to #1/0		2 1/2"
SGB-38840*	#6 to 250 MCM		3"
SGB-388CL*	#14 to #1/0		3"
SGB-38940*	#6 to 250 MCM		3 1/2"
SGB-389CL*	#6 - #3/0		3 1/2"
SGB-39040*	#6 to 250 MCM		4"
SGB-390CL*	#6 to #3/0		4"

*Zinc Die Cast / Nylon Insulator - 150°C

Mighty-Seal® Conduit Sealing Bushings



Catalog Number	Trade Size
CSB-200*	2"
CSB-200F*	2"
CSB-250*	2 1/2"
CSB-250F*	2 1/2"
CSB-300*	3"
CSB-300F*	3"
CSB-350*	3 1/2"
CSB-350F*	3 1/2"
CSB-400*	4"
CSB-400F*	4"

*Stainless Steel and Neoprene Rubber Insert

Reducing Bushings



SP File No. LR39354: Steel

Catalog Number	Trade Size	Material
1160	1/2" - 3/8"	Zinc Plated Steel
1161	3/4" - 1/2"	Zinc Plated Steel
1162	1" - 1/2"	Zinc Plated Steel
1163	1" - 3/4"	Zinc Plated Steel
1164	1 1/4" - 1/2"	Zinc Plated Steel
1165	1 1/4" - 3/4"	Zinc Plated Steel
1166	1 1/4" - 1"	Zinc Plated Steel
1167	1 1/2" - 1/2"	Zinc Plated Steel
1168	1 1/2" - 3/4"	Zinc Plated Steel
1169	1 1/2" - 1"	Zinc Plated Steel
1170	1 1/2" - 1 1/4"	Zinc Plated Steel
1171	2" - 1/2"	Zinc Plated Steel
1172	2" - 3/4"	Zinc Plated Steel
1173	2" - 1"	Zinc Plated Steel
1174	2" - 1 1/4"	Zinc Plated Steel
1175	2" - 1 1/2"	Zinc Plated Steel

1176	2 1/2" - 2"	Malleable Iron
1179	3" - 2 1/2"	Malleable Iron
1182	3 1/2" - 3"	Malleable Iron
1185	4" - 3 1/2"	Malleable Iron

Bushing Pennies



Catalog Number	Trade Size	Material
1661	1/2"	Galvanized Steel
1662	3/4"	Galvanized Steel
1663	1"	Galvanized Steel
1664	1 1/4"	Galvanized Steel
1665	1 1/2"	Galvanized Steel
1666	2"	Galvanized Steel
1667	2 1/2"	Galvanized Steel
1668	3"	Galvanized Steel
1669	3 1/2"	Galvanized Steel
1670	4"	Galvanized Steel
1671	5"	Galvanized Steel

Lock-A-Liners

UL File No. E11259



Catalog Number	Trade Size	Material
191	1/2"	Polypropylene 105°C
192	3/4"	Polypropylene 105°C
193	1"	Polypropylene 105°C
194	1 1/4"	Polypropylene 105°C
195	1 1/2"	Polypropylene 105°C
196	2"	Polypropylene 105°C

Pull Caps



Catalog Number	Trade Size	Material
341	1/2"	Polypropylene
342	3/4"	Polypropylene
343	1"	Polypropylene
344	1 1/4"	Polypropylene
345	1 1/2"	Polypropylene
346	2"	Polypropylene

Pull Elbows

UL File No. E9391



Catalog Number	Trade Size	Material
71-DC2	1/2"	Zinc Die Cast
72-DC2	3/4"	Zinc Die Cast

Rigid to Box

71-DC2	1/2"	Zinc Die Cast
72-DC2	3/4"	Zinc Die Cast

Rigid or EMT to Box

71-DCA	1/2"	Aluminum
72-DCA	3/4"	Aluminum

Rigid to Rigid

81-DC	1/2"	Zinc Die Cast
82-DC	3/4"	Zinc Die Cast
83-DC	1"	Zinc Die Cast
84-DC	1 1/4"	Zinc Die Cast

Rigid to Rigid or EMT to EMT

81-DCA	1/2"	Aluminum
82-DCA	3/4"	Aluminum
83-DCA	1"	Aluminum
84-DCA	1 1/4"	Aluminum

Concrete Slab Elbows

UL File No. E9391



Catalog Number	Trade Size	Material
CSE-075	3/4"	Zinc Die Cast
CSE-100	1"	Zinc Die Cast



Zinc Alloy Threaded Hub with Mounting Flange

 Listed

Catalog Number	Trade Size	Material
CSS-050	1/2"	Zinc
CSS-075	3/4"	Zinc
CSS-100	1"	Zinc

One Hole Pipe Straps

 File No. E161206: 912 thru 913

 File No. LR39354: 900 thru 910

 File No. E161206: 904-S thru 908-S

 File No. LR39354: 901-S thru 910-S



Malleable/Aluminum

Catalog Number	Trade Size	Material
900	3/8"	Malleable Iron
901	1/2"	Malleable Iron
902	3/4"	Malleable Iron
903	1"	Malleable Iron
904	1 1/4"	Malleable Iron
905	1 1/2"	Malleable Iron
906	2"	Malleable Iron
907	2 1/2"	Malleable Iron
908	3"	Malleable Iron
909	3 1/2"	Malleable Iron
910	4"	Malleable Iron
912	5"	Malleable Iron
913	6"	Malleable Iron

901-AL	1/2"	Aluminum
902-AL	3/4"	Aluminum
903-AL	1"	Aluminum
904-AL	1 1/4"	Aluminum
905-AL	1 1/2"	Aluminum
906-AL	2"	Aluminum

901-S	1/2"	Zinc Plated Steel
902-S	3/4"	Zinc Plated Steel
903-S	1"	Zinc Plated Steel
904-S	1 1/4"	Zinc Plated Steel
905-S	1 1/2"	Zinc Plated Steel
906-S	2"	Zinc Plated Steel
907-S	2 1/2"	Zinc Plated Steel
908-S	3"	Zinc Plated Steel
909-S	3 1/2"	Zinc Plated Steel
910-S	4"	Zinc Plated Steel



Steel

Two Hole Pipe Straps

 File No. E161206: 1907 thru 1910

 File No. LR39354



Catalog Number	Trade Size	Material
1901	1/2"	Zinc Plated Steel
1902	3/4"	Zinc Plated Steel
1903	1"	Zinc Plated Steel
1904	1 1/4"	Zinc Plated Steel
1905	1 1/2"	Zinc Plated Steel
1906	2"	Zinc Plated Steel
1907	2 1/2"	Zinc Plated Steel
1908	3"	Zinc Plated Steel
1909	3 1/2"	Zinc Plated Steel
1910	4"	Zinc Plated Steel



Rigid Nail Straps

Catalog Number	Trade Size	Material
901-NS	1/2"	Zinc Plated Steel
902-NS	3/4"	Zinc Plated Steel
903-NS	1"	Zinc Plated Steel



Clamp Backs

 File No. E161206: 9951 thru 9952

Catalog Number	Trade Size	Material
941	1/2"	Malleable Iron
942	3/4"	Malleable Iron
943	1"	Malleable Iron
944	1 1/4"	Malleable Iron
945	1 1/2"	Malleable Iron
946	2"	Malleable Iron
947	2 1/2"	Malleable Iron
948	3"	Malleable Iron
949	3 1/2"	Malleable Iron
950	4"	Malleable Iron
9951	5"	Malleable Iron
9952	6"	Malleable Iron

941-AL	1/2"	Aluminum
942-AL	3/4"	Aluminum
943-AL	1"	Aluminum
944-AL	1 1/4"	Aluminum
945-AL	1 1/2"	Aluminum
946-AL	2"	Aluminum

Conduit Nipples

 File No. E9391  File No. LR39354

Catalog Number	Trade Size	Material
1102	1/2"	Malleable Iron
1103	3/4"	Malleable Iron
1104	1"	Malleable Iron
1105	1 1/4"	Malleable Iron
1106	1 1/2"	Malleable Iron
1107	2"	Malleable Iron
1108	2 1/2"	Malleable Iron
1109	3"	Malleable Iron
1110	3 1/2"	Malleable Iron
1111	4"	Malleable Iron
1112	5"	Malleable Iron
1113	6"	Malleable Iron

1102-I	1/2"	Malleable Iron/ Insulated Throat
1103-I	3/4"	Malleable Iron/ Insulated Throat
1104-I	1"	Malleable Iron/ Insulated Throat
1105-I	1 1/4"	Malleable Iron/ Insulated Throat
1106-I	1 1/2"	Malleable Iron/ Insulated Throat
1107-I	2"	Malleable Iron/ Insulated Throat
1108-I	2 1/2"	Malleable Iron/ Insulated Throat
1109-I	3"	Malleable Iron/ Insulated Throat
1110-I	3 1/2"	Malleable Iron/ Insulated Throat
1111-I	4"	Malleable Iron/ Insulated Throat



RIGID AND IMC CONDUIT FITTINGS (CONT.)



Conduit Nipples (cont.)

Catalog Number	Trade Size	Material
1102-DC	1/2"	Zinc Die Cast
1103-DC	3/4"	Zinc Die Cast
1104-DC	1"	Zinc Die Cast
1105-DC	1 1/4"	Zinc Die Cast
1106-DC	1 1/2"	Zinc Die Cast
1107-DC	2"	Zinc Die Cast
1108-DC	2 1/2"	Zinc Die Cast
1109-DC	3"	Zinc Die Cast
1110-DC	3 1/2"	Zinc Die Cast
1111-DC	4"	Zinc Die Cast
1102-DCI	1/2"	Zinc Die Cast/ Insulated Throat
1103-DCI	3/4"	Zinc Die Cast/ Insulated Throat
1104-DCI	1"	Zinc Die Cast/ Insulated Throat
1105-DCI	1 1/4"	Zinc Die Cast/ Insulated Throat
1106-DCI	1 1/2"	Zinc Die Cast/ Insulated Throat
1107-DCI	2"	Zinc Die Cast/ Insulated Throat
1108-DCI	2 1/2"	Zinc Die Cast/ Insulated Throat
1109-DCI	3"	Zinc Die Cast/ Insulated Throat
1110-DCI	3 1/2"	Zinc Die Cast/ Insulated Throat
1111-DCI	4"	Zinc Die Cast/ Insulated Throat

1" Length Conduit Nipples

UL File No. E9391

SP File No. LR39354



Catalog Number	Trade Size	Material
1791-DC	1/2"	Zinc Die Cast
1792-DC	3/4"	Zinc Die Cast
1793-DC	1"	Zinc Die Cast

Offset Nipples

cULus File No. E9391



Catalog Number	Trade Size	Material
1520-DC	1/2"	Zinc Die Cast
1521-DC	3/4"	Zinc Die Cast
1522-DC	1"	Zinc Die Cast
1523-DC	1 1/4"	Zinc Die Cast
1524-DC	1 1/2"	Zinc Die Cast
1525-DC	2"	Zinc Die Cast
1526-DC	2 1/2"	Cast Zinc
1527-DC	3"	Cast Zinc



Locknuts

UL File No. E9391: 101-S thru 112-S;
101-DC thru 106-DC

SP File No. LR39354: 101-S thru 112-S

Catalog Number	Trade Size	Material
101-DC	1/2"	Zinc Die Cast Fitting Locknut
102-DC	3/4"	Zinc Die Cast Fitting Locknut
103-DC	1"	Zinc Die Cast Fitting Locknut
104-DC	1 1/4"	Zinc Die Cast Fitting Locknut
105-DC	1 1/2"	Zinc Die Cast Fitting Locknut
106-DC	2"	Zinc Die Cast Fitting Locknut
107-DC	2 1/2"	Zinc Die Cast Fitting Locknut
108-DC	3"	Zinc Die Cast Fitting Locknut
109-DC	3 1/2"	Zinc Die Cast Fitting Locknut
110-DC	4"	Zinc Die Cast Fitting Locknut

100	3/8"	Zinc Plated Steel Conduit Locknut
101-S	1/2"	Zinc Plated Steel Conduit Locknut
102-S	3/4"	Zinc Plated Steel Conduit Locknut
103-S	1"	Zinc Plated Steel Conduit Locknut
104-S	1 1/4"	Zinc Plated Steel Conduit Locknut
105-S	1 1/2"	Zinc Plated Steel Conduit Locknut
106-S	2"	Zinc Plated Steel Conduit Locknut
107-S	2 1/2"	Zinc Plated Steel Conduit Locknut
108-S	3"	Zinc Plated Steel Conduit Locknut
109-S	3 1/2"	Zinc Plated Steel Conduit Locknut
110-S	4"	Zinc Plated Steel Conduit Locknut
111-S	5"	Zinc Plated Steel Conduit Locknut
112-S	6"	Zinc Plated Steel Conduit Locknut

Bonding Locknuts

cULus File No. E20412: 121-S thru 130-S



Catalog Number	Trade Size	Material
121-S	1/2"	Steel
122-S	3/4"	Steel
123-S	1"	Steel
124-S	1 1/4"	Steel
125-S	1 1/2"	Steel
126-S	2"	Steel
127-S	2 1/2"	Steel
128-S	3"	Steel
129-S	3 1/2"	Steel
130-S	4"	Steel
131-S	5"	Steel
132-S	6"	Steel

Sealing Locknuts



UL File No. E191572: 141 thru 146

Catalog Number	Trade Size	Material
141	1/2"	Steel/PVC Seal
142	3/4"	Steel/PVC Seal
143	1"	Steel/PVC Seal
144	1 1/4"	Steel/PVC Seal
145	1 1/2"	Steel/PVC Seal
146	2"	Steel/PVC Seal
147	2 1/2"	Steel/PVC Seal
148	3"	Steel/PVC Seal
149	3 1/2"	Steel/PVC Seal
150	4"	Steel/PVC Seal

Reducing Washers



UL File No. E11259: 1061 thru 1088

SF File No. LR39354: 1061 thru 1088

Catalog Number	Trade Size	Material
1061	3/4" - 1/2"	Galvanized Steel
1062	1" - 1/2"	Galvanized Steel
1063	1" - 3/4"	Galvanized Steel
1064	1 1/4" - 1/2"	Galvanized Steel
1065	1 1/4" - 3/4"	Galvanized Steel
1066	1 1/4" - 1"	Galvanized Steel
1067	1 1/2" - 1/2"	Galvanized Steel
1068	1 1/2" - 3/4"	Galvanized Steel
1069	1 1/2" - 1"	Galvanized Steel
1070	1 1/2" - 1 1/4"	Galvanized Steel
1071	2" - 1/2"	Galvanized Steel
1072	2" - 3/4"	Galvanized Steel
1073	2" - 1"	Galvanized Steel
1074	2" - 1 1/4"	Galvanized Steel
1075	2" - 1 1/2"	Galvanized Steel
1076	2 1/2" - 1/2"	Galvanized Steel
1077	2 1/2" - 3/4"	Galvanized Steel
1078	2 1/2" - 1"	Galvanized Steel
1079	2 1/2" - 1 1/4"	Galvanized Steel
1080	2 1/2" - 1 1/2"	Galvanized Steel
1081	2 1/2" - 2"	Galvanized Steel
1082	3" - 1/2"	Galvanized Steel
1083	3" - 3/4"	Galvanized Steel
1084	3" - 1"	Galvanized Steel
1085	3" - 1 1/4"	Galvanized Steel
1086	3" - 1 1/2"	Galvanized Steel
1087	3" - 2"	Galvanized Steel
1088	3" - 2 1/2"	Galvanized Steel
1089-1	3 1/2" - 1/2"	Galvanized Steel
1089-2	3 1/2" - 3/4"	Galvanized Steel
1089-3	3 1/2" - 1"	Galvanized Steel
1089-4	3 1/2" - 1 1/4"	Galvanized Steel
1089-5	3 1/2" - 1 1/2"	Galvanized Steel
1089-6	3 1/2" - 2"	Galvanized Steel
1089-7	3 1/2" - 2 1/2"	Galvanized Steel
1089-8	3 1/2" - 3"	Galvanized Steel
1090-1	4" - 1/2"	Galvanized Steel
1090-2	4" - 3/4"	Galvanized Steel
1090-3	4" - 1"	Galvanized Steel
1090-4	4" - 1 1/4"	Galvanized Steel
1090-5	4" - 1 1/2"	Galvanized Steel
1090-6	4" - 2"	Galvanized Steel
1090-7	4" - 2 1/2"	Galvanized Steel
1090-8	4" - 3"	Galvanized Steel
1090-9	4" - 3 1/2"	Galvanized Steel

Mighty-Seal® Raintight Reducing Sealing Washers



UL File No. E11259

Catalog Number	Trade Size	Material
1061-RT	3/4" - 1/2"	Coated Galvanized Steel
1062-RT	1" - 1/2"	Coated Galvanized Steel
1063-RT	1" - 3/4"	Coated Galvanized Steel
1065-RT	1 1/4" - 3/4"	Coated Galvanized Steel
1071-RT	2" - 1/2"	Coated Galvanized Steel

CLAMPS AND HANGERS

Conduit Hangers



UL File No. E161206

Catalog Number	Rigid Size	Material
2100	3/8" & 1/2"	Zinc Plated Steel with Bolt
2110	3/4"	Zinc Plated Steel with Bolt
2120	1"	Zinc Plated Steel with Bolt
2125	***	Zinc Plated Steel with Bolt
2130	1 1/4"	Zinc Plated Steel with Bolt
2140	1 1/2"	Zinc Plated Steel with Bolt
2100-BN	3/8" & 1/2"	Zinc Plated Steel with Bolt & Nut
2110-BN	3/4"	Zinc Plated Steel with Bolt & Nut
2120-BN	1"	Zinc Plated Steel with Bolt & Nut
2125-BN	***	Zinc Plated Steel with Bolt & Nut
2130-BN	1 1/4"	Zinc Plated Steel with Bolt & Nut
2140-BN	1 1/2"	Zinc Plated Steel with Bolt & Nut
2150	2"	Zinc Plated Steel with Bolt & Nut
2160	2 1/2"	Zinc Plated Steel with Bolt & Nut
2170	3"	Zinc Plated Steel with Bolt & Nut
2180	3 1/2"	Zinc Plated Steel with Bolt & Nut
2190	4"	Zinc Plated Steel with Bolt & Nut

CLAMPS AND HANGERS (CONT.)



Conduit Hangers With Bolt


Catalog Number	Rigid Size	Material
2100-S	3/8" & 1/2"	Zinc Plated 304 Stainless Steel with Bolt & Nut
2110-S	3/4"	Zinc Plated 304 Stainless Steel with Bolt & Nut
2120-S	1"	Zinc Plated 304 Stainless Steel with Bolt & Nut
2125-S	***	Zinc Plated 304 Stainless Steel with Bolt & Nut
2130-S	1 1/4"	Zinc Plated 304 Stainless Steel with Bolt & Nut
2140-S	1 1/2"	Zinc Plated 304 Stainless Steel with Bolt & Nut
2150-S	2"	Zinc Plated 304 Stainless Steel with Bolt & Nut
2160-S	2 1/2"	Zinc Plated 304 Stainless Steel with Bolt & Nut
2170-S	3"	Zinc Plated 304 Stainless Steel with Bolt & Nut
2180-S	3 1/2"	Zinc Plated 304 Stainless Steel with Bolt & Nut
2190-S	4"	Zinc Plated 304 Stainless Steel with Bolt & Nut

Right Angle Type Conduit Clamps



Catalog Number	Trade Size	Material
961	1/2"	Malleable Iron
962	3/4"	Malleable Iron
963	1"	Malleable Iron
964	1 1/4"	Malleable Iron
965	1 1/2"	Malleable Iron
966	2"	Malleable Iron
967	2 1/2"	Malleable Iron
968	3"	Malleable Iron
969	3 1/2"	Malleable Iron
970	4"	Malleable Iron

Edge Type Conduit Clamps

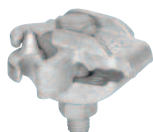

Catalog Number	Trade Size	Material
971	1/2"	Malleable Iron
972	3/4"	Malleable Iron
973	1"	Malleable Iron
974	1 1/4"	Malleable Iron
975	1 1/2"	Malleable Iron
976	2"	Malleable Iron
977	2 1/2"	Malleable Iron
978	3"	Malleable Iron



Parallel Type Conduit Clamps

Catalog Number	Trade Size	Material
981	1/2"	Malleable Iron
982	3/4"	Malleable Iron
983	1"	Malleable Iron
984	1 1/4"	Malleable Iron
985	1 1/2"	Malleable Iron
986	2"	Malleable Iron
987	2 1/2"	Malleable Iron
988	3"	Malleable Iron
989	3 1/2"	Malleable Iron
990	4"	Malleable Iron

SERVICE ENTRANCE

Threaded Type Service Entrance Caps

 File No. E11259: 1201 thru 1210



Catalog Number	Trade Size	Material
1201	1/2"	Aluminum
1202	3/4"	Aluminum
1203	1"	Aluminum
1204	1 1/4"	Aluminum
1205	1 1/2"	Aluminum
1206	2"	Aluminum
1207	2 1/2"	Aluminum
1208	3"	Aluminum
1209	3 1/2"	Aluminum
1210	4"	Aluminum
1211	5"	Aluminum
1212	6"	Aluminum

Mast Type Service Entrance Caps

 File No. E11259



Catalog Number	Trade Size	Material
1246-MT	2"	Aluminum/Phenolic Insulator
1257-MT	2 1/2"	Aluminum/Phenolic Insulator

Clamp-on Type Service Entrance Caps

 File No. E11259



Catalog Number	Trade Size	Material
1251	1/2"	Aluminum
1252	3/4"	Aluminum
1253	1"	Aluminum
1254	1 1/4"	Aluminum
1255	1 1/2"	Aluminum
1256	2"	Aluminum
1257	2 1/2"	Aluminum
1258	3"	Aluminum
1259	3 1/2"	Aluminum
1260	4"	Aluminum

SERVICE ENTRANCE (CONT.)

Set Screw Type Service Entrance Caps



 File No. E11259

Catalog Number	Trade Size	Material
1253-S	1"	Aluminum/Phenolic Insulator
1254-S	1 1/4"	Aluminum/Phenolic Insulator
1255-S	1 1/2"	Aluminum/Phenolic Insulator
1256-S	2"	Aluminum/Phenolic Insulator
1257-S	2 1/2"	Aluminum/Phenolic Insulator
1258-S	3"	Aluminum/Phenolic Insulator
1259-S	3 1/2"	Aluminum/Phenolic Insulator
1260-S	4"	Aluminum/Phenolic Insulator

PVC Service Entrance Heads



 File No. E9391

 File No. LR74878

Catalog Number	Trade Size	Material
1251-PVC	1/2"	PVC
1252-PVC	3/4"	PVC
1253-PVC	1"	PVC
1254-PVC	1 1/4"	PVC
1255-PVC	1 1/2"	PVC
1256-PVC	2"	PVC

EXPANSION COUPLINGS

Raintight Expansion Couplings



Catalog Number	Trade Size	Material
EC-100GRT	1"	Aluminum

Dry Location Expansion Couplings

 File No. E24001

 File No. E9391 3/4" to 2"



Catalog Number	Trade Size	Material
EC-075R	3/4"	Zinc Plated Steel
EC-100R	1"	Zinc Plated Steel
EC-125R	1 1/4"	Zinc Plated Steel
EC-150R	1 1/2"	Zinc Plated Steel
EC-200R	2"	Zinc Plated Steel
EC-250	2 1/2"	Zinc Plated Steel
EC-300	3"	Zinc Plated Steel
EC-350	3 1/2"	Zinc Plated Steel
EC-400	4"	Zinc Plated Steel

GROUNDING PRODUCTS

External Bonding Jumper Assemblies

 File No. E20412



Catalog Number	Trade Size	Material
BJ-100	1/2" thru 1"	Bronze Clamps/ Tin Plated Copper Braid
BJ-200	1 1/4" thru 2"	Bronze Clamps/ Tin Plated Copper Braid
BJ-400	2 1/2" thru 4"	Bronze Clamps/ Tin Plated Copper Braid
BJ-100RT	1"	Aluminum Clamps/Tin Plated Copper Braid



Threaded Hub Type Ground Clamps

 File No. E20412: 1325-B, 1325-B1, 1326-B, 1328-B, 1330-B, 1331-B



Catalog Number	Electrode Size	Trade Size
1325-B*	1/2" - 1"	1/2"
1326-B*	1 1/4" - 2"	1/2"
1328-B*	2 1/2" - 4"	1/2"
1330-B*	1/2" - 1"	3/4"
1331-B*	1 1/4" - 2"	3/4"

1325-B1**	1/2" - 1"	1/2"
-----------	-----------	------

*Brass

**Brass with Brass Screws

Mighty-Bond® Direct Burial Single Bolt Grounding Clamps

 File No. E20412



Catalog Number	Conductor Range	Material
SDB-1300B	#4 - #14 AWG Copper Only	Brass
SDB-1301B	#2 - #10 AWG Copper Only	Brass
SDB-1302B	#2 - #10 AWG Copper Only	Brass

OTHER INNOVATIONS FROM BRIDGEPORT



◀ **Mighty-Seal® Raintight PUSH-EMT® Connectors**

Connecting EMT conduit has never been this fast and simple. With Bridgeport's new MIGHTY-SEAL, just push the fitting onto the conduit and attach the fitting to the box. You're done. In seconds, you have a raintight seal. Patented.

Mighty-Merge® Combination Couplings ▶

Transition fitting saves you the labor and material cost of installing and bonding a junction box, or the assembly time to make up a fitting that provides the necessary transition. Patented.



◀ **Mighty-Rite® Split Grounding Bushings**

Mighty-Rite's hinged design and adjustable grounding lug deliver installation flexibility on every job. Aluminum alloy lug. Patented.

Mighty-Bond® Intersystem Ground Rod Bridge Clamp ▶

Grounding Products are unique, patent-pending products designed for low cost and easy use. Precision machined bodies and stainless steel screws provide the optimum in performance and appearance. Patented.



 
◀ **Mighty-Seal® Conduit Sealing Bushings**

Conduit Sealing Bushing (CSB & CSBF) product line is designed for sealing concrete penetrations around rigid conduit installations in building foundations, ceilings, and walls against the intrusion of water. Factory certified.

THE BRIDGEPORT FITTINGS DIFFERENCE



Distributed by:



Bridgeport Fittings, Inc.
705 Lordship Blvd.
Stratford, CT 06615-7313

Voice: 203.377.5944
Fax: 203.381.3488
E-mail: sales@bptfittings.com

www.bptfittings.com

CONNECT
ONLINE



Printed in the U.S.A.

© 2013 Bridgeport Fittings, Inc. All rights reserved.

