



Range & Dryer Power Receptacles

3-Pole, 3-Wire Non-Grounding
30A, 125/250V/AC
50A, 125/250V/AC

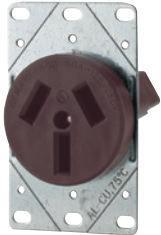

32B

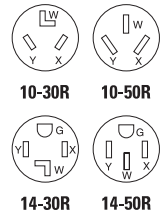

112



1258

Features

- For replacement use in older homes with 3-Wire range and dryer connection points
- Heavy gauge galvanized steel mounting strap for corrosion resistance
- Flush receptacles fit one-gang or two-gang enclosures
- For use with copper or aluminum wire
- Surface receptacles have patented lay-in terminals that accept up to #4 AWG wire
- Surface receptacle backs feature concentric knockouts and an adjustable cord clamp to allow wiring from back or bottom

Flush Power Receptacles



Rating A	V/AC	Description	Color	Catalog No.	
30	125/250	NEMA 10-30R Flush Mount Dryer Power Receptacle V/AC 124/250 Matching Plug S80	Brown	□ 38B	•
50	125/250 124/250	NEMA 10-50R Flush Mount Range Power Receptacle Matching Plug S80	Brown	□ 32B	•

cULus Listed to UL498 & UL943, file no. E60120; NOM certified

Surface Power Receptacles



Rating A	V/AC	Description	Color	Catalog No.	
30	125/250 124/250	NEMA 10-30R Flush Mount Dryer Power Receptacle Matching Plug S80	Black	□ 125	•
50	125/250 124/250	NEMA 10-50R Flush Mount Range Power Receptacle Matching Plug S80	Black	□ 112	•

Listed to UL498, file no. E15058; CSA certified to C22.2, no. 42; NOM certified


Flush Power Receptacles



Rating A	V/AC	Description	Color	Catalog No.	
30	125/250 124/250	NEMA 14-30R Flush Mount Dryer Power Receptacle Matching Plug S21	Black	□ 1257	•
50	125/250 124/250	NEMA 14-50R Flush Mount Range Power Matching Plug S21	Black	□ 1258	•

Listed to UL498, file no. E15058; CSA certified to C22.2, no. 42; NOM certified

 Color Information:
B (Brown), BK (Black)



Dimensional Information: B-70 **Specification Information:** Please visit www.cooperwiringdevices.com.
Specifications and availability are subject to change without notice.

NAFTA Compliant - see page F-21