

PHILIPS Stonco

Special Purpose

Roughlyte

Ceiling and Wall 4" box
mounted, incandescent



VCXL



VWXL

Project:

Location:

Cat.No:

Type:

Lamps:

Qty:

Notes:

Philips Stonco Roughlyte is available in wattages ranging from 60 to 200. Applications include wall, columns, ceilings and canopies in exterior applications. Roughlyte fixtures guard against moisture and debris in exterior applications (for globe down mounting only). Features include heat and shock resistant glass or polycarbonate globe and cast aluminum bayonet guard with Allen head security screws. Not recommended for hazardous locations.

Ordering guide

Example: VCXL11GC

Series	Wattage	Lens*
<input type="text"/>	<input type="text"/>	<input type="text"/>
VCXL Ceiling 4" box mounted	11 100W	GC² Glass globe and cast guard
VWXL Wall 4" box mounted	21 200W	K² Glass globe only
	5¹ 60W	A Lexan globe
	10¹ 75W	
		*No lens suffix for unit with no globe

1. 60W and 75W available with lexan globe only.

2. For use with 100W and 200W units only

Product Specifications

- All incandescent Roughlyte ceiling and wall fixtures are not supplied with a lamp. This fixture requires a medium base incandescent A lamp. The lamp can be clear or coated.
- Roughlyte fixtures guard against moisture and debris in exterior applications (for globe down mounting only).
- cULus listed for wet locations.
- **Not recommended for use in hazardous locations.**

VCXL/VWXL Roughlyte


Incandescent

VCXL/VWXL


- Complete with 4" die-cast aluminum box, four side and top hole tapped 1/2" NPT (four plugs included).
- Heat and shock resistant glass or polycarbonate globe.
- Sockets are pre-wired with extra long 1/2" stripped leads.
- To use VCXL units with 3/4" conduit use VK Series with VXL13 universal box.
- To use VWXL units with 3/4" conduit, use VW Series with VXL13 universal box.

Dimensions

Catalog No.	Height (H)	Dia. (D)
VCXL11	3-3/4"	4-1/4"
VCXL21	3-3/4"	5-1/8"
VCXL11K	8-5/8"	4-1/4"
VCXL21K	10-3/8"	5-1/8"
VCXL11GC	9-1/8"	4-1/4"
VCXL21GC	10-7/8"	5-1/4"
VCXL5A	8-5/8"	4-1/4"
VCXL10A	10-3/8"	5-1/8"

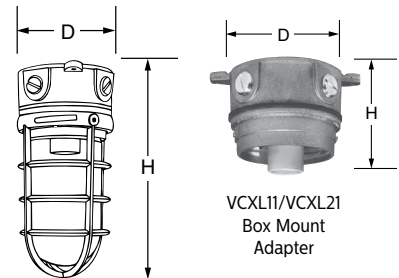

VWXL11	4-1/4"	7-1/8"
VWXL21	4-1/4"	7-7/16"
VWXL11K	9-1/4"	7-1/8"
VWXL21K	10-7/8"	7-7/16"
VWXL11GC	9-3/4"	7-1/4"
VWXL21GC	11-3/8"	7-1/2"
VWXL5A	9-1/4"	7-1/8"
VWXL10A	10-7/8"	7-7/16"

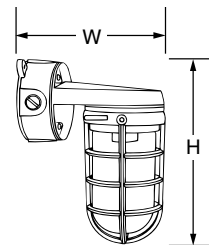

Accessories



4" Round boxes

Die-cast aluminum for use with conduit, Philips Stonco ceiling, surface and wall fixtures and flood lights. Four side and one back hole tapped 3/4" or 1/2", as shown. Heavy-duty gasket (except on VXL1), screws, four aluminum five-threaded plugs. No cover.

Catalog No.	Tap size	Description
VXL1	1/2"	Mounting box
VXL13	3/4"	Mounting box



V127
Plated Wire Guard



V131
Cast Aluminum Guard

Guards

Wire guards are clamp-on type. Cast aluminum guards are twist on/off bayonet type, includes allen head security screws. Shipped with threaded ring adapter for use with standard threaded bases or the new RoughLyte bases.

Wire guard		Cast guard	
Catalog No.	Fits globe diameter	Catalog No.	Fits globe diameter
V127	3-1/2"	V131	3-1/2"

VCXL/VWXL Roughlyte

Incandescent

Accessories (continued)



VGC100
Clear Glass Globe



VGP100
Clear Prismatic Globe



VGR100
Ruby Glass Globe



VPRC10
Prismatic Lexan Globe

Colored and specialty globes

Full molded threads. Fit all Philips Stonco housings. Globes for vertical mounting only.

Catalog No.	Description
3-1/2" Globe dia. Height - 6 11/16"	
VGC100	Clear*
VGCH100	Clear, heat tempered
VGP100	Clear, prismatic
VGA100	Amber (60W max.)
VGB100	Blue (60W max.)
VGG100	Green (60W max.)
VGR100	Ruby (60W max.)

3-1/2" Globe dia.	LEXAN
VPRC5	Clear, prismatic (60W Max.)

Catalog No.	Description
4-3/8" Globe dia. Height - 8 3/8"	
VGC200	Clear*
VGCH200	Clear, heat tempered

4-3/8" Globe dia.	LEXAN
VPRC10	Clear, prismatic (75W Max.)

*Standard with all incandescent glass fixtures.

NOTE: Use of colored globes will down-rate wattage.

