



# HEAVY-DUTY RIGHT ANGLE DRILL ATTACHMENTS



**HIGH  
TORQUE!**



**49-22-8510**

## RIGHT ANGLE DRILL ATTACHMENT 49-22-8510

- Ideal For Cordless Drills And Screwdrivers
- DURABLE – All Metal Construction
- COMPACT – Measures Only 2" Wide
- CONVENIENT – Accepts Standard 1/4" Hex Drive Accessories
- Handles High Torque
- Includes Five Bits

## COMMON APPLICATIONS


- Drill Holes Using 1/4" Hex Twist Drill Bits, Flat Boring Bits Or Add The 49-22-1560 1/4" Chuck Attachment And Use Round Shank Twist Drill Bits
- Drive Screws Up To #8 X 3" Long
- Use The 49-66-3005 1/4" Hex Drive Bit And Drive Hex Head Screws



**48-32-2100**

## OFF-SET™ SCREWDRIVER POWER HEAD 48-32-2100

- Use The Power And Speed Of Your 2.4 Volt Cordless Screwdriver To Fasten Or Remove Screws, Tight Applications. Durable Die Cast Construction. 1/4" Magnetic Bit Reception For Standard Bits. 360° Adjustable Thumb Flange. Maximum 100 In./lbs. Torque 400 RPM

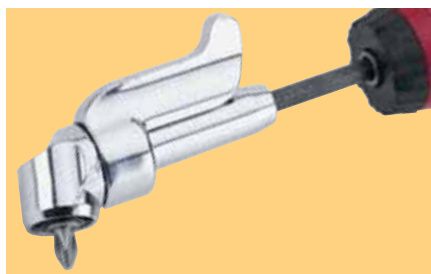

## 48-32-2115

- 12 Pack of 48-32-2100