


# TaskWork LED Tape Light

24 Volt DC Dry Location White & Single Colors

Project:

Location:

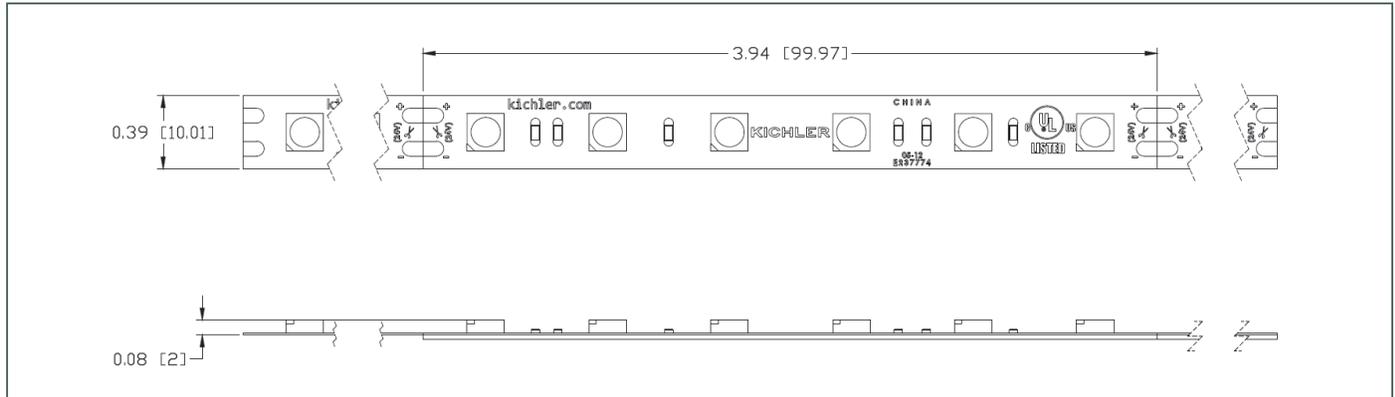

Description	Professional grade 24 volt LED Tape Light
Features	<ul style="list-style-type: none"> <li>• Expected life 50,000 hrs at L70</li> <li>• Fully dimmable when used with dimmable power supply</li> <li>• Tape can be cut every 4" and reconnected</li> <li>• 3M™/VHB professional grade adhesive backing for an easy peel-and-stick installation</li> </ul>
Construction	Flexible, PCB silicone sealed. Tape is clearly marked where it is cuttable every 4".
Operating Voltage	24V DC
CRI	80 (white only)
Light Source	6 High Powered LED per 4" section
Beam Angle	120°
Operating Temperature	-10°C to +50°C (-30°F to +120°F)
Power Supply	Remote electronic or magnetic Class 2 transformer. 120VAC 50/60Hz input, 24VDC output.
Certification	FCC compliant, UL & CUL listed. UL 2108 dry location rated, ROHS compliant
Warranty	5 year warranty. See <a href="http://www.landscapelighting.com">www.landscapelighting.com</a> or <a href="http://www.Kichler.com">www.Kichler.com</a> for full warranty information

# TaskWork LED Tape Light

24 Volt DC Dry Location White & Single Colors

## White: Select Color Temperature & Lumen Output

Description	Low Output
Features	<ul style="list-style-type: none"> <li>• 32.8' Max Run Length</li> <li>• 100 Lumens / Ft.</li> <li>• 1.45 Watts / Ft.</li> <li>• 80 CRI</li> </ul>
Warm White 2700K	<b>116L27 WH, BK</b> 16' (24W) <b>1100L27 WH, BK</b> 100'
Pure White 3000K	<b>116L30 WH, BK</b> 16' (24W) <b>1100L30 WH, BK</b> 100'
Cool White 4000K	<b>116L40 WH, BK</b> 16' (24W) <b>1100L40 WH, BK</b> 100'

Description	High Output
Features	<ul style="list-style-type: none"> <li>• 20' Max Run Length</li> <li>• 200 Lumens / Ft.</li> <li>• 4 Watts / Ft.</li> <li>• 80 CRI</li> </ul>
Warm White 2700K	<b>120H27 WH, BK</b> 20' (80W) <b>1100H27 WH, BK</b> 100'
Pure White 3000K	<b>120H30 WH, BK</b> 20' (80W) <b>1100H30 WH, BK</b> 100'
Cool White 4000K	<b>120H40 WH, BK</b> 20' (80W) <b>1100H40 WH, BK</b> 100'

---

## Colors: Select Color (Red, Blue, Green or Yellow) & Intensity

Description	Low Output
Features	<ul style="list-style-type: none"> <li>• 32.8' Max Run Length</li> <li>• 1.45 Watts / Ft.</li> </ul>
LED Tape:	<b>116LR WH, BK</b> 16' (24W) <b>116LG WH, BK</b> 16' (24W) <b>116LB WH, BK</b> 16" (24W) <b>116LY WH, BK</b> 16" (24W)

Description	High Output
Features	<ul style="list-style-type: none"> <li>• 20' Max Run Length</li> <li>• 4 Watts / Ft.</li> </ul>
LED Tape:	<b>120HR WH, BK</b> 20' (80W) <b>120HG WH, BK</b> 20' (80W) <b>120HB WH, BK</b> 20" (80W) <b>120HY WH, BK</b> 20" (80W)

# TaskWork LED Tape Light


24 Volt DC Dry Location White & Single Colors

## Select Accessories

LED Tape In line Dimmer	<p><b>10198 WH, BK</b></p> <ul style="list-style-type: none"> <li>• 0–100% dimming</li> <li>• Can only be used on 24V output side of power supply</li> <li>• For indoor use only</li> <li>• 48W max</li> </ul>	
3' Track Section	<p><b>12330 WH, BK (10-pack)</b></p> <ul style="list-style-type: none"> <li>• 3' track section</li> <li>• Snaps on the score every 6"</li> <li>• Captive screws every 6"</li> <li>• White or Black finish</li> </ul>	

## Select Power Supply Leads & Interconnect Cables

Power Supply Leads	<p><b>1SL1 WH, BK</b> 1' Supply Lead</p> <p><b>1SL2 WH, BK</b> 2' Supply Lead</p> <p><b>1SL8 WH, BK</b> 8' Supply Lead</p> <p><b>1SL25 WH, BK</b> 25' Supply Lead</p> <ul style="list-style-type: none"> <li>• Connects tape light to power supply</li> <li>• Cannot be used as an interconnect cable</li> </ul>	
Inline Splice	<p><b>1C1 WH, BK</b></p> <ul style="list-style-type: none"> <li>• Connects two sections of tape together</li> </ul>	
3-Way Connector	<p><b>1C3 WH, BK</b></p> <ul style="list-style-type: none"> <li>• Connects 3 sections of tape together.</li> <li>• Ideal for making "T" or "Y" connections.</li> <li>• One input, two outputs.</li> <li>• 6.25" x 3.50"</li> </ul>	

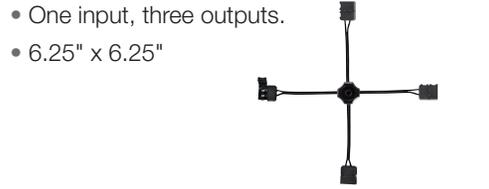4-Way Connector	<p><b>1C4 WH, BK</b></p> <ul style="list-style-type: none"> <li>• Connects 4 sections of tape together.</li> <li>• One input, three outputs.</li> <li>• 6.25" x 6.25"</li> </ul>	
Interconnect Cables	<p><b>1IC02 WH, BK</b> 2" Interconnect 90°</p> <ul style="list-style-type: none"> <li>• Used as a "jumper" wire to connect 2 sections of tape light together.</li> <li>• Flexible connector that is ideal making tight turns.</li> </ul> <p><b>1IC12 WH, BK</b> 12" Interconnect</p> <p><b>1IC36 WH, BK</b> 36" Interconnect</p> <p><b>1IC52 WH, BK</b> 52" Interconnect</p> <p><b>1IC96 WH, BK</b> 96" Interconnect</p>	

# TaskWork LED Tape Light

## 24 Volt DC Dry Location White & Single Colors

### Select Indoor Damp Power Supply

Total wattage of tape light cannot exceed wattage rating of power supply.

<p>Plug-in Power Supply</p>	<p><b>10190BK30</b> 30W  <b>10190BK48</b> 48W  <b>10190BK60</b> 60W</p> <ul style="list-style-type: none"> <li>• 8' of cord with male DC 2.1 jack on end</li> <li>• Class 2/24V DC</li> <li>• 2.4W minimum load requirement</li> </ul> 	<p>Dimmable Direct Wire Power Supply</p> <p><b>10192BK60</b> 60W  <b>10192BK96</b> 96W</p> <ul style="list-style-type: none"> <li>• 6.5" L x 2.5" W x 2.25" H</li> <li>• Rated for both indoor dry and damp locations</li> <li>• Dimmable with low voltage magnetic dimmer</li> <li>• Class 2/24V DC</li> <li>• 5W minimum load requirement</li> <li>• Compatible with Lutron &amp; Leviton low-voltage magnetic analog dimmers</li> </ul> 
<p>Direct Wire Power Supply</p>	<p><b>10191BK60</b> 60W</p> <ul style="list-style-type: none"> <li>• 9.5" L x 3" W x 1.38" H</li> <li>• Includes 6' cord with male DC 2.1 jack on output side</li> <li>• Includes push-in wire connectors on 120V input side</li> <li>• Class 2/24V DC</li> <li>• No minimum load requirement</li> </ul>  <p><b>10191BK96</b> 96W Direct Wire Power Supply</p> <ul style="list-style-type: none"> <li>• 11.5" L x 3" W x 1.38" H</li> <li>• Includes 6' cord with male DC 2.1 jack on output side</li> <li>• Includes push-in wire connectors on 120V input side</li> <li>• Class 2/24V DC</li> <li>• No minimum load requirement</li> </ul> 	<p>Cord &amp; Plug Accessory</p> <p><b>10193BK</b></p> <ul style="list-style-type: none"> <li>• 8' cord &amp; plug accessory for use with <b>10192BK60</b> Direct Wire Dimmable and <b>10192BK986</b> Direct Wire Dimmable</li> </ul> 

#### KICHLER LIGHTING

World Headquarters  
 7711 E. Pleasant Valley Rd.  
 PO Box 318010  
 Cleveland, Ohio 44131-8010  
[www.kichler.com](http://www.kichler.com)

© Copyright All rights reserved  
 Kichler Lighting

style to live by™

KICHLER