



STEP

4

CHOOSE POWER SUPPLY

Total wattage of tape light cannot exceed wattage rating of power supply.

RGB INDOOR CONNECTORS

RGB Power Supply Leads

- 1SL1RGB WH, BK** 1' Supply Lead
- 1SL2RGB WH, BK** 2' Supply Lead
- 1SL8RGB WH, BK** 8' Supply Lead
- 1SL25RGB WH, BK** 25' Supply Lead

- Connects tape light to power supply
- Cannot be used as an interconnect cable



RGB Connectors

1C1RGB WH, BK Inline Splice

- Connects two sections of tape together.



1C3RGB WH, BK 3-Way Connector

- Connects 3 sections of tape together.
- Ideal for making "T" or "Y" connections.
- One input, two outputs.
- 6.25" x 3.50"



1C4RGB WH, BK 4-Way Connector

- Connects 4 sections of tape together.
- One input, three outputs.
- 6.25" x 6.25"



RGB Interconnect Cables

1IC02RGB WH, BK 2" Interconnect 90°

- Used as a "jumper" wire to connect 2 sections of tape light together.
- Flexible connector that is ideal for making tight turns.



- 1IC12RGB WH, BK** 12" Interconnect
- 1IC36RGB WH, BK** 36" Interconnect
- 1IC52RGB WH, BK** 52" Interconnect
- 1IC96RGB WH, BK** 96" Interconnect



- 10190BK30 30W Plug-in Power Supply**
- 10190BK48 48W Plug-in Power Supply**
- 10190BK60 60W Plug-in Power Supply**

- 8' of cord with male DC 2.1 jack on end
- Class 2/24V DC
- 2.4W minimum load requirement



10191BK60 60W Direct Wire Power Supply

- 9.5" L x 3" W x 1.38" tH
- Includes 6' cord with male DC 2.1 jack on output side
- Includes push-in wire connectors on 120V input side
- Class 2/24V DC
- No minimum load requirement



10191BK96 96W Direct Wire Power Supply

- 11.5" L x 3" W x 1.38" H
- Includes 6' cord with male DC 2.1 jack on output side
- Includes push-in wire connectors on 120V input side
- Class 2/24V DC
- No minimum load requirement



- 10192BK60 60W Direct Wire Dimmable**
- 10192BK96 96W Direct Wire Dimmable**


- 6.5" L x 2.5" W x 2.25" tH
- Rated for both indoor dry and damp locations
- Dimmable with magnetic low voltage dimmer
- Class 2/24V DC
- 5W minimum load requirement
- Compatible with Lutron & Leviton low-voltage magnetic analog dimmers



10193BK

- 8' cord & plug accessory for use with 10192BK60 Direct Wire Dimmable and 10192BK986 Direct Wire Dimmable



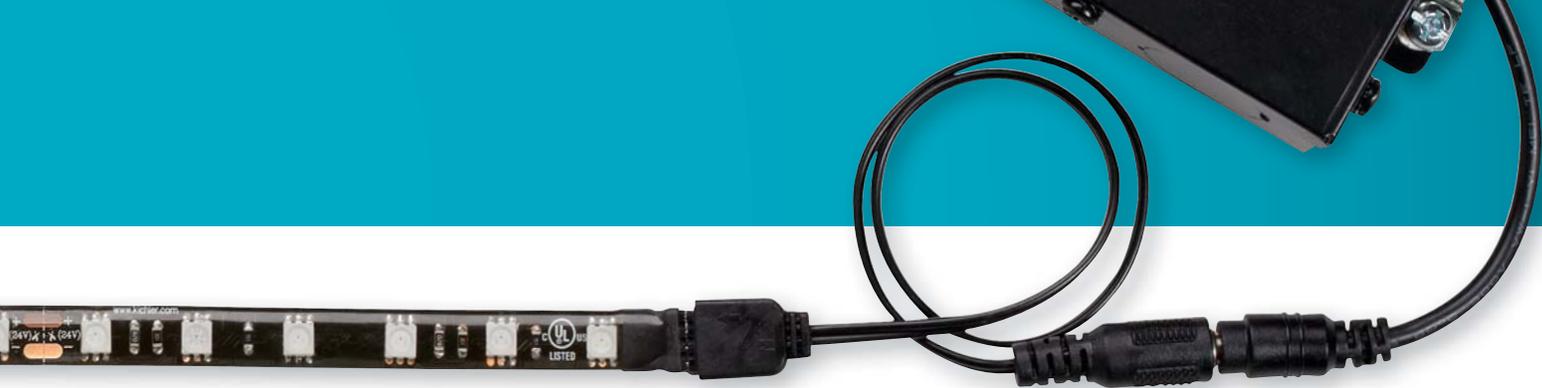

STEP 4

CHOOSE POWER SUPPLY

Total wattage of tape light cannot exceed wattage rating of power supply.

RGB DAMP LOCATION CONNECTORS

Power Supply Leads - RGB

- 2SL1RGB WH, BK** 12" Supply Lead
- 2SL2RGB WH, BK** 2' Supply Lead
- 2SL8RGB WH, BK** 8' Supply Lead
- 2SL25RGB WH, BK** 25' Supply Lead

- Connects tape light to power supply
- Cannot be used as an interconnect cable



Connectors - RGB

2C1 WH, BK Inline Splice

- Connects two sections of tape together.



2C3RGB WH, BK 3-Way Connector

- Connects 3 sections of tape together.
- Ideal for making "T" or "Y" connections.
- One input, two outputs.
- 6.25" x 3.50"



2C4RGB WH, BK 4-Way Connector

- Connects 4 sections of tape together.
- One input, three outputs.
- 6.25" x 6.25"



Interconnect Cables - RGB

2IC02RGB WH, BK 2" Interconnect 90°

- Used as a "jumper" wire to connect 2 sections of tape light together.
- Flexible connector that is ideal for making tight turns.



- 2IC12RGB WH, BK** 12" Interconnect
- 2IC36RGB WH, BK** 36" Interconnect
- 2IC52RGB WH, BK** 52" Interconnect
- 2IC96RGB WH, BK** 96" Interconnect



INDOOR DAMP LOCATION POWER SUPPLIES

- 10190BK30 30W Plug-in Power Supply**
- 10190BK48 48W Plug-in Power Supply**
- 10190BK60 60W Plug-in Power Supply**

- 8' of cord with male DC 2.1 jack on end
- Class 2/24V DC
- 2.4W minimum load requirement



10191BK60 60W Direct Wire Power Supply

- 9.5" L x 3" W x 1.38" H
- Includes 6' cord with male DC 2.1 jack on output side
- Includes push-in wire connectors on 120V input side
- No minimum load requirement



10191BK96 96W Direct Wire Power Supply

- 11.5" L x 3" W x 1.38" H
- Includes 6' cord with male DC 2.1 jack on output side
- Includes push-in wire connectors on 120V input side
- No minimum load requirement



- 10192BK60 60W Direct Wire Dimmable**
- 10192BK96 96W Direct Wire Dimmable**

- 6.5" L x 2.5" W x 2.25" H
- Rated for both indoor dry and damp locations
- Dimmable with low voltage magnetic dimmer
- 5W minimum load requirement
- Compatible with Lutron & Leviton low-voltage magnetic analog dimmers



10193BK

- 8' cord & plug accessory for use with 10192BK60 Direct Wire Dimmable and 10192BK986 Direct Wire Dimmable

