

Accessories

Accessories

Replacement Thermal Protectors

Frame-In Kit	Part#	Order/Pulse#
1004ICV	LH-1209K	921250
1104ICX	LH-3332A	932244
1004IC, 1004ICR, 1004SIC, 1004SICR, 1104IC	LH-3334	929895
1004ICX	LH-3334B	932301
2004ICV	MI-5481C	931759
1102P1, 1002P1, 1003R, 2000LV, 2000LVR, 2002P1, 2003R	SK-3075	916970

Frame-In Kit	Part#	Order/Pulse#
1000LVNT, 2000LVNT	LH-1209K	921250
1000P1, 1100P1	SK-3101	923096
1000AICM, 1000IC, 1000ICV, 1100AICM, 1100DAICM	MI-7400	898640
1000LV, 1000LVR	SK-3104	917117
2000AIC, 2000AICV, 2000IC, 2000P1	SK-3113	925696
1700P1	SK-3114	926417

Note: Please refer to part# and pulse# when ordering.

Lytening Airseal Gasket Kit



LAS56
Converts Lytening housings* 1104IC, 1004IC, 1004SIC, 1104FI to comply with Model Energy Code and Washington State Energy Code air leakage requirements.

*Use with Lytening new construction housings (1104IC, 1004IC, 1104SIC, 1004SIC, 1104FI) only if factory installed tape or knockouts have been removed.

Slot Aperture Faceplate



Conversion faceplates for Lytecaster MR16 low voltage Pinhole reflectors (1000 and 1100 Series). Matte White finish.

1452
For 1052LV Pinhole

1552
For 1152 Pinhole


Mounting Bars

1964*
20" mounting bar extenders. Set of 2. For 2000, 1000 Series.

1966*
Standard length (13") mounting bars. Set of 4. For 2000, 1000 Series (Except IC).

1976*
13" replacement bars. Set of 4. For Series 1100 and IC Frame-In Kits.

1977
Lytefining Mounting Bars.

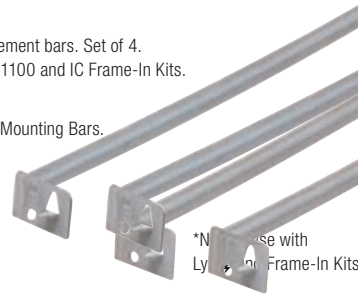

*Not use with Lytefining Frame-In Kits.


Lytecaster Hole Saw



HC356
Dedicated hole saw reduces installation time. Completely adjustable cutter comes with Lytecaster template to take out guess work. Place cutting elements in the holes labeled for the frame you are using and tighten...you're ready to cut. Durable dust shield eliminates clean-up even when remodeling. Comes with additional drill bits, extra cutting elements and contractor pencil all housed in a convenient, durable plastic case.

HC356BLADE
Replacement Hole Saw Blade

MR16 Socket Replacement

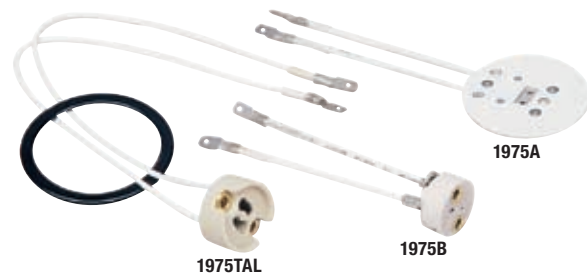

1975B
For Series 2000LV Frame-In Kits and 1052LV Trim.

1975A
For Series 1000LV Frame-In Kits and Trims 1152, 1161.

1975TAL
For GE Turn and Lock Lamps.

Lytening Airseal Gasket Kit



LAS56R
Converts Lytening Remodeler housings* 1104ICR, 1004ICR, 1004SICR, 1104FIR to comply with Model Energy Code and Washington State Energy Code air leakage requirements.

Retaining Clips



1955
For installation in existing ceilings. Box of 100. For Series 2000, 1000, 1100 (except Basic reflectors, Deep and Shallow Specular reflectors). 1 1/4" maximum ceiling thickness.

Accessory Cones



Replacement cones for Lytecaster reflectors (not for use with Basic reflectors, Eyeballs and Shallow Specular reflectors, Pinholes and Slots). To order finishes other than Matte Black Step Baffle, add finish designations after catalog number (for example 1350CL for Specular Clear, 2000 Series).

Finish	Comp. Refl.
1350 Matte Black Step Baffle	2000 Series
1350 CL, GD, BK, BA, BG, WH, WHB, CD	2000 Series
1450 Matte Black Step Baffle	1000 Series
1450 CL, GD, BK, BA, BG, WH, WHB, CD	1000 Series
1550 Matte Black Step Baffle	1100 Series
1550 CL, GD, BK, BA, BG, WH, WHB, CD	1100 Series

CL Specular Clear	BG Brushed Gold
GD Specular Gold	WH Matte White
BK Specular Black	WHB Matte White Baffle
BA Brushed Clear	CD Clear Diffuse

Plaster Ceiling Ring



Fits all Frame-In Kits except Non-IC Remodelers. Full 7/8" deep. Installed after mounting frame, before plastering ceiling.

1959 Series 2000 (Not for 2000AICV)
1960 Series 1000
1961 Series 1100 (Not for Lytening or 1100DAICM)

Extra Thick Ceiling Mounting Ring



Mounting ring holds reflector snug to ceiling. Can be used with Standard Frame-In Kits where ceilings are up to 2" thick.

1967A 1100 Series (except 1104IC/R, 1104SIC/R, 1104FI/R)
1967B 1000 Series (except 1004IC/R, 1004SIC/R)
1967C 2000 Series
Not for 1095, 1096, 1195, 1196 Trims


Extra Wide Flange Trim Ring



1954
For 1100 Series Reflector Trims (except 1126-1128, 1170-1199) – O.D. 8 5/8" I.D. 6 3/4.

1957
For Series 1000 Reflector Trims – O.D. 7" I.D.5 (except 1071, 1082, 1085, 1076).

MR16 Remote Transformer

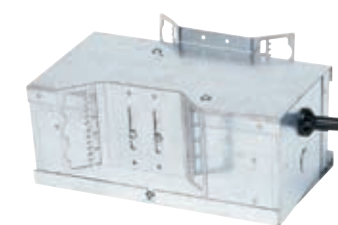

8608
75W Max.
8609
225W Max.

MR16 Remote Transformer
LVNT Frame-In Kits may be installed in new ceilings up to 1" thick. Lightolier Remote Transformers 8608 (75W) and 8609 (225W) are fused and suitable for recessed installation.

277v Operation Remote Step-Down Transformer



7997
Supplies 120v fixture from a 277v branch circuit (20 amp. minimum). Can be used for multiple fixtures (not to exceed 300W maximum load).

Medium Base Socket Extender



1968
For 50W and 75W short neck PAR30 lamps only. Limited compatibility (see individual reflector trim data). Adds 1 1/4".


T-Bar Ceiling Clips



1956
For use with series 2000, 1000 and 1102HF.*


*All other 1100 Series and Lytening Frame-In Kits mounting bars have integral T-bar tab. Position notched area of mounting bar on top of T-bar and lock by bending tab underneath T-bar bead. Mounting bars permit frame to be positioned off-center between 24" joists.

Staples & Nails

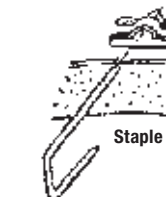

Anchors 1000+1100 Series Frame-In kits when used as a remodeler (See instruction sheet for application and further information)

Order quantity of 1 per fixture (will receive pack of 4)

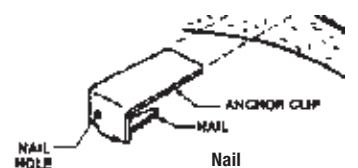

1985N
1000 Series



1985S
1100 Series