


Jumbo/ Oversize


- Ideal for covering broken plaster and irregularly cut holes in sheet rock or paneling around the box.
- Can be used to protect wall surrounding wiring devices thus reducing maintenance.
- Useful for replacement of plates in old work where a mark is left around the original plate.

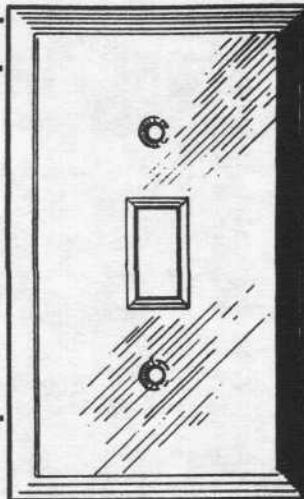














For color photos of finishes see inside front cover.

1 Gang	5.5" x 3.5"
2 Gang	5.5" x 5.5"
3 Gang	5.5" x 7.5"
4 Gang	5.5" x 9.5"
5 Gang	5.5" x 11.5"


















STANDARD SHAPE

 listed 883C except where noted by asterisk(*).

See page A85 for ordering Custom Jumbo/Oversize Plates not found in this listing. Available to 20 gangs on special order.


	SPRAYED BRASS MATTE	BROWN SEMI-GLOSS	CHROME PLATED	IVORY SEMI-GLOSS	WHITE WRINKLE	WHITE SEMI-GLOSS
	Painted Steel (BA)	Painted Steel (BK)	Polished Steel (CA)	Painted Steel (IA)	Painted Steel (DW)	Painted Steel (WA)
 1 Toggle Switch (1T-SL)	81871	82871	83871	84871	85871	86871
 2 Toggle Switches (2T-SL)	81872	82872	83872	84872	85872	86872
 3 Toggle Switches (3T-SL)	81873	82873	83873	84873	85873	86873
 4 Toggle Switches (4T-SL)	81874	82874	83874	84874	85874	86874
 5 Toggle Switches (5T-SL)	81875	82875	83875	84875	85875	86875
 1 Duplex Receptacle (10DR-SL)	81801	82801	83801	84801	85801	86801
 2 Duplex Receptacles (20DR-SL)	81802	82802	83802	84802	85802	86802
 1 Single Recept. (1.405") (10R-SL)	81891	82891	83891	84891	85891	86891
 1 Blank (Box Mntg. 3.281") (1B-SL)	81851	82851	83851	84851	85851	86851
 2 Blanks (Box Mntg. 3.281") (2B-SL)	81852	82852	83852	84852	85852	86852
 3 Blanks (Box Mntg. 3.281") (3B-SL)	81853	82853	83853	84853	85853	86853
 One 3/4" ID Phone (Box Mntg. 3.281") (01-SL)*	81861	82861	83861	84861	85861	86861
 One Phone with .375" ID Grommet and Mounting Strap (Device Mntg. 2.375")*	81881	82881	83881	84881	85881	86881

Jumbo/Oversize

	NOTE: X following Catalog Number denotes that straps are not supplied.	SPRAYED BRASS MATTE	BROWN SEMI-GLOSS	CHROME PLATED	IVORY SEMI-GLOSS	WHITE WRINKLE	WHITE SEMI-GLOSS
	30/50A 3 Wire Range/Dryer Recept. 2.125" ID Hole (3D-SL)	81847	82847	83847	84847	85847	86847
	30/50A 3 Wire Range/Dryer Recept. 2.125" ID Hole 2 Gang Plate (23D-SL)	81937	82937	83937	84937	85937	86937
	Block Duplex/GFI Recept. (SRM-SL)	81834	82834	83834	84834	85834	86834
	2 Block Duplex/GFI Recept. (2SRM-SL)	81835	82835	83835	84835	85835	86835
	Interchangeable 1 Hole Horizontal (71A-SL)	81911X	82911X	83911X	84911X	85911X	86911X
	Interchangeable 2 Holes (71B-SL)	81921X	82921X	83921X	84921X	85921X	86921X
	Interchangeable 3 Holes (71C-SL)	81931X	82931X	83931X	84931X	85931X	86931X
	Toggle Switch, Duplex Recept. (1T-10DR-SL)	81832	82832	83832	84832	85832	86832
	Toggle Switch, Block Duplex/GFI Recept. (1T-SRM-SL)	81865	82865	83865	84865	85865	86865
	Duplex Recept., Single Recept. (1.405" ID Hole) (10DR-10R-SL)	81842	82842	83842	84842	85842	86842
	Toggle Switch, Centered 2 Gang Plate (1T-2G-SL)	81971	82971	83971	84971	85971	86971
	Duplex Recept., Centered 2 Gang Plate (10DR-2G-SL)	81901	82901	83901	84901	85901	86901
	Single Recept., Centered 2 Gang Plate (1.405" ID Hole) (10R-2G-SL)	81991	82991	83991	84991	85991	86991
	2 Toggle Switches, Duplex Receptacle (2T-10DR-SL)	81843	82843	83843	84843	85843	86843
	2 Toggle Switches, Block Duplex/GFI Recept. (2T-SRM-SL)	81883	82883	83883	84883	85883	86883
	Toggle Switch, 2 Duplex Recept. (1T-20DR-SL)	81863	82863	83863	84863	85863	86863
	3 Toggle Switches, Duplex Recept. (3T-10DR-SL)	81844	82844	83844	84844	85844	86844

Jumbo/ Oversize


- Ideal for covering broken plaster and irregularly cut holes in sheet rock or paneling around the box.
- Can be used to protect wall surrounding wiring devices thus reducing maintenance.
- Useful for replacement of plates in old work where a mark is left around the original plate.

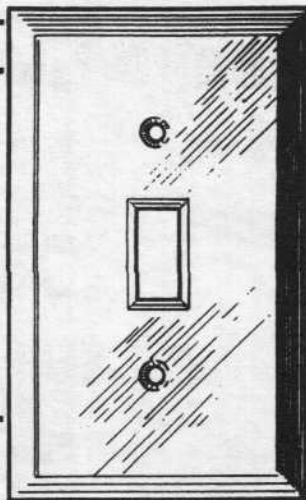














For color photos of finishes see inside front cover.

1 Gang	5.5" x 3.5"
2 Gang	5.5" x 5.5"
3 Gang	5.5" x 7.5"
4 Gang	5.5" x 9.5"
5 Gang	5.5" x 11.5"

STANDARD SHAPE


















 listed 883C except where noted by asterisk(*)

See page A85 for ordering Custom Jumbo/Oversize Plates not found in this listing. Available to 20 gangs on special order.

	STAIN-LESS TYPE 302 (.035") Spec. Grade Satin Finish (302SS)	SATIN BRASS (.040") Satin Finish US#4 (4BB)	ALUMI-NUM (.050") Clear Anodized US#28 (5AA)	STAIN-LESS TYPE 430 (.030") Satin Finish US#32 (SS)	BROWN WRINKLE Painted Steel (DB)	IVORY WRINKLE Painted Steel (DI)
 1 Toggle Switch (1T-SL)	93871	94871	95871	97871	98871	99871
 2 Toggle Switches (2T-SL)	93872	94872	95872	97872	98872	99872
 3 Toggle Switches (3T-SL)	93873	94873	95873	97873	98873	99873
 4 Toggle Switches (4T-SL)	93874	94874	95874	97874	98874	99874
 5 Toggle Switches (5T-SL)	93875	94875	95875	97875	98875	99875
 1 Duplex Receptacle (10DR-SL)	93801	94801	95801	97801	98801	99801
 2 Duplex Receptacles (20DR-SL)	93802	94802	95802	97802	98802	99802
 1 Single Recept. (1.405") (10R-SL)	93891	94891	95891	97891	98891	99891
 1 Blank (Box Mntg. 3.281") (1B-SL)	93851	94851	95851	97851	98851	99851
 2 Blanks (Box Mntg. 3.281") (2B-SL)	93852	94852	95852	97852	98852	99852
 3 Blanks (Box Mntg. 3.281") (3B-SL)	93853	94853	95853	97853	98853	99853
 One 5/8" ID Phone (Box Mntg. 3.281") (01-SL)*	93861	94861	95861	97861	98861	99861
 One Phone with .375" ID Grommet and Mounting Strap (Device Mntg. 2.375")*	93881	94881	95881	97881	98881	99881

Jumbo/Oversize

NOTE: X following Catalog Number denotes that straps are not supplied.

	STAIN- LESS TYPE 302	SATIN BRASS (.040")	ALUMI- NUM (.050")	STAIN- LESS TYPE 430	BROWN WRINKLE	IVORY WRINKLE
 30/50A 3 Wire Range/Dryer Recept. 2.125" ID Hole (3D-SL)	93847	94847	95847	97847	98847	99847
 30/50A 3 Wire Range/Dryer Recept. 2.125" ID Hole 2 Gang Plate (23D-SL)	93937	94937	95937	97937	98937	99937
 Block Duplex/GFI Recept. (SRM-SL)	93834	94834	95834	97834	98834	99834
 2 Block Duplex/GFI Recepts. (2SRM-SL)	93835	94835	95835	97835	98835	99835
 Interchangeable 1 Hole Horizontal (71A-SL)	93911X	94911X	95911X	97911X	98911X	99911X
 Interchangeable 2 Holes (71B-SL)	93921X	94921X	95921X	97921X	98921X	99921X
 Interchangeable 3 Holes (71C-SL)	93931X	94931X	95931X	97931X	98931X	99931X
 Toggle Switch, Duplex Recept. (1T-10DR-SL)	93832	94832	95832	97832	98832	99832
 Toggle Switch, Block Duplex/GFI Recept. (1T-SRM-SL)	93865	94865	95865	97865	98865	99865
 Duplex Recept., Single Recept. (1.405" ID Hole) (10DR-10R-SL)	93842	94842	95842	97842	98842	99842
 Toggle Switch, Centered 2 Gang Plate (1T-2G-SL)	93971	94971	95971	97971	98971	99971
 Duplex Recept., Centered 2 Gang Plate (10DR-2G-SL)	93901	94901	95901	97901	98901	99901
 Single Recept., Centered 2 Gang Plate (1.405" ID Hole) (10R-2G-SL)	93991	94991	95991	97991	98991	99991
 2 Toggle Switches, Duplex Receptacle (2T-10DR-SL)	93843	94843	95843	97843	98843	99843
 2 Toggle Switches, Block Duplex/GFI Recept. (2T-SRM-SL)	93883	94883	95883	97883	98883	99883
 Toggle Switch, 2 Duplex Recepts. (1T-20DR-SL)	93863	94863	95863	97863	98863	99863
 3 Toggle Switches, Duplex Recept. (3T-10DR-SL)	93844	94844	95844	97844	98844	99844