

Pilot and Signaling Devices

Heavy-Duty 30.5 mm Watertight/Oiltight Accessories

CR104P

Section 9

Enclosures and Stations
 600 Volts max. AC/DC
 10 Amperes Continuous


To order 104P Push button enclosures, choose the product number in the following tables. Then specify operator by hole number (see page 9-47) as indicated in the corresponding diagram. Add all the operator list prices to the assembled, unwired station to arrive at the total list price, GO-10P1, for your unit.

Enclosure Only—Surface Mounted


Enclosure Type	Enclosure Material	Enclosure Holes	Product Number
NEMA Type 1	Sheet Steel	1	CR104PEX11
NEMA Type 1	Sheet Steel	2	CR104PEX12
NEMA Type 1	Sheet Steel	3	CR104PEX13
NEMA Type 1	Sheet Steel	4	CR104PEX14 ¹
NEMA Type 1, 3, 3R, 12, 13	Painted Sheet Steel	1	CR104PEG11
NEMA Type 1, 3, 3R, 12, 13	Painted Sheet Steel	2	CR104PEG12
NEMA Type 1, 3, 3R, 12, 13	Painted Sheet Steel	3	CR104PEG13
NEMA Type 1, 3, 3R, 12, 13	Painted Sheet Steel	4	CR104PEG14 ¹
NEMA Type 1, 3, 3R, 12, 13	Painted Sheet Steel	4	CR104PEG22
NEMA Type 1, 3, 3R, 12, 13	Painted Sheet Steel	6	CR104PEG23
NEMA Type 1, 3, 3R, 12, 13	Painted Sheet Steel	9	CR104PEG33
NEMA Type 1, 3, 3R, 12, 13	Painted Sheet Steel	12	CR104PEG34
NEMA Type 1, 3, 3R, 12, 13	Painted Sheet Steel	16	CR104PEG44
NEMA Type 1, 3, 3R, 12, 13	Painted Sheet Steel	20	CR104PEG45
NEMA Type 1, 3, 3R, 12, 13	Painted Sheet Steel	25	CR104PEG55
NEMA Type 3, 3R, 4, 4X, 12, 13	Stainless Steel	1	CR104PES11
NEMA Type 3, 3R, 4, 4X, 12, 13	Stainless Steel	2	CR104PES12
NEMA Type 3, 3R, 4, 4X, 12, 13	Stainless Steel	3	CR104PES13
NEMA Type 3, 3R, 4, 4X, 12, 13	Stainless Steel	4	CR104PES14 ¹
NEMA Type 3, 3R, 4, 4X, 12, 13	Stainless Steel	4	CR104PES22
NEMA Type 3, 3R, 4, 4X, 12, 13	Stainless Steel	6	CR104PES23
NEMA Type 3, 3R, 4, 4X, 12, 13	Stainless Steel	9	CR104PES33
NEMA Type 3, 3R, 4, 4X, 12, 13	Stainless Steel	12	CR104PES34
NEMA Type 3, 3R, 4, 4X, 12, 13	Stainless Steel	16	CR104PES44
NEMA Type 3, 3R, 4, 4X, 12, 13	Stainless Steel	20	CR104PES45
NEMA Type 3, 3R, 4, 4X, 12, 13	Stainless Steel	25	CR104PES55

Does not include push buttons: see ordering instructions above.

¹Four vertical openings.

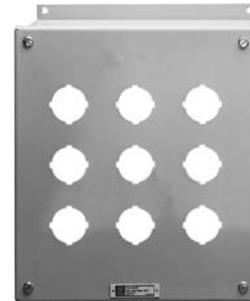

Painted Sheet Steel Enclosure

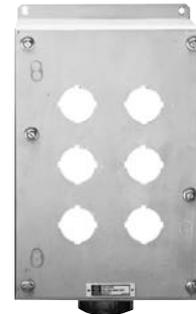

Stainless Steel Enclosure



Nameplates: See pages 9-40 to 9-41
 Technical Data: See pages 9-48 to 9-49
 Drilling Plan and Dimensions: See pages 9-49