


EI700

6" Aperture, New Construction, IC 120V Line Voltage

The EI700 housing is designed for use in insulated ceilings where the housing will be in direct contact with insulation. EI700 may be converted into AIR-TITE installation when used with AIR-TITE trims. Look for the AIR-TITE trim logo in this section.

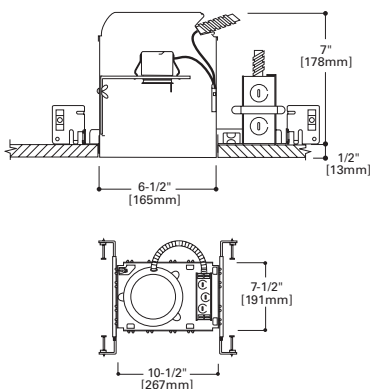

FEATURES

HOUSING

- Aluminum construction for greater heat dissipation.
- Rigid socket plate adjusts and locks without tools for various lamp sizes.

PLASTER FRAME

- Housing adjusts in plaster frame to accommodate up to 1-3/4" thick ceilings.
- Regressed locking screw for securing hanger bars.
- Cutouts for easily crimping hanger bars in position.

JUNCTION BOX

- Positioned to accommodate straight conduit runs.
- Seven conduit knockouts are uniform 1/2" size with true pryout slots.
- Four pryouts with integral strain relief simplify "NM" non-metallic sheathed cable installation.
- Three quick connect wire connectors included.

ALL-NAIL™ BAR HANGERS

Bar Hanger features include:

- Pre-installed nail.
- Mini leveling foot aligns the housing to the bottom of the joist.
- Housing can be positioned at any point within 24" joist spans
- Score lines allow tool-free shortening for narrow joist spacing.
- Bar hangers may be repositioned 90° on plaster frame
- Integral T-bar clip snaps onto T-bars – no additional clips are required

SOCKET

Porcelain E26 socket with nickel plated brass screw shell, snaps into trim for consistent lamp positioning.

THERMAL PROTECTOR

Self resetting thermal protector deactivates fixture if overheating occurs due to improper lamping or misapplied insulation.


LABELS

- UL/cUL Listed 1598 Luminaire
- UL/cUL Listed for Damp Location
- UL/cUL Listed for Feed Through
- UL/cUL Listed for Wet Location, covered ceiling
- UL/cUL Listed for Direct Contact with Insulation and combustible material
- IP Rated (Improper Lamp)

EI700R

6" Aperture, Remodel, IC 120V Line Voltage

The All-Pro EI700R remodel housing is designed for existing ceiling installations where the housing will be in direct contact with insulation. EI700R may be converted into AIR-TITE installation when used with AIR-TITE trims. Look for the AIR-TITE trim logo in this section.

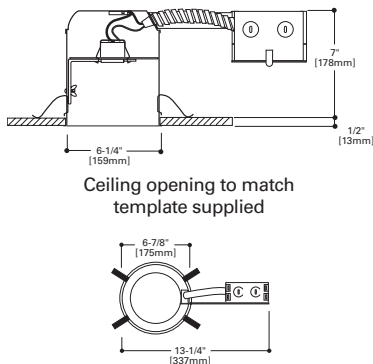

FEATURES

HOUSING

- Aluminum construction for greater heat dissipation.
- Rigid socket plate adjusts and locks without tools for various lamp sizes.

REMODEL CLIPS

Four remodel clips secure housing and accommodate 1/2" and 5/8" ceiling thickness.

JUNCTION BOX

- Seven conduit knockouts are uniform 1/2" size with true pryout slots.
- Four pryouts with integral strain relief simplify "NM" non-metallic sheathed cable installation.
- Three quick connect wire connectors included.

SOCKET

Porcelain E26 socket with nickel plated brass screw shell, snaps into trim for consistent lamp positioning.

THERMAL PROTECTOR

Self resetting thermal protector deactivates fixture if overheating occurs due to improper lamping or misapplied insulation.

LABELS

- UL/cUL Listed 1598 Luminaire
- UL/cUL Listed for Damp Location
- UL/cUL Listed for Feed Through
- UL/cUL Listed for Wet Location, covered ceiling
- UL/cUL Listed for Direct Contact with Insulation and combustible material