

3" RECESSED MR16 | GU10




BULB OPTIONS:			
MR16		GU10	
BULB TYPE:	MR16	BULB TYPE:	GU10
VOLTAGE:	12V	VOLTAGE:	120V
MAX. WATTAGE:	50W	MAX. WATTAGE:	50W

*LED COMPATIBLE

TE04 | 3" EYEBALL

PRODUCT DIMENSION:

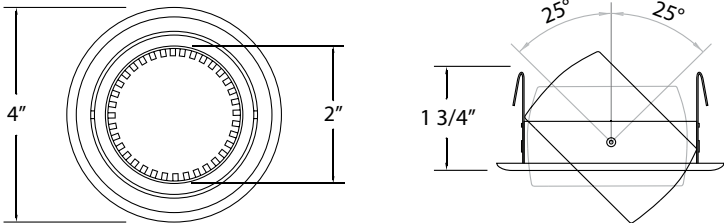

FINISHES:




-02 White



-04 Satin Nickel

TE90 | 3" GIMBAL

PRODUCT DIMENSION:

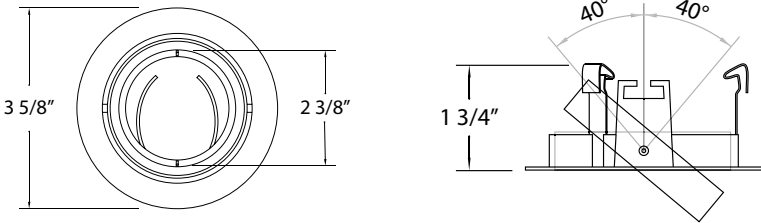

FINISHES:



-01 Black



-02 White



-04 Satin Nickel



-05 Chrome



-06 Antique Brass



-09 Bronze

BULB OPTIONS:			
MR16		GU10	
BULB TYPE:	MR16	BULB TYPE:	GU10
VOLTAGE:	12V	VOLTAGE:	120V
MAX. WATTAGE:	50W	MAX. WATTAGE:	50W

*LED COMPATIBLE