

Hangers/Hanging Systems


Pin Driven Angle Brackets

Features

- Longer leg angle bracket for tool clearance.
- Designed to fit a variety of pin drivers.
- Improved for easier installation with pin drivers.
- Star hole provides more gripping power to align brackets.
- Pregalvanized steel.
- Preassembly options available for Rod, Wire, Strap and Cable Applications.

NOTE:

Load limits apply to CADDY® Fasteners only. Pin must be evaluated separately.

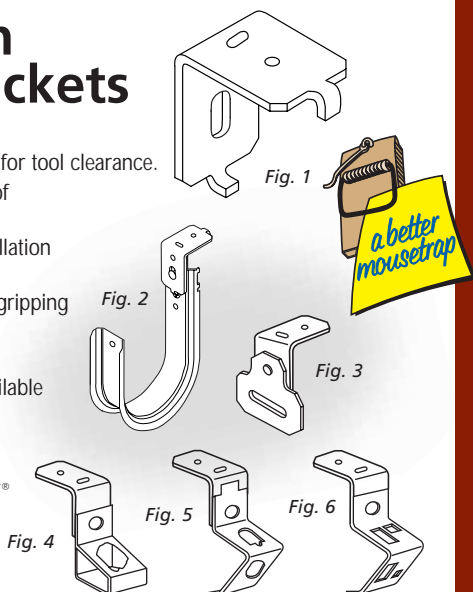

Sizing Chart

PART NUMBER	FIG. NO.	DESCRIPTION	LOAD	QTY. PER BOX
AFAB3	1	Angle bracket with 1/4" slotted hole and 3/16" mounting hole.	160	100
CAT21AFAB3	2	Cable support hanger with angle bracket. 1 5/16" diameter loop.	50	50
CAT32AFAB3	2	Cable support hanger with angle bracket. 2" diameter loop	50	40
CAT64AFAB3	2	Cable support hanger with angle bracket. 4" diameter loop	100	25
CAT12AFAB3	2	Cable support hanger with angle bracket. Holds up to 16 cables of 4 twisted pair or fiber optic.	50	50
MSSAFAB3	3	Strap hanger to angle bracket.	200	50
4TIAFAB3	4	For 1/4" threaded rod, with thread impression.	160	50
6TIAFAB3	4	For 3/8" threaded rod, with thread impression.	160	100
6TAFAB3	4	For 1/4" or 3/8" threaded rod, nuts required.	160	100
6AFAB3	5	For 3/8" plain rod.	160	100
708AFAB3	6	For #8 wire or 1/4" rod.	160	100