



Universal Beam Grounding Clamp



- Universal, fits on a wide range of standard (angled) and wide flange (parallel) structural steel beams
- Provide a mounting pad suitable for a two-hole compression lug
- Install quickly and easily with standard 1/4" key hex wrench tooling
- UL 467 Listed and CSA 22.2 Certified for grounding and bonding suitable for direct burial in earth or concrete
- Comply with vibration tests per MIL-STD-202G (METHOD 201A)
- For the complete line of StructuredGround™ Direct Burial Compression Grounding System, visit www.panduit.com

Part Number	Copper Conductor Size Range AWG	Flange Thickness In.	Stud Size In.	Hole Spacing In.	Thread Size	Figure Dimensions In.			Std. Pkg. Qty.
						L	W	H	
GUBC500-6	#6 – 500	0.250 – 0.675	1/2	1.75	1/2 – 13	3.15	2.13	2.50	1



Auxiliary Cable Brackets and Jumpers

- Bonds ladder rack, wire basket and Panduit® Wyr-Grid® System sections together without drilling holes
- Supports grounding conductors in the telecommunications room, allows separation of grounding conductors from other cables
- Holds up to four conductors in sizes up to 750 kcmil
- Bonds to all 1" and 2" ladder rack rails
- Paint piercing teeth provide electrical continuity between cable pathway sections while minimizing debris
- Front and back mounting screw options allow easy installation and visual inspection
- GACB-2 and GACB-3 can be mounted above or below the cable pathway system for flexibility
- Brackets Meet TIA-607-B




GACB





GACB-2



GACB-3

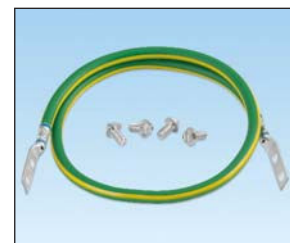

GACBJ618U

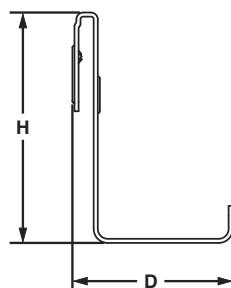 

Part Number	Part Description	Std. Pkg. Qty.	Std. Ctn. Qty.
Auxiliary Cable Brackets			
GACB-1	Auxiliary cable bracket; 1.25" (31.8mm) width; 7.00" (177.8mm) height; 4.87" (123.7mm) depth; provided with one mounting screw.	1	10
GACB-2	Auxiliary cable bracket; 1.63" (41.4mm) width, 3.95" (100.3mm) height, 5.22" (132.6mm) depth; provided with one mounting screw.	1	10
GACB-3	Auxiliary cable bracket; 1.88" (47.6mm) width, 4.58" (116.3mm) height, 5.29" (134.4mm) depth; provided with one mounting screw.	1	10
Bonding Jumper Kits			
GACBJ68U	Auxiliary cable bracket jumper for bonding pathway sections; #6 AWG (16mm ²); 8.0" (203mm) length; factory terminated on both ends with straight, two-hole, long barrel compression lugs; provided with .16 oz. (5cc) of antioxidant and four mounting screws.	1	—
GACBJ612U	Auxiliary cable bracket jumper for bonding pathway sections; #6 AWG (16mm ²); 12.0" (305mm) length; factory terminated on both ends with straight, two-hole, long barrel compression lugs; provided with .16 oz. (5cc) of antioxidant and four mounting screws.	1	—
GACBJ618U	Auxiliary cable bracket jumper for bonding pathway sections; #6 AWG (16mm ²); 18.0" (457mm) length; factory terminated on both ends with straight, two-hole, long barrel compression lugs; provided with .16 oz. (5cc) of antioxidant and four mounting screws.	1	—