



Pass & Seymour

Wall Plates Dustproof Stainless Steel Covers One & Two Gang

WP1, WP2, WP7, WP8, WPH8, WP26, WPH26, WP13, WP23, WPH1-L, WPH7-L, WPH8-L, WP26-L

Exceptional durability plus dust protection.

These brushed stainless steel dust covers are designed to handle challenging conditions including dusty, corrosive environments, or hard-use areas. Yet they provide a smooth, handsome style that fits in anywhere. Note: these covers are not suitable for wet locations — see our Weatherproof Covers if water resistance is required.



Features & Benefits

**Aesthetically
pleasing design.**

**These stainless steel
covers are dustproof
only and do not meet
NEC 406.8(A) or (B).**



**Stainless steel
springs.**

**Made of .030 inch thick
302 brushed stainless
steel to help protect against
corrosion.**

WP26-L

 
 
 
 
Field Uses/Vertical Markets

- | | | | |
|--------------|---------------|-----------------------|---------------------|
| ■ Industrial | ■ Health Care | ■ Education | ■ Institutional |
| ■ Retail | ■ Office | ■ Hospitality/Lodging | ■ Multiple Dwelling |

SF2505R1 — Updated January 2004 — For latest specs visit www.legrand.us/passandseymour

Wall Plates Dustproof Stainless Steel Covers One & Two Gang

Ordering Information

Catalog Number	Description
One & Two Gang Dust Covers	
 WP1	1 Toggle Switch 1 Small Cover, Vertical 1 Gang Plate Available for Box Mount – add suffix -FS.
 WP2	2 Toggle Switches 2 Small Covers, Vertical 2 Gang Plate
 WP7	1 Single Receptacle 1 Small Cover, Vertical 1 Gang Plate Available for Box Mount – add suffix -FS.
 WP8	1 Duplex Receptacle 1 Long Cover, Vertical 1 Gang Plate
 WPH8	1 Duplex Receptacle 1 Long Cover, Horizontal 1 Gang Plate
 WP26	1 Decorator/GFCI 1 Long Cover, Vertical 1 Gang Plate
 WPH26	1 Decorator/GFCI 1 Long Cover, Horizontal 1 Gang Plate
 WP13	1 Gang Blank (Box Mounted) Gasketed
 WP23	2 Gang Blank (Box Mounted) Gasketed
Locking Dust Covers	
 WPH1-L	Toggle Opening Horizontal
 WPH7-L	Single Receptacle Opening Horizontal
 WPH8-L	Duplex Receptacle Opening Horizontal
 WP26-L	Decorator/GFCI Vertical
WP255-K	Key for all Dustproof Locking Covers. (Two keys furnished with each unit.)

For more information on these and other P&S products refer to our Product Guide or visit our web site.

Dustproof Stainless Steel Covers

Wall Plates

One & Two Gang



Pass & Seymour

Technical Specifications

3rd Party Compliance

UL Listed.
CSA Certified.

Performance


Environmental Dustproof Only

Materials


Body	.030" 302 Stainless Steel
Finish	Brushed
Springs	Stainless Steel 17-7
Screws	302 Stainless Steel
Gasket	Vinyl
Lock	Stainless Steel

Warranty


1 Year

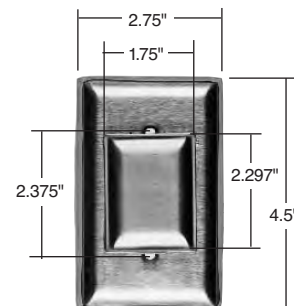

Dimensions for
WP1 & WP7

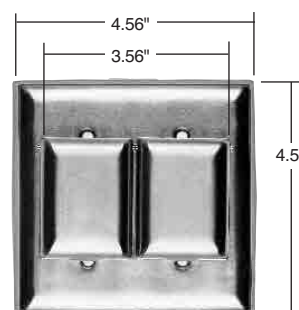

Dimensions for
WP2

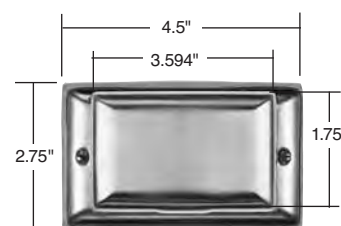


Dimensions for
WPH8 & WPH26




Dimensions for
Vertical Locking



Dimensions for
Horizontal Locking

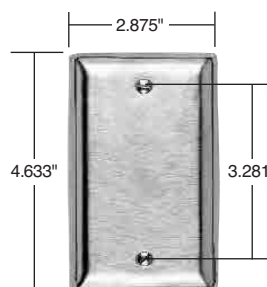

Dimensions for
WP13

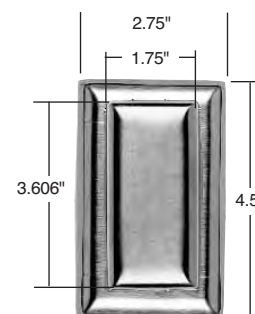


Dimensions for
WP8 & WP26

Complementary Devices & Accessories




WALL PLATES

- TradeMaster® Thermoplastic Nylon
- Stainless Steel
- Brass
- Aluminum

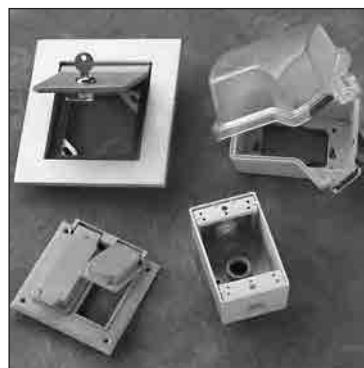


WEATHERPROOF BOXES & COVERS

- While-In-Use Covers
- Heavy Cast Aluminum Covers
- Cast Covers
- Boxes

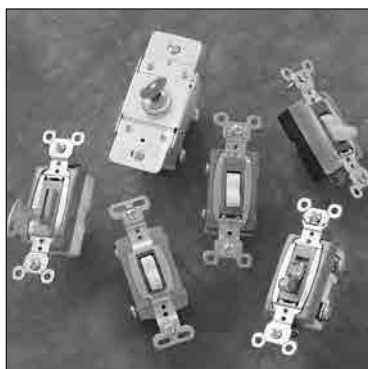


SWITCHES

- Heavy-Duty Toggle
- Heavy-Duty Lighted Toggle
- Heavy-Duty Security
- Heavy-Duty Locking
- Construction Grade Toggle
- Commercial Grade Toggle

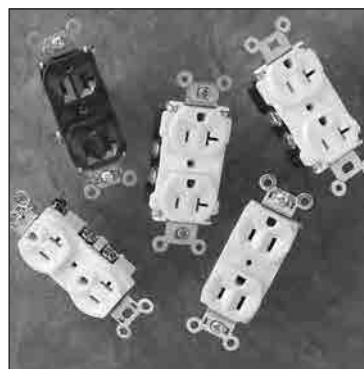

STRAIGHT BLADE RECEPTACLES

- Extra Heavy-Duty
- Heavy-Duty
- Construction Grade
- Commercial Grade

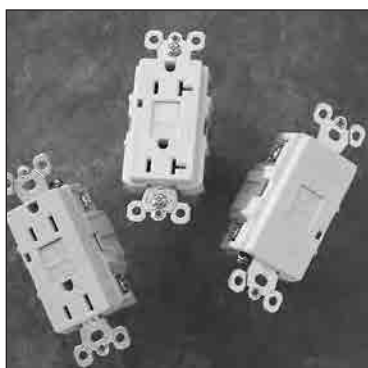

GFCIs

- Construction Grade with Auto-Ground
- Construction Grade
- Construction Grade Dead Front

Also available...

- | | | | |
|--------------------------|--------------------------------------|-------------------------------------|-------------------------------|
| ■ Light Almond Devices | ■ TVSS & Isolated Ground Devices | ■ Straight Blade Plugs & Connectors | ■ IEC 309 Industrial Products |
| ■ Decorator Devices | ■ Ground Continuity Monitoring (GCM) | ■ Turnlok® Locking Devices | ■ Flexcor® Wire Mesh Grips |
| ■ Hospital Grade Devices | | | ■ Configurable Solutions |
| ■ PlugTail™ Devices | | | |



Legrand/Pass & Seymour
P.O. Box 4822
Syracuse, NY 13221-4822
800-223-4185

North America Headquarters
60 Woodlawn Street
West Hartford, CT 06110
Phone: 1.877.BY.LEGRAND (295.3472)
Fax: 1.860.232.2062
www.legrand.us

Legrand Canada
570 Applewood Crescent
Vaughan, ON, L4K 4B4
Phone: 905.738.9195
Fax: 905.738.9721
www.legrand.ca