



**BOX COVERS &
CONDUIT BODIES**



WEATHERPROOF



METAL WALLPLATES




**UNBREAKABLE
THERMOPLASTIC
WALLPLATES**



Mulberry Metal Products, Inc.
2199 Stanley Terrace
P.O. Box 443
Union, New Jersey 07083

tel. 908.688.8850
fax. 908.688.7294
www.mulberrymetal.com

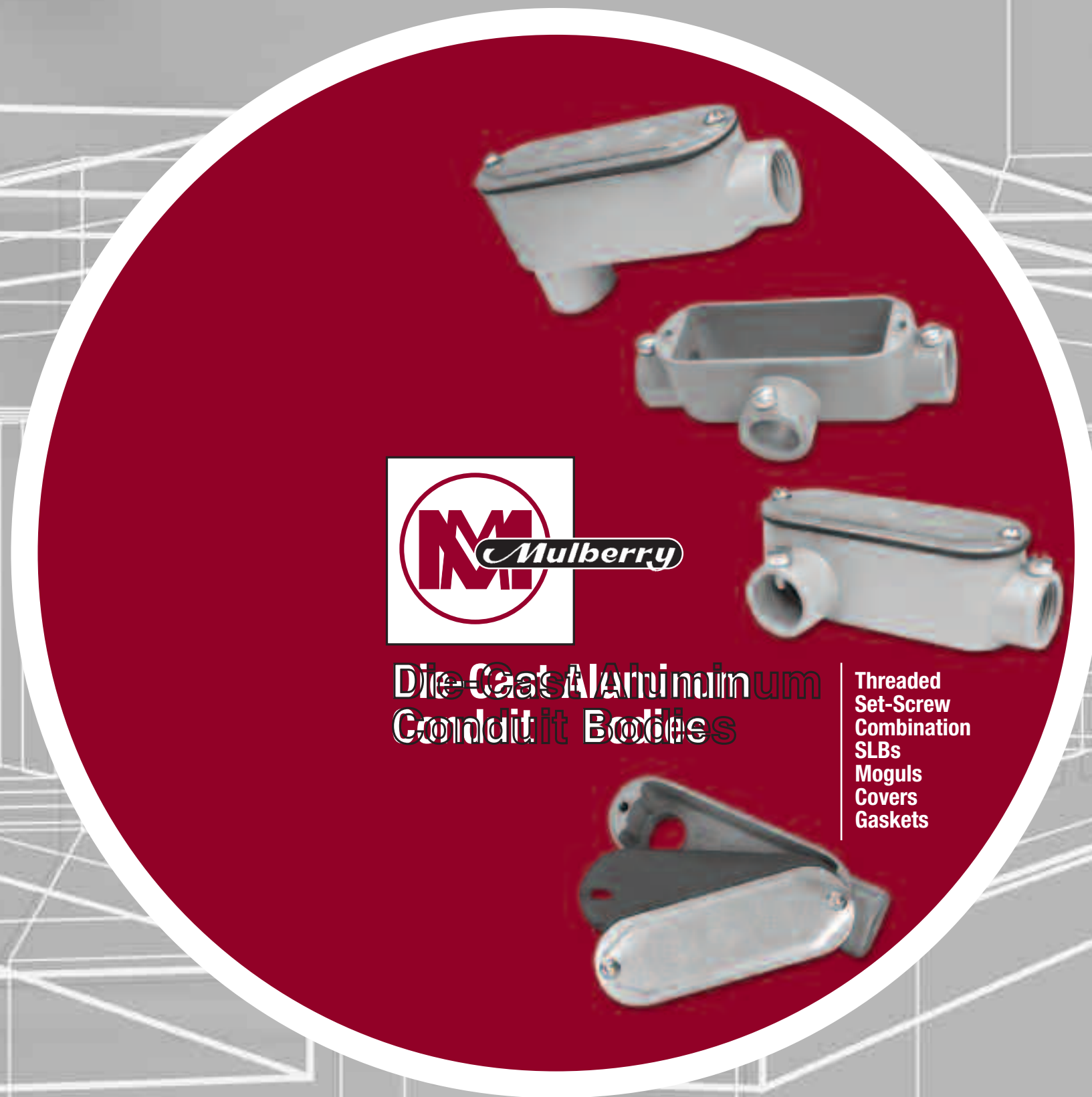

**Die-Cast Aluminum
Conduit Bodies**

Threaded
Set-Screw
Combination
SLBs
Moguls
Covers
Gaskets

Conduit Bodies

Threaded Set Screw and Combination Bodies and its



	3/4	3/4	3/4					
LB								
2"	11801	11851	13801	12801	12851	14801	10	50
"	11802	11852	13802	12802	12852	14802	10	50
1"	11803	11853	13803	12803	12853	14803	5	25
14"	11804	11854	13804	12804	12854	14804	—	2
12"	11805	11855	13805	12805	12855	14805	—	2
2"	11806	11856	13806	12806	12856	14806	—	1
22"				12807	12857		—	1
3"				12808	12858		—	1
32"				12809			—	1
4"				12810			—	1
LL								
2"	11811	11861	13811	12811	12861	14811	10	50
"	11812	11862	13812	12812	12862	14812	10	50
1"	11813	11863	13813	12813	12863	14813	5	25
14"	11814	11864	13814	12814	12864	14814	—	2
12"	11815	11865	13815	12815	12865	14815	—	2
2"	11816	11866	13816	12816	12866	14816	—	1
22"				12817			—	1
3"				12818			—	1
32"				12819			—	1
4"				12820			—	1
LR								
2"	11821	11871	13821	12821	12871	14821	10	50
"	11822	11872	13822	12822	12872	14822	10	50
1"	11823	11873	13823	12823	12873	14823	5	25
14"	11824	11874	13824	12824	12874	14824	—	2
12"	11825	11875	13825	12825	12875	14825	—	2
2"	11826	11876	13826	12826	12876	14826	—	1
22"				12827			—	1
3"				12828			—	1
32"				12829			—	1
4"				12830			—	1
G								
2"	11831	11881	13831	12831	12881	14831	10	50
"	11832	11882	13832	12832	12882	14832	10	50
1"	11833	11883	13833	12833	12883	14833	5	25
14"	11834	11884	13834	12834	12884	14834	—	2
12"	11835	11885	13835	12835	12885	14835	—	2
2"	11836	11886	13836	12836	12886	14836	—	1
22"				12837			—	1
3"				12838			—	1
T								
2"	11841	11891	13841	12841	12891	14841	10	50
"	11842	11892	13842	12842	12892	14842	10	50
1"	11843	11893	13843	12843	12893	14843	5	25
14"	11844	11894	13844	12844	12894	14844	—	2
12"	11845	11895	13845	12845	12895	14845	—	2
2"	11846	11896	13846	12846	12896	14846	—	1
22"				12847			—	1
3"				12848			—	1

Conduit Bodies

SBs and oguls



Catalog No.	Hub Size	Box Quantity	Carton Quantity	Weight per 100 Units
SLBs				
11901	2 "	10	50	24 lbs.
11902	"	10	50	30 lbs.
11903	1 "	5	25	55 lbs.
11904	14 "	—	1	140 lbs.
11905	12 "	—	1	150 lbs.
11906	2 "	—	1	260 lbs.


MOGUL CONDUIT BODIES
COMPLETE WITH COVER, GASKET, AND SCREWS

11914	14 "	5	130 lbs.
11915	12 "	2	350 lbs.
11916	2 "	2	310 lbs.

Conduit itting Covers and askets

valound Series

Catalog No.	Old No.	Description	Box Quantity	Carton Quantity	Weight Per 100 Units
GALVANIZED STEEL — 1/2 - 4"					
11699	1/2F35C	Blank, 2 "	25	250	10 lbs.
11700	3/4F35C	Blank, "	25	250	13 lbs.
11701	1F35C	Blank, 1 "	20	200	15 lbs.
11702	1-1/4F35C	Blank, 1 4 "-12 "	—	25	32 lbs.
11703	2F35C	Blank, 2 "	—	25	51 lbs.
11704	3F35C	Blank, 2 2 "-3"	—	25	88 lbs.
11705	4F35C	Blank, 3 2 "-4"	—	25	142 lbs.
ALUMINUM — 1/2 - 4"					
11710	1/2AF35C	Blank, 2 "	25	250	4 lbs.
11711	3/4AF35C	Blank, "	25	250	5 lbs.
11712	1AF35C	Blank, 1 "	20	200	7 lbs.
11713	1-1/4AF35C	Blank, 1 4 "-12 "	—	25	13 lbs.
11714	2AF35C	Blank, 2 "	—	25	25 lbs.
11715	3AF35C	Blank, 2 2 "-3"	—	25	36 lbs.
11716	4AF35C	Blank, 3 2 "-4"	—	25	66 lbs.
GASKETS — 1/2 - 4"					
11720	1/2F35G	Full, 2 "	100	1000	2 lbs.
11721	3/4F35G	Full, "	100	1000	2 lbs.
11722	1F35G	Full, 1 "	50	500	3 lbs.
11723	1-1/4F35G	Full, 1 4 "-12 "	—	600	5 lbs.
11724	2F35G	Full, 2 "	—	400	7 lbs.
11725	3F35G	Full, 2 2 "-3"	—	200	14 lbs.
11726	4F35G	Full, 3 2 "-4"	—	150	20 lbs.

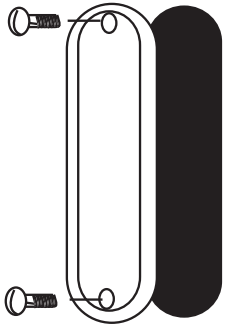

No. 11699 No. 11720