

Calbrite™

Stainless Steel Conduit Systems

Stainless Steel Reducing (Face) Bushings

Features:

- Manufactured in type 316 stainless steel to meet any stringent sanitary condition
- Polished with standard "brite" finish to increase corrosion resistance and aesthetic appearance
- NPT Male by NPSM Female Threads
- No package qty. required

Certifications and Compliances:


Manufactured in strict accordance to blue print, UL / CUL and ANSI standards, NEC Code Compliance, and pertinent requirements issued by Calpipe Industries. Manufactured in the United States

Applications:

Designed for use with stainless steel conduit, to reduce sizes of threaded stainless conduit, nipples, and other threaded fittings.

Industries Commonly Served:

- Food & Beverage Production & Distribution
- Water & Wastewater Treatment
- Pharmaceuticals & Cosmetics
- Refining & Extraction Sites
- Petrochemical
- Pulp & Paper Mills
- Marine & Coastal Facilities
- Along with other corrosive environments

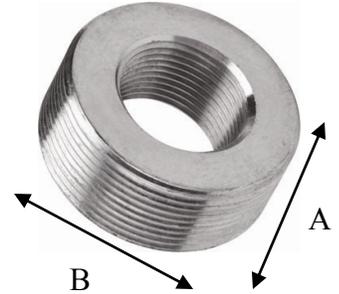

Size	Part Number	A (Height)	B (Width)	Wall Thickness	Weight (ea) per lb.
3/4" X 1/2"	S60700FB05	.740"	1.000"	.013"	.05
1" X 1/2"	S61000FB05	.750"	1.270"	.250"	.14
1" X 3/4"	S61000FB07	.750"	1.280"	.160"	.07
1-1/4" X 1/2"	S61200FB05	1.025"	1.630"	.450"	.40
1-1/4" X 3/4"	S61200FB07	1.000"	1.640"	.360"	.32
1-1/4" X 1"	S61200FB10	1.000"	1.640"	.230"	.16
1-1/2" X 1/2"	S61500FB05	1.000"	1.850"	.550"	.61
1-1/2" X 3/4"	S61500FB07	1.000"	1.860"	.460"	.50
1-1/2" X 1"	S61500FB10	1.020"	1.860"	.320"	.36
1-1/2" X 1-1/4"	S61500FB12	1.025"	1.890"	.160"	.14
2" X 1/2"	S62000FB05	1.000"	2.360"	.800"	1.03
2" X 3/4"	S62000FB07	1.000"	2.360"	.700"	.87
2" X 1"	S62000FB10	1.000"	2.360"	.560"	.79
2" X 1-1/4"	S62000FB12	1.000"	2.360"	.400"	.57
2" X 1-1/2"	S62000FB15	1.020"	2.360"	.285"	.37

Contact factory for 2-1/2" - 4" Face Bushing info

All dimensions are for informational purposes only *Tolerances +/- 5%