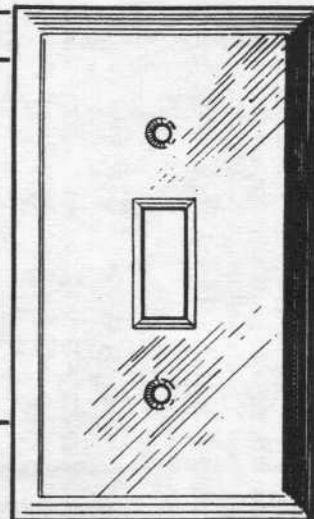


Residential

For color photos of finishes see
inside front cover.

 
STANDARD SHAPE



 
 
 
 
 
listed 883C except where
noted by asterisk(*).

See page A84 for ordering
Custom Plates not found in
this listing.

NEW!

	SPRAYED BRASS MATTE	BROWN SEMI- GLOSS	IVORY SEMI- GLOSS	WHITE WRINKLE	ALMOND SEMI- GLOSS
	Painted (BA)	Painted (BK)	Painted (IA)	Painted (DW)	Painted (ALM)
 1 Toggle Switch (1T)	81071	82071	84071	85071	44071
 2 Toggle Switches (2T)	81072	82072	84072	85072	44072
 3 Toggle Switches (3T)	81073	82073	84073	85073	44073
 4 Toggle Switches (4T)	81074	82074	84074	85074	
 5 Toggle Switches (5T)	81075	82075	84075	85075	
 6 Toggle Switches (6T)	81076	82076	84076	85076	
 7 Toggle Switches (7T)	81077	82077	84077	85077	
 8 Toggle Switches (8T)	81078	82078	84078	85078	
 9 Toggle Switches (9T)	81079	82079	84079	85079	
 10 Toggle Switches (10T)	81080	82080	84080	85080	
 1 Duplex Receptacle (10DR)	81101	82101	84101	85101	44101
 2 Duplex Receptacles (10DR)	81102	82102	84102	85102	44102

Residential • Standard

		SPRAYED BRASS MATTE	BROWN SEMI- GLOSS	IVORY SEMI- GLOSS	WHITE WRINKLE	ALMOND SEMI- GLOSS
	3 Duplex Receptacles (30DR)	81103	82103	84103	85103	
	4 Duplex Receptacles (40DR)	81104	82104	84104	85104	
	5 Duplex Receptacles (50DR)	81105	82105	84105	85105	
	6 Duplex Receptacles (60DR)	81106	82106	84106	85106	
	1 Single Recept. (1.405") (10R)	81091	82091	84091	85091	44091
	2 Single Recepts. (1.405") (20R)	81092	82092	84092	85092	
	3 Single Recepts. (1.405") (30R)	81093	82093	84093	85093	
	1 Blank with Mounting Strap (Device Mntg. 2.375") (1BDE)	81121	82121	84121	85121	
	2 Blanks with Mounting Straps (Device Mntg. 2.375") (2BDE)	81122	82122	84122	85122	
	3 Blanks with Mounting Straps (Device Mntg. 2.375") (3BDE)	81123	82123	84123	85123	
	1 Blank (Box Mntg. 3.281") (1B)	81151	82151	84151	85151	44151
	2 Blanks (Box Mntg. 3.281") (2B)	81152	82152	84152	85152	44152
	3 Blanks (Box Mntg. 3.281") (3B)	81153	82153	84153	85153	
	4 Blanks (Box Mntg. 3.281") (4B)	81154	82154	84154	85154	
	5 Blanks (Box Mntg. 3.281") (5B)	81155	82155	84155	85155	
	6 Blanks (Box Mntg. 3.281") (6B)	81156	82156	84156	85156	
	7 Blanks (Box Mntg. 3.281") (7B)	81157	82157	84157	85157	
	8 Blanks (Box Mntg. 3.281") (8B)	81158	82158	84158	85158	

Residential • Standard

		SPRAYED BRASS	BROWN SEMI- GLOSS	IVORY SEMI- GLOSS	WHITE WRINKLE	ALMOND SEMI- GLOSS
	9 Blanks (Box Mntg. 3.281") (9B)*	81159	82159	84159	85159	
	10 Blanks (Box Mntg. 3.281") (10B)*	81160	82160	84160	85160	
	Block Duplex/GFI Recept. (SRM)	81401	82401	84401	85401	44401
	2 Block Duplex/GFI Recepts. (2SRM)	81402	82402	84402	85402	44402
	3 Block Duplex/GFI Recepts. (3SRM)	81403	82403	84403	85403	
	4 Block Duplex/GFI Recepts. (4SRM)	81404	82404	84404	85404	
	5 Block Duplex/GFI Recepts. (5SRM)	81405	82405	84405	85405	
	6 Block Duplex/GFI Recepts. (6SRM)	81406	82406	84406	85406	
	7 Block Duplex/GFI Recepts. (7SRM)	81407	82407	84407	85407	
	8 Block Duplex/GFI Recepts. (8SRM)	81408	82408	84408	85408	
	9 Block Duplex/GFI Recepts. (9SRM)	81409	82409	84409	85409	
	10 Block Duplex/GFI Recepts. (10SRM)	81410	82410	84410	85410	
	One 5/8" ID Phone (Box Mntg. 3.281") (01)*	81201	82201	84201	85201	
	Two 5/8" ID Phones (Box Mntg. 3.281") (02)*	81202	82202	84202	85202	
	One 5/8" ID Phone with Metal Bushing (Box Mntg. 3.281") (61)*	81591	82591	84591	85591	
	One Phone .5" with .375" ID Grommet and Mounting Strap (Device Mntg. 2.375")*	81181	82181	84181	85181	
	One Phone 1.405" with 1" ID Plastic Bushing (Box Mntg. 3.281") (71)*	81581	82581	84581	85581	

Residential • Standard

	SPRAYED BRASS	BROWN SEMI- GLOSS	IVORY SEMI- GLOSS	WHITE WRINKLE	ALMOND SEMI- GLOSS
 One 20A TL Recept. 1.620" ID Hole (3R)	81111	82111	84111	85111	
 Two 20A TL Recepts. 1.620" ID Hole Must Use 3 Gang Plate (23R)	81113	82113	84113	85113	
 One 30A 3 & 4 Wire TL Recept. 1.730" ID Hole (3330R)	81229	82229	84229	85229	
 30/50A 3 Wire Range/Dryer Recept. 2.125" ID Hole (3D)	81221	82221	84221	85221	
 30/50A 3 Wire Range/Dryer Recept. 2.125" ID Hole 2 Gang Plate (23D)	81222	82222	84222	85222	
 30/50A 3 Wire Range/Dryer Recept. 2.125" ID Hole (N23D)	81227	82227	84227	85227	
 30/50/60A 3 & 4 Wire Recepts. 2.480" ID Hole (5R)	81223	82223	84223	85223	
 30/50/60A 4 Wire for Leviton 278 & 279 Recepts. 2.625" ID Hole (L5R)	81225	82225	84225	85225	
 30/50/60A 4 Wire Offset Recepts. 2.275" ID Hole (N5RR)	81226	82226	84226	85226	
 30/50/60A 4 Wire Recepts. 2.255" ID Hole (P5R)	81228	82228	84228	85228	
 Louver, Horizontal (Device Mntg. 2.375") (LH)	81630	82630	84630	85630	
 Louver, Vertical (Device Mntg. 2.375") (LV)	81631	82631	84631	85631	
 2 Louvers (Device Mntg. 2.375") (2LV)	81632	82632	84632	85632	
 Interchangeable 1 Hole Horizontal (71A)	81011X	82011X	84011X	85011X	
 Interchangeable 1 Hole Per Gang, Horizontal (72A)	81012X	82012X	84012X	85012X	
 Interchangeable 2 Holes (71B)	81021X	82021X	84021X	85021X	
 Interchangeable 2 Holes Per Gang (72B)	81022X	82022X	84022X	85022X	
 Interchangeable 2 Holes Per Gang (73B)	81023X	82023X	84023X	85023X	

Residential • Standard

	SPRAYED BRASS	BROWN SEMI- GLOSS	IVORY SEMI- GLOSS	WHITE WRINKLE	ALMOND SEMI- GLOSS
 Interchangeable 3 Holes (71C)	81031X	82031X	84031X	85031X	
 Interchangeable 3 Holes Per Gang (72C)	81032X	82032X	84032X	85032X	
 Interchangeable 1 Hole Vertical (71G)	81041X	82041X	84041X	85041X	
 Interchangeable 1 Hole Horizontal, 2 Holes (71A-71B)	81052X	82052X	84052X	85052X	
 Toggle Switch, Duplex Recept. (1T-10DR)	81532	82532	84532	85532	44532
 Toggle Switch Interchangeable 2 Holes (1T-71B)	81062X	82062X	84062X	85062X	
 Toggle Switch, Interchangeable 3 Holes (1T-71C)	81132X	82132X	84132X	85132X	
 Toggle Switch, Single Recept. (1.405\" ID Hole (1T-10R)	81512	82512	84512	85512	
 Toggle Switch, 3/4\" ID Phone (Box Mntg. 3.281\") (1T-01)	81472	82472	84472	85472	
 Toggle Switch, Blank (Box Mntg. 3.281\") (1T-1B)	81522	82522	84522	85522	
 Toggle Switch, Block Duplex/GFI Recept. (1T-SRM)	81432	82432	84432	85432	44432
 Duplex Recept., Blank (Box Mntg. 3.281\") (10DR-1B)	81542	82542	84542	85542	
 Duplex Recept., 3/4\" ID Phone (Box Mntg. 3.281\") (10DR-01)	81582	82582	84582	85582	
 Duplex Recept., Single Recept. (1.405\" ID Hole) (10DR-10R)	81572	82572	84572	85572	
 Duplex Recept., Block Duplex/GFI Recept. (10DR-SRM)	81672	82672	84672	85672	44672
 Duplex Recept., Interchangeable 2 Holes (10DR-71B)	81142X	82142X	84142X	85142X	
 Duplex Recept., Interchangeable 3 Holes (10DR-71C)	81172X	82172X	84172X	85172X	
 Duplex Recept. 20A TL Recept. (1.620\" ID Hole) (10DR-3R)	81390	82390	84390	85390	

Residential • Standard

	SPRAYED BRASS	BROWN SEMI- GLOSS	IVORY SEMI- GLOSS	WHITE WRINKLE	ALMOND SEMI- GLOSS
 Duplex Recept., 30A Range/Dryer Recept. (2.125" ID Hole) (10DR-3D)	81180	82180	84180	85180	
 Single Recept. (1.405" ID Hole) Blank (Box Mntg. 3.281") (10R-1B)	81552	82552	84552	85552	
 Block Duplex/GFI Recept., Blank (Box Mntg. 3.281") (SRM-1B)	81422	82422	84422	85422	
 Toggle Switch, Centered 2 Gang Plate (1T-2G)	81772	82772	84772	85772	
 Duplex Recept., Centered 2 Gang Plate (10DR-2G)	81773	82773	84773	85773	
 Single Recept. (1.405" ID Hole), Centered 2 Gang Plate (10R-2G)	81774	82774	84774	85774	
 5/8" ID Phone (Box Mntg. 3.281"), Centered 2 Gang Plate (01-2G)	81775	82775	84775	85775	
 2 Toggle Switches, Duplex Receptacle (2T-10DR)	81543	82543	84543	85543	44543
 2 Toggle Switches, Blank (Box Mntg. 3.281") (2T-1B)	81533	82533	84533	85533	
 2 Toggle Switches, Block Duplex/GFI Recept. (2T-SRM)	81443	82443	84443	85443	
 Toggle Switch, 2 Block Duplex/GFI Recepts. (1T-2SRM)	81453	82453	84453	85453	
 Toggle Switch, 2 Blanks (Box Mntg. 3.281") (1T-2B)	81133	82133	84133	85133	
 Toggle Switch, 2 Duplex Recepts. (1T-20DR)	81553	82553	84553	85553	
 Toggle Switch, Block Duplex, Duplex Recept. (1T-SRM-10DR)	81503	82503	84503	85503	
 Duplex Recept., 2 Blanks (Box Mntg. 3.281") (10DR-2B)	81423	82423	84423	85423	
 Blank (Box Mntg. 3.281"), Duplex Recept., Blank (Box Mntg. 3.281") (1B-10DR-1B)	81193	82193	84193	85193	

Residential • Standard

		SPRAYED BRASS	BROWN SEMI- GLOSS	IVORY SEMI- GLOSS	WHITE WRINKLE	ALMOND SEMI- GLOSS
	Blank (Box Mntg. 3.281\"), 2 Duplex Recepts. (1B-20DR)	81163	82163	84163	85163	
	Single Recept. (1.405\" ID Hole), 2 Duplex Recepts. (10R-20DR)	81593	82593	84593	85593	
	Toggle Switch, Blank (Box Mntg. 3.281\"), Duplex Recept. (1T-1B-10DR)	81233	82233	84233	85233	
	3 Toggle Switches, Duplex Recept. (3T-10DR)	81554	82554	84554	85554	
	3 Toggle Switches, Block Duplex/GFI Recept. (3T-SRM)	81454	82454	84454	85454	
	3 Toggle Switches, Blank (Box Mntg. 3.281\"), (3T-1B)	81544	82544	84544	85544	
	2 Toggle Switches, 2 Duplex Recepts. (2T-20DR)	81564	82564	84564	85564	
	2 Toggle Switches, 2 Blanks (Box Mntg. 3.281\"), (2T-2B)	81574	82574	84574	85574	
	Toggle Switch, 3 Duplex Recepts. (1T-30DR)	81584	82584	84584	85584	
	2 Duplex Recepts., 2 Blanks (Box Mntg. 3.281\"), (20DR-2B)	81164	82164	84164	85164	
	4 Toggle Switches, Duplex Recept. (4T-10DR)	81565	82565	84565	85565	
	4 Toggle Switches, Block Duplex/GFI Recept. (4T-SRM)	81465	82465	84465	85465	
	3 Toggle Switches, 2 Duplex Recepts. (3T-20DR)	81575	82575	84575	85575	
	5 Toggle Switches, Duplex Recept. (5T-10DR)	81576	82576	84576	85576	