

InvisiLED® Pro 2

24V LED Tape Light

WAC LIGHTING

Responsible Lighting®



Tape Section

5 LED "L" Connector

Fixture Type:

Catalog Number:

Project:

Location:

PRODUCT DESCRIPTION

Professional grade white tape light that delivers optimal color consistency and brightness. An ideal system for task or accent lighting applications.

FEATURES

 
- Ultra thin profile at 1/8"
- Diodes spaced evenly at 1" on center
- Minimum run length of 1'
- May be field cut every 6" at the end of a run
- Specially rated for installation in the storage area of a clothes closet
- 80,000 hour rated life
- 5 year WAC Lighting product warranty

SPECIFICATIONS

- Construction:** Flexible, silicone cased tape light. Peel and stick 3M construction adhesive on back. Indicating marks on back for field cutting.
- Power Supply:** Remote and plug-in electronic Class 2 transformers 120VAC 50/60Hz input, 24V 60W and 96W output
- Light Source:** 12 LEDs per foot
- Dimming:** May be dimmed with electronic low voltage (ELV) dimmer.
- Operating Temp:** -4°F – 122°F (-20°C – 50°C) at relative humidity 95%
- Standards:** UL & CUL Listed for damp locations.

ORDER NUMBER – TAPE SECTION

Model	Watts/ft	Color Temp	CRI	Lumens/ft	Title 24	Length	Qty	Tape Color
LED-TX24	4W/ft	22 2200K	90	275	No	6IN 6 inches	1	WT White
		27 2700K	90	325	Yes	1 1 foot	1	
		30 3000K	90	300	Yes	1-40 1 foot	40	
		35 3500K	90	330	Yes	5 5 feet	1	
		45 4500K	85	330	No			




LED-TX24 - -WT

Example: LED-TX2445-1-40-WT

ORDER NUMBER – 5 LED "L" CONNECTOR

Model	Watts	Color Temp	CRI	Lumens	Title 24	Tape Color
LED-TX24	2W/ft	22 2200K	90	110	No	5L-WT White
		27 2700K	90	130	Yes	
		30 3000K	90	130	Yes	
		35 3500K	90	135	Yes	
		45 4500K	85	135	No	

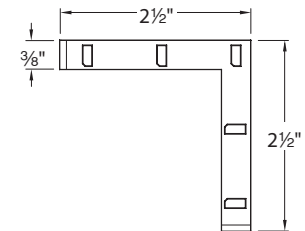

LED-TX24 -5L-WT

Example: LED-TX2435-5L-WT

Class 2 Power Supply (Required)

Type	Model	Input	Output	Max Run	Dim	
Remote	 EN-2460-RB2-T EN-24100-RB2-T	120VAC	24VAC / 60W	15 feet	ELV	Includes a 6 foot lead wire
		120VAC	24VAC / 96W	25 feet	ELV	
Plug-in	 EN-2460-P-AR-T EN-24100-P-AR-T	120VAC	24VAC / 60W	15 feet	ELV	Includes a 6 foot lead wire
		120VAC	24VAC / 96W	25 feet	ELV	
Remote 277V	 EN-24100-277-RB2-T	277VAC	24VDC / 96W	25 feet	0-10V	Includes a 6 foot lead wire

waclighting.com
Phone (800) 526.2588
Fax (800) 526.2585

Headquarters/Eastern Distribution Center
44 Harbor Park Drive
Port Washington, NY 11050

Central Distribution Center
1600 Distribution Ct
Lithia Springs, GA 30122

Western Distribution Center
1750 Archibald Avenue
Ontario, CA 91760

InvisiLED® Pro 2

24V LED Tape Light

WAC LIGHTING

Responsible Lighting®

Indoor Controller

	Touch Panel and Motion Sensor Includes a Touch Panel, an Occupancy Sensor, and a Controller AC/DC input at 12V(60W Max) or 24V(96W Max) Connect on secondary side of driver/transformer	CT-6A-R2	Pro, Pro2, Pro3, LITE, Classic Daylight to Sunset, Palette
---	---	------------------------	---

Indoor Electrical Accessories

	In Wall Rated Extension Cable Extends distance between a hard wired power supply or a wiring box to a tape section.	LED-TC-WEXT-144 LED-TC-WEXT-144-WT LED-TC-WEXT-240 LED-TC-WEXT-240-WT	Black 12 ft White 12 ft Black 20 ft White 20 ft
	In Wall Rated Joiner Cable Connects tape sections. 2 female ends. 1 male to male connector included	LED-TC-WIC-144 LED-TC-WIC-144-WT LED-TC-WIC-240 LED-TC-WIC-240-WT	Black 12 ft White 12 ft Black 20 ft White 20 ft
	Lead Wire Alternative lengths for plug-in power supplies	LED-TC-P-2 LED-TC-P-2-WT LED-TC-P-12 LED-TC-P-12-WT	Black 2 ft White 2 ft Black 12 ft White 12 ft
	Extension Cable Extends distance between a hard wired power supply or a wiring box to a tape section	LED-TC-EXT-144 LED-TC-EXT-144-WT	Black 12 ft White 12 ft
	Low Voltage Wiring Box With Feed Neatly houses connectors for up to two wires with 12" female feed	LED-TC-B-2 LED-TC-B-2-WT	Black L: 1½ in White W: ¾ in H: 7⁄8 in
	Low Voltage Wiring Box Neatly houses connections for up to two wires	LED-T-B	L: 1½ in W: ¾ in H: 7⁄8 in
	Wiring Box With Switch Use when spanning a large gap in a system layout without leaving exposed wiring. Optional switch included	TB-S	L: 6¼ in W: 1½ in H: 1¼ in

Compatible with Pro, Pro2, Pro3, LITE, Classic

	Joiner Cable	LED-TC-IC2 LED-TC-IC2-WT LED-TC-IC6 LED-TC-IC6-WT LED-TC-IC12 LED-TC-IC12-WT LED-TC-IC36 LED-TC-IC36-WT LED-TC-IC72 LED-TC-IC72-WT	Black 2 in White 2 in Black 6 in White 6 in Black 12 in White 12 in Black 36 in White 36 in Black 72 in White 72 in
	Male to male connector	LED-TC-MM	Black 50 Qty

Compatible with Pro, Pro2, Pro3, LITE, Classic, Palette. Change directionality of tape runs and reuse cut ends of tape.

	3-Way "Y" Connector Connects tape sections	LED-TC-Y LED-TC-Y-WT	Black White
	4-Way "X" Connector Connects tape sections	LED-TC-X LED-TC-X-WT	Black White
	"L" Connector Connects tape sections	LED-TC-L LED-TC-L-WT	Black White
	End cap 1 cut and 1 male end cap	LED-TC-EC LED-TC-EC-WT	Black White

 
Compatible with Pro, Pro2, Pro3, LITE, Classic, Palette

InvisiLED® Pro 2

Indoor Aluminum Channels

WAC LIGHTING

Responsible Lighting®



Aluminum Channel
Additional End Caps

LED-T-CH
LED-T-CH-EC

5 feet
2 pcs

Diffuses light from InvisiLED tape

*Includes a diffuser, two end caps, and five screws
Compatible with Pro, Pro2, Pro3, LITE, Classic, Palette
See pages 1-6, 191-194 for recessed channels*




Deep Aluminum Channel
Additional End Cap

LED-T-CH1
LED-T-CH1-EC

5 feet
2 pcs

Eliminates visible hot spots

*Includes a diffuser, two end caps, and five screws
Compatible with Pro, Pro2, Pro3, LITE, Classic, Palette
See pages 1-6, 191-194 for recessed channels*

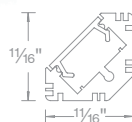


45° Angled Aluminum Channel
Additional End Caps

LED-T-CH2
LED-T-CH2-EC

5 feet
2 pcs

*Includes a diffuser, two end caps, and ten screws
Compatible with Pro, Pro2, Pro3, LITE, Classic, Palette
See pages 1-6, 191-194 for recessed channels*

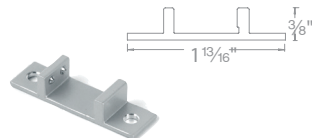

Fixed Angle
Channel Clip

LED-T-CL3-PT

 


Adjustable
Channel
Clip

LED-T-CL2-PT

*Includes 2 pieces, 4 screws. Use to mount Aluminum Channel,
Deep Aluminum Channel, 45° Angled Aluminum Channel*

INDOOR MOUNTING ACCESSORIES



Aluminum Retrofit Channel

LED-T-RC 3 feet

*Can be bent to create fixed curves or used as a glare shield
Compatible with Pro, Pro2, Pro3, LITE, Classic, Palette*



Clear Channel

LED-TO24-CH5

5 feet

*Includes a diffuser, two end caps, and five screws
Provides a clean mounting surface for 3M adhesive*



Clip
For surfaces that are
difficult to adhere

LED-T-CL 10 pcs
10 Screws



Curve Clip
Secures on one edge

LED-T-CL1 10 pcs
10 Screws

*Clips to hold indoor InvisiLED tapes sections
Compatible with Pro, Pro2, Pro3, LITE, Classic, Palette*