

NuTone Ventilation Heater/Fan/Lights – Bulb

- Heat-A-Ventlite® Fan Light Features
- Designer white polymeric grilles complement virtually any décor
 - Fan, light and heater function independently or together

- Single packs only
 - Type IC

QuietTest™ Heat-A-Ventlite®

- All QT9093 models include a four-function wall switch
- Convenient nightlight
- Powerful ventilation
- Bright ceiling light
- Extra-quiet operation

Model QT9093BR



- Polished brass grille
- 1500 watts

Model QT9093CH




- Chrome grille
- 1500 watts

Model QT9093WH



- White enamel grille
- 1500 watts

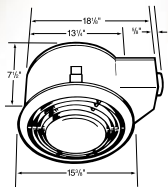

Heat-A-Ventlite®

- Convenient nightlight
- Powerful ventilation
- Bright ceiling light
- Includes four-function wall switch

Model 9093BR



- Polished brass grille
- 1500 watts

Model 9093CH




- Chrome grille
- 1500 watts

Model 9093WH



- White enamel grille
- 1500 watts

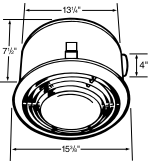

QuietTest Heat-A-Ventlite	CFM	Sones	Lighting	Watts	Finish
QT9093BR	110	3.0	100/7	1500	Polished Brass
QT9093CH	110	3.0	100/7	1500	Chrome
QT9093WH	110	3.0	100/7	1500	White Enamel
Heat-A-Ventlite					
9093BR	70	3.5	100/7	1500	Polished Brass
9093CH	70	3.5	100/7	1500	Chrome
9093WH	70	3.5	100/7	1500	White Enamel
9093FWH*	70	3.5	26/7	1500	White Enamel
665RP	70	4.0	100	1500	White Polymeric
665RF*	70	4.0	13	1500	White Polymeric
665RSP*	70	4.0	100	1500	White Polymeric
Heat-A-Vent					
605RP	70	4.0	n/a	1500	White Polymeric

*Includes HS-93 switch
*Fluorescent light

Heater/Fan/Light

- Fits easily into 2" x 6" beam
- Heating element provides optimum performance in smaller spaces
- White polymeric grille

Model 665RP


- Bright 100W incandescent light capacity

Model 665RSP

- Same as 665RP and includes HS-93 switch

Model 665RF


- Bright energy-efficient 13-watt fluorescent bulb capacity

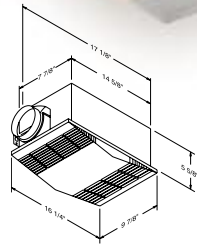

Heat-A-Vent®

- Fits easily into 2" x 6" beam
- Heating element provides optimum performance in smaller space
- Improved hanger bar locks position after securing unit to rafters

Model 605RP (switch not included)

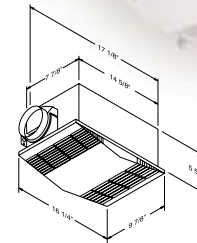

- White polymeric finish grille
- 1500 watts

NuTone Ventilation Heater/Fan/Lights – Combination


Bulb Heater Fans

Silent warmth and superior ventilation. Trust NuTone Bulb Heater/Fans for energy-saving warmth and instant comfort without ever having to touch your central thermostat. These units deliver superior performance and excellent ventilation in a compact package.

Bulb Heater Fan Features


- Quiet, highly efficient polymeric blower wheels
- Polymeric dampers prevent backdrafts and eliminate mechanical noise
- Polymeric 4" round duct connectors with tapered sleeves simplify ducting
- Operate fan and heater independently or together
- Attractive white polymeric grilles
- Compact steel housings with adjustable mounting brackets with keyhole slots that span up to 24"
- 250-watt R40 or BR40 size infrared bulbs (not included)
- Type IC, UL Listed for 60°C wiring (retrofits)

Model 9417DN

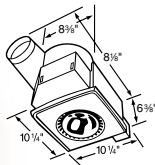

- One-Bulb Heater/Fan

Model 9427P

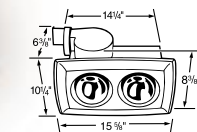

- Two-Bulb Heater/Fan
- Two-function control (available separately)


Model	CFM	Sones	Lighting
9417DN	70	3.5	250
9427P	70	3.5	500

Combination Heater Fans

Model 9905




- Fan-forced heat and exhaust fan
- Includes two-function switch
- 1500 watts

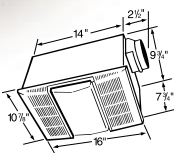


Model 9960



- Fan-forced heat, ceiling & nightlights
- Includes three-function switch
- 1500 watts

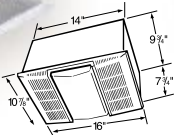

Model 9965

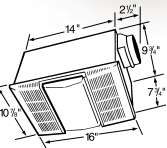

- Fan-forced heat, exhaust fan, ceiling & nightlights
- Includes four-function switch
- 1500 watts


Model 9965F

- Same as 9965 except uses fluorescent lighting
- 1500 watts


Model 9013NL



- Fan-forced heat, ceiling light & nightlight
- Includes three-function switch
- Chrome finish grille
- 1500 watts

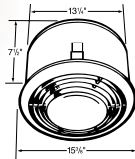

Model 660RP

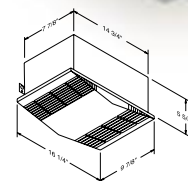

- Fan-forced heat and ceiling light
- Polymeric white grille
- 1500 watts

Model	CFM	Sones	Lighting	Watts
9905	70	4.0	n/a	1500
9960	—	—	100/7	1500
9965	70	4.0	100/7	1500
9965F	70	4.0	26/7	1500
9013NL	—	—	100/7	1500
660RP heater/light only			100	1500

Heater/Fan/Lights

	Page	CFM	Sones, HVI- certified	Lighting Watts Main/ Nightlight	Housing Dimensions			Grille Dimensions		Grille finish	Duct Size"	Amps	Total Connected Load In Watts	Element Watts	Exhaust Motor Watts	Heating Motor Watts	BTU
QTXN110HL	27	110	0.9	120/7	17⅞	11⅜	7⅞	20	15	White Polymeric	6	14.6	1710	1500	55	55	5120
QT9093BR	28	110	3.0	100/7	18⅝	131/4	7½	15⅜ Dia		Polished Brass	4	14.2	1717	1500	55	55	5118
QT9093CH	28	110	3.0	100/7	18⅝	131/4	7½	15⅜ Dia		Chrome	4	14.2	1717	1500	55	55	5118
QT9093WH	28	110	3.0	100/7	18⅝	131/4	7½	15⅜ Dia		White Enamel	4	14.2	1717	1500	55	55	5118
9093BR	28	70	3.5	100/7	13¾ Dia x 7½			15⅝ Dia		Polished Brass	4	14.2	1717	1500	55	55	5118
9093CH	28	70	3.5	100/7	13¾ Dia x 7½			15⅝ Dia		Chrome	4	14.2	1717	1500	55	55	5118
9093WH	28	70	3.5	100/7	13¾ Dia x 7½			15⅝ Dia		White Enamel	4	14.2	1717	1500	55	55	5118
9093FWH	28	70	3.5	26/7	13¾ Dia x 7½			15⅝ Dia		White Enamel	4	14.2	1717	1500	55	55	5118
605RP	28	70	4.0	n/a	14⅞	7⅞	5⅞	16¼	9⅞	White Polymeric	4	13.5	1620	1500	60	60	5118
660RP	29	-	-	100	14⅞	7⅞	5⅞	16¼	9⅞	White Polymeric	-	13.5	1660	1500	-	60	5118
665RP	28	70	4.0	100	14⅞	7⅞	5⅞	16¼	9⅞	White Polymeric	4	14.2	1720	1500	60	60	5118
665RSP	28	70	4.0	100	14⅞	7⅞	5⅞	16¼	9⅞	White Polymeric	4	14.2	1720	1500	60	60	5118
665RF	28	70	4.0	13	14⅞	7⅞	5⅞	16¼	9⅞	White Polymeric	4	13.8	1633	1500	60	60	5118
9905	29	70	4.0	n/a	14	9¾	7¾	16	10⅞	White Polymeric	4	13.5	1620	1500	60	60	5118
9960	29	n/a	n/a	100/7	14	9¾	7¾	16	10⅞	White Polymeric	4	13.9	1667	1500	n/a	60	5118
9965	29	70	4.0	100/7	16½	9¾	7¾	16	10⅞	White Polymeric	4	14.2	1727	1500	60	60	5118
9965F	29	70	4.0	26/7	16½	9¾	7¾	16	10⅞	White Polymeric	4	14.1	1690	1500	60	60	5118
9013NL	29	-	-	100/7	13¾ Dia x 7½			15⅝ Dia		Chrome	-	13.9	1662	1500	-	55	5118
9417DN	29	70	3.5	250	8⅝	8⅝	6⅝	10¼	10¼	White Polymeric	4	2.6	310	n/a	60	n/a	853
9427P	29	70	3.5	500	14¼	8⅝	6⅝	10¼	15⅝	White Polymeric	4	5.0	560	n/a	60	n/a	1706

Heaters

	Page	Watts	Volts	Heating Motor Amps	BTU/hr	Housing Dimensions			Grille Dimensions		Grille finish
9315T	32	750/1500	120	13.0	2560/5120	11½	8⅞	3⅝	12	9⅝	Almond Enamel
9315XT	32	750/1500	240	13.0	2560/5120	11½	8⅞	3⅝	12	9⅝	Almond Enamel
9376N	33	1250	120	10.6	4267	8½	12½	4	10⅞	14⅞	Aluminum
9810BWN	33	1000	120/240	8.75	3413	10½	12½	3⅝	11⅞	14¾	Brown Polymeric
9810WH	33	1000	120/240	8.75	3413	10½	12½	3⅝	11⅞	14¾	White Polymeric
9815BWN	33	1500	120/240	13.0	5120	10½	12½	3⅝	11⅞	14¾	Brown Polymeric
9815WH	33	1500	120/240	13.0	5120	10½	12½	3⅝	11⅞	14¾	White Polymeric
9819BWN	33	1920	120/240	16.5	6554	10½	12½	3⅝	11⅞	14¾	Brown Polymeric
9819WH	33	1920	120/240	16.5	6554	10½	12½	3⅝	11⅞	14¾	White Polymeric
9192NT	33	750/1500	208	3.61/7.21	2560/5120	14¾	18	3¾	16⅝	20¼	White Metal
		1000/2000	240	4.17/8.33	3413/6827	14¾	18	3¾	16⅝	20¼	
9194NT	33	1125/2250	208	5.41/10.82	3840/7680	14¾	18	3¾	16⅝	20¼	White Metal
		1500/3000	240	6.25/12.5	5120/10240	14¾	18	3¾	16⅝	20¼	
9198NT	33	1500/3000	208	7.21/14.42	5120/10240	14¾	18	3¾	16⅝	20¼	White Metal
		2000/4000	240	8.33/16.67	6827/13653	14¾	18	3¾	16⅝	20¼	
9112NT	34	1500	120	12.5	5120	18	3⅝	12	19¼	3⅝	White Metal
		750	120	6.25	2560	18	3⅝	12	19¼	3⅝	
		1125	208	5.41	3840	18	3⅝	12	19¼	3⅝	
		1500	240	8.25	5120	18	3⅝	12	19¼	3⅝	
9114NT	34	1500	120	12.5	5120	18	3⅝	12	19¼	3⅝	White Metal
		750	120	6.25	2560	18	3⅝	12	19¼	3⅝	
		1125	208	5.41	3840	18	3⅝	12	19¼	3⅝	
		1500	240	8.25	5120	18	3⅝	12	19¼	3⅝	
6200	34	1200/1500	120	10.0 / 12.5	n/a	4¾	5	6	n/a	n/a	Brown / Chrome
H910W	35	250	120	-	853	n/a	5½		n/a	n/a	White Enamel
9412D	35	250	120	2.1	853	8⅝	8⅝	6	10¼	10¼	White Polymeric
9422P	35	500	120	4.6	1706	14¼	8⅝	6	15⅝	10¼	White Polymeric
9297T	35	1250	120	10.6	4265	Surfaced-mounted			11 Dia.		Aluminum
9157NT	35	1250	120	10.7	4266	Surfaced-mounted			11 Dia		Aluminum

Powered Attic Ventilators Roof Mount

Model No.	Page	L" Flashing	W"	Diameter "	Dome Height "	CFM	Amps
RF69NR	36	23	23	22	9	1250	3.9
RF68HRPSC	36	23	23	25	10⅞	1530	4.3
RF-49AM	36	25⅝	25⅝	24½	9	1000	4
RF-49BR	36	25⅝	25⅝	24½	9	1000	4
RF-49WG	36	25⅝	25⅝	24½	9	1000	4
RF-59NRPSCBL	36	23	23	22	9	1250	3.9
RF-59NRPSCBR	36	23	23	22	9	1250	3.9
RF-85RBL	36	25⅝	25⅝	22	9	1500	4.3
RF-85RBR	36	25⅝	25⅝	22	9	1500	4.3
RF-49RP	36	25⅝	25⅝	24½	9	1000	4
RF-59RP	36	23	23	22	9	1250	3.9
RF-79RP	36	25⅝	25⅝	22	9	1400	4.3
HU-100	39	Wall Control Switch					6
AHS-200	39	Wall Control Switch					10
RFTH95	39	Wall Control Switch					15

Powered Attic Ventilators Gable Mount

Model No.	Page	Louver W" Flange H"	Housing Depth"	CFM	Amps
WF57NR	36	20¾ 21¾	16¾ dia x 10½	2090	5.6
WF37	36	20¾ 21¾	16¾ dia x 10½	1500	4.9
GF900N	36	18¾ 20	14¾ dia x 5¾	900	3.1
GFL900	36	18¾ 20	-	-	-
GF1200N	36	18¾ 20	14¾ dia x 7¾	1260	3.9

Whole-house Ventilators

Model No.	Page	Overall Louver Dimensions		Overall Fan Dimensions			Louver Opening		CFM	Amps
WHV30BD	37	30¾	36	34	34	19½	29	34¼	5600	6.5
WHV36BD	37	38½	36	39¾	39¾	19½	36	34¼	6800	6.5
WHV30-02	37	30¾	35⅞	34	34	7⅞	34⅞	28⅞	4800	5
WHV24DD	37	29⅞	30¾	27¾	27¾	7½	28¾	28¾	2800	3.6
WHV20	37	28⅞	24⅞	26¾	22¼	12½	26½	22½	3200	3.5
WHL30	37	30¾	36	-	-	-	29	34¼	-	-
WHL36	37	38½	36	-	-	-	36	34¼	-	-