



Metallics SNAPTOGGLE®

Secure Installations in Seconds-Not Minutes!
Grip range 3/8"-2 1/2" (9mm-64mm)

NEW!


Total Anchoring Security!

TOGGLER® Brand Toggle Bolts for
Maximum Strength & Precise Alignment

- Hollow Block
- Cinder Block
- Concrete Block
- Cement Board
- Hollow Brick
- Stucco
- Gypsum Board/Drywall
- Plaster
- Composite Panels
- Fiberglass
- Boat Decks
- Paneling

*Another NEW
exciting solution
from Metallics!
Toggler® Brand
Snaptoggle® the
strongest togglebolt
in the smallest hole!*

1. Drill 1/2" hole. Hold metal channel flat alongside plastic straps, slide channel through hole.
2. With one hand, pull ring so metal channel rests flush behind wall. Slide plastic cap along straps with other hand until flange of cap is flush with wall.
3. Place thumb between plastic straps. Push side to side snapping off straps flush with wall.
4. Insert bolt through item to be attached and tighten until flush with fixture. Minimum clearance behind wall: 1-7/8" (48mm)

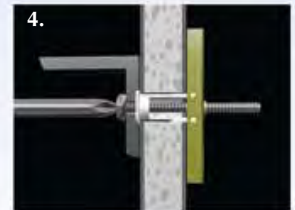

Stock Number	UPC#	Description	Quantity Per Pkg.	Suggested Trade List Per Pkg.
MBA25	73944	Toggler Snaptoggle #10-24	25	\$41.45
MBA50	73971	Toggler Snaptoggle #10-24	50	\$75.83
MBB25	73945	Toggler Snaptoggle 1/4-20	25	\$41.45
MBB50	73972	Toggle Snaptoggle 1/4-20	50	\$75.83

Metallics

229 Cross Street,
Bristol, Ct. 06010
Tel: 800-243-8272
Fax: 800-831-9358
Email: sales@metallicsonline.com

"Growth Through Innovation"

Metallics West

651 North Main Street
Mancos, Co. 81328
Tel: 800-269-5183
Fax: 800-269-6278
Email: saleswest@metallicsonline.com

SNAPTOGGLE® IS A REGISTERED TRADEMARK