
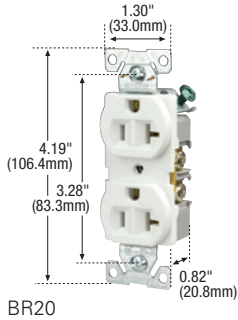



Commercial grade straight blade receptacles

Product description


2-pole, 3-wire grounding
15A, 125V/AC
20A, 125V/AC
NEMA 5-15R, 5-20R

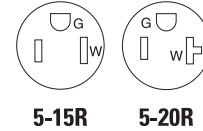


BR20

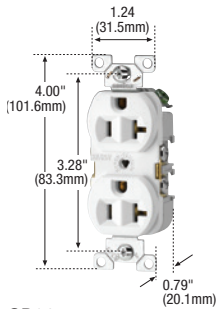

CR20

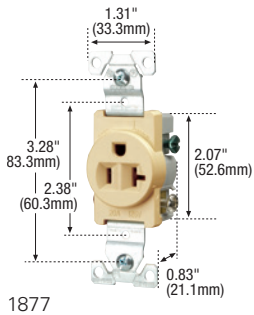

1877

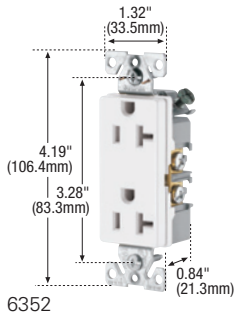

6352

Commercial grade receptacles



Rating	A	V/AC	NEMA	Description	Color suffix	Catalog no.			
15	125	5-15R	Duplex receptacle, back & side wire	A, B, BK, GY, LA, V, W	□ BR15__				
			Duplex receptacle, side wire	A, B, BK, GY, LA, V, W	□ CR15__ ^Δ				
			Single receptacle, side wire	B, BK, LA, V, W	□ 817__ [*]				
20	125	5-20R	Duplex receptacle, back & side wire	A, B, BK, GY, LA, RD, V, W	□ BR20__				
			Duplex receptacle, side wire	A, B, BK, GY, LA, V, W	□ CR20__ ^Δ				
			Single receptacle, side wire	A, B, BK, LA, V, W	□ 1877__ [*]				

* Not Fed Spec, ^Δ cULus Listed

Decorator commercial grade receptacles



Rating	A	V/AC	NEMA	Description	Color suffix	Catalog no.			
15	125	5-15R	Duplex receptacle, back & side wire	B, BK, GY, LA, V, W	□ 6252__ [†]				
			Single receptacle, back & side wire	V, W	□ 6250__				
20	125	5-20R	Duplex receptacle, back & side wire	A, B, BK, GY, LA, V, W	□ 6352__				
			Single receptacle, back & side wire	B, V, W	□ 6350__ [†]				

[†] Not NOM cert

Accessories for construction grade 5-15 & 5-20 receptacles

Description	Color suffix	Catalog no.		
2-Gang standard size duplex receptacle wallplate	A, B, BK, GY, LA, RD, V, W	□ 5150__		
1-Gang mid-size single receptacle wallplate, 1.4" hole	A, B, BK, GY, LA, RD, V, W	□ PJ7__		



5150B



PJ7GY

Color ordering information:

For ordering devices, include Catalog no. followed by the Color suffix: A (Almond), B (Brown), BK (Black), GY (Gray), LA (Light Almond), RD (Red), V (Ivory), W (White)

A	B	BK	GY	LA	RD	V	W
(Almond)	(Brown)	(Black)	(Gray)	(Lt. Almond)	(Red)	(Ivory)	(White)

Specification information: Commercial receptacles: A-38

Compliances, specifications and availability are subject to change without notice.

Build-to-spec customizable devices - Page A-6

Indicates NAFTA compliant - Page Q-30

RoHS compliant - Page Q-30